

Item description/product images



Description

Material:
NdFeB N35 (neodymium).

Version:
nickel-plated.


Note:
Unshielded system.

Temperature range:
max. 80°C.

Assembly:
The magnets can be mounted by press-fit, screwing-in or gluing.

Drawing reference:
1) magnetic face

Drawings

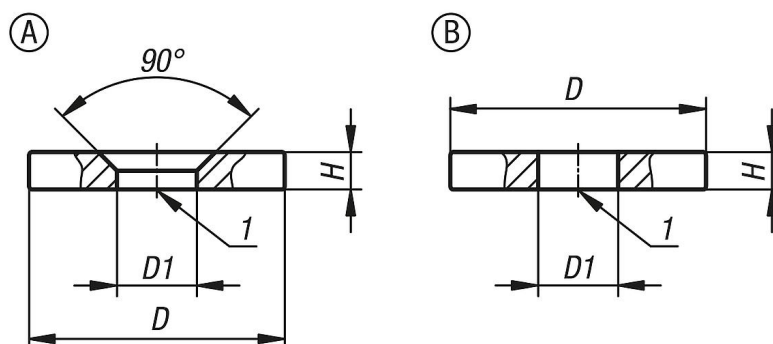

Overview of items

Order No.	Form	D	D1	H	Tightening torque max. Nm	Magnetic force N
09001-12	A	12 ±0,1	3,5 ±0,1	3 ±0,1	3	18
09001-15	A	15 ±0,1	4,5 ±0,1	3,5 ±0,1	3	29
09001-18	A	18 ±0,1	4,5 ±0,1	4 ±0,1	3	41
09001-24	A	24 ±0,1	5,5 ±0,1	4 ±0,1	3	66
09001-32	B	32 ±0,1	10,5 ±0,1	2 ±0,1	3	42
09001-38	B	38 ±0,1	12 ±0,1	4 ±0,1	3	110
09001-48	B	48 ±0,2	15 ±0,1	5 ±0,1	3	165
09001-56	B	56 ±0,2	15 ±0,1	6 ±0,1	3	230