

## Item description/product images

INCH  
Parts

## Description

**Material:**

Handle die-cast zinc DIN EN 12844.  
Steel parts grade 5.8.

**Version:**

Handle powder-coated.  
Steel parts black oxidised.

**Note for ordering:**

Screws from 70 mm long have 60 mm long threads.

**Note:**

Standard colours are:  
orange RAL 2004, ruby red RAL 3003, silver metallic.

Where  $L \geq 60$  mm the thread length is 60 mm.

**On request:**

Other threads, screw lengths, colours and special versions.  
Dimension "H1" available in other lengths at extra charge.

**Drawing reference:**

1) flat point DIN EN ISO 4753


Item description/product images



lift to  
disengage



Drawings

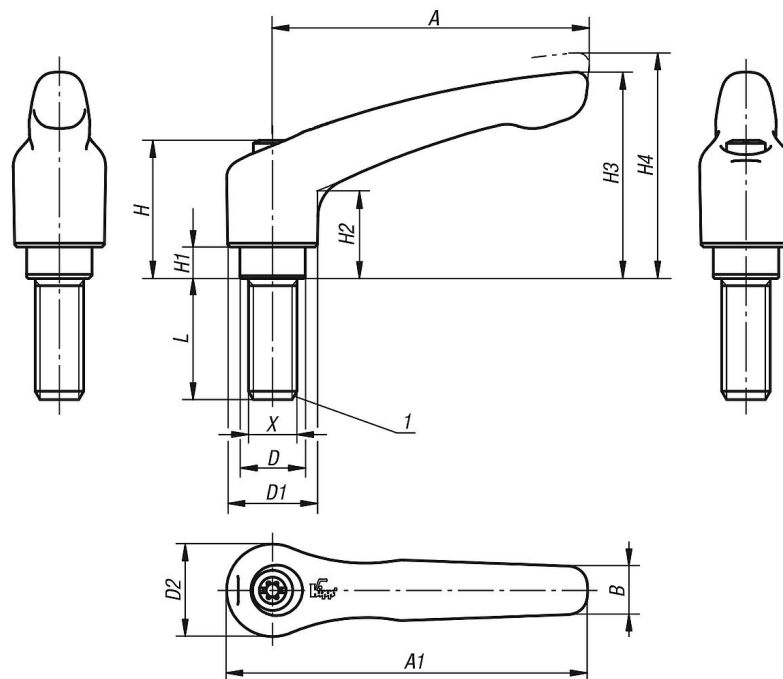

Overview of items

Order No.	Main colour	Surface finish body	Size	X	D	D1	D2	H	H1	H2	H3	H4	A	A1	B	No. of teeth	L
06460-0A22X35	orange RAL 2004	satin finish	0	1/4-20	10	13	14	24,5	4	14,5	30	33	30	37	7	16	35
06460-0A23X10	silver metallic	satin finish	0	1/4-20	10	13	14	24,5	4	14,5	30	33	30	37	7	16	10
06460-0A23X35	silver metallic	satin finish	0	1/4-20	10	13	14	24,5	4	14,5	30	33	30	37	7	16	35
06460-0A22X15	orange RAL 2004	satin finish	0	1/4-20	10	13	14	24,5	4	14,5	30	33	30	37	7	16	15
06460-0A12X15	orange RAL 2004	satin finish	0	10-32	10	13	14	24,5	4	14,5	30	33	30	37	7	16	15
06460-0A23X25	silver metallic	satin finish	0	1/4-20	10	13	14	24,5	4	14,5	30	33	30	37	7	16	25
06460-0A127X45	ruby red RAL3003	satin finish	0	10-32	10	13	14	24,5	4	14,5	30	33	30	37	7	16	45
06460-0A12X30	orange RAL 2004	satin finish	0	10-32	10	13	14	24,5	4	14,5	30	33	30	37	7	16	30
06460-0A227X20	ruby red RAL3003	satin finish	0	1/4-20	10	13	14	24,5	4	14,5	30	33	30	37	7	16	20
06460-0A227X25	ruby red RAL3003	satin finish	0	1/4-20	10	13	14	24,5	4	14,5	30	33	30	37	7	16	25
06460-0A23X50	silver metallic	satin finish	0	1/4-20	10	13	14	24,5	4	14,5	30	33	30	37	7	16	50
06460-0A23X40	silver metallic	satin finish	0	1/4-20	10	13	14	24,5	4	14,5	30	33	30	37	7	16	40
06460-0A23X30	silver metallic	satin finish	0	1/4-20	10	13	14	24,5	4	14,5	30	33	30	37	7	16	30
06460-0A227X40	ruby red RAL3003	satin finish	0	1/4-20	10	13	14	24,5	4	14,5	30	33	30	37	7	16	40
06460-0A13X20	silver metallic	satin finish	0	10-32	10	13	14	24,5	4	14,5	30	33	30	37	7	16	20
06460-0A12X50	orange RAL 2004	satin finish	0	10-32	10	13	14	24,5	4	14,5	30	33	30	37	7	16	50
06460-0A13X25	silver metallic	satin finish	0	10-32	10	13	14	24,5	4	14,5	30	33	30	37	7	16	25
06460-0A22X40	orange RAL 2004	satin finish	0	1/4-20	10	13	14	24,5	4	14,5	30	33	30	37	7	16	40
06460-0A127X20	ruby red RAL3003	satin finish	0	10-32	10	13	14	24,5	4	14,5	30	33	30	37	7	16	20
06460-0A12X25	orange RAL 2004	satin finish	0	10-32	10	13	14	24,5	4	14,5	30	33	30	37	7	16	25
06460-0A127X10	ruby red RAL3003	satin finish	0	10-32	10	13	14	24,5	4	14,5	30	33	30	37	7	16	10
06460-0A22X50	orange RAL 2004	satin finish	0	1/4-20	10	13	14	24,5	4	14,5	30	33	30	37	7	16	50
06460-0A227X10	ruby red RAL3003	satin finish	0	1/4-20	10	13	14	24,5	4	14,5	30	33	30	37	7	16	10
06460-0A22X20	orange RAL 2004	satin finish	0	1/4-20	10	13	14	24,5	4	14,5	30	33	30	37	7	16	20
06460-0A23X20	silver metallic	satin finish	0	1/4-20	10	13	14	24,5	4	14,5	30	33	30	37	7	16	20
06460-0A127X50	ruby red RAL3003	satin finish	0	10-32	10	13	14	24,5	4	14,5	30	33	30	37	7	16	50
06460-0A227X15	ruby red RAL3003	satin finish	0	1/4-20	10	13	14	24,5	4	14,5	30	33	30	37	7	16	15
06460-0A23X45	silver metallic	satin finish	0	1/4-20	10	13	14	24,5	4	14,5	30	33	30	37	7	16	45
06460-0A13X15	silver metallic	satin finish	0	10-32	10	13	14	24,5	4	14,5	30	33	30	37	7	16	15
06460-0A13X50	silver metallic	satin finish	0	10-32	10	13	14	24,5	4	14,5	30	33	30	37	7	16	50
06460-0A127X35	ruby red RAL3003	satin finish	0	10-32	10	13	14	24,5	4	14,5	30	33	30	37	7	16	35
06460-0A227X30	ruby red RAL3003	satin finish	0	1/4-20	10	13	14	24,5	4	14,5	30	33	30	37	7	16	30
06460-0A23X15	silver metallic	satin finish	0	1/4-20	10	13	14	24,5	4	14,5	30	33	30	37	7	16	15
06460-0A12X20	orange RAL 2004	satin finish	0	10-32	10	13	14	24,5	4	14,5	30	33	30	37	7	16	20
06460-0A12X10	orange RAL 2004	satin finish	0	10-32	10	13	14	24,5	4	14,5	30	33	30	37	7	16	10















## Overview of items

Order No.	Main colour	Surface finish body	Size	X	D	D1	D2	H	H1	H2	H3	H4	A	A1	B	No. of teeth	L
06460-5A52X40	orange RAL 2004	satin finish	5	1/2-13	23	31	32	49	12	31,5	73	77,5	110	126	15	26	40
06460-5A52X45	orange RAL 2004	satin finish	5	1/2-13	23	31	32	49	12	31,5	73	77,5	110	126	15	26	45
06460-5A52X50	orange RAL 2004	satin finish	5	1/2-13	23	31	32	49	12	31,5	73	77,5	110	126	15	26	50
06460-5A52X55	orange RAL 2004	satin finish	5	1/2-13	23	31	32	49	12	31,5	73	77,5	110	126	15	26	55
06460-5A52X60	orange RAL 2004	satin finish	5	1/2-13	23	31	32	49	12	31,5	73	77,5	110	126	15	26	60
06460-5A52X70	orange RAL 2004	satin finish	5	1/2-13	23	31	32	49	12	31,5	73	77,5	110	126	15	26	70
06460-5A52X80	orange RAL 2004	satin finish	5	1/2-13	23	31	32	49	12	31,5	73	77,5	110	126	15	26	80
06460-5A52X90	orange RAL 2004	satin finish	5	1/2-13	23	31	32	49	12	31,5	73	77,5	110	126	15	26	90
06460-5A53X25	silver metallic	satin finish	5	1/2-13	23	31	32	49	12	31,5	73	77,5	110	126	15	26	25
06460-5A53X30	silver metallic	satin finish	5	1/2-13	23	31	32	49	12	31,5	73	77,5	110	126	15	26	30
06460-5A53X35	silver metallic	satin finish	5	1/2-13	23	31	32	49	12	31,5	73	77,5	110	126	15	26	35
06460-5A53X40	silver metallic	satin finish	5	1/2-13	23	31	32	49	12	31,5	73	77,5	110	126	15	26	40
06460-5A53X45	silver metallic	satin finish	5	1/2-13	23	31	32	49	12	31,5	73	77,5	110	126	15	26	45
06460-5A53X50	silver metallic	satin finish	5	1/2-13	23	31	32	49	12	31,5	73	77,5	110	126	15	26	50
06460-5A53X55	silver metallic	satin finish	5	1/2-13	23	31	32	49	12	31,5	73	77,5	110	126	15	26	55
06460-5A53X60	silver metallic	satin finish	5	1/2-13	23	31	32	49	12	31,5	73	77,5	110	126	15	26	60
06460-5A53X70	silver metallic	satin finish	5	1/2-13	23	31	32	49	12	31,5	73	77,5	110	126	15	26	70
06460-5A53X80	silver metallic	satin finish	5	1/2-13	23	31	32	49	12	31,5	73	77,5	110	126	15	26	80
06460-5A53X90	silver metallic	satin finish	5	1/2-13	23	31	32	49	12	31,5	73	77,5	110	126	15	26	90
06460-5A627X25	ruby red RAL3003	satin finish	5	5/8-11	23	31	32	49	12	31,5	73	77,5	110	126	15	26	25
06460-5A627X30	ruby red RAL3003	satin finish	5	5/8-11	23	31	32	49	12	31,5	73	77,5	110	126	15	26	30
06460-5A627X35	ruby red RAL3003	satin finish	5	5/8-11	23	31	32	49	12	31,5	73	77,5	110	126	15	26	35
06460-5A627X40	ruby red RAL3003	satin finish	5	5/8-11	23	31	32	49	12	31,5	73	77,5	110	126	15	26	40
06460-5A627X45	ruby red RAL3003	satin finish	5	5/8-11	23	31	32	49	12	31,5	73	77,5	110	126	15	26	45
06460-5A627X50	ruby red RAL3003	satin finish	5	5/8-11	23	31	32	49	12	31,5	73	77,5	110	126	15	26	50
06460-5A627X55	ruby red RAL3003	satin finish	5	5/8-11	23	31	32	49	12	31,5	73	77,5	110	126	15	26	55
06460-5A627X60	ruby red RAL3003	satin finish	5	5/8-11	23	31	32	49	12	31,5	73	77,5	110	126	15	26	60
06460-5A627X70	ruby red RAL3003	satin finish	5	5/8-11	23	31	32	49	12	31,5	73	77,5	110	126	15	26	70
06460-5A627X80	ruby red RAL3003	satin finish	5	5/8-11	23	31	32	49	12	31,5	73	77,5	110	126	15	26	80
06460-5A627X90	ruby red RAL3003	satin finish	5	5/8-11	23	31	32	49	12	31,5	73	77,5	110	126	15	26	90
06460-5A62X25	orange RAL 2004	satin finish	5	5/8-11	23	31	32	49	12	31,5	73	77,5	110	126	15	26	25
06460-5A62X30	orange RAL 2004	satin finish	5	5/8-11	23	31	32	49	12	31,5	73	77,5	110	126	15	26	30
06460-5A62X35	orange RAL 2004	satin finish	5	5/8-11	23	31	32	49	12	31,5	73	77,5	110	126	15	26	35
06460-5A62X40	orange RAL 2004	satin finish	5	5/8-11	23	31	32	49	12	31,5	73	77,5	110	126	15	26	40
06460-5A62X45	orange RAL 2004	satin finish	5	5/8-11	23	31	32	49	12	31,5	73	77,5	110	126	15	26	45
06460-5A62X50	orange RAL 2004	satin finish	5	5/8-11	23	31	32	49	12	31,5	73	77,5	110	126	15	26	50
06460-5A62X55	orange RAL 2004	satin finish	5	5/8-11	23	31	32	49	12	31,5	73	77,5	110	126	15	26	55
06460-5A62X60	orange RAL 2004	satin finish	5	5/8-11	23	31	32	49	12	31,5	73	77,5	110	126	15	26	60
06460-5A62X70	orange RAL 2004	satin finish	5	5/8-11	23	31	32	49	12	31,5	73	77,5	110	126	15	26	70
06460-5A62X80	orange RAL 2004	satin finish	5	5/8-11	23	31	32	49	12	31,5	73	77,5	110	126	15	26	80
06460-5A62X90	orange RAL 2004	satin finish	5	5/8-11	23	31	32	49	12	31,5	73	77,5	110	126	15	26	90
06460-5A63X25	silver metallic	satin finish	5	5/8-11	23	31	32	49	12	31,5	73	77,5	110	126	15	26	25
06460-5A63X30	silver metallic	satin finish	5	5/8-11	23	31	32	49	12	31,5	73	77,5	110	126	15	26	30
06460-5A63X35	silver metallic	satin finish	5	5/8-11	23	31	32	49	12	31,5	73	77,5	110	126	15	26	35
06460-5A63X40	silver metallic	satin finish	5	5/8-11	23	31	32	49	12	31,5	73	77,5	110	126	15	26	40
06460-5A63X45	silver metallic	satin finish	5	5/8-11	23	31	32	49	12	31,5	73	77,5	110	126	15	26	45
06460-5A63X50	silver metallic	satin finish	5	5/8-11	23	31	32	49	12	31,5	73	77,5	110	126	15	26	50
06460-5A63X55	silver metallic	satin finish	5	5/8-11	23	31	32	49	12	31,5	73	77,5	110	126	15	26	55
06460-5A63X60	silver metallic	satin finish	5	5/8-11	23	31	32	49	12	31,5	73	77,5	110	126	15	26	60
06460-5A63X70	silver metallic	satin finish	5	5/8-11	23	31	32	49	12	31,5	73	77,5	110	126	15	26	70
06460-5A63X80	silver metallic	satin finish	5	5/8-11	23	31	32	49	12	31,5	73	77,5	110	126	15	26	80
06460-5A63X90	silver metallic	satin finish	5	5/8-11	23	31	32	49	12	31,5	73	77,5	110	126	15	26	90