

Item description/product images



Description

Material:
Aluminium.

Version:
Natural or black anodised.

Note for ordering:
Order the fastening material and end washers separately.


Assembly:
From the rear.

Accessory:
End washers 06917.

Item description/product images



Drawings

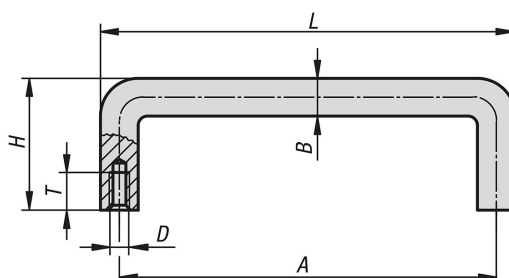

Overview of items

Order No.	Main colour	A	B	D	H	L	T	Load capacity N	Order No. end washer
06917-032041	9-pin	32	8	M4	32	40	10	500	06917-4
06917-055041	9-pin	55	8	M4	32	63	10	500	06917-4
06917-064041	9-pin	64	8	M4	32	72	10	500	06917-4
06917-076041	9-pin	76	8	M4	32	84	10	500	06917-4
06917-088041	A	88	8	M4	32	96	10	500	06917-4
06917-096041	A	96	8	M4	32	104	10	500	06917-4
06917-098041	A	98	8	M4	32	106	10	500	06917-4
06917-100041	A	100	8	M4	32	108	10	500	06917-4
06917-102041	A	102	8	M4	32	110	10	500	06917-4
06917-120041	A	120	8	M4	32	128	10	500	06917-4
06917-136041	A	136	8	M4	32	144	10	500	06917-4
06917-055051	9 + S (travel)	55	10	M5	40	65	10	500	06917-1
06917-064051	A	64	10	M5	40	74	10	500	06917-1
06917-076051	A	76	10	M5	40	86	10	500	06917-1
06917-088051	9 + S (travel)	88	10	M5	40	98	10	500	06917-1
06917-096051	A	96	10	M5	40	106	10	500	06917-1
06917-098051	A	98	10	M5	40	108	10	500	06917-1
06917-100051	9 + S (travel)	100	10	M5	40	110	10	500	06917-1
06917-102051	A	102	10	M5	40	112	10	500	06917-1
06917-120051	9 + S (travel)	120	10	M5	40	130	10	500	06917-1
06917-136051	A	136	10	M5	40	146	10	500	06917-1
06917-140051	A	140	10	M5	40	150	10	500	06917-1
06917-160051	A	160	10	M5	40	170	10	500	06917-1
06917-180051	9 + S (travel)	180	10	M5	40	190	10	500	06917-1
06917-200051	9 + S (travel)	200	10	M5	40	210	10	500	06917-1
06917-235051	9 + S (travel)	235	10	M5	40	245	10	500	06917-1
06917-250051	9 + S (travel)	250	10	M5	40	260	10	500	06917-1
06917-300051	A	300	10	M5	40	310	10	500	06917-1

Overview of items

Order No.	Main colour	A	B	D	H	L	T	Load capacity N	Order No. end washer
06917-350051	A	350	10	M5	40	360	10	500	06917-1
06917-120061	A	120	12	M6	42	132	12	500	06917-6
06917-136061	A	136	12	M6	42	148	12	500	06917-6
06917-140061	A	140	12	M6	42	152	12	500	06917-6
06917-160061	A	160	12	M6	42	172	12	500	06917-6
06917-180061	A	180	12	M6	42	192	12	500	06917-6
06917-200061	A	200	12	M6	42	212	12	500	06917-6
06917-235061	A	235	12	M6	42	247	12	500	06917-6
06917-250061	A	250	12	M6	42	262	12	500	06917-6
06917-300061	A	300	12	M6	42	312	12	500	06917-6
06917-350061	A	350	12	M6	42	362	12	500	06917-6
06917-140081	A	140	16	M8	58	156	12	500	-
06917-160081	A	160	16	M8	58	176	12	500	-
06917-180081	A	180	16	M8	58	196	12	500	-
06917-200081	A	200	16	M8	58	216	12	500	-
06917-235081	A	235	16	M8	58	251	12	500	-
06917-250081	A	250	16	M8	58	266	12	500	-
06917-300081	A	300	16	M8	58	316	12	500	-
06917-350081	A	350	16	M8	58	366	12	500	-
06917-200101	A	200	20	M10	70	220	19	500	-
06917-235101	A	235	20	M10	70	255	19	500	-
06917-250101	A	250	20	M10	70	270	19	500	-
06917-300101	A	300	20	M10	70	320	19	500	-
06917-350101	A	350	20	M10	70	370	19	500	-
06917-032043	Adapter plate	32	8	M4	32	40	10	500	06917-5
06917-055043	Adapter plate	55	8	M4	32	63	10	500	06917-5
06917-064043	Adapter plate	64	8	M4	32	72	10	500	06917-5
06917-076043	Adapter plate	76	8	M4	32	84	10	500	06917-5
06917-088043	Adapter plate	88	8	M4	32	96	10	500	06917-5
06917-096043	Adapter plate	96	8	M4	32	104	10	500	06917-5
06917-098043	Adapter plate	98	8	M4	32	106	10	500	06917-5
06917-100043	Adapter plate	100	8	M4	32	108	10	500	06917-5
06917-102043	Adapter plate	102	8	M4	32	110	10	500	06917-5
06917-120043	Adapter plate	120	8	M4	32	128	10	500	06917-5
06917-136043	Adapter plate	136	8	M4	32	144	10	500	06917-5
06917-055053	Adapter plate	55	10	M5	40	65	10	500	06917-3
06917-064053	Adapter plate	64	10	M5	40	74	10	500	06917-3
06917-076053	Adapter plate	76	10	M5	40	86	10	500	06917-3
06917-088053	Adapter plate	88	10	M5	40	98	10	500	06917-3
06917-096053	Adapter plate	96	10	M5	40	106	10	500	06917-3
06917-098053	Adapter plate	98	10	M5	40	108	10	500	06917-3
06917-100053	Adapter plate	100	10	M5	40	110	10	500	06917-3
06917-102053	Adapter plate	102	10	M5	40	112	10	500	06917-3
06917-120053	Adapter plate	120	10	M5	40	130	10	500	06917-3
06917-136053	Adapter plate	136	10	M5	40	146	10	500	06917-3
06917-140053	Adapter plate	140	10	M5	40	150	10	500	06917-3
06917-160053	Adapter plate	160	10	M5	40	170	10	500	06917-3
06917-180053	Adapter plate	180	10	M5	40	190	10	500	06917-3
06917-200053	Adapter plate	200	10	M5	40	210	10	500	06917-3
06917-235053	Adapter plate	235	10	M5	40	245	10	500	06917-3
06917-250053	Adapter plate	250	10	M5	40	260	10	500	06917-3
06917-300053	Adapter plate	300	10	M5	40	310	10	500	06917-3
06917-350053	Adapter plate	350	10	M5	40	360	10	500	06917-3
06917-120063	Adapter plate	120	12	M6	42	132	12	500	06917-7
06917-136063	Adapter plate	136	12	M6	42	148	12	500	06917-7
06917-140063	Adapter plate	140	12	M6	42	152	12	500	06917-7
06917-160063	Adapter plate	160	12	M6	42	172	12	500	06917-7
06917-180063	Adapter plate	180	12	M6	42	192	12	500	06917-7
06917-200063	Adapter plate	200	12	M6	42	212	12	500	06917-7
06917-235063	Adapter plate	235	12	M6	42	247	12	500	06917-7
06917-250063	Adapter plate	250	12	M6	42	262	12	500	06917-7
06917-300063	Adapter plate	300	12	M6	42	312	12	500	06917-7
06917-350063	Adapter plate	350	12	M6	42	362	12	500	06917-7
06917-140083	Adapter plate	140	16	M8	58	156	12	500	-

Overview of items

Order No.	Main colour	A	B	D	H	L	T	Load capacity N	Order No. end washer
06917-160083	Adapter plate	160	16	M8	58	176	12	500	-
06917-180083	Adapter plate	180	16	M8	58	196	12	500	-
06917-200083	Adapter plate	200	16	M8	58	216	12	500	-
06917-235083	Adapter plate	235	16	M8	58	251	12	500	-
06917-250083	Adapter plate	250	16	M8	58	266	12	500	-
06917-300083	Adapter plate	300	16	M8	58	316	12	500	-
06917-350083	Adapter plate	350	16	M8	58	366	12	500	-
06917-200103	Adapter plate	200	20	M10	70	220	19	500	-
06917-235103	Adapter plate	235	20	M10	70	255	19	500	-
06917-250103	Adapter plate	250	20	M10	70	270	19	500	-
06917-300103	Adapter plate	300	20	M10	70	320	19	500	-
06917-350103	Adapter plate	350	20	M10	70	370	19	500	-