


Item description/product images

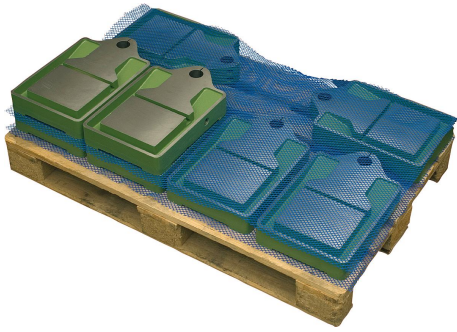

Description

Material:

Polyethylene

Note:

Effective protection for surfaces and delicate goods. Very resistant to external influences and environmentally friendly (recyclable). Cut to size as required.

Overview of items

Order No.	Version 1	Version 2	LB=Dimensions	Mesh size	Mat thickness	Colour	G=Weight g/m
96510-07500950	for transport	-	750x950 mm	11x11 mm	3,8 mm	blue	640
96510-078011804	for transport	-	780x1180 mm	4X4 mm	3,7 mm	black	900
96510-078011806	for transport	-	780x1180 mm	6x6 mm	2,8 mm	black	460
96510-07501000007	for transport	-	750x100000 mm	7x7 mm	2,2 mm	blue	200
96510-07507500010	for transport	-	750x75000 mm	10x10 mm	3 mm	white	410
96510-07505000011	for transport	-	750x50000 mm	11x11 mm	3,8 mm	blue	640
96510-120030000206	for parts cleaning	for chemical solutions	1200x30000 mm	6x6 mm	2,8 mm	white	450
96510-102050000203	for parts cleaning	for aqueous solutions	1020x50000 mm	3x3 mm	2 mm	white	450
96510-081050000208	for parts cleaning	for aqueous solutions	810x50000 mm	8x8 mm	3,1 mm	black	610
96510-118025000104	non-slip	-	1180x25000 mm	4x6 mm	1,8 mm	colourless	460
96510-118025000106	non-slip	-	1180x25000 mm	6x6 mm	3,3 mm	colourless	410