

## Item description/product images



## Description

**Material:**

Carriage body zinc.

Plastic bearing material iglidur® J.

Rails anodised aluminium.

**Version:**

Body chromed.

Guide rail natural colour anodised.

**Note:**

Miniature slide guides are maintenance-free and corrosion resistant. Very high speeds and accelerations are possible due to the low weight. Applicable temperature max. 80 °C.


Miniature slide guides are insensitive to dust and are ideal for dry running.

\*\* length L2 = 30 mm and


\* L = 1000 mm included

L2 and L only available in full mm.

## Drawings

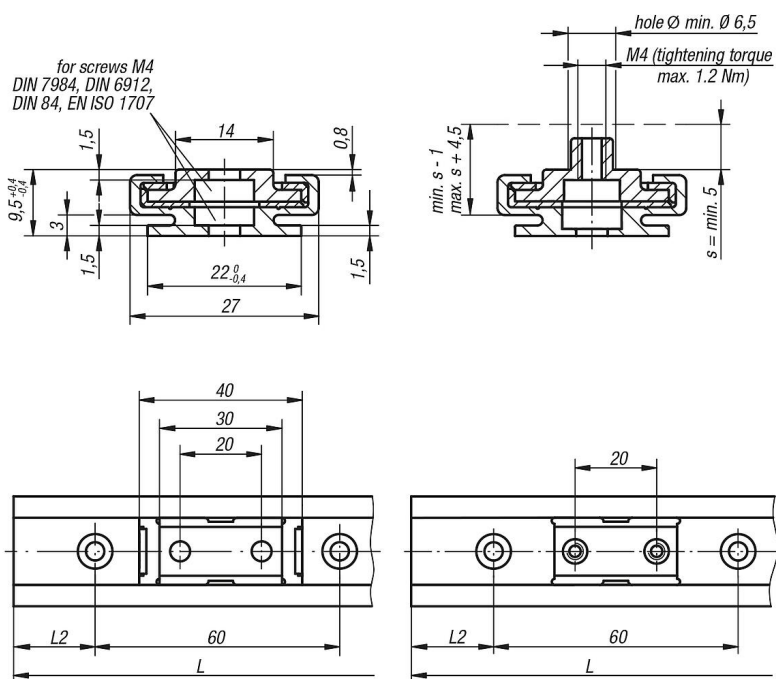

## Drawings

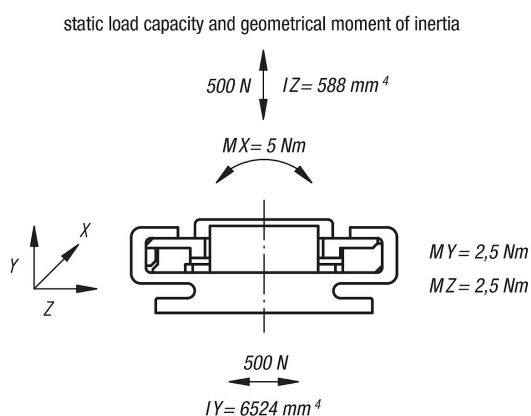

## Overview of items

## Carriage

| Order No.  | Item           | Version 1        | Version 2         |
|------------|----------------|------------------|-------------------|
| 21230-2700 | Guide Carriage | fixed bearing    | with through hole |
| 21230-2701 | Guide Carriage | floating bearing | with through hole |
| 21230-2710 | Guide Carriage | fixed bearing    | with tapped holes |
| 21230-2711 | Guide Carriage | floating bearing | with tapped holes |

## Guide rails

| Order No.       | Item       | L max. | L2 |
|-----------------|------------|--------|----|
| 21230-2730X3000 | Guide Rail | 3000   | 30 |

| Order No.    | Item       | Version 1                  | Version 2         | L max. | L | L2 | L2 min. | L2 max. |
|--------------|------------|----------------------------|-------------------|--------|---|----|---------|---------|
| 21230-27**X* | Guide Rail | L2 and L customer specific | with through hole | 3000   | * | ** | 20      | 49      |