

Item description/product images



Description

Material:

Aluminium.

Grub screw stainless steel 1.4305.

Pin stainless steel 1.4310.

Version:

Vibratory ground or ground and polished.

Grub screw and pin bright.

On request:

Blank palm grips (not tumbled).

Drawing reference:

Form A: blank

Form B: drilled through


Form C: blind hole

Form D: tapped and counterbored

Form E: tapped blind hole

Form L: external thread

Drawings

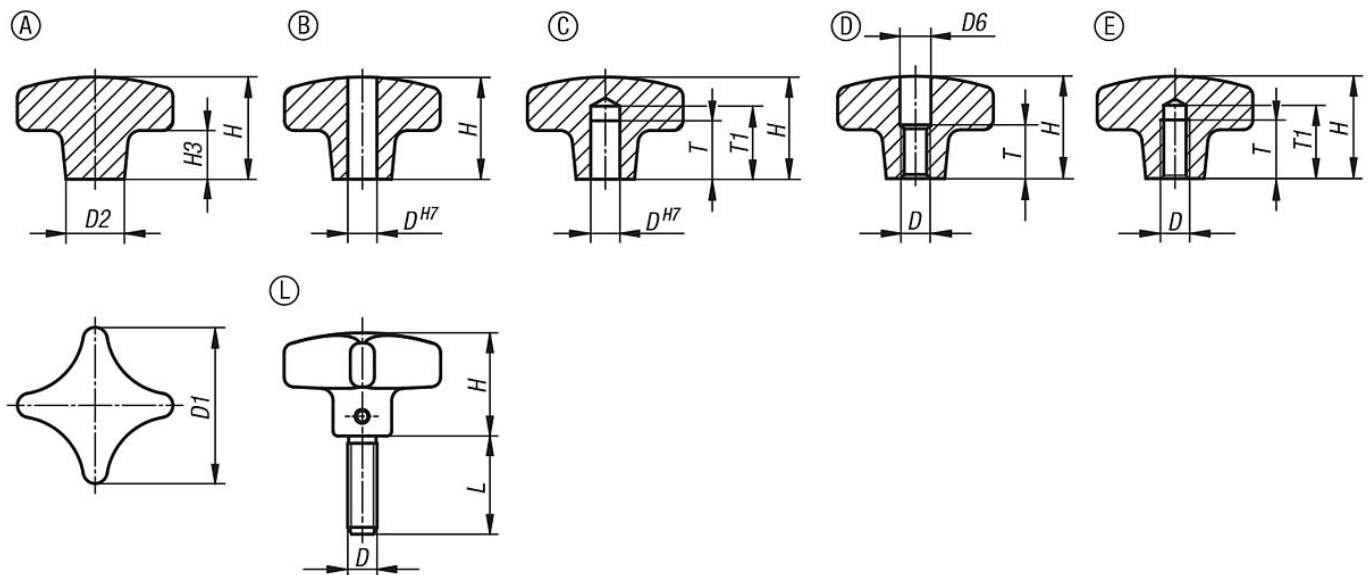

Overview of items

Order No.	Form	Finish	D	D1	D2	D6	H	H3	L	T	T1
06156-104008	A	Kipp	-	40	14	-	26	14	-	-	-
06156-105010	A	Kipp	-	50	18	-	34	20	-	-	-
06156-106312	A	Kipp	-	63	25	-	42	25	-	-	-
06156-108016	A	Kipp	-	80	25	-	52	30	-	-	-
06156-204008	B	Kipp	8	40	14	-	25	-	-	-	-
06156-205010	B	Kipp	10	50	18	-	32	-	-	-	-
06156-206312	B	Kipp	12	63	25	-	40	-	-	-	-
06156-208016	B	Kipp	16	80	25	-	50	-	-	-	-
06156-2040082	B	from 18.5 to 22.0	8	40	14	-	25	-	-	-	-
06156-2050102	B	from 18.5 to 22.0	10	50	18	-	32	-	-	-	-
06156-2063122	B	from 18.5 to 22.0	12	63	25	-	40	-	-	-	-

Overview of items

Order No.	Form	Finish	D	D1	D2	D6	H	H3	L	T	T1
06156-2080162	B	from 18.5 to 22.0	16	80	25	-	50	-	-	-	-
06156-304008	C	Kipp	8	40	14	-	25	14	-	15	18
06156-305010	C	Kipp	10	50	18	-	32	20	-	18	21
06156-306312	C	Kipp	12	63	25	-	40	25	-	22	25
06156-308016	C	Kipp	16	80	25	-	50	30	-	28	32
06156-3040082	C	from 18.5 to 22.0	8	40	14	-	25	14	-	15	18
06156-3050102	C	from 18.5 to 22.0	10	50	18	-	32	20	-	18	21
06156-3063122	C	from 18.5 to 22.0	12	63	25	-	40	25	-	22	25
06156-3080162	C	from 18.5 to 22.0	16	80	25	-	50	30	-	28	32
06156-404008	D	Kipp	M8	40	14	8,4	25	-	-	15	-
06156-405010	D	Kipp	M10	50	18	10,5	32	-	-	18	-
06156-406312	D	Kipp	M12	63	25	13	40	-	-	22	-
06156-408016	D	Kipp	M16	80	25	17	50	-	-	28	-
06156-4040082	D	from 18.5 to 22.0	M8	40	14	8,4	25	-	-	15	-
06156-4050102	D	from 18.5 to 22.0	M10	50	18	10,5	32	-	-	18	-
06156-4063122	D	from 18.5 to 22.0	M12	63	25	13	40	-	-	22	-
06156-4080162	D	from 18.5 to 22.0	M16	80	25	17	50	-	-	28	-
06156-504008	E	Kipp	M8	40	14	-	25	14	-	15	18
06156-505010	E	Kipp	M10	50	18	-	32	20	-	18	21
06156-506312	E	Kipp	M12	63	25	-	40	25	-	22	25
06156-508016	E	Kipp	M16	80	25	-	50	30	-	28	32
06156-5040082	E	from 18.5 to 22.0	M8	40	14	-	25	14	-	15	18
06156-5050102	E	from 18.5 to 22.0	M10	50	18	-	32	20	-	18	21
06156-5063122	E	from 18.5 to 22.0	M12	63	25	-	40	25	-	22	25
06156-5080162	E	from 18.5 to 22.0	M16	80	25	-	50	30	-	28	32
06156-604008X20	L	Kipp	M8	40	14	-	25	-	20	-	-
06156-604008X25	L	Kipp	M8	40	14	-	25	-	25	-	-
06156-604008X30	L	Kipp	M8	40	14	-	25	-	30	-	-
06156-604008X40	L	Kipp	M8	40	14	-	25	-	40	-	-
06156-604008X50	L	Kipp	M8	40	14	-	25	-	50	-	-
06156-605010X20	L	Kipp	M10	50	18	-	32	-	20	-	-
06156-605010X25	L	Kipp	M10	50	18	-	32	-	25	-	-
06156-605010X30	L	Kipp	M10	50	18	-	32	-	30	-	-
06156-605010X40	L	Kipp	M10	50	18	-	32	-	40	-	-
06156-605010X50	L	Kipp	M10	50	18	-	32	-	50	-	-
06156-606312X20	L	Kipp	M12	63	25	-	40	-	20	-	-
06156-606312X30	L	Kipp	M12	63	25	-	40	-	30	-	-
06156-606312X40	L	Kipp	M12	63	25	-	40	-	40	-	-
06156-606312X50	L	Kipp	M12	63	25	-	40	-	50	-	-