


Item description/product images

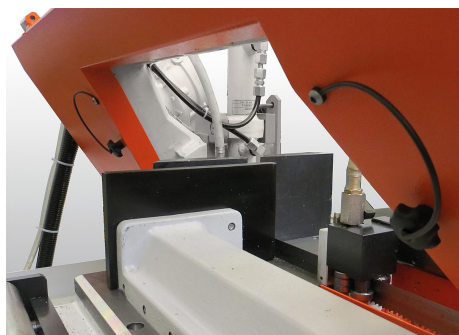

Description

Material:

Grip thermoplastic.
Bush and screw steel.
Safety cable elastic TPU.

Version:

Bush and screw bright.

Note:

Δ Add the desired cap colour code here. No colour code is required for black caps.

Attach the safety cable to a base to make the star grip unlosable. The star grip cannot be moved far from the object to which it belongs, simplifying screwing and unscrewing of the grip and ensuring against loss.

Assembly:

Do not stretch the band during assembly.
Make sure that the anchor is not too far from where the star grip is to be used.


Accessory:

The safety cable is also available as an accessory, see 03198-04190.

Drawing reference:

Form KS: tapped bush, with cap
Form LS: external thread

Drawings

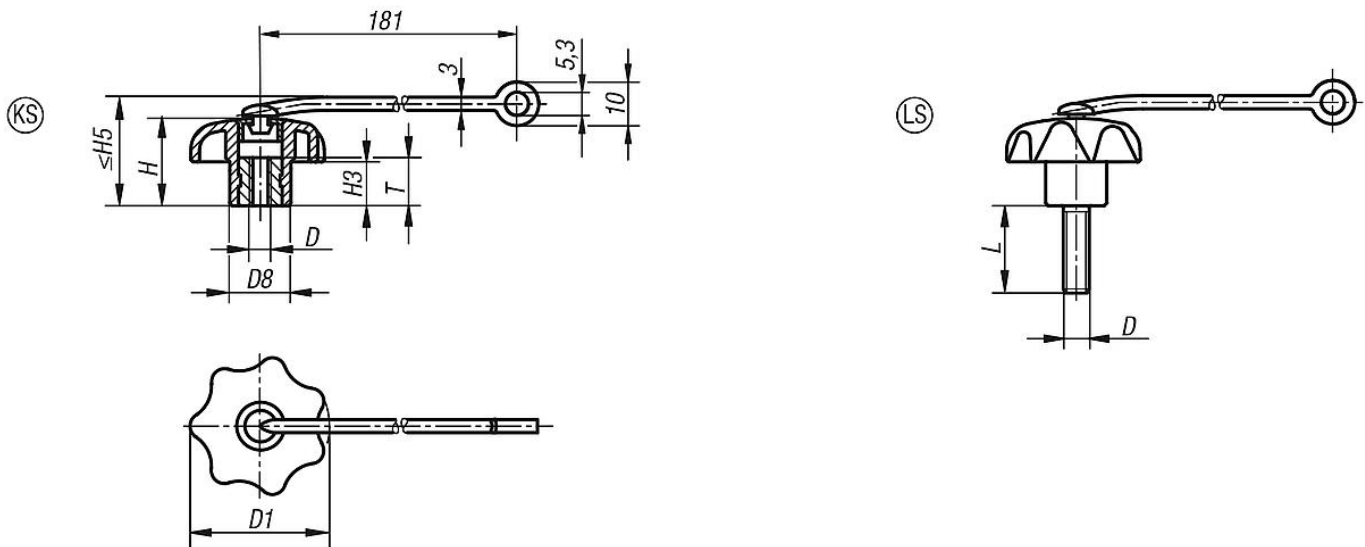

Overview of items

Order No.	Form	Colour Cap	D	D1	D8	H	H5 max.	T	L
06220-604	KS	jet black	M4	25	12	16	22	10	-
06220-6045	KS	light grey RAL 7035	M4	25	12	16	22	10	-
06220-6046	KS	traffic red RAL 3020	M4	25	12	16	22	10	-
06220-6047	KS	colza yellow RAL 1021	M4	25	12	16	22	10	-
06220-605	KS	jet black	M5	25	12	16	22	10	-
06220-6055	KS	light grey RAL 7035	M5	25	12	16	22	10	-
06220-6056	KS	traffic red RAL 3020	M5	25	12	16	22	10	-
06220-6057	KS	colza yellow RAL 1021	M5	25	12	16	22	10	-
06220-6061	KS	jet black	M6	25	12	16	22	10	-
06220-60615	KS	light grey RAL 7035	M6	25	12	16	22	10	-
06220-60616	KS	traffic red RAL 3020	M6	25	12	16	22	10	-
06220-60617	KS	colza yellow RAL 1021	M6	25	12	16	22	10	-
06220-6051	KS	jet black	M5	32	14	20	26	10	-
06220-60515	KS	light grey RAL 7035	M5	32	14	20	26	10	-
06220-60516	KS	traffic red RAL 3020	M5	32	14	20	26	10	-
06220-60517	KS	colza yellow RAL 1021	M5	32	14	20	26	10	-
06220-606	KS	jet black	M6	32	14	20	26	10	-
06220-6065	KS	light grey RAL 7035	M6	32	14	20	26	10	-
06220-6066	KS	traffic red RAL 3020	M6	32	14	20	26	10	-
06220-6067	KS	colza yellow RAL 1021	M6	32	14	20	26	10	-
06220-608	KS	jet black	M8	40	18	25	31	14	-
06220-6085	KS	light grey RAL 7035	M8	40	18	25	31	14	-
06220-6086	KS	traffic red RAL 3020	M8	40	18	25	31	14	-
06220-6087	KS	colza yellow RAL 1021	M8	40	18	25	31	14	-
06220-6101	KS	jet black	M10	40	18	25	31	14	-
06220-61015	KS	light grey RAL 7035	M10	40	18	25	31	14	-
06220-61016	KS	traffic red RAL 3020	M10	40	18	25	31	14	-
06220-61017	KS	colza yellow RAL 1021	M10	40	18	25	31	14	-
06220-6081	KS	jet black	M8	50	22	32	38	14	-
06220-60815	KS	light grey RAL 7035	M8	50	22	32	38	14	-
06220-60816	KS	traffic red RAL 3020	M8	50	22	32	38	14	-
06220-60817	KS	colza yellow RAL 1021	M8	50	22	32	38	14	-
06220-610	KS	jet black	M10	50	22	32	38	14	-
06220-6105	KS	light grey RAL 7035	M10	50	22	32	38	14	-
06220-6106	KS	traffic red RAL 3020	M10	50	22	32	38	14	-
06220-6107	KS	colza yellow RAL 1021	M10	50	22	32	38	14	-
06220-6121	KS	jet black	M12	50	22	32	38	14	-
06220-61215	KS	light grey RAL 7035	M12	50	22	32	38	14	-
06220-61216	KS	traffic red RAL 3020	M12	50	22	32	38	14	-
06220-61217	KS	colza yellow RAL 1021	M12	50	22	32	38	14	-

Overview of items

Order No.	Form	Colour Cap	D	D1	D8	H	H5 max.	T	L
06220-6102	KS	jet black	M10	63	26	40	46	14	-
06220-61025	KS	light grey RAL 7035	M10	63	26	40	46	14	-
06220-61026	KS	traffic red RAL 3020	M10	63	26	40	46	14	-
06220-61027	KS	colza yellow RAL 1021	M10	63	26	40	46	14	-
06220-612	KS	jet black	M12	63	26	40	46	14	-
06220-6125	KS	light grey RAL 7035	M12	63	26	40	46	14	-
06220-6126	KS	traffic red RAL 3020	M12	63	26	40	46	14	-
06220-6127	KS	colza yellow RAL 1021	M12	63	26	40	46	14	-
06220-616	KS	jet black	M16	63	26	40	46	14	-
06220-6165	KS	light grey RAL 7035	M16	63	26	40	46	14	-
06220-6166	KS	traffic red RAL 3020	M16	63	26	40	46	14	-
06220-6167	KS	colza yellow RAL 1021	M16	63	26	40	46	14	-
06220-705X10	LS	jet black	M5	25	12	16	22	-	10
06220-7055X10	LS	light grey RAL 7035	M5	25	12	16	22	-	10
06220-7056X10	LS	traffic red RAL 3020	M5	25	12	16	22	-	10
06220-7057X10	LS	colza yellow RAL 1021	M5	25	12	16	22	-	10
06220-705X15	LS	jet black	M5	25	12	16	22	-	15
06220-7055X15	LS	light grey RAL 7035	M5	25	12	16	22	-	15
06220-7056X15	LS	traffic red RAL 3020	M5	25	12	16	22	-	15
06220-7057X15	LS	colza yellow RAL 1021	M5	25	12	16	22	-	15
06220-705X20	LS	jet black	M5	25	12	16	22	-	20
06220-7055X20	LS	light grey RAL 7035	M5	25	12	16	22	-	20
06220-7056X20	LS	traffic red RAL 3020	M5	25	12	16	22	-	20
06220-7057X20	LS	colza yellow RAL 1021	M5	25	12	16	22	-	20
06220-705X25	LS	jet black	M5	25	12	16	22	-	25
06220-7055X25	LS	light grey RAL 7035	M5	25	12	16	22	-	25
06220-7056X25	LS	traffic red RAL 3020	M5	25	12	16	22	-	25
06220-7057X25	LS	colza yellow RAL 1021	M5	25	12	16	22	-	25
06220-705X30	LS	jet black	M5	25	12	16	22	-	30
06220-7055X30	LS	light grey RAL 7035	M5	25	12	16	22	-	30
06220-7056X30	LS	traffic red RAL 3020	M5	25	12	16	22	-	30
06220-7057X30	LS	colza yellow RAL 1021	M5	25	12	16	22	-	30
06220-705X35	LS	jet black	M5	25	12	16	22	-	35
06220-7055X35	LS	light grey RAL 7035	M5	25	12	16	22	-	35
06220-7056X35	LS	traffic red RAL 3020	M5	25	12	16	22	-	35
06220-7057X35	LS	colza yellow RAL 1021	M5	25	12	16	22	-	35
06220-705X40	LS	jet black	M5	25	12	16	22	-	40
06220-7055X40	LS	light grey RAL 7035	M5	25	12	16	22	-	40
06220-7056X40	LS	traffic red RAL 3020	M5	25	12	16	22	-	40
06220-7057X40	LS	colza yellow RAL 1021	M5	25	12	16	22	-	40
06220-705X45	LS	jet black	M5	25	12	16	22	-	45
06220-7055X45	LS	light grey RAL 7035	M5	25	12	16	22	-	45
06220-7056X45	LS	traffic red RAL 3020	M5	25	12	16	22	-	45
06220-7057X45	LS	colza yellow RAL 1021	M5	25	12	16	22	-	45
06220-705X50	LS	jet black	M5	25	12	16	22	-	50
06220-7055X50	LS	light grey RAL 7035	M5	25	12	16	22	-	50
06220-7056X50	LS	traffic red RAL 3020	M5	25	12	16	22	-	50
06220-7057X50	LS	colza yellow RAL 1021	M5	25	12	16	22	-	50
06220-705X60	LS	jet black	M5	25	12	16	22	-	60
06220-7055X60	LS	light grey RAL 7035	M5	25	12	16	22	-	60
06220-7056X60	LS	traffic red RAL 3020	M5	25	12	16	22	-	60
06220-7057X60	LS	colza yellow RAL 1021	M5	25	12	16	22	-	60
06220-706X10	LS	jet black	M6	25	12	16	22	-	10
06220-7065X10	LS	light grey RAL 7035	M6	25	12	16	22	-	10
06220-7066X10	LS	traffic red RAL 3020	M6	25	12	16	22	-	10
06220-7067X10	LS	colza yellow RAL 1021	M6	25	12	16	22	-	10
06220-706X15	LS	jet black	M6	25	12	16	22	-	15
06220-7065X15	LS	light grey RAL 7035	M6	25	12	16	22	-	15
06220-7066X15	LS	traffic red RAL 3020	M6	25	12	16	22	-	15
06220-7067X15	LS	colza yellow RAL 1021	M6	25	12	16	22	-	15
06220-706X20	LS	jet black	M6	25	12	16	22	-	20
06220-7065X20	LS	light grey RAL 7035	M6	25	12	16	22	-	20
06220-7066X20	LS	traffic red RAL 3020	M6	25	12	16	22	-	20
06220-7067X20	LS	colza yellow RAL 1021	M6	25	12	16	22	-	20
06220-706X25	LS	jet black	M6	25	12	16	22	-	25

Overview of items

Order No.	Form	Colour Cap	D	D1	D8	H	H5 max.	T	L
06220-7065X25	LS	light grey RAL 7035	M6	25	12	16	22	-	25
06220-7066X25	LS	traffic red RAL 3020	M6	25	12	16	22	-	25
06220-7067X25	LS	colza yellow RAL 1021	M6	25	12	16	22	-	25
06220-706X30	LS	jet black	M6	25	12	16	22	-	30
06220-7065X30	LS	light grey RAL 7035	M6	25	12	16	22	-	30
06220-7066X30	LS	traffic red RAL 3020	M6	25	12	16	22	-	30
06220-7067X30	LS	colza yellow RAL 1021	M6	25	12	16	22	-	30
06220-706X35	LS	jet black	M6	25	12	16	22	-	35
06220-7065X35	LS	light grey RAL 7035	M6	25	12	16	22	-	35
06220-7066X35	LS	traffic red RAL 3020	M6	25	12	16	22	-	35
06220-7067X35	LS	colza yellow RAL 1021	M6	25	12	16	22	-	35
06220-706X40	LS	jet black	M6	25	12	16	22	-	40
06220-7065X40	LS	light grey RAL 7035	M6	25	12	16	22	-	40
06220-7066X40	LS	traffic red RAL 3020	M6	25	12	16	22	-	40
06220-7067X40	LS	colza yellow RAL 1021	M6	25	12	16	22	-	40
06220-706X45	LS	jet black	M6	25	12	16	22	-	45
06220-7065X45	LS	light grey RAL 7035	M6	25	12	16	22	-	45
06220-7066X45	LS	traffic red RAL 3020	M6	25	12	16	22	-	45
06220-7067X45	LS	colza yellow RAL 1021	M6	25	12	16	22	-	45
06220-706X50	LS	jet black	M6	25	12	16	22	-	50
06220-7065X50	LS	light grey RAL 7035	M6	25	12	16	22	-	50
06220-7066X50	LS	traffic red RAL 3020	M6	25	12	16	22	-	50
06220-7067X50	LS	colza yellow RAL 1021	M6	25	12	16	22	-	50
06220-706X60	LS	jet black	M6	25	12	16	22	-	60
06220-7065X60	LS	light grey RAL 7035	M6	25	12	16	22	-	60
06220-7066X60	LS	traffic red RAL 3020	M6	25	12	16	22	-	60
06220-7067X60	LS	colza yellow RAL 1021	M6	25	12	16	22	-	60
06220-7061X10	LS	jet black	M6	32	14	20	26	-	10
06220-70615X10	LS	light grey RAL 7035	M6	32	14	20	26	-	10
06220-70616X10	LS	traffic red RAL 3020	M6	32	14	20	26	-	10
06220-70617X10	LS	colza yellow RAL 1021	M6	32	14	20	26	-	10
06220-7061X15	LS	jet black	M6	32	14	20	26	-	15
06220-70615X15	LS	light grey RAL 7035	M6	32	14	20	26	-	15
06220-70616X15	LS	traffic red RAL 3020	M6	32	14	20	26	-	15
06220-70617X15	LS	colza yellow RAL 1021	M6	32	14	20	26	-	15
06220-7061X20	LS	jet black	M6	32	14	20	26	-	20
06220-70615X20	LS	light grey RAL 7035	M6	32	14	20	26	-	20
06220-70616X20	LS	traffic red RAL 3020	M6	32	14	20	26	-	20
06220-70617X20	LS	colza yellow RAL 1021	M6	32	14	20	26	-	20
06220-7061X25	LS	jet black	M6	32	14	20	26	-	25
06220-70615X25	LS	light grey RAL 7035	M6	32	14	20	26	-	25
06220-70616X25	LS	traffic red RAL 3020	M6	32	14	20	26	-	25
06220-70617X25	LS	colza yellow RAL 1021	M6	32	14	20	26	-	25
06220-7061X30	LS	jet black	M6	32	14	20	26	-	30
06220-70615X30	LS	light grey RAL 7035	M6	32	14	20	26	-	30
06220-70616X30	LS	traffic red RAL 3020	M6	32	14	20	26	-	30
06220-70617X30	LS	colza yellow RAL 1021	M6	32	14	20	26	-	30
06220-7061X35	LS	jet black	M6	32	14	20	26	-	35
06220-70615X35	LS	light grey RAL 7035	M6	32	14	20	26	-	35
06220-70616X35	LS	traffic red RAL 3020	M6	32	14	20	26	-	35
06220-70617X35	LS	colza yellow RAL 1021	M6	32	14	20	26	-	35
06220-7061X40	LS	jet black	M6	32	14	20	26	-	40
06220-70615X40	LS	light grey RAL 7035	M6	32	14	20	26	-	40
06220-70616X40	LS	traffic red RAL 3020	M6	32	14	20	26	-	40
06220-70617X40	LS	colza yellow RAL 1021	M6	32	14	20	26	-	40
06220-7061X45	LS	jet black	M6	32	14	20	26	-	45
06220-70615X45	LS	light grey RAL 7035	M6	32	14	20	26	-	45
06220-70616X45	LS	traffic red RAL 3020	M6	32	14	20	26	-	45
06220-70617X45	LS	colza yellow RAL 1021	M6	32	14	20	26	-	45
06220-7061X50	LS	jet black	M6	32	14	20	26	-	50
06220-70615X50	LS	light grey RAL 7035	M6	32	14	20	26	-	50
06220-70616X50	LS	traffic red RAL 3020	M6	32	14	20	26	-	50
06220-70617X50	LS	colza yellow RAL 1021	M6	32	14	20	26	-	50
06220-7061X60	LS	jet black	M6	32	14	20	26	-	60
06220-70615X60	LS	light grey RAL 7035	M6	32	14	20	26	-	60

Overview of items

Order No.	Form	Colour Cap	D	D1	D8	H	H5 max.	T	L
06220-70616X60	LS	traffic red RAL 3020	M6	32	14	20	26	-	60
06220-70617X60	LS	colza yellow RAL 1021	M6	32	14	20	26	-	60
06220-708X15	LS	jet black	M8	32	14	20	26	-	15
06220-7085X15	LS	light grey RAL 7035	M8	32	14	20	26	-	15
06220-7086X15	LS	traffic red RAL 3020	M8	32	14	20	26	-	15
06220-7087X15	LS	colza yellow RAL 1021	M8	32	14	20	26	-	15
06220-708X20	LS	jet black	M8	32	14	20	26	-	20
06220-7085X20	LS	light grey RAL 7035	M8	32	14	20	26	-	20
06220-7086X20	LS	traffic red RAL 3020	M8	32	14	20	26	-	20
06220-7087X20	LS	colza yellow RAL 1021	M8	32	14	20	26	-	20
06220-708X25	LS	jet black	M8	32	14	20	26	-	25
06220-7085X25	LS	light grey RAL 7035	M8	32	14	20	26	-	25
06220-7086X25	LS	traffic red RAL 3020	M8	32	14	20	26	-	25
06220-7087X25	LS	colza yellow RAL 1021	M8	32	14	20	26	-	25
06220-708X30	LS	jet black	M8	32	14	20	26	-	30
06220-7085X30	LS	light grey RAL 7035	M8	32	14	20	26	-	30
06220-7086X30	LS	traffic red RAL 3020	M8	32	14	20	26	-	30
06220-7087X30	LS	colza yellow RAL 1021	M8	32	14	20	26	-	30
06220-708X35	LS	jet black	M8	32	14	20	26	-	35
06220-7085X35	LS	light grey RAL 7035	M8	32	14	20	26	-	35
06220-7086X35	LS	traffic red RAL 3020	M8	32	14	20	26	-	35
06220-7087X35	LS	colza yellow RAL 1021	M8	32	14	20	26	-	35
06220-708X40	LS	jet black	M8	32	14	20	26	-	40
06220-7085X40	LS	light grey RAL 7035	M8	32	14	20	26	-	40
06220-7086X40	LS	traffic red RAL 3020	M8	32	14	20	26	-	40
06220-7087X40	LS	colza yellow RAL 1021	M8	32	14	20	26	-	40
06220-708X45	LS	jet black	M8	32	14	20	26	-	45
06220-7085X45	LS	light grey RAL 7035	M8	32	14	20	26	-	45
06220-7086X45	LS	traffic red RAL 3020	M8	32	14	20	26	-	45
06220-7087X45	LS	colza yellow RAL 1021	M8	32	14	20	26	-	45
06220-708X50	LS	jet black	M8	32	14	20	26	-	50
06220-7085X50	LS	light grey RAL 7035	M8	32	14	20	26	-	50
06220-7086X50	LS	traffic red RAL 3020	M8	32	14	20	26	-	50
06220-7087X50	LS	colza yellow RAL 1021	M8	32	14	20	26	-	50
06220-708X60	LS	jet black	M8	32	14	20	26	-	60
06220-7085X60	LS	light grey RAL 7035	M8	32	14	20	26	-	60
06220-7086X60	LS	traffic red RAL 3020	M8	32	14	20	26	-	60
06220-7087X60	LS	colza yellow RAL 1021	M8	32	14	20	26	-	60
06220-7081X15	LS	jet black	M8	40	18	25	31	-	15
06220-70815X15	LS	light grey RAL 7035	M8	40	18	25	31	-	15
06220-70816X15	LS	traffic red RAL 3020	M8	40	18	25	31	-	15
06220-70817X15	LS	colza yellow RAL 1021	M8	40	18	25	31	-	15
06220-7081X20	LS	jet black	M8	40	18	25	31	-	20
06220-70815X20	LS	light grey RAL 7035	M8	40	18	25	31	-	20
06220-70816X20	LS	traffic red RAL 3020	M8	40	18	25	31	-	20
06220-70817X20	LS	colza yellow RAL 1021	M8	40	18	25	31	-	20
06220-7081X25	LS	jet black	M8	40	18	25	31	-	25
06220-70815X25	LS	light grey RAL 7035	M8	40	18	25	31	-	25
06220-70816X25	LS	traffic red RAL 3020	M8	40	18	25	31	-	25
06220-70817X25	LS	colza yellow RAL 1021	M8	40	18	25	31	-	25
06220-7081X30	LS	jet black	M8	40	18	25	31	-	30
06220-70815X30	LS	light grey RAL 7035	M8	40	18	25	31	-	30
06220-70816X30	LS	traffic red RAL 3020	M8	40	18	25	31	-	30
06220-70817X30	LS	colza yellow RAL 1021	M8	40	18	25	31	-	30
06220-7081X35	LS	jet black	M8	40	18	25	31	-	35
06220-70815X35	LS	light grey RAL 7035	M8	40	18	25	31	-	35
06220-70816X35	LS	traffic red RAL 3020	M8	40	18	25	31	-	35
06220-70817X35	LS	colza yellow RAL 1021	M8	40	18	25	31	-	35
06220-7081X40	LS	jet black	M8	40	18	25	31	-	40
06220-70815X40	LS	light grey RAL 7035	M8	40	18	25	31	-	40
06220-70816X40	LS	traffic red RAL 3020	M8	40	18	25	31	-	40
06220-70817X40	LS	colza yellow RAL 1021	M8	40	18	25	31	-	40
06220-7081X45	LS	jet black	M8	40	18	25	31	-	45
06220-70815X45	LS	light grey RAL 7035	M8	40	18	25	31	-	45
06220-70816X45	LS	traffic red RAL 3020	M8	40	18	25	31	-	45

Overview of items

Order No.	Form	Colour Cap	D	D1	D8	H	H5 max.	T	L
06220-70817X45	LS	colza yellow RAL 1021	M8	40	18	25	31	-	45
06220-7081X50	LS	jet black	M8	40	18	25	31	-	50
06220-70815X50	LS	light grey RAL 7035	M8	40	18	25	31	-	50
06220-70816X50	LS	traffic red RAL 3020	M8	40	18	25	31	-	50
06220-70817X50	LS	colza yellow RAL 1021	M8	40	18	25	31	-	50
06220-7081X60	LS	jet black	M8	40	18	25	31	-	60
06220-70815X60	LS	light grey RAL 7035	M8	40	18	25	31	-	60
06220-70816X60	LS	traffic red RAL 3020	M8	40	18	25	31	-	60
06220-70817X60	LS	colza yellow RAL 1021	M8	40	18	25	31	-	60
06220-710X15	LS	jet black	M10	40	18	25	31	-	15
06220-7105X15	LS	light grey RAL 7035	M10	40	18	25	31	-	15
06220-7106X15	LS	traffic red RAL 3020	M10	40	18	25	31	-	15
06220-7107X15	LS	colza yellow RAL 1021	M10	40	18	25	31	-	15
06220-710X20	LS	jet black	M10	40	18	25	31	-	20
06220-7105X20	LS	light grey RAL 7035	M10	40	18	25	31	-	20
06220-7106X20	LS	traffic red RAL 3020	M10	40	18	25	31	-	20
06220-7107X20	LS	colza yellow RAL 1021	M10	40	18	25	31	-	20
06220-710X25	LS	jet black	M10	40	18	25	31	-	25
06220-7105X25	LS	light grey RAL 7035	M10	40	18	25	31	-	25
06220-7106X25	LS	traffic red RAL 3020	M10	40	18	25	31	-	25
06220-7107X25	LS	colza yellow RAL 1021	M10	40	18	25	31	-	25
06220-710X30	LS	jet black	M10	40	18	25	31	-	30
06220-7105X30	LS	light grey RAL 7035	M10	40	18	25	31	-	30
06220-7106X30	LS	traffic red RAL 3020	M10	40	18	25	31	-	30
06220-7107X30	LS	colza yellow RAL 1021	M10	40	18	25	31	-	30
06220-710X35	LS	jet black	M10	40	18	25	31	-	35
06220-7105X35	LS	light grey RAL 7035	M10	40	18	25	31	-	35
06220-7106X35	LS	traffic red RAL 3020	M10	40	18	25	31	-	35
06220-7107X35	LS	colza yellow RAL 1021	M10	40	18	25	31	-	35
06220-710X40	LS	jet black	M10	40	18	25	31	-	40
06220-7105X40	LS	light grey RAL 7035	M10	40	18	25	31	-	40
06220-7106X40	LS	traffic red RAL 3020	M10	40	18	25	31	-	40
06220-7107X40	LS	colza yellow RAL 1021	M10	40	18	25	31	-	40
06220-710X45	LS	jet black	M10	40	18	25	31	-	45
06220-7105X45	LS	light grey RAL 7035	M10	40	18	25	31	-	45
06220-7106X45	LS	traffic red RAL 3020	M10	40	18	25	31	-	45
06220-7107X45	LS	colza yellow RAL 1021	M10	40	18	25	31	-	45
06220-710X50	LS	jet black	M10	40	18	25	31	-	50
06220-7105X50	LS	light grey RAL 7035	M10	40	18	25	31	-	50
06220-7106X50	LS	traffic red RAL 3020	M10	40	18	25	31	-	50
06220-7107X50	LS	colza yellow RAL 1021	M10	40	18	25	31	-	50
06220-710X60	LS	jet black	M10	40	18	25	31	-	60
06220-7105X60	LS	light grey RAL 7035	M10	40	18	25	31	-	60
06220-7106X60	LS	traffic red RAL 3020	M10	40	18	25	31	-	60
06220-7107X60	LS	colza yellow RAL 1021	M10	40	18	25	31	-	60
06220-7101X15	LS	jet black	M10	50	22	32	38	-	15
06220-71015X15	LS	light grey RAL 7035	M10	50	22	32	38	-	15
06220-71016X15	LS	traffic red RAL 3020	M10	50	22	32	38	-	15
06220-71017X15	LS	colza yellow RAL 1021	M10	50	22	32	38	-	15
06220-7101X20	LS	jet black	M10	50	22	32	38	-	20
06220-71015X20	LS	light grey RAL 7035	M10	50	22	32	38	-	20
06220-71016X20	LS	traffic red RAL 3020	M10	50	22	32	38	-	20
06220-71017X20	LS	colza yellow RAL 1021	M10	50	22	32	38	-	20
06220-7101X25	LS	jet black	M10	50	22	32	38	-	25
06220-71015X25	LS	light grey RAL 7035	M10	50	22	32	38	-	25
06220-71016X25	LS	traffic red RAL 3020	M10	50	22	32	38	-	25
06220-71017X25	LS	colza yellow RAL 1021	M10	50	22	32	38	-	25
06220-7101X30	LS	jet black	M10	50	22	32	38	-	30
06220-71015X30	LS	light grey RAL 7035	M10	50	22	32	38	-	30
06220-71016X30	LS	traffic red RAL 3020	M10	50	22	32	38	-	30
06220-71017X30	LS	colza yellow RAL 1021	M10	50	22	32	38	-	30
06220-7101X35	LS	jet black	M10	50	22	32	38	-	35
06220-71015X35	LS	light grey RAL 7035	M10	50	22	32	38	-	35
06220-71016X35	LS	traffic red RAL 3020	M10	50	22	32	38	-	35
06220-71017X35	LS	colza yellow RAL 1021	M10	50	22	32	38	-	35

Overview of items

Order No.	Form	Colour Cap	D	D1	D8	H	H5 max.	T	L
06220-7101X40	LS	jet black	M10	50	22	32	38	-	40
06220-71015X40	LS	light grey RAL 7035	M10	50	22	32	38	-	40
06220-71016X40	LS	traffic red RAL 3020	M10	50	22	32	38	-	40
06220-71017X40	LS	colza yellow RAL 1021	M10	50	22	32	38	-	40
06220-7101X45	LS	jet black	M10	50	22	32	38	-	45
06220-71015X45	LS	light grey RAL 7035	M10	50	22	32	38	-	45
06220-71016X45	LS	traffic red RAL 3020	M10	50	22	32	38	-	45
06220-71017X45	LS	colza yellow RAL 1021	M10	50	22	32	38	-	45
06220-7101X50	LS	jet black	M10	50	22	32	38	-	50
06220-71015X50	LS	light grey RAL 7035	M10	50	22	32	38	-	50
06220-71016X50	LS	traffic red RAL 3020	M10	50	22	32	38	-	50
06220-71017X50	LS	colza yellow RAL 1021	M10	50	22	32	38	-	50
06220-7101X60	LS	jet black	M10	50	22	32	38	-	60
06220-71015X60	LS	light grey RAL 7035	M10	50	22	32	38	-	60
06220-71016X60	LS	traffic red RAL 3020	M10	50	22	32	38	-	60
06220-71017X60	LS	colza yellow RAL 1021	M10	50	22	32	38	-	60
06220-712X15	LS	jet black	M12	50	22	32	38	-	15
06220-7125X15	LS	light grey RAL 7035	M12	50	22	32	38	-	15
06220-7126X15	LS	traffic red RAL 3020	M12	50	22	32	38	-	15
06220-7127X15	LS	colza yellow RAL 1021	M12	50	22	32	38	-	15
06220-712X20	LS	jet black	M12	50	22	32	38	-	20
06220-7125X20	LS	light grey RAL 7035	M12	50	22	32	38	-	20
06220-7126X20	LS	traffic red RAL 3020	M12	50	22	32	38	-	20
06220-7127X20	LS	colza yellow RAL 1021	M12	50	22	32	38	-	20
06220-712X25	LS	jet black	M12	50	22	32	38	-	25
06220-7125X25	LS	light grey RAL 7035	M12	50	22	32	38	-	25
06220-7126X25	LS	traffic red RAL 3020	M12	50	22	32	38	-	25
06220-7127X25	LS	colza yellow RAL 1021	M12	50	22	32	38	-	25
06220-712X30	LS	jet black	M12	50	22	32	38	-	30
06220-7125X30	LS	light grey RAL 7035	M12	50	22	32	38	-	30
06220-7126X30	LS	traffic red RAL 3020	M12	50	22	32	38	-	30
06220-7127X30	LS	colza yellow RAL 1021	M12	50	22	32	38	-	30
06220-712X35	LS	jet black	M12	50	22	32	38	-	35
06220-7125X35	LS	light grey RAL 7035	M12	50	22	32	38	-	35
06220-7126X35	LS	traffic red RAL 3020	M12	50	22	32	38	-	35
06220-7127X35	LS	colza yellow RAL 1021	M12	50	22	32	38	-	35
06220-712X40	LS	jet black	M12	50	22	32	38	-	40
06220-7125X40	LS	light grey RAL 7035	M12	50	22	32	38	-	40
06220-7126X40	LS	traffic red RAL 3020	M12	50	22	32	38	-	40
06220-7127X40	LS	colza yellow RAL 1021	M12	50	22	32	38	-	40
06220-712X45	LS	jet black	M12	50	22	32	38	-	45
06220-7125X45	LS	light grey RAL 7035	M12	50	22	32	38	-	45
06220-7126X45	LS	traffic red RAL 3020	M12	50	22	32	38	-	45
06220-7127X45	LS	colza yellow RAL 1021	M12	50	22	32	38	-	45
06220-712X50	LS	jet black	M12	50	22	32	38	-	50
06220-7125X50	LS	light grey RAL 7035	M12	50	22	32	38	-	50
06220-7126X50	LS	traffic red RAL 3020	M12	50	22	32	38	-	50
06220-7127X50	LS	colza yellow RAL 1021	M12	50	22	32	38	-	50
06220-712X60	LS	jet black	M12	50	22	32	38	-	60
06220-7125X60	LS	light grey RAL 7035	M12	50	22	32	38	-	60
06220-7126X60	LS	traffic red RAL 3020	M12	50	22	32	38	-	60
06220-7127X60	LS	colza yellow RAL 1021	M12	50	22	32	38	-	60
06220-7102X20	LS	jet black	M10	63	26	40	46	-	20
06220-71025X20	LS	light grey RAL 7035	M10	63	26	40	46	-	20
06220-71026X20	LS	traffic red RAL 3020	M10	63	26	40	46	-	20
06220-71027X20	LS	colza yellow RAL 1021	M10	63	26	40	46	-	20
06220-7102X25	LS	jet black	M10	63	26	40	46	-	25
06220-71025X25	LS	light grey RAL 7035	M10	63	26	40	46	-	25
06220-71026X25	LS	traffic red RAL 3020	M10	63	26	40	46	-	25
06220-71027X25	LS	colza yellow RAL 1021	M10	63	26	40	46	-	25
06220-7102X30	LS	jet black	M10	63	26	40	46	-	30
06220-71025X30	LS	light grey RAL 7035	M10	63	26	40	46	-	30
06220-71026X30	LS	traffic red RAL 3020	M10	63	26	40	46	-	30
06220-71027X30	LS	colza yellow RAL 1021	M10	63	26	40	46	-	30
06220-7102X35	LS	jet black	M10	63	26	40	46	-	35

Overview of items

Order No.	Form	Colour Cap	D	D1	D8	H	H5 max.	T	L
06220-71025X35	LS	light grey RAL 7035	M10	63	26	40	46	-	35
06220-71026X35	LS	traffic red RAL 3020	M10	63	26	40	46	-	35
06220-71027X35	LS	colza yellow RAL 1021	M10	63	26	40	46	-	35
06220-7102X40	LS	jet black	M10	63	26	40	46	-	40
06220-71025X40	LS	light grey RAL 7035	M10	63	26	40	46	-	40
06220-71026X40	LS	traffic red RAL 3020	M10	63	26	40	46	-	40
06220-71027X40	LS	colza yellow RAL 1021	M10	63	26	40	46	-	40
06220-7102X45	LS	jet black	M10	63	26	40	46	-	45
06220-71025X45	LS	light grey RAL 7035	M10	63	26	40	46	-	45
06220-71026X45	LS	traffic red RAL 3020	M10	63	26	40	46	-	45
06220-71027X45	LS	colza yellow RAL 1021	M10	63	26	40	46	-	45
06220-7102X50	LS	jet black	M10	63	26	40	46	-	50
06220-71025X50	LS	light grey RAL 7035	M10	63	26	40	46	-	50
06220-71026X50	LS	traffic red RAL 3020	M10	63	26	40	46	-	50
06220-71027X50	LS	colza yellow RAL 1021	M10	63	26	40	46	-	50
06220-7102X60	LS	jet black	M10	63	26	40	46	-	60
06220-71025X60	LS	light grey RAL 7035	M10	63	26	40	46	-	60
06220-71026X60	LS	traffic red RAL 3020	M10	63	26	40	46	-	60
06220-71027X60	LS	colza yellow RAL 1021	M10	63	26	40	46	-	60
06220-7121X20	LS	jet black	M12	63	26	40	46	-	20
06220-71215X20	LS	light grey RAL 7035	M12	63	26	40	46	-	20
06220-71216X20	LS	traffic red RAL 3020	M12	63	26	40	46	-	20
06220-71217X20	LS	colza yellow RAL 1021	M12	63	26	40	46	-	20
06220-7121X25	LS	jet black	M12	63	26	40	46	-	25
06220-71215X25	LS	light grey RAL 7035	M12	63	26	40	46	-	25
06220-71216X25	LS	traffic red RAL 3020	M12	63	26	40	46	-	25
06220-71217X25	LS	colza yellow RAL 1021	M12	63	26	40	46	-	25
06220-7121X30	LS	jet black	M12	63	26	40	46	-	30
06220-71215X30	LS	light grey RAL 7035	M12	63	26	40	46	-	30
06220-71216X30	LS	traffic red RAL 3020	M12	63	26	40	46	-	30
06220-71217X30	LS	colza yellow RAL 1021	M12	63	26	40	46	-	30
06220-7121X35	LS	jet black	M12	63	26	40	46	-	35
06220-71215X35	LS	light grey RAL 7035	M12	63	26	40	46	-	35
06220-71216X35	LS	traffic red RAL 3020	M12	63	26	40	46	-	35
06220-71217X35	LS	colza yellow RAL 1021	M12	63	26	40	46	-	35
06220-7121X40	LS	jet black	M12	63	26	40	46	-	40
06220-71215X40	LS	light grey RAL 7035	M12	63	26	40	46	-	40
06220-71216X40	LS	traffic red RAL 3020	M12	63	26	40	46	-	40
06220-71217X40	LS	colza yellow RAL 1021	M12	63	26	40	46	-	40
06220-7121X45	LS	jet black	M12	63	26	40	46	-	45
06220-71215X45	LS	light grey RAL 7035	M12	63	26	40	46	-	45
06220-71216X45	LS	traffic red RAL 3020	M12	63	26	40	46	-	45
06220-71217X45	LS	colza yellow RAL 1021	M12	63	26	40	46	-	45
06220-7121X50	LS	jet black	M12	63	26	40	46	-	50
06220-71215X50	LS	light grey RAL 7035	M12	63	26	40	46	-	50
06220-71216X50	LS	traffic red RAL 3020	M12	63	26	40	46	-	50
06220-71217X50	LS	colza yellow RAL 1021	M12	63	26	40	46	-	50
06220-7121X60	LS	jet black	M12	63	26	40	46	-	60
06220-71215X60	LS	light grey RAL 7035	M12	63	26	40	46	-	60
06220-71216X60	LS	traffic red RAL 3020	M12	63	26	40	46	-	60
06220-71217X60	LS	colza yellow RAL 1021	M12	63	26	40	46	-	60
06220-716X30	LS	jet black	M16	63	26	40	46	-	30
06220-7165X30	LS	light grey RAL 7035	M16	63	26	40	46	-	30
06220-7166X30	LS	traffic red RAL 3020	M16	63	26	40	46	-	30
06220-7167X30	LS	colza yellow RAL 1021	M16	63	26	40	46	-	30
06220-716X35	LS	jet black	M16	63	26	40	46	-	35
06220-7165X35	LS	light grey RAL 7035	M16	63	26	40	46	-	35
06220-7166X35	LS	traffic red RAL 3020	M16	63	26	40	46	-	35
06220-7167X35	LS	colza yellow RAL 1021	M16	63	26	40	46	-	35
06220-716X40	LS	jet black	M16	63	26	40	46	-	40
06220-7165X40	LS	light grey RAL 7035	M16	63	26	40	46	-	40
06220-7166X40	LS	traffic red RAL 3020	M16	63	26	40	46	-	40
06220-7167X40	LS	colza yellow RAL 1021	M16	63	26	40	46	-	40
06220-716X45	LS	jet black	M16	63	26	40	46	-	45
06220-7165X45	LS	light grey RAL 7035	M16	63	26	40	46	-	45

Overview of items

Order No.	Form	Colour Cap	D	D1	D8	H	H5 max.	T	L
06220-7166X45	LS	traffic red RAL 3020	M16	63	26	40	46	-	45
06220-7167X45	LS	colza yellow RAL 1021	M16	63	26	40	46	-	45
06220-716X50	LS	jet black	M16	63	26	40	46	-	50
06220-7165X50	LS	light grey RAL 7035	M16	63	26	40	46	-	50
06220-7166X50	LS	traffic red RAL 3020	M16	63	26	40	46	-	50
06220-7167X50	LS	colza yellow RAL 1021	M16	63	26	40	46	-	50
06220-716X60	LS	jet black	M16	63	26	40	46	-	60
06220-7165X60	LS	light grey RAL 7035	M16	63	26	40	46	-	60
06220-7166X60	LS	traffic red RAL 3020	M16	63	26	40	46	-	60
06220-7167X60	LS	colza yellow RAL 1021	M16	63	26	40	46	-	60