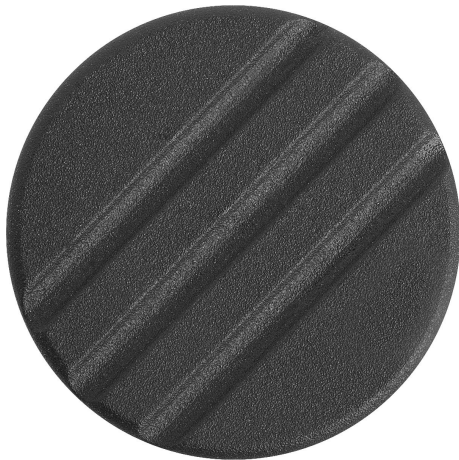


## Item description/product images

**Description****Material:**

Black thermoplastic.

Bush and screw 5.8 steel or 1.4305 stainless steel.

**Version:**

Steel trivalent blue passivated, stainless steel bright.


**Note:**

For the inch series, dimension D is in inches, all other dimensions are in mm.

Item description/product images



Drawings

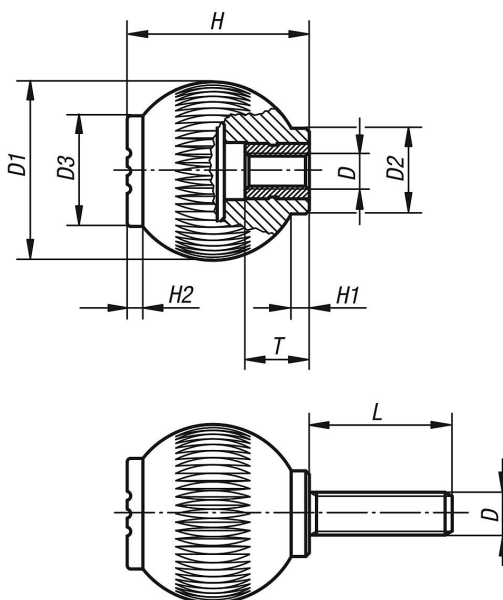

Overview of items

Ball Grips, internal thread, inch

Order No.	Component material	Colour Cap	Size	D	D1	D2	D3	H	H1	H2	T
06245-1A2	steel	black grey RAL 7021	1	1/4-20	25	12	17	25	3	2	10
06245-1A25	steel	light grey RAL 7035	1	1/4-20	25	12	17	25	3	2	10
06245-1A26	steel	traffic red RAL 3020	1	1/4-20	25	12	17	25	3	2	10
06245-1A27	steel	colza yellow RAL 1021	1	1/4-20	25	12	17	25	3	2	10
06245-2A3	steel	black grey RAL 7021	2	5/16-18	32	15,5	19	33	3,5	2,6	14
06245-2A35	steel	light grey RAL 7035	2	5/16-18	32	15,5	19	33	3,5	2,6	14
06245-2A36	steel	traffic red RAL 3020	2	5/16-18	32	15,5	19	33	3,5	2,6	14
06245-2A37	steel	colza yellow RAL 1021	2	5/16-18	32	15,5	19	33	3,5	2,6	14
06245-3A4	steel	black grey RAL 7021	3	3/8-16	40	19	23	41	4	3	14
06245-3A45	steel	light grey RAL 7035	3	3/8-16	40	19	23	41	4	3	14
06245-3A46	steel	traffic red RAL 3020	3	3/8-16	40	19	23	41	4	3	14
06245-3A47	steel	colza yellow RAL 1021	3	3/8-16	40	19	23	41	4	3	14
06245-4A4	steel	black grey RAL 7021	4	3/8-16	50	24	31	51	5,5	4,5	14
06245-4A45	steel	light grey RAL 7035	4	3/8-16	50	24	31	51	5,5	4,5	14
06245-4A46	steel	traffic red RAL 3020	4	3/8-16	50	24	31	51	5,5	4,5	14

## Overview of items

Order No.	Component material	Colour Cap	Size	D	D1	D2	D3	H	H1	H2	T
06245-4A47	steel	colza yellow RAL 1021	4	3/8-16	50	24	31	51	5,5	4,5	14
06245-4A5	steel	black grey RAL 7021	4	1/2-13	50	24	31	51	5,5	4,5	18
06245-4A55	steel	light grey RAL 7035	4	1/2-13	50	24	31	51	5,5	4,5	18
06245-4A56	steel	traffic red RAL 3020	4	1/2-13	50	24	31	51	5,5	4,5	18
06245-4A57	steel	colza yellow RAL 1021	4	1/2-13	50	24	31	51	5,5	4,5	18
06245-01A2	stainless steel	black grey RAL 7021	1	1/4-20	25	12	17	25	3	2	10
06245-01A25	stainless steel	light grey RAL 7035	1	1/4-20	25	12	17	25	3	2	10
06245-01A26	stainless steel	traffic red RAL 3020	1	1/4-20	25	12	17	25	3	2	10
06245-01A27	stainless steel	colza yellow RAL 1021	1	1/4-20	25	12	17	25	3	2	10
06245-02A3	stainless steel	black grey RAL 7021	2	5/16-18	32	15,5	19	33	3,5	2,6	14
06245-02A35	stainless steel	light grey RAL 7035	2	5/16-18	32	15,5	19	33	3,5	2,6	14
06245-02A36	stainless steel	traffic red RAL 3020	2	5/16-18	32	15,5	19	33	3,5	2,6	14
06245-02A37	stainless steel	colza yellow RAL 1021	2	5/16-18	32	15,5	19	33	3,5	2,6	14
06245-03A4	stainless steel	black grey RAL 7021	3	3/8-16	40	19	23	41	4	3	14
06245-03A45	stainless steel	light grey RAL 7035	3	3/8-16	40	19	23	41	4	3	14
06245-03A46	stainless steel	traffic red RAL 3020	3	3/8-16	40	19	23	41	4	3	14
06245-03A47	stainless steel	colza yellow RAL 1021	3	3/8-16	40	19	23	41	4	3	14
06245-04A4	stainless steel	black grey RAL 7021	4	3/8-16	50	24	31	51	5,5	4,5	14
06245-04A45	stainless steel	light grey RAL 7035	4	3/8-16	50	24	31	51	5,5	4,5	14
06245-04A46	stainless steel	traffic red RAL 3020	4	3/8-16	50	24	31	51	5,5	4,5	14
06245-04A47	stainless steel	colza yellow RAL 1021	4	3/8-16	50	24	31	51	5,5	4,5	14
06245-04A5	stainless steel	black grey RAL 7021	4	1/2-13	50	24	31	51	5,5	4,5	18
06245-04A55	stainless steel	light grey RAL 7035	4	1/2-13	50	24	31	51	5,5	4,5	18
06245-04A56	stainless steel	traffic red RAL 3020	4	1/2-13	50	24	31	51	5,5	4,5	18
06245-04A57	stainless steel	colza yellow RAL 1021	4	1/2-13	50	24	31	51	5,5	4,5	18

## Ball Grips, external thread, inch

Order No.	Thread type	Component material	Colour Cap	D	D1	D2	D3	H	H1	H2	L	T
06245-1A2X20	external thread	steel	black grey RAL 7021	1/4-20	25	12	17	25	3	2	20	10
06245-1A25X20	external thread	steel	light grey RAL 7035	1/4-20	25	12	17	25	3	2	20	10
06245-1A26X20	external thread	steel	traffic red RAL 3020	1/4-20	25	12	17	25	3	2	20	10
06245-1A27X20	external thread	steel	colza yellow RAL 1021	1/4-20	25	12	17	25	3	2	20	10
06245-1A2X30	external thread	steel	black grey RAL 7021	1/4-20	25	12	17	25	3	2	30	10
06245-1A25X30	external thread	steel	light grey RAL 7035	1/4-20	25	12	17	25	3	2	30	10
06245-1A26X30	external thread	steel	traffic red RAL 3020	1/4-20	25	12	17	25	3	2	30	10
06245-1A27X30	external thread	steel	colza yellow RAL 1021	1/4-20	25	12	17	25	3	2	30	10
06245-2A3X20	external thread	steel	black grey RAL 7021	5/16-18	32	15,5	19	33	3,5	2,6	20	-
06245-2A35X20	external thread	steel	light grey RAL 7035	5/16-18	32	15,5	19	33	3,5	2,6	20	-
06245-2A36X20	external thread	steel	traffic red RAL 3020	5/16-18	32	15,5	19	33	3,5	2,6	20	-
06245-2A37X20	external thread	steel	colza yellow RAL 1021	5/16-18	32	15,5	19	33	3,5	2,6	20	-
06245-2A3X40	external thread	steel	black grey RAL 7021	5/16-18	32	15,5	19	33	3,5	2,6	40	-
06245-2A35X40	external thread	steel	light grey RAL 7035	5/16-18	32	15,5	19	33	3,5	2,6	40	-
06245-2A36X40	external thread	steel	traffic red RAL 3020	5/16-18	32	15,5	19	33	3,5	2,6	40	-
06245-2A37X40	external thread	steel	colza yellow RAL 1021	5/16-18	32	15,5	19	33	3,5	2,6	40	-
06245-3A4X20	external thread	steel	black grey RAL 7021	3/8-16	40	19	23	41	4	3	20	14
06245-3A45X20	external thread	steel	light grey RAL 7035	3/8-16	40	19	23	41	4	3	20	14
06245-3A46X20	external thread	steel	traffic red RAL 3020	3/8-16	40	19	23	41	4	3	20	14
06245-3A47X20	external thread	steel	colza yellow RAL 1021	3/8-16	40	19	23	41	4	3	20	14
06245-3A4X40	external thread	steel	black grey RAL 7021	3/8-16	40	19	23	41	4	3	40	14
06245-3A45X40	external thread	steel	light grey RAL 7035	3/8-16	40	19	23	41	4	3	40	14
06245-3A46X40	external thread	steel	traffic red RAL 3020	3/8-16	40	19	23	41	4	3	40	14
06245-3A47X40	external thread	steel	colza yellow RAL 1021	3/8-16	40	19	23	41	4	3	40	14
06245-4A4X20	external thread	steel	black grey RAL 7021	3/8-16	50	24	31	51	5,5	4,5	20	14
06245-4A45X20	external thread	steel	light grey RAL 7035	3/8-16	50	24	31	51	5,5	4,5	20	14
06245-4A46X20	external thread	steel	traffic red RAL 3020	3/8-16	50	24	31	51	5,5	4,5	20	14
06245-4A47X20	external thread	steel	colza yellow RAL 1021	3/8-16	50	24	31	51	5,5	4,5	20	14
06245-4A4X40	external thread	steel	black grey RAL 7021	3/8-16	50	24	31	51	5,5	4,5	40	14
06245-4A45X40	external thread	steel	light grey RAL 7035	3/8-16	50	24	31	51	5,5	4,5	40	14
06245-4A46X40	external thread	steel	traffic red RAL 3020	3/8-16	50	24	31	51	5,5	4,5	40	14
06245-4A47X40	external thread	steel	colza yellow RAL 1021	3/8-16	50	24	31	51	5,5	4,5	40	14
06245-4A5X30	external thread	steel	black grey RAL 7021	1/2-13	50	24	31	51	5,5	4,5	30	18
06245-4A55X30	external thread	steel	light grey RAL 7035	1/2-13	50	24	31	51	5,5	4,5	30	18

## Overview of items

Order No.	Thread type	Component material	Colour Cap	D	D1	D2	D3	H	H1	H2	L	T
06245-4A56X30	external thread	steel	traffic red RAL 3020	1/2-13	50	24	31	51	5,5	4,5	30	18
06245-4A57X30	external thread	steel	colza yellow RAL 1021	1/2-13	50	24	31	51	5,5	4,5	30	18
06245-4A5X60	external thread	steel	black grey RAL 7021	1/2-13	50	24	31	51	5,5	4,5	60	18
06245-4A55X60	external thread	steel	light grey RAL 7035	1/2-13	50	24	31	51	5,5	4,5	60	18
06245-4A56X60	external thread	steel	traffic red RAL 3020	1/2-13	50	24	31	51	5,5	4,5	60	18
06245-4A57X60	external thread	steel	colza yellow RAL 1021	1/2-13	50	24	31	51	5,5	4,5	60	18
06245-01A2X20	external thread	stainless steel	black grey RAL 7021	1/4-20	25	12	17	25	3	2	20	10
06245-01A25X20	external thread	stainless steel	light grey RAL 7035	1/4-20	25	12	17	25	3	2	20	10
06245-01A26X20	external thread	stainless steel	traffic red RAL 3020	1/4-20	25	12	17	25	3	2	20	10
06245-01A27X20	external thread	stainless steel	colza yellow RAL 1021	1/4-20	25	12	17	25	3	2	20	10
06245-01A2X30	external thread	stainless steel	black grey RAL 7021	1/4-20	25	12	17	25	3	2	30	10
06245-01A25X30	external thread	stainless steel	light grey RAL 7035	1/4-20	25	12	17	25	3	2	30	10
06245-01A26X30	external thread	stainless steel	traffic red RAL 3020	1/4-20	25	12	17	25	3	2	30	10
06245-01A27X30	external thread	stainless steel	colza yellow RAL 1021	1/4-20	25	12	17	25	3	2	30	10
06245-02A3X20	external thread	stainless steel	black grey RAL 7021	5/16-18	32	15,5	19	33	3,5	2,6	20	-
06245-02A35X20	external thread	stainless steel	light grey RAL 7035	5/16-18	32	15,5	19	33	3,5	2,6	20	-
06245-02A36X20	external thread	stainless steel	traffic red RAL 3020	5/16-18	32	15,5	19	33	3,5	2,6	20	-
06245-02A37X20	external thread	stainless steel	colza yellow RAL 1021	5/16-18	32	15,5	19	33	3,5	2,6	20	-
06245-02A3X40	external thread	stainless steel	black grey RAL 7021	5/16-18	32	15,5	19	33	3,5	2,6	40	-
06245-02A35X40	external thread	stainless steel	light grey RAL 7035	5/16-18	32	15,5	19	33	3,5	2,6	40	-
06245-02A36X40	external thread	stainless steel	traffic red RAL 3020	5/16-18	32	15,5	19	33	3,5	2,6	40	-
06245-02A37X40	external thread	stainless steel	colza yellow RAL 1021	5/16-18	32	15,5	19	33	3,5	2,6	40	-
06245-03A4X20	external thread	stainless steel	black grey RAL 7021	3/8-16	40	19	23	41	4	3	20	14
06245-03A45X20	external thread	stainless steel	light grey RAL 7035	3/8-16	40	19	23	41	4	3	20	14
06245-03A46X20	external thread	stainless steel	traffic red RAL 3020	3/8-16	40	19	23	41	4	3	20	14
06245-03A47X20	external thread	stainless steel	colza yellow RAL 1021	3/8-16	40	19	23	41	4	3	20	14
06245-03A4X40	external thread	stainless steel	black grey RAL 7021	3/8-16	40	19	23	41	4	3	40	14
06245-03A45X40	external thread	stainless steel	light grey RAL 7035	3/8-16	40	19	23	41	4	3	40	14
06245-03A46X40	external thread	stainless steel	traffic red RAL 3020	3/8-16	40	19	23	41	4	3	40	14
06245-03A47X40	external thread	stainless steel	colza yellow RAL 1021	3/8-16	40	19	23	41	4	3	40	14
06245-04A4X20	external thread	stainless steel	black grey RAL 7021	3/8-16	50	24	31	51	5,5	4,5	20	14
06245-04A45X20	external thread	stainless steel	light grey RAL 7035	3/8-16	50	24	31	51	5,5	4,5	20	14
06245-04A46X20	external thread	stainless steel	traffic red RAL 3020	3/8-16	50	24	31	51	5,5	4,5	20	14
06245-04A47X20	external thread	stainless steel	colza yellow RAL 1021	3/8-16	50	24	31	51	5,5	4,5	20	14
06245-04A4X40	external thread	stainless steel	black grey RAL 7021	3/8-16	50	24	31	51	5,5	4,5	40	14
06245-04A45X40	external thread	stainless steel	light grey RAL 7035	3/8-16	50	24	31	51	5,5	4,5	40	14
06245-04A46X40	external thread	stainless steel	traffic red RAL 3020	3/8-16	50	24	31	51	5,5	4,5	40	14
06245-04A47X40	external thread	stainless steel	colza yellow RAL 1021	3/8-16	50	24	31	51	5,5	4,5	40	14