

## Item description/product images



## Description

**Material:**


Steel or stainless steel 1.4404.

**Version:**

Steel electro zinc-plated.

Stainless steel bright.

## Drawings

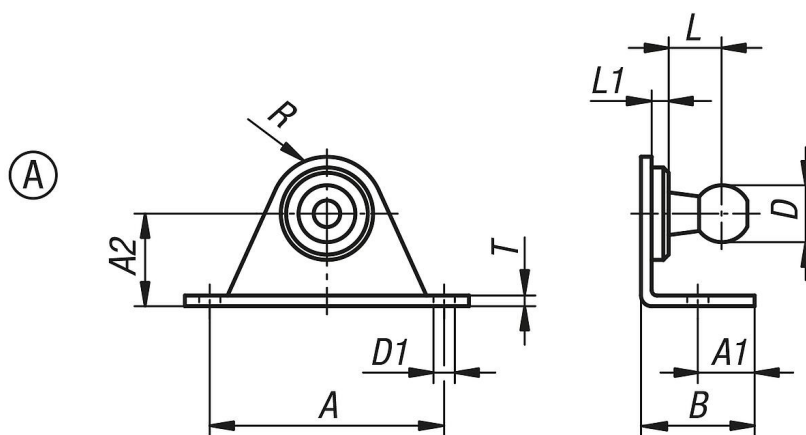

## Overview of items

| Order No.    | Main material   | Form | A  | A1   | A2 | B  | D  | D1  | L   | L1 | R  | T   | Strength N |
|--------------|-----------------|------|----|------|----|----|----|-----|-----|----|----|-----|------------|
| 27657-00810  | steel           | A    | 19 | 4,25 | 10 | 10 | 8  | 3,4 | 8   | 3  | 4  | 1,5 | 180        |
| 27657-00816  | steel           | A    | 40 | 10   | 16 | 20 | 8  | 4,3 | 8   | 3  | 10 | 2   | 500        |
| 27657-01016  | steel           | A    | 40 | 10   | 16 | 20 | 10 | 4,3 | 9   | 3  | 10 | 2   | 800        |
| 27657-01316  | steel           | A    | 40 | 10   | 16 | 20 | 13 | 4,3 | 9,5 | 3  | 10 | 2   | 1200       |
| 27657-008101 | stainless steel | A    | 19 | 4,25 | 10 | 10 | 8  | 3,4 | 8   | 3  | 4  | 1,5 | 180        |
| 27657-008161 | stainless steel | A    | 40 | 10   | 16 | 20 | 8  | 4,3 | 8   | 3  | 10 | 2   | 500        |
| 27657-010161 | stainless steel | A    | 40 | 10   | 16 | 20 | 10 | 4,3 | 9   | 3  | 10 | 2   | 800        |
| 27657-013161 | stainless steel | A    | 40 | 10   | 16 | 20 | 13 | 4,3 | 9,5 | 3  | 10 | 2   | 1200       |