

Item description/product images



Description

Material:

Neoprene with polyester tensile cord.

Note:

Endless V-belt acc. to DIN 2215 (classic V-belt). Electrically conductive acc. to ISO 1813. The V-belts are of equal length (from 1000 mm).

The V-belts have limited oil resistance. Avoid continuous contact with mineral oils and grease as these will reduce the service life.

Temperature range:

-55 °C to +70 °C.


Service life is reduced if the V-belts are exposed to continuous temperatures above +60 °C.

Assembly:

The belts need to be tensioned after installation. Re-tensioning is required after an initial run time of 15 - 20 minutes.

If, by a drive with several belts, one belt requires changing, then the full belt set should be replaced.

Drawings

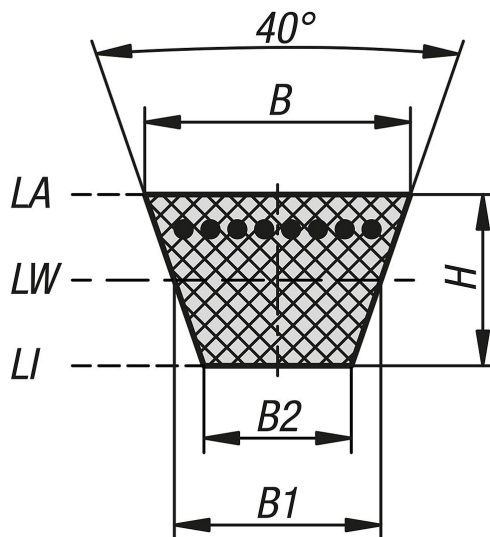

Overview of items

Order No.	Version 1	BW=Belt width	B1	B2	H	External length LA	Internal length LI	Effective length LW
22071-10425	Type 10/Z	10	8,5	6,1	6	463	425	448
22071-10450	Type 10/Z	10	8,5	6,1	6	488	450	473
22071-10475	Type 10/Z	10	8,5	6,1	6	513	475	498
22071-10483	Type 10/Z	10	8,5	6,1	6	521	483	506
22071-10500	Type 10/Z	10	8,5	6,1	6	538	500	523
22071-10508	Type 10/Z	10	8,5	6,1	6	546	508	531
22071-10520	Type 10/Z	10	8,5	6,1	6	558	520	543
22071-10530	Type 10/Z	10	8,5	6,1	6	568	530	553

Overview of items

Order No.	Version 1	BW=Belt width	B1	B2	H	External length LA	Internal length LI	Effective length LW
22071-10560	Type 10/Z	10	8,5	6,1	6	598	560	583
22071-10575	Type 10/Z	10	8,5	6,1	6	613	575	598
22071-10584	Type 10/Z	10	8,5	6,1	6	622	584	607
22071-10600	Type 10/Z	10	8,5	6,1	6	638	600	623
22071-10610	Type 10/Z	10	8,5	6,1	6	648	610	633
22071-10630	Type 10/Z	10	8,5	6,1	6	668	630	653
22071-10650	Type 10/Z	10	8,5	6,1	6	688	650	673
22071-10670	Type 10/Z	10	8,5	6,1	6	708	670	693
22071-10686	Type 10/Z	10	8,5	6,1	6	724	686	709
22071-10700	Type 10/Z	10	8,5	6,1	6	738	700	723
22071-10710	Type 10/Z	10	8,5	6,1	6	748	710	733
22071-10725	Type 10/Z	10	8,5	6,1	6	763	725	748
22071-10730	Type 10/Z	10	8,5	6,1	6	768	730	753
22071-10750	Type 10/Z	10	8,5	6,1	6	788	750	773
22071-10765	Type 10/Z	10	8,5	6,1	6	803	765	788
22071-10775	Type 10/Z	10	8,5	6,1	6	813	775	798
22071-10800	Type 10/Z	10	8,5	6,1	6	838	800	823
22071-10813	Type 10/Z	10	8,5	6,1	6	851	813	836
22071-10820	Type 10/Z	10	8,5	6,1	6	858	820	843
22071-10825	Type 10/Z	10	8,5	6,1	6	863	825	848
22071-10838	Type 10/Z	10	8,5	6,1	6	876	838	861
22071-10850	Type 10/Z	10	8,5	6,1	6	888	850	873
22071-10865	Type 10/Z	10	8,5	6,1	6	903	865	888
22071-10875	Type 10/Z	10	8,5	6,1	6	913	875	898
22071-10889	Type 10/Z	10	8,5	6,1	6	927	889	912
22071-10900	Type 10/Z	10	8,5	6,1	6	938	900	923
22071-10914	Type 10/Z	10	8,5	6,1	6	952	914	937
22071-10925	Type 10/Z	10	8,5	6,1	6	963	925	948
22071-10953	Type 10/Z	10	8,5	6,1	6	991	953	976
22071-10990	Type 10/Z	10	8,5	6,1	6	1028	990	1013
22071-11000	Type 10/Z	10	8,5	6,1	6	1038	1000	1023
22071-11016	Type 10/Z	10	8,5	6,1	6	1054	1016	1039
22071-11030	Type 10/Z	10	8,5	6,1	6	1068	1030	1053
22071-11041	Type 10/Z	10	8,5	6,1	6	1079	1041	1064
22071-11060	Type 10/Z	10	8,5	6,1	6	1098	1060	1083
22071-11080	Type 10/Z	10	8,5	6,1	6	1118	1080	1103
22071-11105	Type 10/Z	10	8,5	6,1	6	1143	1105	1128
22071-11120	Type 10/Z	10	8,5	6,1	6	1158	1120	1143
22071-11150	Type 10/Z	10	8,5	6,1	6	1188	1150	1173
22071-11170	Type 10/Z	10	8,5	6,1	6	1208	1170	1193
22071-11180	Type 10/Z	10	8,5	6,1	6	1218	1180	1203
22071-11194	Type 10/Z	10	8,5	6,1	6	1232	1194	1217
22071-11215	Type 10/Z	10	8,5	6,1	6	1253	1215	1238
22071-11230	Type 10/Z	10	8,5	6,1	6	1268	1230	1253
22071-11250	Type 10/Z	10	8,5	6,1	6	1288	1250	1273
22071-11270	Type 10/Z	10	8,5	6,1	6	1308	1270	1293
22071-11295	Type 10/Z	10	8,5	6,1	6	1333	1295	1318
22071-11320	Type 10/Z	10	8,5	6,1	6	1358	1320	1343
22071-11346	Type 10/Z	10	8,5	6,1	6	1384	1346	1369
22071-11371	Type 10/Z	10	8,5	6,1	6	1409	1371	1394
22071-11400	Type 10/Z	10	8,5	6,1	6	1438	1400	1423
22071-11450	Type 10/Z	10	8,5	6,1	6	1488	1450	1473
22071-11475	Type 10/Z	10	8,5	6,1	6	1513	1475	1498
22071-11500	Type 10/Z	10	8,5	6,1	6	1538	1500	1523
22071-11550	Type 10/Z	10	8,5	6,1	6	1588	1550	1573
22071-11575	Type 10/Z	10	8,5	6,1	6	1613	1575	1598
22071-11600	Type 10/Z	10	8,5	6,1	6	1638	1600	1623
22071-11680	Type 10/Z	10	8,5	6,1	6	1718	1680	1703
22071-11700	Type 10/Z	10	8,5	6,1	6	1738	1700	1723
22071-11750	Type 10/Z	10	8,5	6,1	6	1788	1750	1773
22071-11800	Type 10/Z	10	8,5	6,1	6	1838	1800	1823
22071-11900	Type 10/Z	10	8,5	6,1	6	1938	1900	1923
22071-11975	Type 10/Z	10	8,5	6,1	6	2013	1975	1998
22071-12000	Type 10/Z	10	8,5	6,1	6	2038	2000	2023
22071-12080	Type 10/Z	10	8,5	6,1	6	2118	2080	2103

Overview of items

Order No.	Version 1	BW=Belt width	B1	B2	H	External length LA	Internal length LI	Effective length LW
22071-12120	Type 10/Z	10	8,5	6,1	6	2158	2120	2143
22071-12360	Type 10/Z	10	8,5	6,1	6	2398	2360	2383
22071-20457	Type 13/A	13	11	7,8	8	495	457	480
22071-20483	Type 13/A	13	11	7,8	8	521	483	506
22071-20508	Type 13/A	13	11	7,8	8	546	508	531
22071-20535	Type 13/A	13	11	7,8	8	573	535	558
22071-20560	Type 13/A	13	11	7,8	8	598	560	583
22071-20580	Type 13/A	13	11	7,8	8	618	580	603
22071-20600	Type 13/A	13	11	7,8	8	638	600	623
22071-20630	Type 13/A	13	11	7,8	8	668	630	653
22071-20660	Type 13/A	13	11	7,8	8	698	660	683
22071-20670	Type 13/A	13	11	7,8	8	708	670	693
22071-20690	Type 13/A	13	11	7,8	8	728	690	713
22071-20710	Type 13/A	13	11	7,8	8	748	710	733
22071-20730	Type 13/A	13	11	7,8	8	768	730	753
22071-20750	Type 13/A	13	11	7,8	8	788	750	773
22071-20767	Type 13/A	13	11	7,8	8	805	767	790
22071-20780	Type 13/A	13	11	7,8	8	818	780	803
22071-20787	Type 13/A	13	11	7,8	8	825	787	810
22071-20800	Type 13/A	13	11	7,8	8	838	800	823
22071-20813	Type 13/A	13	11	7,8	8	851	813	836
22071-20825	Type 13/A	13	11	7,8	8	863	825	848
22071-20838	Type 13/A	13	11	7,8	8	876	838	861
22071-20850	Type 13/A	13	11	7,8	8	888	850	873
22071-20855	Type 13/A	13	11	7,8	8	893	855	878
22071-20875	Type 13/A	13	11	7,8	8	913	875	898
22071-20889	Type 13/A	13	11	7,8	8	927	889	912
22071-20900	Type 13/A	13	11	7,8	8	938	900	923
22071-20914	Type 13/A	13	11	7,8	8	952	914	937
22071-20925	Type 13/A	13	11	7,8	8	963	925	948
22071-20939	Type 13/A	13	11	7,8	8	977	939	962
22071-20950	Type 13/A	13	11	7,8	8	988	950	973
22071-20965	Type 13/A	13	11	7,8	8	1003	965	988
22071-20975	Type 13/A	13	11	7,8	8	1013	975	998
22071-20991	Type 13/A	13	11	7,8	8	1029	991	1014
22071-21000	Type 13/A	13	11	7,8	8	1038	1000	1023
22071-21016	Type 13/A	13	11	7,8	8	1054	1016	1039
22071-21030	Type 13/A	13	11	7,8	8	1068	1030	1053
22071-21041	Type 13/A	13	11	7,8	8	1079	1041	1064
22071-21060	Type 13/A	13	11	7,8	8	1098	1060	1083
22071-21075	Type 13/A	13	11	7,8	8	1113	1075	1098
22071-21090	Type 13/A	13	11	7,8	8	1128	1090	1113
22071-21105	Type 13/A	13	11	7,8	8	1143	1105	1128
22071-21120	Type 13/A	13	11	7,8	8	1158	1120	1143
22071-21143	Type 13/A	13	11	7,8	8	1181	1143	1166
22071-21168	Type 13/A	13	11	7,8	8	1206	1168	1191
22071-21180	Type 13/A	13	11	7,8	8	1218	1180	1203
22071-21200	Type 13/A	13	11	7,8	8	1238	1200	1223
22071-21220	Type 13/A	13	11	7,8	8	1258	1220	1243
22071-21240	Type 13/A	13	11	7,8	8	1278	1240	1263
22071-21250	Type 13/A	13	11	7,8	8	1288	1250	1273
22071-21270	Type 13/A	13	11	7,8	8	1308	1270	1293
22071-21300	Type 13/A	13	11	7,8	8	1338	1300	1323
22071-21320	Type 13/A	13	11	7,8	8	1358	1320	1343
22071-21346	Type 13/A	13	11	7,8	8	1384	1346	1369
22071-21372	Type 13/A	13	11	7,8	8	1410	1372	1395
22071-21400	Type 13/A	13	11	7,8	8	1438	1400	1423
22071-21422	Type 13/A	13	11	7,8	8	1460	1422	1445
22071-21448	Type 13/A	13	11	7,8	8	1486	1448	1471
22071-21475	Type 13/A	13	11	7,8	8	1513	1475	1498
22071-21500	Type 13/A	13	11	7,8	8	1538	1500	1523
22071-21525	Type 13/A	13	11	7,8	8	1563	1525	1548
22071-21550	Type 13/A	13	11	7,8	8	1588	1550	1573
22071-21575	Type 13/A	13	11	7,8	8	1613	1575	1598
22071-21600	Type 13/A	13	11	7,8	8	1638	1600	1623

Overview of items

Order No.	Version 1	BW=Belt width	B1	B2	H	External length LA	Internal length LI	Effective length LW
22071-21625	Type 13/A	13	11	7,8	8	1663	1625	1648
22071-21651	Type 13/A	13	11	7,8	8	1689	1651	1674
22071-21676	Type 13/A	13	11	7,8	8	1714	1676	1699
22071-21700	Type 13/A	13	11	7,8	8	1738	1700	1723
22071-21725	Type 13/A	13	11	7,8	8	1763	1725	1748
22071-21750	Type 13/A	13	11	7,8	8	1788	1750	1773
22071-21780	Type 13/A	13	11	7,8	8	1818	1780	1803
22071-21800	Type 13/A	13	11	7,8	8	1838	1800	1823
22071-21825	Type 13/A	13	11	7,8	8	1863	1825	1848
22071-21854	Type 13/A	13	11	7,8	8	1892	1854	1877
22071-21880	Type 13/A	13	11	7,8	8	1918	1880	1903
22071-21900	Type 13/A	13	11	7,8	8	1938	1900	1923
22071-21930	Type 13/A	13	11	7,8	8	1968	1930	1953
22071-21956	Type 13/A	13	11	7,8	8	1994	1956	1979
22071-21980	Type 13/A	13	11	7,8	8	2018	1980	2003
22071-22000	Type 13/A	13	11	7,8	8	2038	2000	2023
22071-22010	Type 13/A	13	11	7,8	8	2048	2010	2033
22071-22030	Type 13/A	13	11	7,8	8	2068	2030	2053
22071-22040	Type 13/A	13	11	7,8	8	2078	2040	2063
22071-22057	Type 13/A	13	11	7,8	8	2095	2057	2080
22071-22083	Type 13/A	13	11	7,8	8	2121	2083	2106
22071-22100	Type 13/A	13	11	7,8	8	2138	2100	2123
22071-22120	Type 13/A	13	11	7,8	8	2158	2120	2143
22071-22134	Type 13/A	13	11	7,8	8	2172	2134	2157
22071-22150	Type 13/A	13	11	7,8	8	2188	2150	2173
22071-22184	Type 13/A	13	11	7,8	8	2222	2184	2207
22071-22200	Type 13/A	13	11	7,8	8	2238	2200	2223
22071-22240	Type 13/A	13	11	7,8	8	2278	2240	2263
22071-22261	Type 13/A	13	11	7,8	8	2299	2261	2284
22071-22285	Type 13/A	13	11	7,8	8	2323	2285	2308
22071-22311	Type 13/A	13	11	7,8	8	2349	2311	2334
22071-22337	Type 13/A	13	11	7,8	8	2375	2337	2360
22071-22360	Type 13/A	13	11	7,8	8	2398	2360	2383
22071-22388	Type 13/A	13	11	7,8	8	2426	2388	2411
22071-22413	Type 13/A	13	11	7,8	8	2451	2413	2436
22071-22435	Type 13/A	13	11	7,8	8	2473	2435	2458
22071-22475	Type 13/A	13	11	7,8	8	2513	2475	2498
22071-22500	Type 13/A	13	11	7,8	8	2538	2500	2523
22071-22540	Type 13/A	13	11	7,8	8	2578	2540	2563
22071-22591	Type 13/A	13	11	7,8	8	2629	2591	2614
22071-22616	Type 13/A	13	11	7,8	8	2654	2616	2639
22071-22650	Type 13/A	13	11	7,8	8	2688	2650	2673
22071-22667	Type 13/A	13	11	7,8	8	2705	2667	2690
22071-22730	Type 13/A	13	11	7,8	8	2768	2730	2753
22071-22743	Type 13/A	13	11	7,8	8	2781	2743	2766
22071-22800	Type 13/A	13	11	7,8	8	2838	2800	2823
22071-22840	Type 13/A	13	11	7,8	8	2878	2840	2863
22071-22946	Type 13/A	13	11	7,8	8	2984	2946	2969
22071-23000	Type 13/A	13	11	7,8	8	3038	3000	3023
22071-23050	Type 13/A	13	11	7,8	8	3088	3050	3073
22071-23150	Type 13/A	13	11	7,8	8	3188	3150	3173
22071-23250	Type 13/A	13	11	7,8	8	3288	3250	3273
22071-23350	Type 13/A	13	11	7,8	8	3388	3350	3373
22071-23404	Type 13/A	13	11	7,8	8	3442	3404	3427
22071-23454	Type 13/A	13	11	7,8	8	3492	3454	3477
22071-23550	Type 13/A	13	11	7,8	8	3588	3550	3573
22071-23650	Type 13/A	13	11	7,8	8	3688	3650	3673
22071-23683	Type 13/A	13	11	7,8	8	3721	3683	3706
22071-24000	Type 13/A	13	11	7,8	8	4038	4000	4023
22071-24572	Type 13/A	13	11	7,8	8	4610	4572	4595
22071-25000	Type 13/A	13	11	7,8	8	5038	5000	5023
22071-30615	Type 17/B	17	14	9,4	11	653	615	638
22071-30635	Type 17/B	17	14	9,4	11	673	635	658
22071-30650	Type 17/B	17	14	9,4	11	688	650	673
22071-30670	Type 17/B	17	14	9,4	11	708	670	693

Overview of items

Order No.	Version 1	BW=Belt width	B1	B2	H	External length LA	Internal length LI	Effective length LW
22071-30686	Type 17/B	17	14	9,4	11	724	686	709
22071-30710	Type 17/B	17	14	9,4	11	748	710	733
22071-30725	Type 17/B	17	14	9,4	11	763	725	748
22071-30737	Type 17/B	17	14	9,4	11	775	737	760
22071-30750	Type 17/B	17	14	9,4	11	788	750	773
22071-30762	Type 17/B	17	14	9,4	11	800	762	785
22071-30775	Type 17/B	17	14	9,4	11	813	775	798
22071-30788	Type 17/B	17	14	9,4	11	826	788	811
22071-30800	Type 17/B	17	14	9,4	11	838	800	823
22071-30813	Type 17/B	17	14	9,4	11	851	813	836
22071-30826	Type 17/B	17	14	9,4	11	864	826	849
22071-30838	Type 17/B	17	14	9,4	11	876	838	861
22071-30850	Type 17/B	17	14	9,4	11	888	850	873
22071-30864	Type 17/B	17	14	9,4	11	902	864	887
22071-30875	Type 17/B	17	14	9,4	11	913	875	898
22071-30889	Type 17/B	17	14	9,4	11	927	889	912
22071-30900	Type 17/B	17	14	9,4	11	938	900	923
22071-30915	Type 17/B	17	14	9,4	11	953	915	938
22071-30925	Type 17/B	17	14	9,4	11	963	925	948
22071-30940	Type 17/B	17	14	9,4	11	978	940	963
22071-30950	Type 17/B	17	14	9,4	11	988	950	973
22071-30965	Type 17/B	17	14	9,4	11	1003	965	988
22071-30975	Type 17/B	17	14	9,4	11	1013	975	998
22071-30991	Type 17/B	17	14	9,4	11	1029	991	1014
22071-31000	Type 17/B	17	14	9,4	11	1038	1000	1023
22071-31017	Type 17/B	17	14	9,4	11	1055	1017	1040
22071-31030	Type 17/B	17	14	9,4	11	1068	1030	1053
22071-31040	Type 17/B	17	14	9,4	11	1078	1040	1063
22071-31050	Type 17/B	17	14	9,4	11	1088	1050	1073
22071-31060	Type 17/B	17	14	9,4	11	1098	1060	1083
22071-31075	Type 17/B	17	14	9,4	11	1113	1075	1098
22071-31090	Type 17/B	17	14	9,4	11	1128	1090	1113
22071-31100	Type 17/B	17	14	9,4	11	1138	1100	1123
22071-31120	Type 17/B	17	14	9,4	11	1158	1120	1143
22071-31150	Type 17/B	17	14	9,4	11	1188	1150	1173
22071-31175	Type 17/B	17	14	9,4	11	1213	1175	1198
22071-31180	Type 17/B	17	14	9,4	11	1218	1180	1203
22071-31200	Type 17/B	17	14	9,4	11	1238	1200	1223
22071-31215	Type 17/B	17	14	9,4	11	1253	1215	1238
22071-31225	Type 17/B	17	14	9,4	11	1263	1225	1248
22071-31250	Type 17/B	17	14	9,4	11	1288	1250	1273
22071-31270	Type 17/B	17	14	9,4	11	1308	1270	1293
22071-31300	Type 17/B	17	14	9,4	11	1338	1300	1323
22071-31320	Type 17/B	17	14	9,4	11	1358	1320	1343
22071-31335	Type 17/B	17	14	9,4	11	1373	1335	1358
22071-31350	Type 17/B	17	14	9,4	11	1388	1350	1373
22071-31360	Type 17/B	17	14	9,4	11	1398	1360	1383
22071-31372	Type 17/B	17	14	9,4	11	1410	1372	1395
22071-31400	Type 17/B	17	14	9,4	11	1438	1400	1423
22071-31422	Type 17/B	17	14	9,4	11	1460	1422	1445
22071-31450	Type 17/B	17	14	9,4	11	1488	1450	1473
22071-31470	Type 17/B	17	14	9,4	11	1508	1470	1493
22071-31500	Type 17/B	17	14	9,4	11	1538	1500	1523
22071-31525	Type 17/B	17	14	9,4	11	1563	1525	1548
22071-31550	Type 17/B	17	14	9,4	11	1588	1550	1573
22071-31575	Type 17/B	17	14	9,4	11	1613	1575	1598
22071-31600	Type 17/B	17	14	9,4	11	1638	1600	1623
22071-31625	Type 17/B	17	14	9,4	11	1663	1625	1648
22071-31650	Type 17/B	17	14	9,4	11	1688	1650	1673
22071-31676	Type 17/B	17	14	9,4	11	1714	1676	1699
22071-31700	Type 17/B	17	14	9,4	11	1738	1700	1723
22071-31725	Type 17/B	17	14	9,4	11	1763	1725	1748
22071-31750	Type 17/B	17	14	9,4	11	1788	1750	1773
22071-31761	Type 17/B	17	14	9,4	11	1799	1761	1784
22071-31775	Type 17/B	17	14	9,4	11	1813	1775	1798

Overview of items

Order No.	Version 1	BW=Belt width	B1	B2	H	External length LA	Internal length LI	Effective length LW
22071-31800	Type 17/B	17	14	9,4	11	1838	1800	1823
22071-31829	Type 17/B	17	14	9,4	11	1867	1829	1852
22071-31850	Type 17/B	17	14	9,4	11	1888	1850	1873
22071-31880	Type 17/B	17	14	9,4	11	1918	1880	1903
22071-31900	Type 17/B	17	14	9,4	11	1938	1900	1923
22071-31930	Type 17/B	17	14	9,4	11	1968	1930	1953
22071-31950	Type 17/B	17	14	9,4	11	1988	1950	1973
22071-31981	Type 17/B	17	14	9,4	11	2019	1981	2004
22071-32000	Type 17/B	17	14	9,4	11	2038	2000	2023
22071-32030	Type 17/B	17	14	9,4	11	2068	2030	2053
22071-32060	Type 17/B	17	14	9,4	11	2098	2060	2083
22071-32083	Type 17/B	17	14	9,4	11	2121	2083	2106
22071-32108	Type 17/B	17	14	9,4	11	2146	2108	2131
22071-32120	Type 17/B	17	14	9,4	11	2158	2120	2143
22071-32134	Type 17/B	17	14	9,4	11	2172	2134	2157
22071-32160	Type 17/B	17	14	9,4	11	2198	2160	2183
22071-32184	Type 17/B	17	14	9,4	11	2222	2184	2207
22071-32200	Type 17/B	17	14	9,4	11	2238	2200	2223
22071-32210	Type 17/B	17	14	9,4	11	2248	2210	2233
22071-32240	Type 17/B	17	14	9,4	11	2278	2240	2263
22071-32261	Type 17/B	17	14	9,4	11	2299	2261	2284
22071-32286	Type 17/B	17	14	9,4	11	2324	2286	2309
22071-32300	Type 17/B	17	14	9,4	11	2338	2300	2323
22071-32337	Type 17/B	17	14	9,4	11	2375	2337	2360
22071-32360	Type 17/B	17	14	9,4	11	2398	2360	2383
22071-32388	Type 17/B	17	14	9,4	11	2426	2388	2411
22071-32400	Type 17/B	17	14	9,4	11	2438	2400	2423
22071-32413	Type 17/B	17	14	9,4	11	2451	2413	2436
22071-32438	Type 17/B	17	14	9,4	11	2476	2438	2461
22071-32450	Type 17/B	17	14	9,4	11	2488	2450	2473
22071-32465	Type 17/B	17	14	9,4	11	2503	2465	2488
22071-32500	Type 17/B	17	14	9,4	11	2538	2500	2523
22071-32515	Type 17/B	17	14	9,4	11	2553	2515	2538
22071-32540	Type 17/B	17	14	9,4	11	2578	2540	2563
22071-32565	Type 17/B	17	14	9,4	11	2603	2565	2588
22071-32600	Type 17/B	17	14	9,4	11	2638	2600	2623
22071-32616	Type 17/B	17	14	9,4	11	2654	2616	2639
22071-32650	Type 17/B	17	14	9,4	11	2688	2650	2673
22071-32667	Type 17/B	17	14	9,4	11	2705	2667	2690
22071-32700	Type 17/B	17	14	9,4	11	2738	2700	2723
22071-32718	Type 17/B	17	14	9,4	11	2756	2718	2741
22071-32750	Type 17/B	17	14	9,4	11	2788	2750	2773
22071-32800	Type 17/B	17	14	9,4	11	2838	2800	2823
22071-32840	Type 17/B	17	14	9,4	11	2878	2840	2863
22071-32900	Type 17/B	17	14	9,4	11	2938	2900	2923
22071-32921	Type 17/B	17	14	9,4	11	2959	2921	2944
22071-32950	Type 17/B	17	14	9,4	11	2988	2950	2973
22071-33000	Type 17/B	17	14	9,4	11	3038	3000	3023
22071-33050	Type 17/B	17	14	9,4	11	3088	3050	3073
22071-33100	Type 17/B	17	14	9,4	11	3138	3100	3123
22071-33150	Type 17/B	17	14	9,4	11	3188	3150	3173
22071-33175	Type 17/B	17	14	9,4	11	3213	3175	3198
22071-33200	Type 17/B	17	14	9,4	11	3238	3200	3223
22071-33250	Type 17/B	17	14	9,4	11	3288	3250	3273
22071-33302	Type 17/B	17	14	9,4	11	3340	3302	3325
22071-33350	Type 17/B	17	14	9,4	11	3388	3350	3373
22071-33378	Type 17/B	17	14	9,4	11	3416	3378	3401
22071-33404	Type 17/B	17	14	9,4	11	3442	3404	3427
22071-33450	Type 17/B	17	14	9,4	11	3488	3450	3473
22071-33505	Type 17/B	17	14	9,4	11	3543	3505	3528
22071-33550	Type 17/B	17	14	9,4	11	3588	3550	3573
22071-33581	Type 17/B	17	14	9,4	11	3619	3581	3604
22071-33600	Type 17/B	17	14	9,4	11	3638	3600	3623
22071-33658	Type 17/B	17	14	9,4	11	3696	3658	3681
22071-33700	Type 17/B	17	14	9,4	11	3738	3700	3723

Overview of items

Order No.	Version 1	BW=Belt width	B1	B2	H	External length LA	Internal length LI	Effective length LW
22071-33750	Type 17/B	17	14	9,4	11	3788	3750	3773
22071-33810	Type 17/B	17	14	9,4	11	3848	3810	3833
22071-33895	Type 17/B	17	14	9,4	11	3933	3895	3918
22071-33861	Type 17/B	17	14	9,4	11	3899	3861	3884
22071-33912	Type 17/B	17	14	9,4	11	3950	3912	3935
22071-33950	Type 17/B	17	14	9,4	11	3988	3950	3973
22071-34000	Type 17/B	17	14	9,4	11	4038	4000	4023
22071-34115	Type 17/B	17	14	9,4	11	4153	4115	4138
22071-34200	Type 17/B	17	14	9,4	11	4238	4200	4223
22071-34250	Type 17/B	17	14	9,4	11	4288	4250	4273
22071-34378	Type 17/B	17	14	9,4	11	4416	4378	4401
22071-34394	Type 17/B	17	14	9,4	11	4432	4394	4417
22071-34450	Type 17/B	17	14	9,4	11	4488	4450	4473
22071-34500	Type 17/B	17	14	9,4	11	4538	4500	4523
22071-34572	Type 17/B	17	14	9,4	11	4610	4572	4595
22071-34699	Type 17/B	17	14	9,4	11	4737	4699	4722
22071-34750	Type 17/B	17	14	9,4	11	4788	4750	4773
22071-34826	Type 17/B	17	14	9,4	11	4864	4826	4849
22071-34877	Type 17/B	17	14	9,4	11	4915	4877	4900
22071-34953	Type 17/B	17	14	9,4	11	4991	4953	4976
22071-35000	Type 17/B	17	14	9,4	11	5038	5000	5023