

Item description/product images



Description

Material:

Steel.

Version:

Roller rim nickel-plated.

Note:

The roller rim and ball bearing are held firmly held together by a circlip.

The load ratings refer to the ball bearing.

On request:

Heavy-duty versions.


Roller rim black oxidised or black polyacetal.

Stainless steel guide rollers.

Accessory:

Matching pins 95102.

Drawings

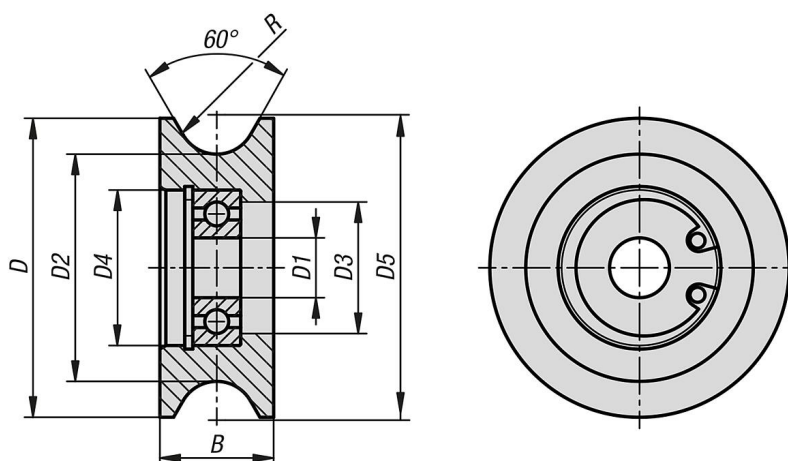

Overview of items

Guide rollers, steel, concave

Order No.	B	D	D1	D2	D3	D4	D5	Ball bearing	R	Dynamic load rating N	Static load rating N
95101-10-003012	12	30	6	22	13	17	31	606-ZZ	4,5	2260	840
95101-10-004016	16	40	8	30	18	22	41	608-ZZ	5,5	3300	1360
95101-10-005019	19	50	10	38	22	26	51	6000-ZZ	6,5	4550	1970
95101-10-006023	23	60	12	44	26	32	61	6201-ZZ	8,5	6800	3050
95101-10-007028	28	70	15	51	29	35	72	6202-ZZ	10,5	7650	3700

Overview of items
