




Mounting instructions 06894

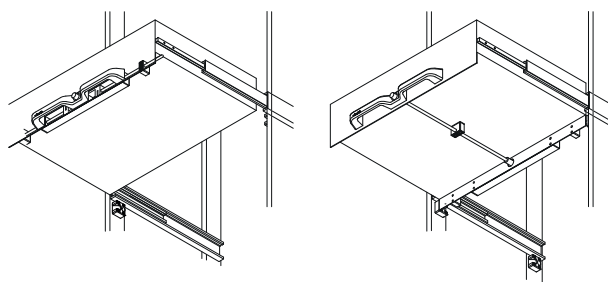


06894-060
06894-120

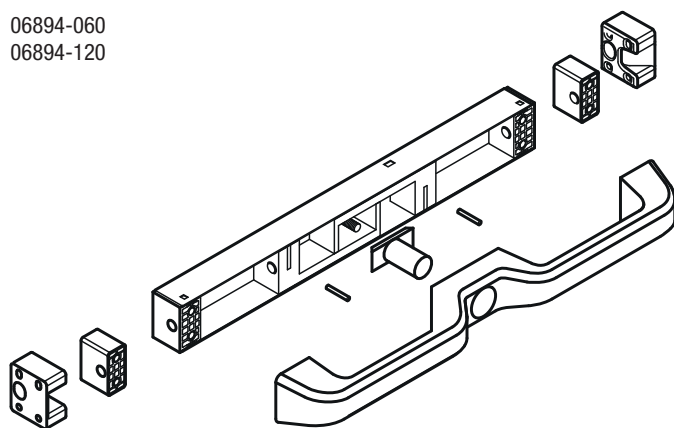

06894-91

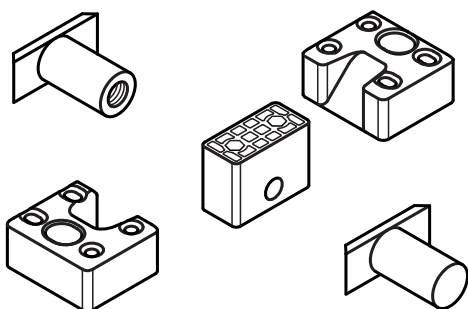


06894-90050
06894-900750
06894-910500
06894-910750

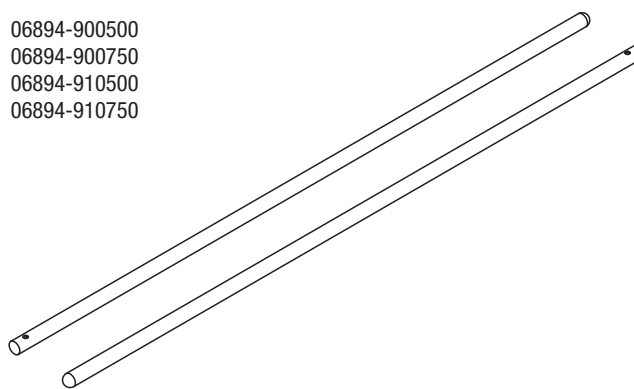


06894-060 + 06894-900500 or 06894-910500

06894-120 + 06894-900750 or 06894-910750

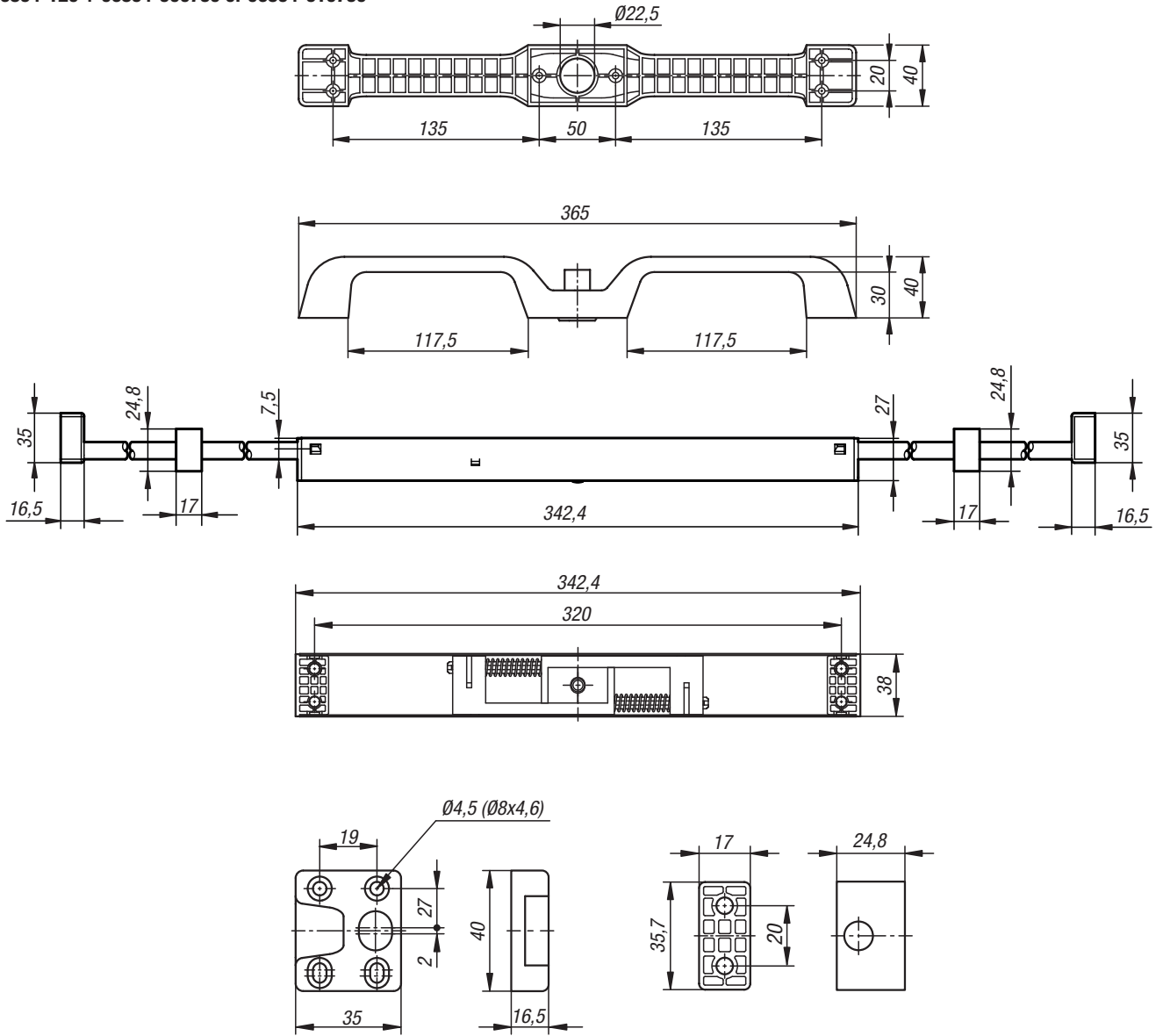



06894-060 + 06894-900500
 or 06894-910500 + 06894-91
 06894-120 + 06894-900750
 or 06894-910750



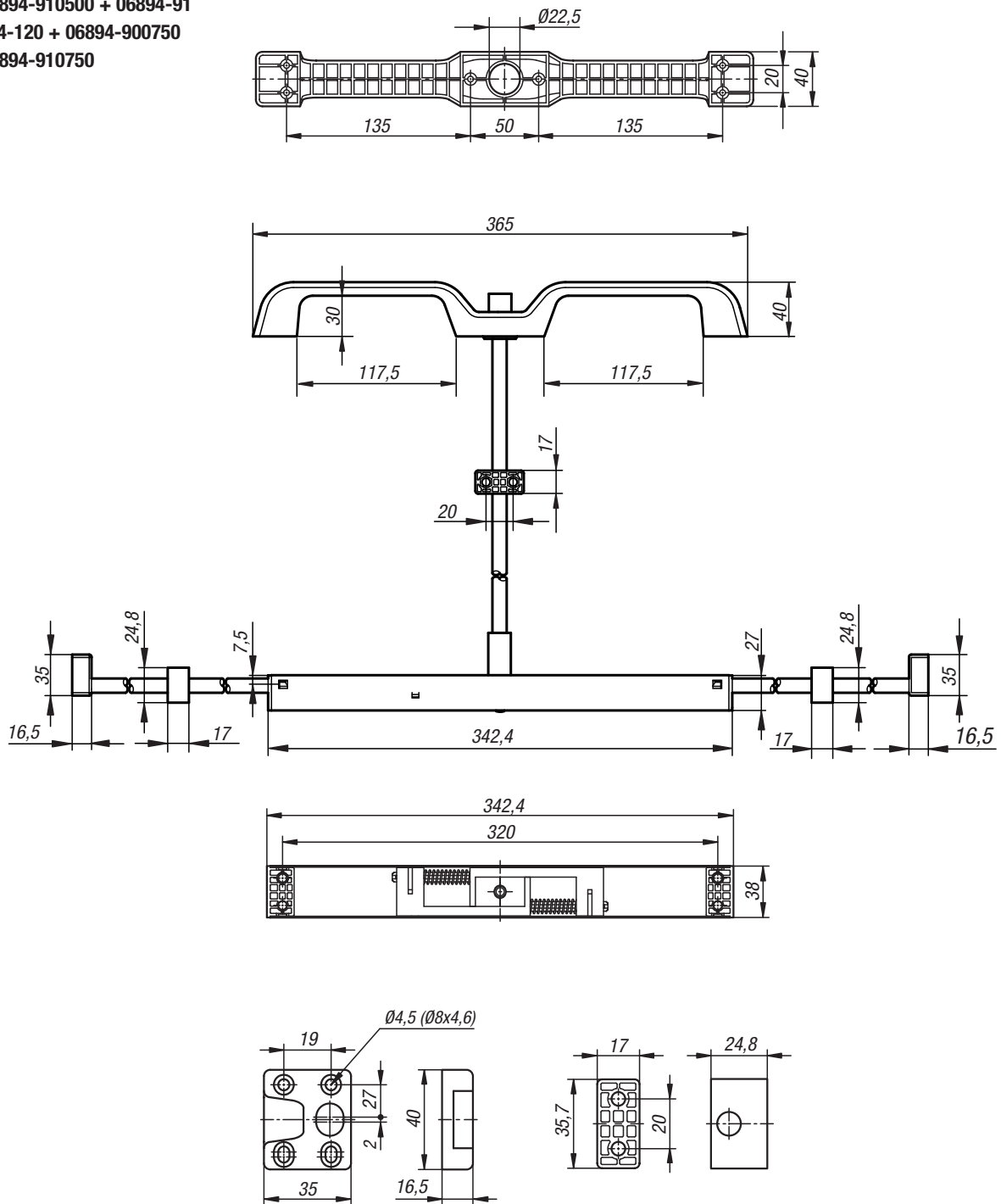




Retention and latching



Locking in the open position cannot be used for over extension slides (more that 100% extension).

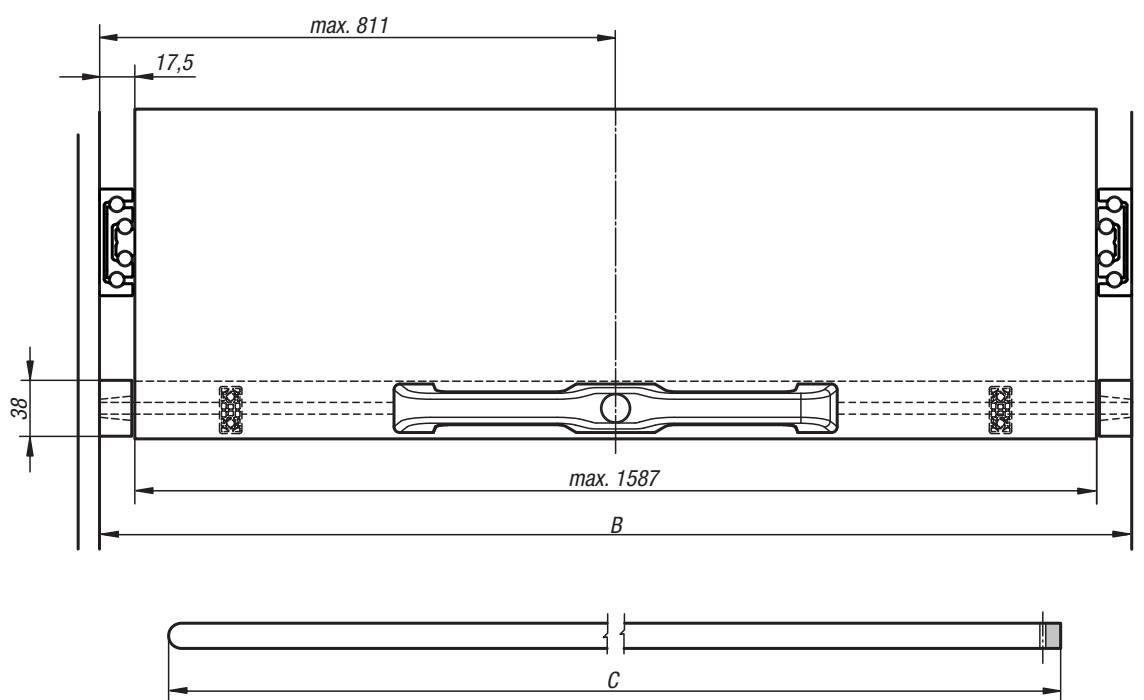


 $C = (B - 122,3) / 2$
 $C < 500$
 $C > 500$

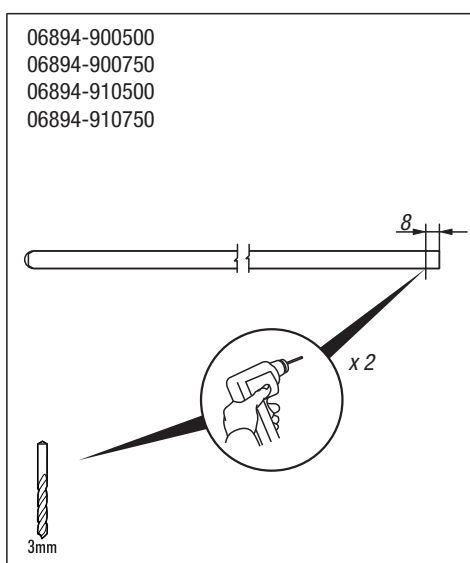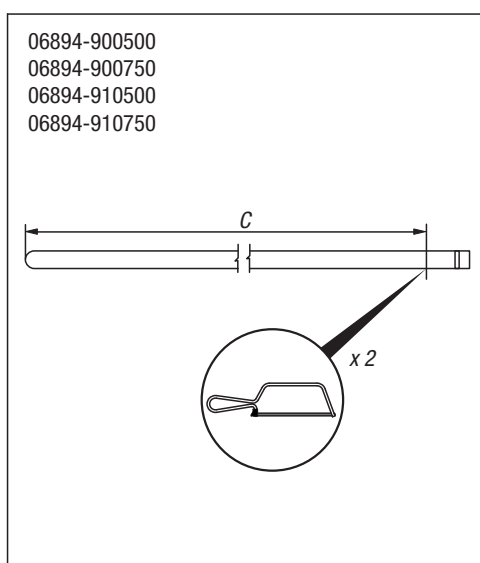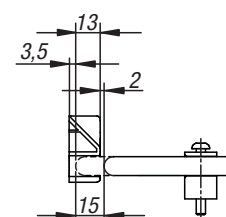

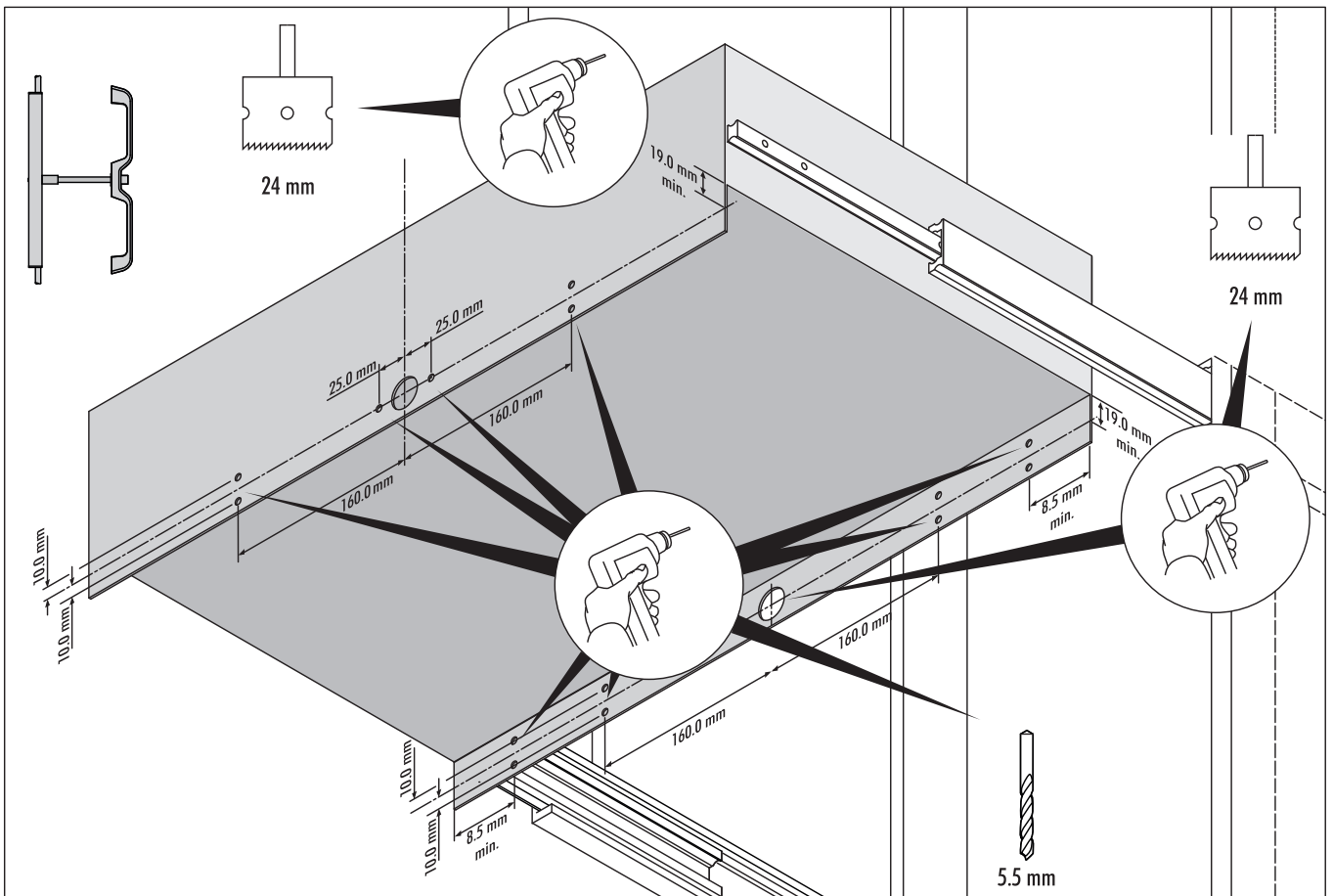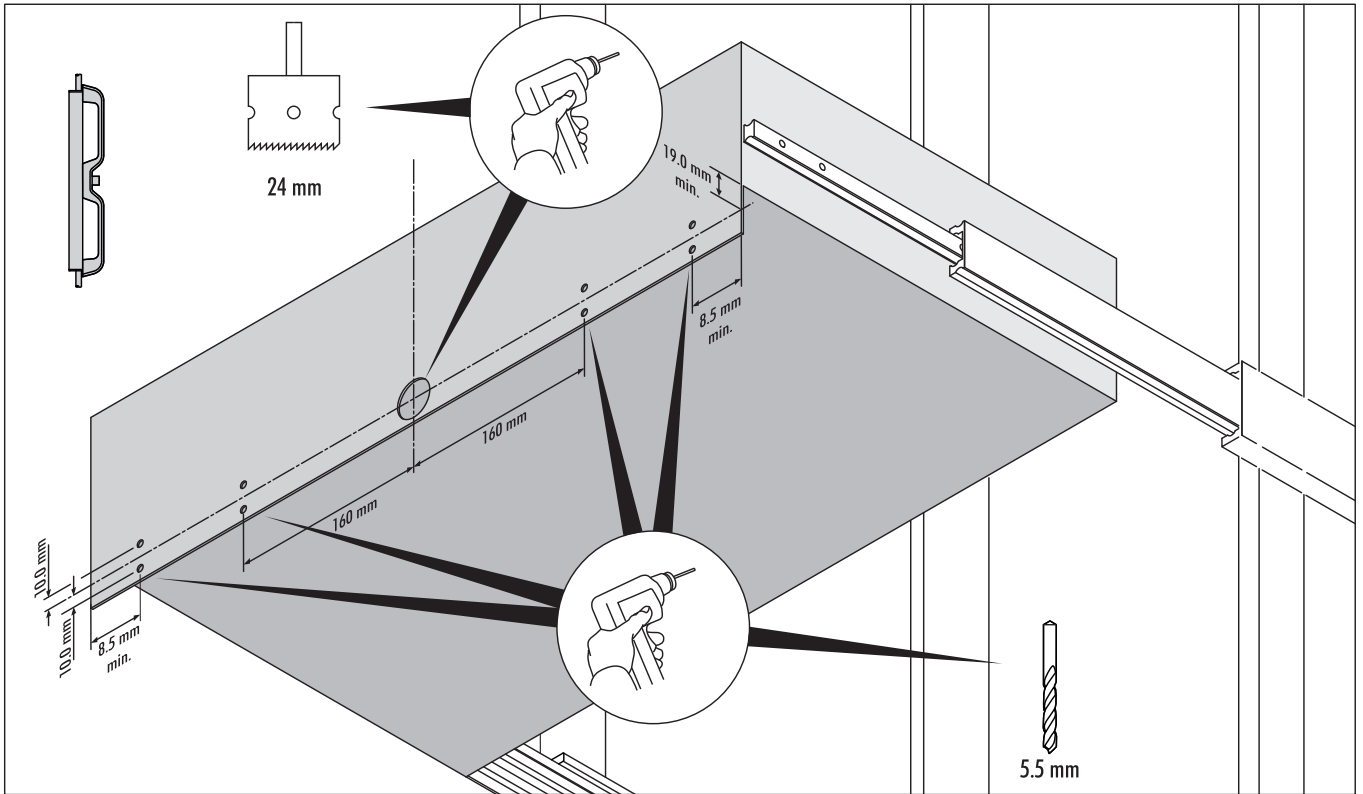

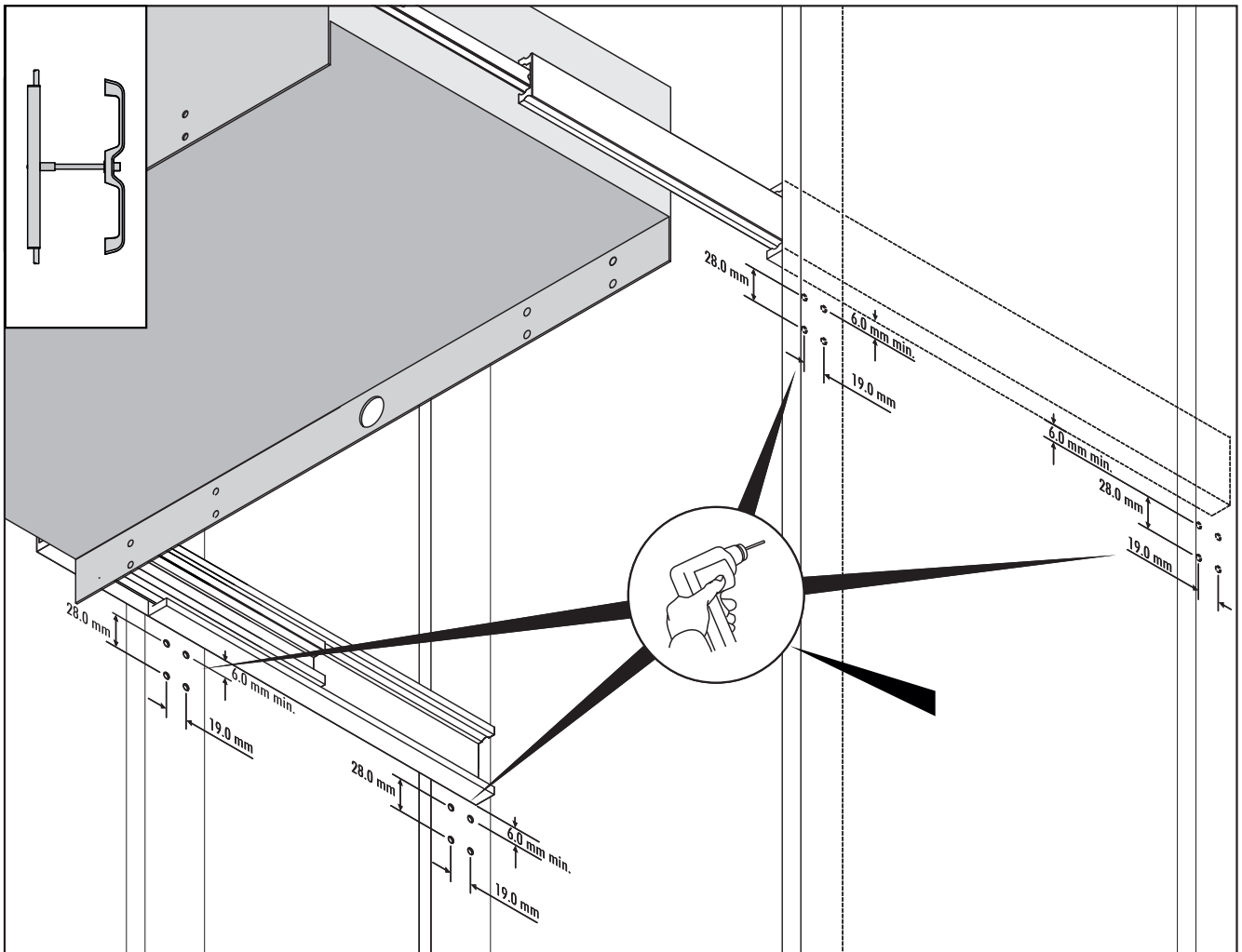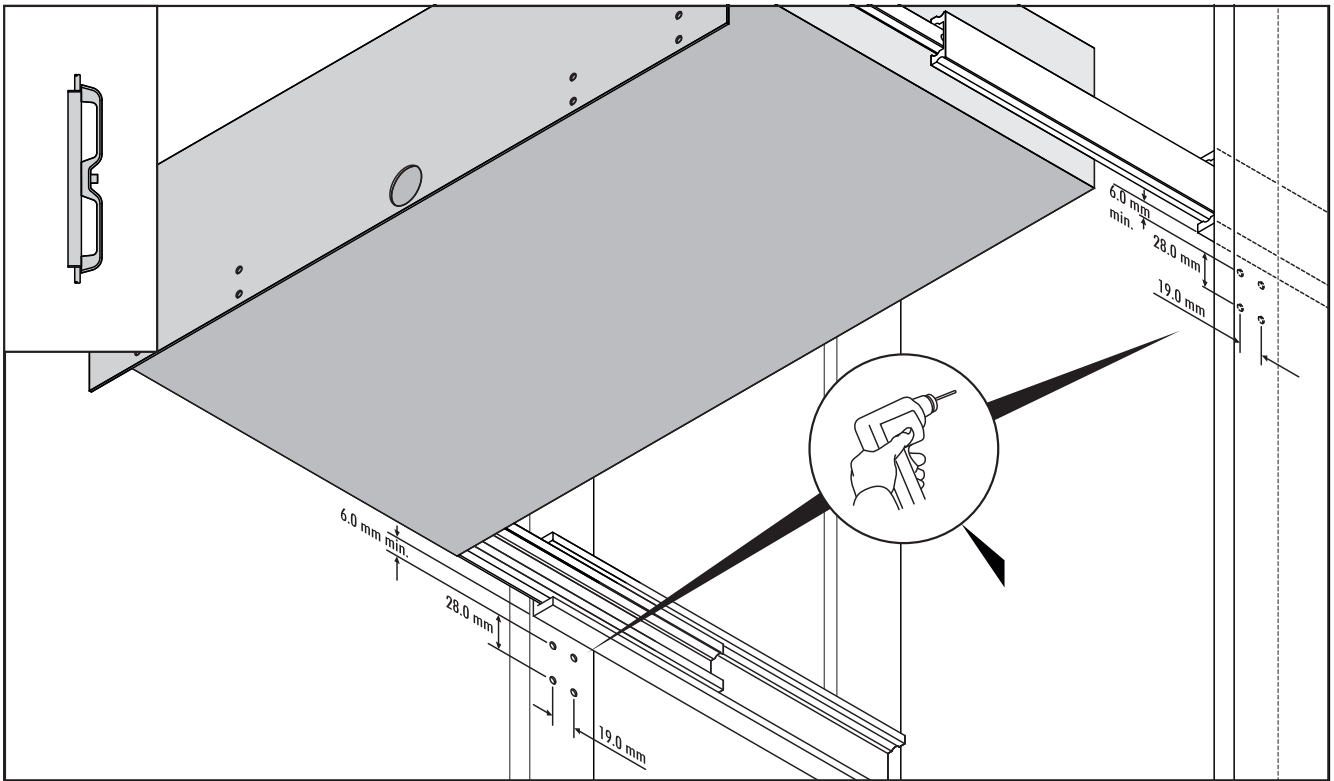

Situation-specific drilling and fastening

