

Item description/product images



black grey RAL 7021	pure orange RAL 2004	signal green RAL 6032	traffic blue RAL 5017
light grey RAL 7035	traffic red RAL 3020	colza yellow RAL 1021	

Description

Material:

Black thermoplastic.
Bush grade 5.8 steel.


Version:

Steel trivalent blue-passivated.

Note:

Form H: without locking grub screw
Form M: with locking grub screw

Drawings

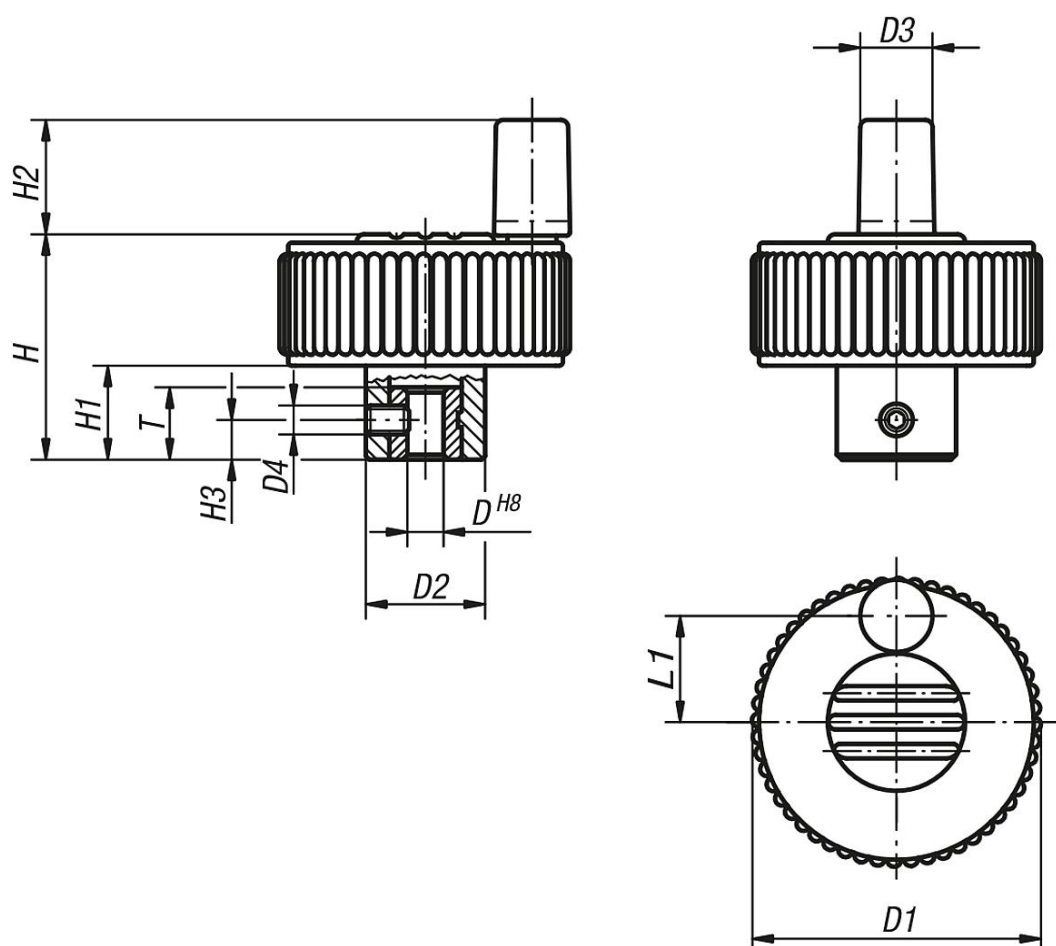

Overview of items

Order No.	Form	Colour Cap	D	D1	D2	D3	D4	H	H1	H2	H3	L1	T
06268-2106	H	black grey RAL 7021	6H8	40	16,5	10	-	31	13	16	-	15	10
06268-21061	H	orange RAL 2004	6H8	40	16,5	10	-	31	13	16	-	15	10

Overview of items

Order No.	Form	Colour Cap	D	D1	D2	D3	D4	H	H1	H2	H3	L1	T
06268-21062	H	signal green RAL6032	6H8	40	16,5	10	-	31	13	16	-	15	10
06268-21063	H	blue RAL5017	6H8	40	16,5	10	-	31	13	16	-	15	10
06268-21065	H	light grey RAL 7035	6H8	40	16,5	10	-	31	13	16	-	15	10
06268-21066	H	traffic red RAL 3020	6H8	40	16,5	10	-	31	13	16	-	15	10
06268-21067	H	colza yellow RAL 1021	6H8	40	16,5	10	-	31	13	16	-	15	10
06268-2206	H	black grey RAL 7021	6H8	50	18	10	-	36	15	16	-	18,5	10
06268-22061	H	orange RAL 2004	6H8	50	18	10	-	36	15	16	-	18,5	10
06268-22062	H	signal green RAL6032	6H8	50	18	10	-	36	15	16	-	18,5	10
06268-22063	H	blue RAL5017	6H8	50	18	10	-	36	15	16	-	18,5	10
06268-22065	H	light grey RAL 7035	6H8	50	18	10	-	36	15	16	-	18,5	10
06268-22066	H	traffic red RAL 3020	6H8	50	18	10	-	36	15	16	-	18,5	10
06268-22067	H	colza yellow RAL 1021	6H8	50	18	10	-	36	15	16	-	18,5	10
06268-2308	H	black grey RAL 7021	8H8	63	22	10	-	41	17	16	-	25	14
06268-23081	H	orange RAL 2004	8H8	63	22	10	-	41	17	16	-	25	14
06268-23082	H	signal green RAL6032	8H8	63	22	10	-	41	17	16	-	25	14
06268-23083	H	blue RAL5017	8H8	63	22	10	-	41	17	16	-	25	14
06268-23085	H	light grey RAL 7035	8H8	63	22	10	-	41	17	16	-	25	14
06268-23086	H	traffic red RAL 3020	8H8	63	22	10	-	41	17	16	-	25	14
06268-23087	H	colza yellow RAL 1021	8H8	63	22	10	-	41	17	16	-	25	14
06268-1106	M	black grey RAL 7021	6H8	40	16,5	10	M4	31	13	16	5,5	15	10
06268-11061	M	orange RAL 2004	6H8	40	16,5	10	M4	31	13	16	5,5	15	10
06268-11062	M	signal green RAL6032	6H8	40	16,5	10	M4	31	13	16	5,5	15	10
06268-11063	M	blue RAL5017	6H8	40	16,5	10	M4	31	13	16	5,5	15	10
06268-11065	M	light grey RAL 7035	6H8	40	16,5	10	M4	31	13	16	5,5	15	10
06268-11066	M	traffic red RAL 3020	6H8	40	16,5	10	M4	31	13	16	5,5	15	10
06268-11067	M	colza yellow RAL 1021	6H8	40	16,5	10	M4	31	13	16	5,5	15	10
06268-1206	M	black grey RAL 7021	6H8	50	18	10	M4	36	15	16	5,5	18,5	10
06268-12061	M	orange RAL 2004	6H8	50	18	10	M4	36	15	16	5,5	18,5	10
06268-12062	M	signal green RAL6032	6H8	50	18	10	M4	36	15	16	5,5	18,5	10
06268-12063	M	blue RAL5017	6H8	50	18	10	M4	36	15	16	5,5	18,5	10
06268-12065	M	light grey RAL 7035	6H8	50	18	10	M4	36	15	16	5,5	18,5	10
06268-12066	M	traffic red RAL 3020	6H8	50	18	10	M4	36	15	16	5,5	18,5	10
06268-12067	M	colza yellow RAL 1021	6H8	50	18	10	M4	36	15	16	5,5	18,5	10
06268-1308	M	black grey RAL 7021	8H8	63	22	10	M4	41	17	16	8	25	14
06268-13081	M	orange RAL 2004	8H8	63	22	10	M4	41	17	16	8	25	14
06268-13082	M	signal green RAL6032	8H8	63	22	10	M4	41	17	16	8	25	14
06268-13083	M	blue RAL5017	8H8	63	22	10	M4	41	17	16	8	25	14
06268-13085	M	light grey RAL 7035	8H8	63	22	10	M4	41	17	16	8	25	14
06268-13086	M	traffic red RAL 3020	8H8	63	22	10	M4	41	17	16	8	25	14
06268-13087	M	colza yellow RAL 1021	8H8	63	22	10	M4	41	17	16	8	25	14