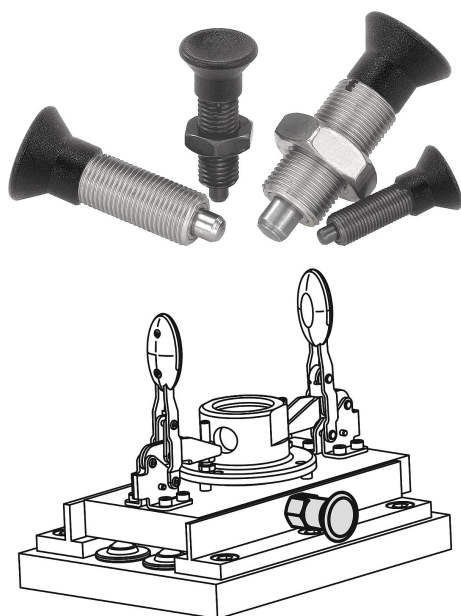


Item description/product images

**Description****Material:**

Steel version
Indexing pin hardened:
grade 5.8.

Stainless steel version
Indexing pin hardened:
Threaded sleeve 1.4305.
Indexing pin 1.4034.

Indexing pin not hardened:
Threaded sleeve 1.4305.
Indexing pin 1.4305.

Mushroom knob black-grey thermoplastic.

Version:

Steel version:
Indexing pin hardened, ground, black oxidised.

Stainless steel version:
Indexing pin hardened, ground and bright.
Indexing pin not hardened, ground and bright.

Note:

Indexing plungers are used to prevent any change in locking position due to lateral forces. A new locking position can only be set after the pin has been manually disengaged.

A washer is available to aid by screwing in the indexing plungers. The washer slides beneath the mushroom knob so that the carrier pins engage in the slot.

On request:


Special versions.

Drawing reference:

Form G: without locknut
Form H: with locknut

1) Indexing plunger with screw-in washer

Drawings

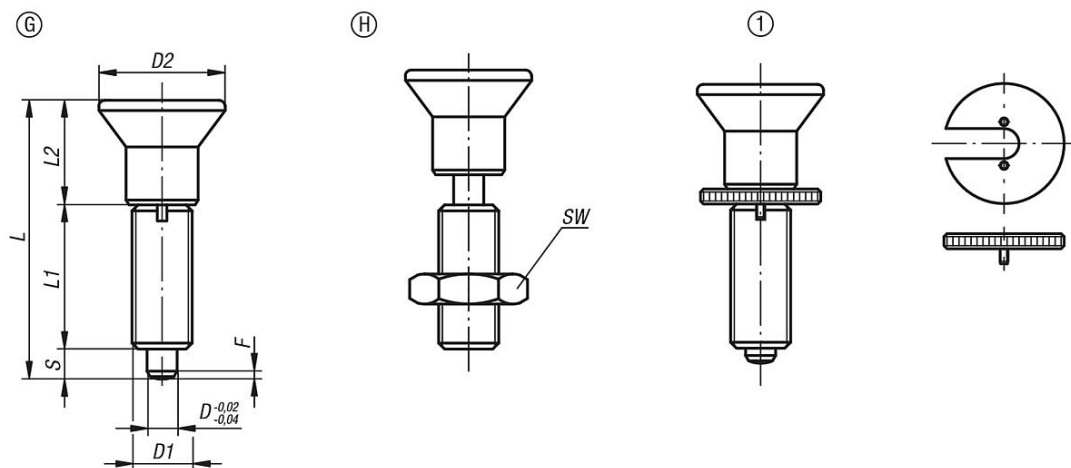

Overview of items

Order No.	Form	Main material	Surface finish body	D	D1	D2	L	L1	L2	Travel S	Fx30°	Spring force initial pressure F1 approx. N	Spring force final pressure F2 approx. N	Order No. screw-in washer
03093-1903AJ	G	steel	hardened	3	1/4-28	14	31,5	17	11	3,5	0,8	4,5	10	03094-99
03093-1004AK	G	steel	hardened	4	5/16-24	18	38,5	21	13,5	4	1,3	6	12	03094-90
03093-1105AL	G	steel	hardened	5	3/8-24	21	43,5	24	14,5	5	1,3	5	12	03094-91
03093-1206A5	G	steel	hardened	6	1/2-13	25	51,7	28	17,7	6	1,8	6	14	03094-92
03093-1308A6	G	steel	hardened	8	5/8-11	33	68	36	24	8	2,3	15	35	03094-93
03093-1410A7	G	steel	hardened	10	3/4-10	33	74	40	24	10	2,8	15	34	03094-94
03093-1412A0	G	steel	hardened	12	3/4-16	33	78	42	24	12	2,8	15	39	03094-94
03093-1516A8	G	steel	hardened	16	1-8	40	96	50	30	16	3,2	20	46	03094-95
03093-01903AJ	G	stainless steel	hardened	3	1/4-28	14	31,5	17	11	3,5	0,8	4,5	10	03094-99
03093-01004AK	G	stainless steel	hardened	4	5/16-24	18	38,5	21	13,5	4	1,3	6	12	03094-90
03093-01105AL	G	stainless steel	hardened	5	3/8-24	21	43,5	24	14,5	5	1,3	5	12	03094-91
03093-01206A5	G	stainless steel	hardened	6	1/2-13	25	51,7	28	17,7	6	1,8	6	14	03094-92
03093-01308A6	G	stainless steel	hardened	8	5/8-11	33	68	36	24	8	2,3	15	35	03094-93
03093-01410A7	G	stainless steel	hardened	10	3/4-10	33	74	40	24	10	2,8	15	34	03094-94
03093-01412A0	G	stainless steel	hardened	12	3/4-16	33	78	42	24	12	2,8	15	39	03094-94
03093-01516A8	G	stainless steel	hardened	16	1-8	40	96	50	30	16	3,2	20	46	03094-95
03093-11903AJ	G	stainless steel	not hardened	3	1/4-28	14	31,5	17	11	3,5	0,8	4,5	10	03094-99
03093-11004AK	G	stainless steel	not hardened	4	5/16-24	18	38,5	21	13,5	4	1,3	6	12	03094-90
03093-11105AL	G	stainless steel	not hardened	5	3/8-24	21	43,5	24	14,5	5	1,3	5	12	03094-91
03093-11206A5	G	stainless steel	not hardened	6	1/2-13	25	51,7	28	17,7	6	1,8	6	14	03094-92
03093-11308A6	G	stainless steel	not hardened	8	5/8-11	33	68	36	24	8	2,3	15	35	03094-93
03093-11410A7	G	stainless steel	not hardened	10	3/4-10	33	74	40	24	10	2,8	15	34	03094-94
03093-11412A0	G	stainless steel	not hardened	12	3/4-16	33	78	42	24	12	2,8	15	39	03094-94
03093-11516A8	G	stainless steel	not hardened	16	1-8	40	96	50	30	16	3,2	20	46	03094-95
03093-2903AJ	H	steel	hardened	3	1/4-28	14	31,5	17	11	3,5	0,8	4,5	10	03094-99
03093-2004AK	H	steel	hardened	4	5/16-24	18	38,5	21	13,5	4	1,3	6	12	03094-90
03093-2105AL	H	steel	hardened	5	3/8-24	21	43,5	24	14,5	5	1,3	5	12	03094-91
03093-2206A5	H	steel	hardened	6	1/2-13	25	51,7	28	17,7	6	1,8	6	14	03094-92
03093-2308A6	H	steel	hardened	8	5/8-11	33	68	36	24	8	2,3	15	35	03094-93
03093-2410A7	H	steel	hardened	10	3/4-10	33	74	40	24	10	2,8	15	34	03094-94
03093-2412A0	H	steel	hardened	12	3/4-16	33	78	42	24	12	2,8	15	39	03094-94
03093-2516A8	H	steel	hardened	16	1-8	40	96	50	30	16	3,2	20	46	03094-95
03093-02903AJ	H	stainless steel	hardened	3	1/4-28	14	31,5	17	11	3,5	0,8	4,5	10	03094-99
03093-02004AK	H	stainless steel	hardened	4	5/16-24	18	38,5	21	13,5	4	1,3	6	12	03094-90
03093-02105AL	H	stainless steel	hardened	5	3/8-24	21	43,5	24	14,5	5	1,3	5	12	03094-91
03093-02206A5	H	stainless steel	hardened	6	1/2-13	25	51,7	28	17,7	6	1,8	6	14	03094-92
03093-02308A6	H	stainless steel	hardened	8	5/8-11	33	68	36	24	8	2,3	15	35	03094-93
03093-02410A7	H	stainless steel	hardened	10	3/4-10	33	74	40	24	10	2,8	15	34	03094-94
03093-02412A0	H	stainless steel	hardened	12	3/4-16	33	78	42	24	12	2,8	15	39	03094-94
03093-02516A8	H	stainless steel	hardened	16	1-8	40	96	50	30	16	3,2	20	46	03094-95
03093-12903AJ	H	stainless steel	not hardened	3	1/4-28	14	31,5	17	11	3,5	0,8	4,5	10	03094-99
03093-12004AK	H	stainless steel	not hardened	4	5/16-24	18	38,5	21	13,5	4	1,3	6	12	03094-90
03093-12105AL	H	stainless steel	not hardened	5	3/8-24	21	43,5	24	14,5	5	1,3	5	12	03094-91

Overview of items

Order No.	Form	Main material	Surface finish body	D	D1	D2	L	L1	L2	Travel S	Fx30°	Spring force initial pressure F1 approx. N	Spring force final pressure F2 approx. N	Order No. screw-in washer
03093-12206A5	H	stainless steel	not hardened	6	1/2-13	25	51,7	28	17,7	6	1,8	6	14	03094-92
03093-12308A6	H	stainless steel	not hardened	8	5/8-11	33	68	36	24	8	2,3	15	35	03094-93
03093-12410A7	H	stainless steel	not hardened	10	3/4-10	33	74	40	24	10	2,8	15	34	03094-94
03093-12412A0	H	stainless steel	not hardened	12	3/4-16	33	78	42	24	12	2,8	15	39	03094-94
03093-12516A8	H	stainless steel	not hardened	16	1-8	40	96	50	30	16	3,2	20	46	03094-95