

Item description/product images



examples of grip cap designs



Description

Material:

Black thermoplastic.
Bush and screw steel.

Version:

Bush and screw trivalent blue passivated.

Note:

Δ Add the desired cap colour code here. No colour code is required for black caps.

On request:

Other colours or designs, such as company logo.

Drawing reference:

Form D: tapped bush without cap

Form G: without bush


Form H: with reamed bush

Form K: tapped bush with cap

Form L: external thread

Form S: hexagon

Drawings

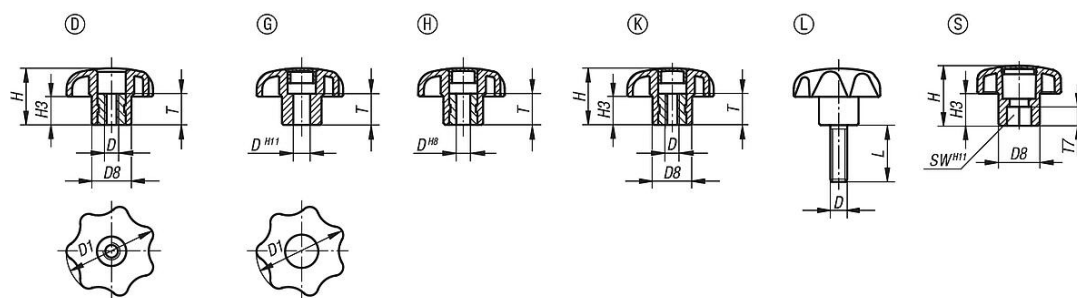

Overview of items

Order No.	Form	Colour Cap	D	D1	D8	H	H3	L	SW	T	T7
06220-504	D	-	M4	25	12	16	8	-	-	10	-
06220-505	D	-	M5	25	12	16	8	-	-	10	-
06220-5061	D	-	M6	25	12	16	8	-	-	10	-
06220-5051	D	-	M5	32	14	20	10	-	-	10	-
06220-506	D	-	M6	32	14	20	10	-	-	10	-
06220-508	D	-	M8	40	18	25	13	-	-	14	-
06220-5101	D	-	M10	40	18	25	13	-	-	14	-
06220-5081	D	-	M8	50	22	32	17	-	-	14	-
06220-510	D	-	M10	50	22	32	17	-	-	14	-
06220-5121	D	-	M12	50	22	32	17	-	-	18	-
06220-5102	D	-	M10	63	26	40	21	-	-	14	-
06220-512	D	-	M12	63	26	40	21	-	-	18	-
06220-516	D	-	M16	63	26	40	21	-	-	18	-
06220-305	G	jet black	5	25	12	16	8	-	-	10	-
06220-3055	G	light grey RAL 7035	5	25	12	16	8	-	-	10	-
06220-3056	G	traffic red RAL 3020	5	25	12	16	8	-	-	10	-
06220-3057	G	colza yellow RAL 1021	5	25	12	16	8	-	-	10	-
06220-306	G	jet black	6	32	14	20	10	-	-	10	-
06220-3065	G	light grey RAL 7035	6	32	14	20	10	-	-	10	-
06220-3066	G	traffic red RAL 3020	6	32	14	20	10	-	-	10	-

Overview of items

Order No.	Form	Colour Cap	D	D1	D8	H	H3	L	SW	T	T7
06220-3067	G	colza yellow RAL 1021	6	32	14	20	10	-	-	10	-
06220-308	G	jet black	8	40	18	25	13	-	-	14	-
06220-3085	G	light grey RAL 7035	8	40	18	25	13	-	-	14	-
06220-3086	G	traffic red RAL 3020	8	40	18	25	13	-	-	14	-
06220-3087	G	colza yellow RAL 1021	8	40	18	25	13	-	-	14	-
06220-310	G	jet black	10	50	22	32	17	-	-	14	-
06220-3105	G	light grey RAL 7035	10	50	22	32	17	-	-	14	-
06220-3106	G	traffic red RAL 3020	10	50	22	32	17	-	-	14	-
06220-3107	G	colza yellow RAL 1021	10	50	22	32	17	-	-	14	-
06220-312	G	jet black	12	63	26	40	21	-	-	18	-
06220-3125	G	light grey RAL 7035	12	63	26	40	21	-	-	18	-
06220-3126	G	traffic red RAL 3020	12	63	26	40	21	-	-	18	-
06220-3127	G	colza yellow RAL 1021	12	63	26	40	21	-	-	18	-
06220-105	H	jet black	5	25	12	16	8	-	-	10	-
06220-1055	H	light grey RAL 7035	5	25	12	16	8	-	-	10	-
06220-1056	H	traffic red RAL 3020	5	25	12	16	8	-	-	10	-
06220-1057	H	colza yellow RAL 1021	5	25	12	16	8	-	-	10	-
06220-106	H	jet black	6	32	14	20	10	-	-	10	-
06220-1065	H	light grey RAL 7035	6	32	14	20	10	-	-	10	-
06220-1066	H	traffic red RAL 3020	6	32	14	20	10	-	-	10	-
06220-1067	H	colza yellow RAL 1021	6	32	14	20	10	-	-	10	-
06220-108	H	jet black	8	40	18	25	13	-	-	14	-
06220-1085	H	light grey RAL 7035	8	40	18	25	13	-	-	14	-
06220-1086	H	traffic red RAL 3020	8	40	18	25	13	-	-	14	-
06220-1087	H	colza yellow RAL 1021	8	40	18	25	13	-	-	14	-
06220-110	H	jet black	10	50	22	32	17	-	-	14	-
06220-1105	H	light grey RAL 7035	10	50	22	32	17	-	-	14	-
06220-1106	H	traffic red RAL 3020	10	50	22	32	17	-	-	14	-
06220-1107	H	colza yellow RAL 1021	10	50	22	32	17	-	-	14	-
06220-1101	H	jet black	10	63	26	40	21	-	-	14	-
06220-11015	H	light grey RAL 7035	10	63	26	40	21	-	-	14	-
06220-11016	H	traffic red RAL 3020	10	63	26	40	21	-	-	14	-
06220-11017	H	colza yellow RAL 1021	10	63	26	40	21	-	-	14	-
06220-112	H	jet black	12	63	26	40	21	-	-	18	-
06220-1125	H	light grey RAL 7035	12	63	26	40	21	-	-	18	-
06220-1126	H	traffic red RAL 3020	12	63	26	40	21	-	-	18	-
06220-1127	H	colza yellow RAL 1021	12	63	26	40	21	-	-	18	-
06220-204	K	jet black	M4	25	12	16	8	-	-	10	-
06220-2045	K	light grey RAL 7035	M4	25	12	16	8	-	-	10	-
06220-2046	K	traffic red RAL 3020	M4	25	12	16	8	-	-	10	-
06220-2047	K	colza yellow RAL 1021	M4	25	12	16	8	-	-	10	-
06220-205	K	jet black	M5	25	12	16	8	-	-	10	-
06220-2055	K	light grey RAL 7035	M5	25	12	16	8	-	-	10	-
06220-2056	K	traffic red RAL 3020	M5	25	12	16	8	-	-	10	-
06220-2057	K	colza yellow RAL 1021	M5	25	12	16	8	-	-	10	-
06220-2061	K	jet black	M6	25	12	16	8	-	-	10	-
06220-20615	K	light grey RAL 7035	M6	25	12	16	8	-	-	10	-
06220-20616	K	traffic red RAL 3020	M6	25	12	16	8	-	-	10	-
06220-20617	K	colza yellow RAL 1021	M6	25	12	16	8	-	-	10	-
06220-2051	K	jet black	M5	32	14	20	10	-	-	10	-
06220-20515	K	light grey RAL 7035	M5	32	14	20	10	-	-	10	-
06220-20516	K	traffic red RAL 3020	M5	32	14	20	10	-	-	10	-
06220-20517	K	colza yellow RAL 1021	M5	32	14	20	10	-	-	10	-
06220-206	K	jet black	M6	32	14	20	10	-	-	10	-
06220-2065	K	light grey RAL 7035	M6	32	14	20	10	-	-	10	-
06220-2066	K	traffic red RAL 3020	M6	32	14	20	10	-	-	10	-
06220-2067	K	colza yellow RAL 1021	M6	32	14	20	10	-	-	10	-
06220-208	K	jet black	M8	40	18	25	13	-	-	14	-
06220-2085	K	light grey RAL 7035	M8	40	18	25	13	-	-	14	-
06220-2086	K	traffic red RAL 3020	M8	40	18	25	13	-	-	14	-
06220-2087	K	colza yellow RAL 1021	M8	40	18	25	13	-	-	14	-
06220-2101	K	jet black	M10	40	18	25	13	-	-	14	-
06220-21015	K	light grey RAL 7035	M10	40	18	25	13	-	-	14	-
06220-21016	K	traffic red RAL 3020	M10	40	18	25	13	-	-	14	-
06220-21017	K	colza yellow RAL 1021	M10	40	18	25	13	-	-	14	-

Overview of items

Order No.	Form	Colour Cap	D	D1	D8	H	H3	L	SW	T	T7
06220-2081	K	jet black	M8	50	22	32	17	-	-	14	-
06220-20815	K	light grey RAL 7035	M8	50	22	32	17	-	-	14	-
06220-20816	K	traffic red RAL 3020	M8	50	22	32	17	-	-	14	-
06220-20817	K	colza yellow RAL 1021	M8	50	22	32	17	-	-	14	-
06220-210	K	jet black	M10	50	22	32	17	-	-	14	-
06220-2105	K	light grey RAL 7035	M10	50	22	32	17	-	-	14	-
06220-2106	K	traffic red RAL 3020	M10	50	22	32	17	-	-	14	-
06220-2107	K	colza yellow RAL 1021	M10	50	22	32	17	-	-	14	-
06220-2121	K	jet black	M12	50	22	32	17	-	-	18	-
06220-21215	K	light grey RAL 7035	M12	50	22	32	17	-	-	18	-
06220-21216	K	traffic red RAL 3020	M12	50	22	32	17	-	-	18	-
06220-21217	K	colza yellow RAL 1021	M12	50	22	32	17	-	-	18	-
06220-2102	K	jet black	M10	63	26	40	21	-	-	14	-
06220-21025	K	light grey RAL 7035	M10	63	26	40	21	-	-	14	-
06220-21026	K	traffic red RAL 3020	M10	63	26	40	21	-	-	14	-
06220-21027	K	colza yellow RAL 1021	M10	63	26	40	21	-	-	14	-
06220-212	K	jet black	M12	63	26	40	21	-	-	18	-
06220-2125	K	light grey RAL 7035	M12	63	26	40	21	-	-	18	-
06220-2126	K	traffic red RAL 3020	M12	63	26	40	21	-	-	18	-
06220-2127	K	colza yellow RAL 1021	M12	63	26	40	21	-	-	18	-
06220-216	K	jet black	M16	63	26	40	21	-	-	18	-
06220-2165	K	light grey RAL 7035	M16	63	26	40	21	-	-	18	-
06220-2166	K	traffic red RAL 3020	M16	63	26	40	21	-	-	18	-
06220-2167	K	colza yellow RAL 1021	M16	63	26	40	21	-	-	18	-
06220-405X10	L	jet black	M5	25	12	16	8	10	-	-	-
06220-4055X10	L	light grey RAL 7035	M5	25	12	16	8	10	-	-	-
06220-4056X10	L	traffic red RAL 3020	M5	25	12	16	8	10	-	-	-
06220-4057X10	L	colza yellow RAL 1021	M5	25	12	16	8	10	-	-	-
06220-405X15	L	jet black	M5	25	12	16	8	15	-	-	-
06220-4055X15	L	light grey RAL 7035	M5	25	12	16	8	15	-	-	-
06220-4056X15	L	traffic red RAL 3020	M5	25	12	16	8	15	-	-	-
06220-4057X15	L	colza yellow RAL 1021	M5	25	12	16	8	15	-	-	-
06220-405X20	L	jet black	M5	25	12	16	8	20	-	-	-
06220-4055X20	L	light grey RAL 7035	M5	25	12	16	8	20	-	-	-
06220-4056X20	L	traffic red RAL 3020	M5	25	12	16	8	20	-	-	-
06220-4057X20	L	colza yellow RAL 1021	M5	25	12	16	8	20	-	-	-
06220-405X25	L	jet black	M5	25	12	16	8	25	-	-	-
06220-4055X25	L	light grey RAL 7035	M5	25	12	16	8	25	-	-	-
06220-4056X25	L	traffic red RAL 3020	M5	25	12	16	8	25	-	-	-
06220-4057X25	L	colza yellow RAL 1021	M5	25	12	16	8	25	-	-	-
06220-405X30	L	jet black	M5	25	12	16	8	30	-	-	-
06220-4055X30	L	light grey RAL 7035	M5	25	12	16	8	30	-	-	-
06220-4056X30	L	traffic red RAL 3020	M5	25	12	16	8	30	-	-	-
06220-4057X30	L	colza yellow RAL 1021	M5	25	12	16	8	30	-	-	-
06220-405X35	L	jet black	M5	25	12	16	8	35	-	-	-
06220-4055X35	L	light grey RAL 7035	M5	25	12	16	8	35	-	-	-
06220-4056X35	L	traffic red RAL 3020	M5	25	12	16	8	35	-	-	-
06220-4057X35	L	colza yellow RAL 1021	M5	25	12	16	8	35	-	-	-
06220-405X40	L	jet black	M5	25	12	16	8	40	-	-	-
06220-4055X40	L	light grey RAL 7035	M5	25	12	16	8	40	-	-	-
06220-4056X40	L	traffic red RAL 3020	M5	25	12	16	8	40	-	-	-
06220-4057X40	L	colza yellow RAL 1021	M5	25	12	16	8	40	-	-	-
06220-405X45	L	jet black	M5	25	12	16	8	45	-	-	-
06220-4055X45	L	light grey RAL 7035	M5	25	12	16	8	45	-	-	-
06220-4056X45	L	traffic red RAL 3020	M5	25	12	16	8	45	-	-	-
06220-4057X45	L	colza yellow RAL 1021	M5	25	12	16	8	45	-	-	-
06220-405X50	L	jet black	M5	25	12	16	8	50	-	-	-
06220-4055X50	L	light grey RAL 7035	M5	25	12	16	8	50	-	-	-
06220-4056X50	L	traffic red RAL 3020	M5	25	12	16	8	50	-	-	-
06220-4057X50	L	colza yellow RAL 1021	M5	25	12	16	8	50	-	-	-
06220-405X60	L	jet black	M5	25	12	16	8	60	-	-	-
06220-4055X60	L	light grey RAL 7035	M5	25	12	16	8	60	-	-	-
06220-4056X60	L	traffic red RAL 3020	M5	25	12	16	8	60	-	-	-
06220-4057X60	L	colza yellow RAL 1021	M5	25	12	16	8	60	-	-	-
06220-406X10	L	jet black	M6	25	12	16	8	10	-	-	-

Overview of items

Order No.	Form	Colour Cap	D	D1	D8	H	H3	L	SW	T	T7
06220-4065X10	L	light grey RAL 7035	M6	25	12	16	8	10	-	-	-
06220-4066X10	L	traffic red RAL 3020	M6	25	12	16	8	10	-	-	-
06220-4067X10	L	colza yellow RAL 1021	M6	25	12	16	8	10	-	-	-
06220-406X15	L	jet black	M6	25	12	16	8	15	-	-	-
06220-4065X15	L	light grey RAL 7035	M6	25	12	16	8	15	-	-	-
06220-4066X15	L	traffic red RAL 3020	M6	25	12	16	8	15	-	-	-
06220-4067X15	L	colza yellow RAL 1021	M6	25	12	16	8	15	-	-	-
06220-406X20	L	jet black	M6	25	12	16	8	20	-	-	-
06220-4065X20	L	light grey RAL 7035	M6	25	12	16	8	20	-	-	-
06220-4066X20	L	traffic red RAL 3020	M6	25	12	16	8	20	-	-	-
06220-4067X20	L	colza yellow RAL 1021	M6	25	12	16	8	20	-	-	-
06220-406X25	L	jet black	M6	25	12	16	8	25	-	-	-
06220-4065X25	L	light grey RAL 7035	M6	25	12	16	8	25	-	-	-
06220-4066X25	L	traffic red RAL 3020	M6	25	12	16	8	25	-	-	-
06220-4067X25	L	colza yellow RAL 1021	M6	25	12	16	8	25	-	-	-
06220-406X30	L	jet black	M6	25	12	16	8	30	-	-	-
06220-4065X30	L	light grey RAL 7035	M6	25	12	16	8	30	-	-	-
06220-4066X30	L	traffic red RAL 3020	M6	25	12	16	8	30	-	-	-
06220-4067X30	L	colza yellow RAL 1021	M6	25	12	16	8	30	-	-	-
06220-406X35	L	jet black	M6	25	12	16	8	35	-	-	-
06220-4065X35	L	light grey RAL 7035	M6	25	12	16	8	35	-	-	-
06220-4066X35	L	traffic red RAL 3020	M6	25	12	16	8	35	-	-	-
06220-4067X35	L	colza yellow RAL 1021	M6	25	12	16	8	35	-	-	-
06220-406X40	L	jet black	M6	25	12	16	8	40	-	-	-
06220-4065X40	L	light grey RAL 7035	M6	25	12	16	8	40	-	-	-
06220-4066X40	L	traffic red RAL 3020	M6	25	12	16	8	40	-	-	-
06220-4067X40	L	colza yellow RAL 1021	M6	25	12	16	8	40	-	-	-
06220-406X45	L	jet black	M6	25	12	16	8	45	-	-	-
06220-4065X45	L	light grey RAL 7035	M6	25	12	16	8	45	-	-	-
06220-4066X45	L	traffic red RAL 3020	M6	25	12	16	8	45	-	-	-
06220-4067X45	L	colza yellow RAL 1021	M6	25	12	16	8	45	-	-	-
06220-406X50	L	jet black	M6	25	12	16	8	50	-	-	-
06220-4065X50	L	light grey RAL 7035	M6	25	12	16	8	50	-	-	-
06220-4066X50	L	traffic red RAL 3020	M6	25	12	16	8	50	-	-	-
06220-4067X50	L	colza yellow RAL 1021	M6	25	12	16	8	50	-	-	-
06220-406X60	L	jet black	M6	25	12	16	8	60	-	-	-
06220-4065X60	L	light grey RAL 7035	M6	25	12	16	8	60	-	-	-
06220-4066X60	L	traffic red RAL 3020	M6	25	12	16	8	60	-	-	-
06220-4067X60	L	colza yellow RAL 1021	M6	25	12	16	8	60	-	-	-
06220-4061X10	L	jet black	M6	32	14	20	10	10	-	-	-
06220-40615X10	L	light grey RAL 7035	M6	32	14	20	10	10	-	-	-
06220-40616X10	L	traffic red RAL 3020	M6	32	14	20	10	10	-	-	-
06220-40617X10	L	colza yellow RAL 1021	M6	32	14	20	10	10	-	-	-
06220-4061X15	L	jet black	M6	32	14	20	10	15	-	-	-
06220-40615X15	L	light grey RAL 7035	M6	32	14	20	10	15	-	-	-
06220-40616X15	L	traffic red RAL 3020	M6	32	14	20	10	15	-	-	-
06220-40617X15	L	colza yellow RAL 1021	M6	32	14	20	10	15	-	-	-
06220-4061X20	L	jet black	M6	32	14	20	10	20	-	-	-
06220-40615X20	L	light grey RAL 7035	M6	32	14	20	10	20	-	-	-
06220-40616X20	L	traffic red RAL 3020	M6	32	14	20	10	20	-	-	-
06220-40617X20	L	colza yellow RAL 1021	M6	32	14	20	10	20	-	-	-
06220-4061X25	L	jet black	M6	32	14	20	10	25	-	-	-
06220-40615X25	L	light grey RAL 7035	M6	32	14	20	10	25	-	-	-
06220-40616X25	L	traffic red RAL 3020	M6	32	14	20	10	25	-	-	-
06220-40617X25	L	colza yellow RAL 1021	M6	32	14	20	10	25	-	-	-
06220-4061X30	L	jet black	M6	32	14	20	10	30	-	-	-
06220-40615X30	L	light grey RAL 7035	M6	32	14	20	10	30	-	-	-
06220-40616X30	L	traffic red RAL 3020	M6	32	14	20	10	30	-	-	-
06220-40617X30	L	colza yellow RAL 1021	M6	32	14	20	10	30	-	-	-
06220-4061X35	L	jet black	M6	32	14	20	10	35	-	-	-
06220-40615X35	L	light grey RAL 7035	M6	32	14	20	10	35	-	-	-
06220-40616X35	L	traffic red RAL 3020	M6	32	14	20	10	35	-	-	-
06220-40617X35	L	colza yellow RAL 1021	M6	32	14	20	10	35	-	-	-
06220-4061X40	L	jet black	M6	32	14	20	10	40	-	-	-
06220-40615X40	L	light grey RAL 7035	M6	32	14	20	10	40	-	-	-

Overview of items

Order No.	Form	Colour Cap	D	D1	D8	H	H3	L	SW	T	T7
06220-40616X40	L	traffic red RAL 3020	M6	32	14	20	10	40	-	-	-
06220-40617X40	L	colza yellow RAL 1021	M6	32	14	20	10	40	-	-	-
06220-4061X45	L	jet black	M6	32	14	20	10	45	-	-	-
06220-40615X45	L	light grey RAL 7035	M6	32	14	20	10	45	-	-	-
06220-40616X45	L	traffic red RAL 3020	M6	32	14	20	10	45	-	-	-
06220-40617X45	L	colza yellow RAL 1021	M6	32	14	20	10	45	-	-	-
06220-4061X50	L	jet black	M6	32	14	20	10	50	-	-	-
06220-40615X50	L	light grey RAL 7035	M6	32	14	20	10	50	-	-	-
06220-40616X50	L	traffic red RAL 3020	M6	32	14	20	10	50	-	-	-
06220-40617X50	L	colza yellow RAL 1021	M6	32	14	20	10	50	-	-	-
06220-4061X60	L	jet black	M6	32	14	20	10	60	-	-	-
06220-40615X60	L	light grey RAL 7035	M6	32	14	20	10	60	-	-	-
06220-40616X60	L	traffic red RAL 3020	M6	32	14	20	10	60	-	-	-
06220-40617X60	L	colza yellow RAL 1021	M6	32	14	20	10	60	-	-	-
06220-408X15	L	jet black	M8	32	14	20	10	15	-	-	-
06220-4085X15	L	light grey RAL 7035	M8	32	14	20	10	15	-	-	-
06220-4086X15	L	traffic red RAL 3020	M8	32	14	20	10	15	-	-	-
06220-4087X15	L	colza yellow RAL 1021	M8	32	14	20	10	15	-	-	-
06220-408X20	L	jet black	M8	32	14	20	10	20	-	-	-
06220-4085X20	L	light grey RAL 7035	M8	32	14	20	10	20	-	-	-
06220-4086X20	L	traffic red RAL 3020	M8	32	14	20	10	20	-	-	-
06220-4087X20	L	colza yellow RAL 1021	M8	32	14	20	10	20	-	-	-
06220-408X25	L	jet black	M8	32	14	20	10	25	-	-	-
06220-4085X25	L	light grey RAL 7035	M8	32	14	20	10	25	-	-	-
06220-4086X25	L	traffic red RAL 3020	M8	32	14	20	10	25	-	-	-
06220-4087X25	L	colza yellow RAL 1021	M8	32	14	20	10	25	-	-	-
06220-408X30	L	jet black	M8	32	14	20	10	30	-	-	-
06220-4085X30	L	light grey RAL 7035	M8	32	14	20	10	30	-	-	-
06220-4086X30	L	traffic red RAL 3020	M8	32	14	20	10	30	-	-	-
06220-4087X30	L	colza yellow RAL 1021	M8	32	14	20	10	30	-	-	-
06220-408X35	L	jet black	M8	32	14	20	10	35	-	-	-
06220-4085X35	L	light grey RAL 7035	M8	32	14	20	10	35	-	-	-
06220-4086X35	L	traffic red RAL 3020	M8	32	14	20	10	35	-	-	-
06220-4087X35	L	colza yellow RAL 1021	M8	32	14	20	10	35	-	-	-
06220-408X40	L	jet black	M8	32	14	20	10	40	-	-	-
06220-4085X40	L	light grey RAL 7035	M8	32	14	20	10	40	-	-	-
06220-4086X40	L	traffic red RAL 3020	M8	32	14	20	10	40	-	-	-
06220-4087X40	L	colza yellow RAL 1021	M8	32	14	20	10	40	-	-	-
06220-408X45	L	jet black	M8	32	14	20	10	45	-	-	-
06220-4085X45	L	light grey RAL 7035	M8	32	14	20	10	45	-	-	-
06220-4086X45	L	traffic red RAL 3020	M8	32	14	20	10	45	-	-	-
06220-4087X45	L	colza yellow RAL 1021	M8	32	14	20	10	45	-	-	-
06220-408X50	L	jet black	M8	32	14	20	10	50	-	-	-
06220-4085X50	L	light grey RAL 7035	M8	32	14	20	10	50	-	-	-
06220-4086X50	L	traffic red RAL 3020	M8	32	14	20	10	50	-	-	-
06220-4087X50	L	colza yellow RAL 1021	M8	32	14	20	10	50	-	-	-
06220-408X60	L	jet black	M8	32	14	20	10	60	-	-	-
06220-4085X60	L	light grey RAL 7035	M8	32	14	20	10	60	-	-	-
06220-4086X60	L	traffic red RAL 3020	M8	32	14	20	10	60	-	-	-
06220-4087X60	L	colza yellow RAL 1021	M8	32	14	20	10	60	-	-	-
06220-4081X15	L	jet black	M8	40	18	25	13	15	-	-	-
06220-40815X15	L	light grey RAL 7035	M8	40	18	25	13	15	-	-	-
06220-40816X15	L	traffic red RAL 3020	M8	40	18	25	13	15	-	-	-
06220-40817X15	L	colza yellow RAL 1021	M8	40	18	25	13	15	-	-	-
06220-4081X20	L	jet black	M8	40	18	25	13	20	-	-	-
06220-40815X20	L	light grey RAL 7035	M8	40	18	25	13	20	-	-	-
06220-40816X20	L	traffic red RAL 3020	M8	40	18	25	13	20	-	-	-
06220-40817X20	L	colza yellow RAL 1021	M8	40	18	25	13	20	-	-	-
06220-4081X25	L	jet black	M8	40	18	25	13	25	-	-	-
06220-40815X25	L	light grey RAL 7035	M8	40	18	25	13	25	-	-	-
06220-40816X25	L	traffic red RAL 3020	M8	40	18	25	13	25	-	-	-
06220-40817X25	L	colza yellow RAL 1021	M8	40	18	25	13	25	-	-	-
06220-4081X30	L	jet black	M8	40	18	25	13	30	-	-	-
06220-40815X30	L	light grey RAL 7035	M8	40	18	25	13	30	-	-	-
06220-40816X30	L	traffic red RAL 3020	M8	40	18	25	13	30	-	-	-

Overview of items

Order No.	Form	Colour Cap	D	D1	D8	H	H3	L	SW	T	T7
06220-40817X30	L	colza yellow RAL 1021	M8	40	18	25	13	30	-	-	-
06220-4081X35	L	jet black	M8	40	18	25	13	35	-	-	-
06220-40815X35	L	light grey RAL 7035	M8	40	18	25	13	35	-	-	-
06220-40816X35	L	traffic red RAL 3020	M8	40	18	25	13	35	-	-	-
06220-40817X35	L	colza yellow RAL 1021	M8	40	18	25	13	35	-	-	-
06220-4081X40	L	jet black	M8	40	18	25	13	40	-	-	-
06220-40815X40	L	light grey RAL 7035	M8	40	18	25	13	40	-	-	-
06220-40816X40	L	traffic red RAL 3020	M8	40	18	25	13	40	-	-	-
06220-40817X40	L	colza yellow RAL 1021	M8	40	18	25	13	40	-	-	-
06220-4081X45	L	jet black	M8	40	18	25	13	45	-	-	-
06220-40815X45	L	light grey RAL 7035	M8	40	18	25	13	45	-	-	-
06220-40816X45	L	traffic red RAL 3020	M8	40	18	25	13	45	-	-	-
06220-40817X45	L	colza yellow RAL 1021	M8	40	18	25	13	45	-	-	-
06220-4081X50	L	jet black	M8	40	18	25	13	50	-	-	-
06220-40815X50	L	light grey RAL 7035	M8	40	18	25	13	50	-	-	-
06220-40816X50	L	traffic red RAL 3020	M8	40	18	25	13	50	-	-	-
06220-40817X50	L	colza yellow RAL 1021	M8	40	18	25	13	50	-	-	-
06220-4081X60	L	jet black	M8	40	18	25	13	60	-	-	-
06220-40815X60	L	light grey RAL 7035	M8	40	18	25	13	60	-	-	-
06220-40816X60	L	traffic red RAL 3020	M8	40	18	25	13	60	-	-	-
06220-40817X60	L	colza yellow RAL 1021	M8	40	18	25	13	60	-	-	-
06220-410X15	L	jet black	M10	40	18	25	13	15	-	-	-
06220-4105X15	L	light grey RAL 7035	M10	40	18	25	13	15	-	-	-
06220-4106X15	L	traffic red RAL 3020	M10	40	18	25	13	15	-	-	-
06220-4107X15	L	colza yellow RAL 1021	M10	40	18	25	13	15	-	-	-
06220-410X20	L	jet black	M10	40	18	25	13	20	-	-	-
06220-4105X20	L	light grey RAL 7035	M10	40	18	25	13	20	-	-	-
06220-4106X20	L	traffic red RAL 3020	M10	40	18	25	13	20	-	-	-
06220-4107X20	L	colza yellow RAL 1021	M10	40	18	25	13	20	-	-	-
06220-410X25	L	jet black	M10	40	18	25	13	25	-	-	-
06220-4105X25	L	light grey RAL 7035	M10	40	18	25	13	25	-	-	-
06220-4106X25	L	traffic red RAL 3020	M10	40	18	25	13	25	-	-	-
06220-4107X25	L	colza yellow RAL 1021	M10	40	18	25	13	25	-	-	-
06220-410X30	L	jet black	M10	40	18	25	13	30	-	-	-
06220-4105X30	L	light grey RAL 7035	M10	40	18	25	13	30	-	-	-
06220-4106X30	L	traffic red RAL 3020	M10	40	18	25	13	30	-	-	-
06220-4107X30	L	colza yellow RAL 1021	M10	40	18	25	13	30	-	-	-
06220-410X35	L	jet black	M10	40	18	25	13	35	-	-	-
06220-4105X35	L	light grey RAL 7035	M10	40	18	25	13	35	-	-	-
06220-4106X35	L	traffic red RAL 3020	M10	40	18	25	13	35	-	-	-
06220-4107X35	L	colza yellow RAL 1021	M10	40	18	25	13	35	-	-	-
06220-410X40	L	jet black	M10	40	18	25	13	40	-	-	-
06220-4105X40	L	light grey RAL 7035	M10	40	18	25	13	40	-	-	-
06220-4106X40	L	traffic red RAL 3020	M10	40	18	25	13	40	-	-	-
06220-4107X40	L	colza yellow RAL 1021	M10	40	18	25	13	40	-	-	-
06220-410X45	L	jet black	M10	40	18	25	13	45	-	-	-
06220-4105X45	L	light grey RAL 7035	M10	40	18	25	13	45	-	-	-
06220-4106X45	L	traffic red RAL 3020	M10	40	18	25	13	45	-	-	-
06220-4107X45	L	colza yellow RAL 1021	M10	40	18	25	13	45	-	-	-
06220-410X50	L	jet black	M10	40	18	25	13	50	-	-	-
06220-4105X50	L	light grey RAL 7035	M10	40	18	25	13	50	-	-	-
06220-4106X50	L	traffic red RAL 3020	M10	40	18	25	13	50	-	-	-
06220-4107X50	L	colza yellow RAL 1021	M10	40	18	25	13	50	-	-	-
06220-410X60	L	jet black	M10	40	18	25	13	60	-	-	-
06220-4105X60	L	light grey RAL 7035	M10	40	18	25	13	60	-	-	-
06220-4106X60	L	traffic red RAL 3020	M10	40	18	25	13	60	-	-	-
06220-4107X60	L	colza yellow RAL 1021	M10	40	18	25	13	60	-	-	-
06220-4101X15	L	jet black	M10	50	22	32	17	15	-	-	-
06220-41015X15	L	light grey RAL 7035	M10	50	22	32	17	15	-	-	-
06220-41016X15	L	traffic red RAL 3020	M10	50	22	32	17	15	-	-	-
06220-41017X15	L	colza yellow RAL 1021	M10	50	22	32	17	15	-	-	-
06220-4101X20	L	jet black	M10	50	22	32	17	20	-	-	-
06220-41015X20	L	light grey RAL 7035	M10	50	22	32	17	20	-	-	-
06220-41016X20	L	traffic red RAL 3020	M10	50	22	32	17	20	-	-	-
06220-41017X20	L	colza yellow RAL 1021	M10	50	22	32	17	20	-	-	-

Overview of items

Order No.	Form	Colour Cap	D	D1	D8	H	H3	L	SW	T	T7
06220-4101X25	L	jet black	M10	50	22	32	17	25	-	-	-
06220-41015X25	L	light grey RAL 7035	M10	50	22	32	17	25	-	-	-
06220-41016X25	L	traffic red RAL 3020	M10	50	22	32	17	25	-	-	-
06220-41017X25	L	colza yellow RAL 1021	M10	50	22	32	17	25	-	-	-
06220-4101X30	L	jet black	M10	50	22	32	17	30	-	-	-
06220-41015X30	L	light grey RAL 7035	M10	50	22	32	17	30	-	-	-
06220-41016X30	L	traffic red RAL 3020	M10	50	22	32	17	30	-	-	-
06220-41017X30	L	colza yellow RAL 1021	M10	50	22	32	17	30	-	-	-
06220-4101X35	L	jet black	M10	50	22	32	17	35	-	-	-
06220-41015X35	L	light grey RAL 7035	M10	50	22	32	17	35	-	-	-
06220-41016X35	L	traffic red RAL 3020	M10	50	22	32	17	35	-	-	-
06220-41017X35	L	colza yellow RAL 1021	M10	50	22	32	17	35	-	-	-
06220-4101X40	L	jet black	M10	50	22	32	17	40	-	-	-
06220-41015X40	L	light grey RAL 7035	M10	50	22	32	17	40	-	-	-
06220-41016X40	L	traffic red RAL 3020	M10	50	22	32	17	40	-	-	-
06220-41017X40	L	colza yellow RAL 1021	M10	50	22	32	17	40	-	-	-
06220-4101X45	L	jet black	M10	50	22	32	17	45	-	-	-
06220-41015X45	L	light grey RAL 7035	M10	50	22	32	17	45	-	-	-
06220-41016X45	L	traffic red RAL 3020	M10	50	22	32	17	45	-	-	-
06220-41017X45	L	colza yellow RAL 1021	M10	50	22	32	17	45	-	-	-
06220-4101X50	L	jet black	M10	50	22	32	17	50	-	-	-
06220-41015X50	L	light grey RAL 7035	M10	50	22	32	17	50	-	-	-
06220-41016X50	L	traffic red RAL 3020	M10	50	22	32	17	50	-	-	-
06220-41017X50	L	colza yellow RAL 1021	M10	50	22	32	17	50	-	-	-
06220-4101X60	L	jet black	M10	50	22	32	17	60	-	-	-
06220-41015X60	L	light grey RAL 7035	M10	50	22	32	17	60	-	-	-
06220-41016X60	L	traffic red RAL 3020	M10	50	22	32	17	60	-	-	-
06220-41017X60	L	colza yellow RAL 1021	M10	50	22	32	17	60	-	-	-
06220-412X15	L	jet black	M12	50	22	32	17	15	-	-	-
06220-4125X15	L	light grey RAL 7035	M12	50	22	32	17	15	-	-	-
06220-4126X15	L	traffic red RAL 3020	M12	50	22	32	17	15	-	-	-
06220-4127X15	L	colza yellow RAL 1021	M12	50	22	32	17	15	-	-	-
06220-412X20	L	jet black	M12	50	22	32	17	20	-	-	-
06220-4125X20	L	light grey RAL 7035	M12	50	22	32	17	20	-	-	-
06220-4126X20	L	traffic red RAL 3020	M12	50	22	32	17	20	-	-	-
06220-4127X20	L	colza yellow RAL 1021	M12	50	22	32	17	20	-	-	-
06220-412X25	L	jet black	M12	50	22	32	17	25	-	-	-
06220-4125X25	L	light grey RAL 7035	M12	50	22	32	17	25	-	-	-
06220-4126X25	L	traffic red RAL 3020	M12	50	22	32	17	25	-	-	-
06220-4127X25	L	colza yellow RAL 1021	M12	50	22	32	17	25	-	-	-
06220-412X30	L	jet black	M12	50	22	32	17	30	-	-	-
06220-4125X30	L	light grey RAL 7035	M12	50	22	32	17	30	-	-	-
06220-4126X30	L	traffic red RAL 3020	M12	50	22	32	17	30	-	-	-
06220-4127X30	L	colza yellow RAL 1021	M12	50	22	32	17	30	-	-	-
06220-412X35	L	jet black	M12	50	22	32	17	35	-	-	-
06220-4125X35	L	light grey RAL 7035	M12	50	22	32	17	35	-	-	-
06220-4126X35	L	traffic red RAL 3020	M12	50	22	32	17	35	-	-	-
06220-4127X35	L	colza yellow RAL 1021	M12	50	22	32	17	35	-	-	-
06220-412X40	L	jet black	M12	50	22	32	17	40	-	-	-
06220-4125X40	L	light grey RAL 7035	M12	50	22	32	17	40	-	-	-
06220-4126X40	L	traffic red RAL 3020	M12	50	22	32	17	40	-	-	-
06220-4127X40	L	colza yellow RAL 1021	M12	50	22	32	17	40	-	-	-
06220-412X45	L	jet black	M12	50	22	32	17	45	-	-	-
06220-4125X45	L	light grey RAL 7035	M12	50	22	32	17	45	-	-	-
06220-4126X45	L	traffic red RAL 3020	M12	50	22	32	17	45	-	-	-
06220-4127X45	L	colza yellow RAL 1021	M12	50	22	32	17	45	-	-	-
06220-412X50	L	jet black	M12	50	22	32	17	50	-	-	-
06220-4125X50	L	light grey RAL 7035	M12	50	22	32	17	50	-	-	-
06220-4126X50	L	traffic red RAL 3020	M12	50	22	32	17	50	-	-	-
06220-4127X50	L	colza yellow RAL 1021	M12	50	22	32	17	50	-	-	-
06220-412X60	L	jet black	M12	50	22	32	17	60	-	-	-
06220-4125X60	L	light grey RAL 7035	M12	50	22	32	17	60	-	-	-
06220-4126X60	L	traffic red RAL 3020	M12	50	22	32	17	60	-	-	-
06220-4127X60	L	colza yellow RAL 1021	M12	50	22	32	17	60	-	-	-
06220-4102X20	L	jet black	M10	63	26	40	21	20	-	-	-

Overview of items

Order No.	Form	Colour Cap	D	D1	D8	H	H3	L	SW	T	T7
06220-41025X20	L	light grey RAL 7035	M10	63	26	40	21	20	-	-	-
06220-41026X20	L	traffic red RAL 3020	M10	63	26	40	21	20	-	-	-
06220-41027X20	L	colza yellow RAL 1021	M10	63	26	40	21	20	-	-	-
06220-4102X25	L	jet black	M10	63	26	40	21	25	-	-	-
06220-41025X25	L	light grey RAL 7035	M10	63	26	40	21	25	-	-	-
06220-41026X25	L	traffic red RAL 3020	M10	63	26	40	21	25	-	-	-
06220-41027X25	L	colza yellow RAL 1021	M10	63	26	40	21	25	-	-	-
06220-4102X30	L	jet black	M10	63	26	40	21	30	-	-	-
06220-41025X30	L	light grey RAL 7035	M10	63	26	40	21	30	-	-	-
06220-41026X30	L	traffic red RAL 3020	M10	63	26	40	21	30	-	-	-
06220-41027X30	L	colza yellow RAL 1021	M10	63	26	40	21	30	-	-	-
06220-4102X35	L	jet black	M10	63	26	40	21	35	-	-	-
06220-41025X35	L	light grey RAL 7035	M10	63	26	40	21	35	-	-	-
06220-41026X35	L	traffic red RAL 3020	M10	63	26	40	21	35	-	-	-
06220-41027X35	L	colza yellow RAL 1021	M10	63	26	40	21	35	-	-	-
06220-4102X40	L	jet black	M10	63	26	40	21	40	-	-	-
06220-41025X40	L	light grey RAL 7035	M10	63	26	40	21	40	-	-	-
06220-41026X40	L	traffic red RAL 3020	M10	63	26	40	21	40	-	-	-
06220-41027X40	L	colza yellow RAL 1021	M10	63	26	40	21	40	-	-	-
06220-4102X45	L	jet black	M10	63	26	40	21	45	-	-	-
06220-41025X45	L	light grey RAL 7035	M10	63	26	40	21	45	-	-	-
06220-41026X45	L	traffic red RAL 3020	M10	63	26	40	21	45	-	-	-
06220-41027X45	L	colza yellow RAL 1021	M10	63	26	40	21	45	-	-	-
06220-4102X50	L	jet black	M10	63	26	40	21	50	-	-	-
06220-41025X50	L	light grey RAL 7035	M10	63	26	40	21	50	-	-	-
06220-41026X50	L	traffic red RAL 3020	M10	63	26	40	21	50	-	-	-
06220-41027X50	L	colza yellow RAL 1021	M10	63	26	40	21	50	-	-	-
06220-4102X60	L	jet black	M10	63	26	40	21	60	-	-	-
06220-41025X60	L	light grey RAL 7035	M10	63	26	40	21	60	-	-	-
06220-41026X60	L	traffic red RAL 3020	M10	63	26	40	21	60	-	-	-
06220-41027X60	L	colza yellow RAL 1021	M10	63	26	40	21	60	-	-	-
06220-4121X20	L	jet black	M12	63	26	40	21	20	-	-	-
06220-41215X20	L	light grey RAL 7035	M12	63	26	40	21	20	-	-	-
06220-41216X20	L	traffic red RAL 3020	M12	63	26	40	21	20	-	-	-
06220-41217X20	L	colza yellow RAL 1021	M12	63	26	40	21	20	-	-	-
06220-4121X25	L	jet black	M12	63	26	40	21	25	-	-	-
06220-41215X25	L	light grey RAL 7035	M12	63	26	40	21	25	-	-	-
06220-41216X25	L	traffic red RAL 3020	M12	63	26	40	21	25	-	-	-
06220-41217X25	L	colza yellow RAL 1021	M12	63	26	40	21	25	-	-	-
06220-4121X30	L	jet black	M12	63	26	40	21	30	-	-	-
06220-41215X30	L	light grey RAL 7035	M12	63	26	40	21	30	-	-	-
06220-41216X30	L	traffic red RAL 3020	M12	63	26	40	21	30	-	-	-
06220-41217X30	L	colza yellow RAL 1021	M12	63	26	40	21	30	-	-	-
06220-4121X35	L	jet black	M12	63	26	40	21	35	-	-	-
06220-41215X35	L	light grey RAL 7035	M12	63	26	40	21	35	-	-	-
06220-41216X35	L	traffic red RAL 3020	M12	63	26	40	21	35	-	-	-
06220-41217X35	L	colza yellow RAL 1021	M12	63	26	40	21	35	-	-	-
06220-4121X40	L	jet black	M12	63	26	40	21	40	-	-	-
06220-41215X40	L	light grey RAL 7035	M12	63	26	40	21	40	-	-	-
06220-41216X40	L	traffic red RAL 3020	M12	63	26	40	21	40	-	-	-
06220-41217X40	L	colza yellow RAL 1021	M12	63	26	40	21	40	-	-	-
06220-4121X45	L	jet black	M12	63	26	40	21	45	-	-	-
06220-41215X45	L	light grey RAL 7035	M12	63	26	40	21	45	-	-	-
06220-41216X45	L	traffic red RAL 3020	M12	63	26	40	21	45	-	-	-
06220-41217X45	L	colza yellow RAL 1021	M12	63	26	40	21	45	-	-	-
06220-4121X50	L	jet black	M12	63	26	40	21	50	-	-	-
06220-41215X50	L	light grey RAL 7035	M12	63	26	40	21	50	-	-	-
06220-41216X50	L	traffic red RAL 3020	M12	63	26	40	21	50	-	-	-
06220-41217X50	L	colza yellow RAL 1021	M12	63	26	40	21	50	-	-	-
06220-4121X60	L	jet black	M12	63	26	40	21	60	-	-	-
06220-41215X60	L	light grey RAL 7035	M12	63	26	40	21	60	-	-	-
06220-41216X60	L	traffic red RAL 3020	M12	63	26	40	21	60	-	-	-
06220-41217X60	L	colza yellow RAL 1021	M12	63	26	40	21	60	-	-	-
06220-416X30	L	jet black	M16	63	26	40	21	30	-	-	-
06220-4165X30	L	light grey RAL 7035	M16	63	26	40	21	30	-	-	-

Overview of items

Order No.	Form	Colour Cap	D	D1	D8	H	H3	L	SW	T	T7
06220-4166X30	L	traffic red RAL 3020	M16	63	26	40	21	30	-	-	-
06220-4167X30	L	colza yellow RAL 1021	M16	63	26	40	21	30	-	-	-
06220-416X35	L	jet black	M16	63	26	40	21	35	-	-	-
06220-4165X35	L	light grey RAL 7035	M16	63	26	40	21	35	-	-	-
06220-4166X35	L	traffic red RAL 3020	M16	63	26	40	21	35	-	-	-
06220-4167X35	L	colza yellow RAL 1021	M16	63	26	40	21	35	-	-	-
06220-416X40	L	jet black	M16	63	26	40	21	40	-	-	-
06220-4165X40	L	light grey RAL 7035	M16	63	26	40	21	40	-	-	-
06220-4166X40	L	traffic red RAL 3020	M16	63	26	40	21	40	-	-	-
06220-4167X40	L	colza yellow RAL 1021	M16	63	26	40	21	40	-	-	-
06220-416X45	L	jet black	M16	63	26	40	21	45	-	-	-
06220-4165X45	L	light grey RAL 7035	M16	63	26	40	21	45	-	-	-
06220-4166X45	L	traffic red RAL 3020	M16	63	26	40	21	45	-	-	-
06220-4167X45	L	colza yellow RAL 1021	M16	63	26	40	21	45	-	-	-
06220-416X50	L	jet black	M16	63	26	40	21	50	-	-	-
06220-4165X50	L	light grey RAL 7035	M16	63	26	40	21	50	-	-	-
06220-4166X50	L	traffic red RAL 3020	M16	63	26	40	21	50	-	-	-
06220-4167X50	L	colza yellow RAL 1021	M16	63	26	40	21	50	-	-	-
06220-416X60	L	jet black	M16	63	26	40	21	60	-	-	-
06220-4165X60	L	light grey RAL 7035	M16	63	26	40	21	60	-	-	-
06220-4166X60	L	traffic red RAL 3020	M16	63	26	40	21	60	-	-	-
06220-4167X60	L	colza yellow RAL 1021	M16	63	26	40	21	60	-	-	-
06220-808	S	jet black	-	32	14	20	10	-	8	-	5
06220-810	S	jet black	-	40	18	25	13	-	10	-	10
06220-813	S	jet black	-	50	22	32	17	-	13	-	10
06220-816	S	jet black	-	63	26	40	21	-	16	-	15