

## Item description/product images



## Description

**Material:**

Main component polypropylene (PP).  
Soft components thermoplastic elastomer.  
Tapped bushes brass.

**Version:**

Main component black.  
Soft components black, orange, yellow, red, green, blue, grey.  
Tapped bushes electro zinc-plated.

**Note:**

Excellent carrying and gripping comfort thanks to its soft inner surface.


**Assembly:**

From the rear.

**On request:**

Main components grey with other colour combinations.

## Drawings

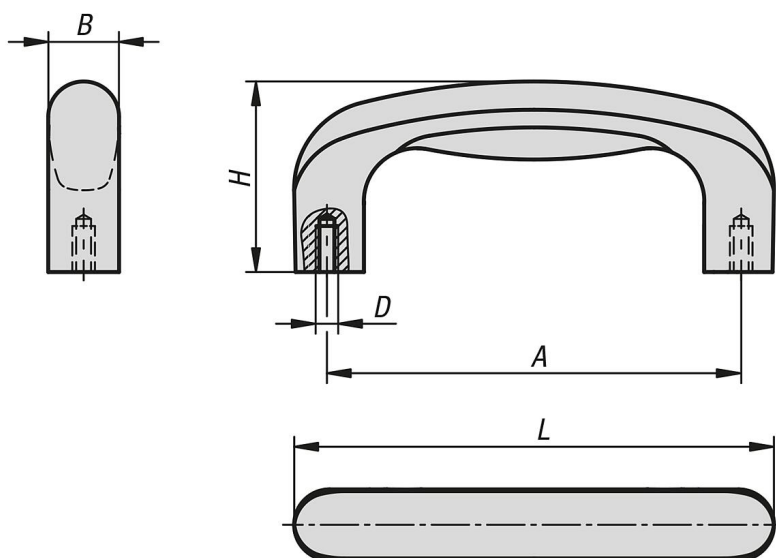

## Overview of items

Order No.	Component colour	A	B	D	H	L	Load capacity N
06913-10-0940411	black	93,7	16,3	M4	48,8	105	500
06913-10-09404187	blue	93,7	16,3	M4	48,8	105	500
06913-10-09404186	green	93,7	16,3	M4	48,8	105	500
06913-10-09404184	red	93,7	16,3	M4	48,8	105	500
06913-10-0940412	orange	93,7	16,3	M4	48,8	105	500
06913-10-09404116	yellow	93,7	16,3	M4	48,8	105	500
06913-10-09404188	grey	93,7	16,3	M4	48,8	105	500
06913-10-1170511	black	117	20,6	M5	53,8	134,7	500
06913-10-11705187	blue	117	20,6	M5	53,8	134,7	500
06913-10-11705186	green	117	20,6	M5	53,8	134,7	500
06913-10-11705184	red	117	20,6	M5	53,8	134,7	500

## Overview of items

Order No.	Component colour	A	B	D	H	L	Load capacity N
06913-10-1170512	orange	117	20,6	M5	53,8	134,7	500
06913-10-11705116	yellow	117	20,6	M5	53,8	134,7	500
06913-10-11705188	grey	117	20,6	M5	53,8	134,7	500
06913-10-1540611	black	148,5	26,7	M6	65	170,3	500
06913-10-15406187	blue	148,5	26,7	M6	65	170,3	500
06913-10-15406186	green	148,5	26,7	M6	65	170,3	500
06913-10-15406184	red	148,5	26,7	M6	65	170,3	500
06913-10-1540612	orange	148,5	26,7	M6	65	170,3	500
06913-10-15406116	yellow	148,5	26,7	M6	65	170,3	500
06913-10-15406188	grey	148,5	26,7	M6	65	170,3	500
06913-10-1540811	black	148,5	26,7	M8	65	170,3	500
06913-10-15408187	blue	148,5	26,7	M8	65	170,3	500
06913-10-15408186	green	148,5	26,7	M8	65	170,3	500
06913-10-15408184	red	148,5	26,7	M8	65	170,3	500
06913-10-1540812	orange	148,5	26,7	M8	65	170,3	500
06913-10-15408116	yellow	148,5	26,7	M8	65	170,3	500
06913-10-15408188	grey	148,5	26,7	M8	65	170,3	500