


Item description/product images

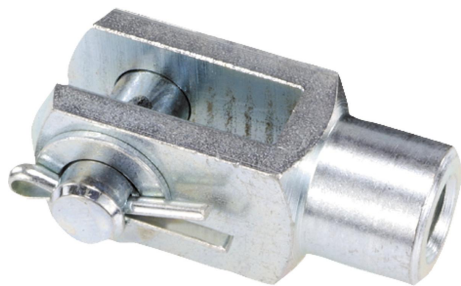

Description


Material:

Steel.

Version:

Electro zinc-plated.

Drawings

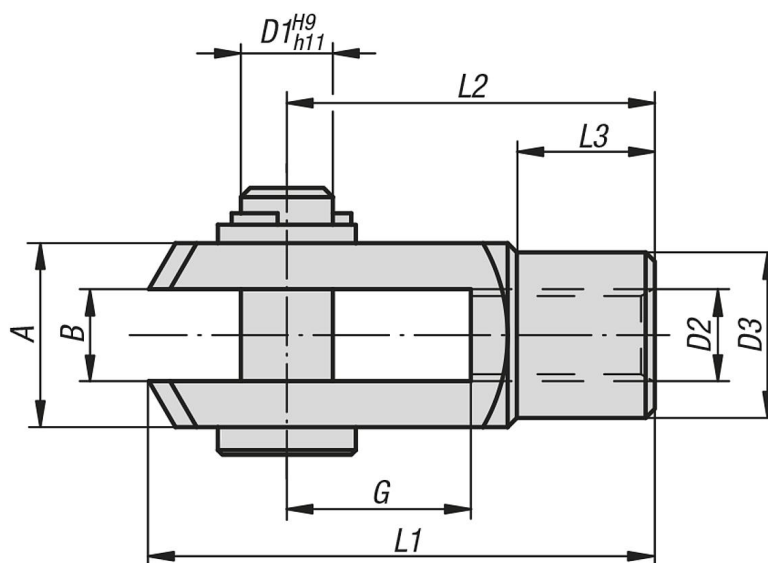

Overview of items

Order No.	Version 2	B	G	D1	D2	D3	L1	L2	L3	A
27624-0510	Base / magnet 245012 Assembly / Clamping joint 240011 Fixing element / dial gauge holder 246028	5	10	5	M5	9	26	20	7,5	10
27624-0612	Base / magnet 245012 Assembly / Clamping joint 240011 Fixing element / dial gauge holder 246028	6	12	6	M6	10	31	24	9	12
27624-0816	Base / magnet 245012 Assembly / Clamping joint 240011 Fixing element / dial gauge holder 246028	8	16	8	M8	14	42	32	12	16
27624-0832	Base / magnet 245012 Assembly / Clamping joint 240011 Fixing element / dial gauge holder 246028	8	32	8	M8	14	58	48	12	16
27624-1020	Base / magnet 245012 Assembly / Clamping joint 240011 Fixing element / dial gauge holder 246028	10	20	10	M10	18	52	40	15	20
27624-10120	Base / magnet 245012 Assembly / Clamping joint 240011 Fixing element / dial gauge holder 246028	10	20	10	M10x1,25	18	52	40	15	20
27624-1040	Base / magnet 245012 Assembly / Clamping joint 240011 Fixing element / dial gauge holder 246028	10	40	10	M10	18	72	60	15	20
27624-10140	Base / magnet 245012 Assembly / Clamping joint 240011 Fixing element / dial gauge holder 246028	10	40	10	M10x1,25	18	72	60	15	20
27624-1224	Base / magnet 245012 Assembly / Clamping joint 240011 Fixing element / dial gauge holder 246028	12	24	12	M12	20	62	48	18	24

Overview of items

Order No.	Version 2	B	G	D1	D2	D3	L1	L2	L3	A
27624-12124	Base / magnet 245012 Assembly / Clamping joint 240011 Fixing element / dial gauge holder 246028	12	24	12	M12x1,25	20	62	48	18	24
27624-1248	Base / magnet 245012 Assembly / Clamping joint 240011 Fixing element / dial gauge holder 246028	12	48	12	M12	20	86	72	18	24
27624-12148	Base / magnet 245012 Assembly / Clamping joint 240011 Fixing element / dial gauge holder 246028	12	48	12	M12x1,25	20	86	72	18	24
27624-1428	Base / magnet 245012 Assembly / Clamping joint 240011 Fixing element / dial gauge holder 246028	14	28	14	M14	24	72	56	22,5	27
27624-1632	Base / magnet 245012 Assembly / Clamping joint 240011 Fixing element / dial gauge holder 246028	16	32	16	M16	26	83	64	24	32
27624-16132	Base / magnet 245012 Assembly / Clamping joint 240011 Fixing element / dial gauge holder 246028	16	32	16	M16x1,5	26	83	64	24	32
27624-2040	Base / magnet 245012 Assembly / Clamping joint 240011 Fixing element / dial gauge holder 246028	20	40	20	M20	34	105	80	30	40
27624-05101	Base / magnet 245012 Assembly / Clamping joint 240021 Fixing element / dial gauge holder 246038	5	10	5	M5	9	26	20	7,5	10
27624-06121	Base / magnet 245012 Assembly / Clamping joint 240021 Fixing element / dial gauge holder 246038	6	12	6	M6	10	31	24	9	12
27624-08161	Base / magnet 245012 Assembly / Clamping joint 240021 Fixing element / dial gauge holder 246038	8	16	8	M8	14	42	32	12	16
27624-10201	Base / magnet 245012 Assembly / Clamping joint 240021 Fixing element / dial gauge holder 246038	10	20	10	M10	18	52	40	15	20
27624-12241	Base / magnet 245012 Assembly / Clamping joint 240021 Fixing element / dial gauge holder 246038	12	24	12	M12	20	62	48	18	24
27624-16321	Base / magnet 245012 Assembly / Clamping joint 240021 Fixing element / dial gauge holder 246038	16	32	16	M16	26	83	64	24	32
27624-20401	Base / magnet 245012 Assembly / Clamping joint 240021 Fixing element / dial gauge holder 246038	20	40	20	M20	34	105	80	30	40