

Item description/product images



Description

Material:

Housing steel.

Lever polyamide.

Load ball stainless steel 1.4034 or polyamide.


Version:

Steel electro zinc-plated.

Note:

Ball transfer units with lockable balls are suitable for transporting and positioning sensitive goods such as glass or polished aluminium, brass and steel sheets. Ball transfer units can also be used as an alternative to standard rollers, making it easy to transport and position low profiles, e.g. in retail, production or at home.

Drawings

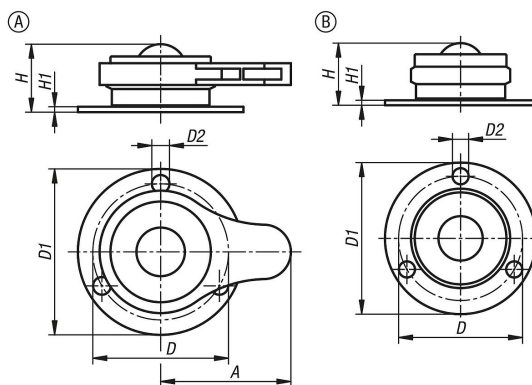

Overview of items

Order No.	Form	Form definition	Component material	Ball-Ø	A	D	D1	D2	H	H1	Max load in kg ball on top	Max load in kg ball under
95161-1119	A	pneumatic	5000	19	48	50	63	6,5	25	2	120	80
95161-2119	A	pneumatic	PPA GF30 FDA EU10/2011+NSF	19	48	50	63	6,5	25	2	120	80
95161-1219	B	Power supply unit	5000	19	-	50	63	6,5	25	2	120	80
95161-2219	B	Power supply unit	PPA GF30 FDA EU10/2011+NSF	19	-	50	63	6,5	25	2	120	80