

Item description/product images



Description

Material:
Thermoplastic.

Version:
black-grey RAL 7021, pure orange RAL 2004, colza yellow RAL 1021, signal green RAL 6032, traffic blue RAL 5017, traffic red RAL 3020 and light grey RAL 7035.

Note:
The max. tightening torque is 2 Nm.


Assembly:
From the rear.

Advantages:
Fastened using self-tapping screws
Mounted from the rear
Grip in different colours

Supplied with:
Self-tapping fastening screws for plastics, L=12 mm are supplied.

Drawing reference:
Form A: with collar
Form B: without collar

Drawings

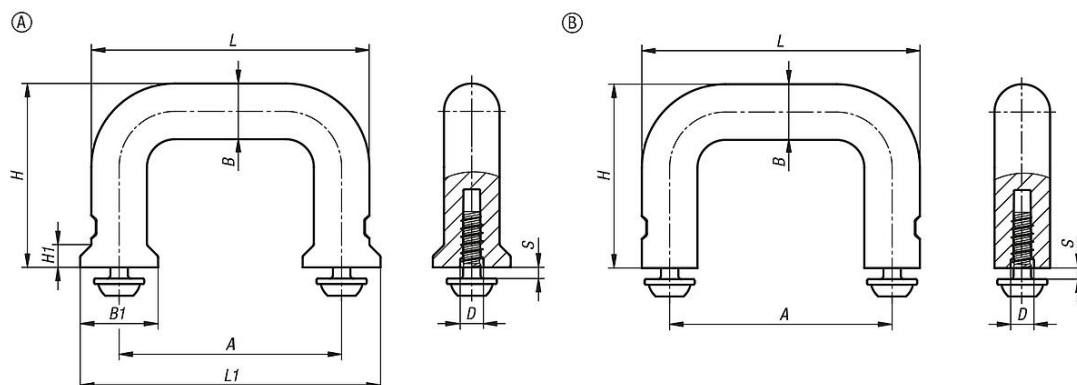

Overview of items

Finger grips, plastic, round

Order No.	Form	Main colour	A	B	B1	D	H	H1	L	L1	S max.	Load capacity N
06901-50-108030	A	black grey RAL 7021	30	8	12	4	32	4	38	42	4,5	500
06901-50-1080302	A	orange RAL 2004	30	8	12	4	32	4	38	42	4,5	500
06901-50-10803016	A	colza yellow RAL 1021	30	8	12	4	32	4	38	42	4,5	500
06901-50-10803086	A	signal green RAL 6032	30	8	12	4	32	4	38	42	4,5	500
06901-50-10803087	A	traffic blue RAL 5017	30	8	12	4	32	4	38	42	4,5	500
06901-50-10803084	A	traffic red RAL 3020	30	8	12	4	32	4	38	42	4,5	500
06901-50-10803088	A	light grey RAL 7035	30	8	12	4	32	4	38	42	4,5	500
06901-50-108040	A	black grey RAL 7021	40	8	12	4	32	4	48	52	4,5	500
06901-50-1080402	A	orange RAL 2004	40	8	12	4	32	4	48	52	4,5	500

Overview of items

Order No.	Form	Main colour	A	B	B1	D	H	H1	L	L1	S max.	Load capacity N
06901-50-10804016	A	colza yellow RAL 1021	40	8	12	4	32	4	48	52	4,5	500
06901-50-10804086	A	signal green RAL 6032	40	8	12	4	32	4	48	52	4,5	500
06901-50-10804087	A	traffic blue RAL 5017	40	8	12	4	32	4	48	52	4,5	500
06901-50-10804084	A	traffic red RAL 3020	40	8	12	4	32	4	48	52	4,5	500
06901-50-10804088	A	light grey RAL 7035	40	8	12	4	32	4	48	52	4,5	500
06901-50-110040	A	black grey RAL 7021	40	10	14	4	33	4	50	54	4,5	500
06901-50-1100402	A	orange RAL 2004	40	10	14	4	33	4	50	54	4,5	500
06901-50-11004016	A	colza yellow RAL 1021	40	10	14	4	33	4	50	54	4,5	500
06901-50-11004086	A	signal green RAL 6032	40	10	14	4	33	4	50	54	4,5	500
06901-50-11004087	A	traffic blue RAL 5017	40	10	14	4	33	4	50	54	4,5	500
06901-50-11004084	A	traffic red RAL 3020	40	10	14	4	33	4	50	54	4,5	500
06901-50-11004088	A	light grey RAL 7035	40	10	14	4	33	4	50	54	4,5	500
06901-50-208030	B	black grey RAL 7021	30	8	-	4	32	-	38	-	4,5	500
06901-50-2080302	B	orange RAL 2004	30	8	-	4	32	-	38	-	4,5	500
06901-50-20803016	B	colza yellow RAL 1021	30	8	-	4	32	-	38	-	4,5	500
06901-50-20803086	B	signal green RAL 6032	30	8	-	4	32	-	38	-	4,5	500
06901-50-20803087	B	traffic blue RAL 5017	30	8	-	4	32	-	38	-	4,5	500
06901-50-20803084	B	traffic red RAL 3020	30	8	-	4	32	-	38	-	4,5	500
06901-50-20803088	B	light grey RAL 7035	30	8	-	4	32	-	38	-	4,5	500
06901-50-208040	B	black grey RAL 7021	40	8	-	4	32	-	48	-	4,5	500
06901-50-2080402	B	orange RAL 2004	40	8	-	4	32	-	48	-	4,5	500
06901-50-20804016	B	colza yellow RAL 1021	40	8	-	4	32	-	48	-	4,5	500
06901-50-20804086	B	signal green RAL 6032	40	8	-	4	32	-	48	-	4,5	500
06901-50-20804087	B	traffic blue RAL 5017	40	8	-	4	32	-	48	-	4,5	500
06901-50-20804084	B	traffic red RAL 3020	40	8	-	4	32	-	48	-	4,5	500
06901-50-20804088	B	light grey RAL 7035	40	8	-	4	32	-	48	-	4,5	500
06901-50-210040	B	black grey RAL 7021	40	10	-	4	33	-	50	-	4,5	500
06901-50-2100402	B	orange RAL 2004	40	10	-	4	33	-	50	-	4,5	500
06901-50-21004016	B	colza yellow RAL 1021	40	10	-	4	33	-	50	-	4,5	500
06901-50-21004086	B	signal green RAL 6032	40	10	-	4	33	-	50	-	4,5	500
06901-50-21004087	B	traffic blue RAL 5017	40	10	-	4	33	-	50	-	4,5	500
06901-50-21004084	B	traffic red RAL 3020	40	10	-	4	33	-	50	-	4,5	500
06901-50-21004088	B	light grey RAL 7035	40	10	-	4	33	-	50	-	4,5	500