

Item description/product images

INCH
Parts**Description****Material:**

Foot plate and threaded spindle steel.

Rubber support (NBR) 80 Shore.

Version:

Foot plate and threaded spindle electro zinc-plated steel.


Rubber support, vulcanised, black.

Note:

Steel levelling feet with rotatable threaded spindle and rubber base. The solid rubber base is permanently vulcanised onto the sheet metal plate. The rubber base has excellent surface traction. It is sound damping and impedes transmission of vibrations and impacts to or from the floor.

The load values specified in the table are based on a test series in which a static load was applied perpendicular to the plates through the centre of the spindle. Radially acting forces, such as those produced by vibrations or other shaking effects, affect the load rating and are not taken into account for the specified values.

Supplied with matching nut.

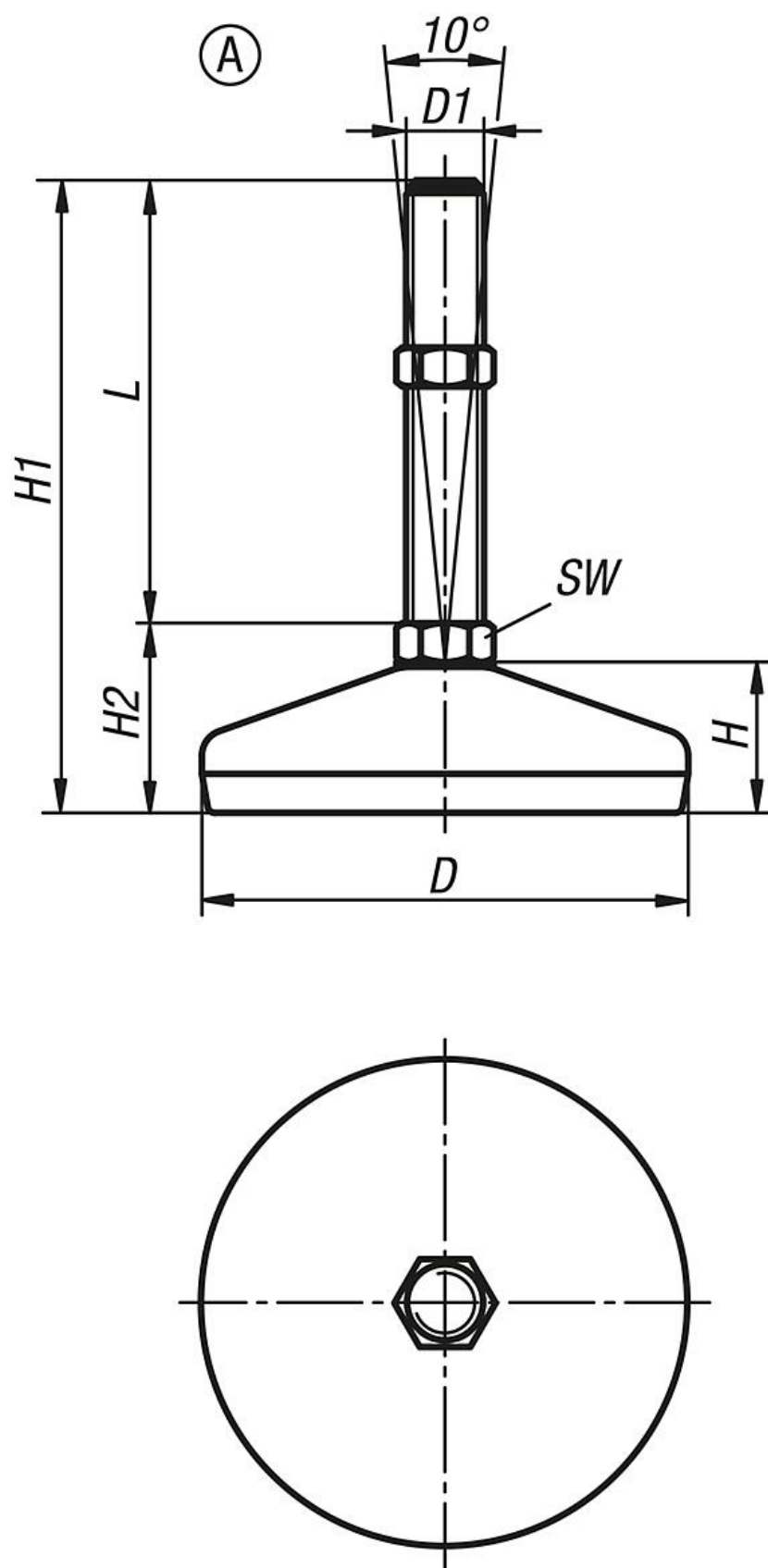

Overview of items

Order No.	Form	D	D1	H	H1	H2	L	SW	Load rating max. kN (static load only)
27790-11040A2X25	A	40	1/4-20	15	49,5	24,5	25	1/2	3
27790-11040A2X50	A	40	1/4-20	15	74,5	24,5	50	1/2	3
27790-11040A2X75	A	40	1/4-20	15	99,5	24,5	75	1/2	3
27790-11040A3X25	A	40	5/16-18	15	49,5	24,5	25	1/2	3
27790-11040A3X50	A	40	5/16-18	15	74,5	24,5	50	1/2	3
27790-11040A3X75	A	40	5/16-18	15	99,5	24,5	75	1/2	3
27790-11040A3X100	A	40	5/16-18	15	124,5	24,5	100	1/2	3
27790-11040A4X25	A	40	3/8-16	15	49,5	24,5	25	1/2	3
27790-11040A4X50	A	40	3/8-16	15	74,5	24,5	50	1/2	3
27790-11040A4X75	A	40	3/8-16	15	99,5	24,5	75	1/2	3
27790-11040A4X100	A	40	3/8-16	15	124,5	24,5	100	1/2	3
27790-11040A4X125	A	40	3/8-16	15	149,5	24,5	125	1/2	3
27790-11040A4X150	A	40	3/8-16	15	174,5	24,5	150	1/2	3
27790-11040A5X50	A	40	1/2-13	15	74,5	24,5	50	1/2	3
27790-11040A5X75	A	40	1/2-13	15	99,5	24,5	75	1/2	3
27790-11040A5X100	A	40	1/2-13	15	124,5	24,5	100	1/2	3
27790-11040A5X125	A	40	1/2-13	15	149,5	24,5	125	1/2	3
27790-11040A5X150	A	40	1/2-13	15	174,5	24,5	150	1/2	3
27790-11050A4X50	A	50	3/8-16	19	79	29	50	5/8	4
27790-11050A4X100	A	50	3/8-16	19	129	29	100	5/8	4
27790-11050A4X150	A	50	3/8-16	19	179	29	150	5/8	4
27790-11050A5X50	A	50	1/2-13	19	79	29	50	5/8	4
27790-11050A5X100	A	50	1/2-13	19	129	29	100	5/8	4
27790-11050A5X150	A	50	1/2-13	19	179	29	150	5/8	4
27790-11050A6X75	A	50	5/8-11	19	104	29	75	5/8	4
27790-11050A6X100	A	50	5/8-11	19	129	29	100	5/8	4
27790-11050A6X150	A	50	5/8-11	19	179	29	150	5/8	4
27790-11050A6X200	A	50	5/8-11	19	229	29	200	5/8	4
27790-11060A4X50	A	60	3/8-16	22	82	32	50	5/8	7
27790-11060A4X100	A	60	3/8-16	22	132	32	100	5/8	7
27790-11060A4X150	A	60	3/8-16	22	182	32	150	5/8	7
27790-11060A5X50	A	60	1/2-13	22	82	32	50	5/8	7
27790-11060A5X100	A	60	1/2-13	22	132	32	100	5/8	7
27790-11060A5X150	A	60	1/2-13	22	182	32	150	5/8	7
27790-11060A6X75	A	60	5/8-11	22	107	32	75	5/8	7
27790-11060A6X100	A	60	5/8-11	22	132	32	100	5/8	7
27790-11060A6X150	A	60	5/8-11	22	182	32	150	5/8	7
27790-11060A6X200	A	60	5/8-11	22	232	32	200	5/8	7
27790-11060A7X75	A	60	3/4-10	22	111	36	75	3/4	7
27790-11060A7X100	A	60	3/4-10	22	136	36	100	3/4	7
27790-11060A7X150	A	60	3/4-10	22	186	36	150	3/4	7
27790-11060A7X200	A	60	3/4-10	22	236	36	200	3/4	7
27790-11060A7X250	A	60	3/4-10	22	286	36	250	3/4	7
27790-11080A4X50	A	80	3/8-16	25	85	35	50	5/8	10
27790-11080A4X100	A	80	3/8-16	25	135	35	100	5/8	10
27790-11080A4X150	A	80	3/8-16	25	185	35	150	5/8	10
27790-11080A5X50	A	80	1/2-13	25	85	35	50	5/8	10
27790-11080A5X100	A	80	1/2-13	25	135	35	100	5/8	10
27790-11080A5X150	A	80	1/2-13	25	185	35	150	5/8	10
27790-11080A6X75	A	80	5/8-11	25	110	35	75	5/8	10
27790-11080A6X100	A	80	5/8-11	25	135	35	100	5/8	10
27790-11080A6X150	A	80	5/8-11	25	185	35	150	5/8	10
27790-11080A6X200	A	80	5/8-11	25	235	35	200	5/8	10
27790-11080A7X75	A	80	3/4-10	25	114	39	75	3/4	10
27790-11080A7X100	A	80	3/4-10	25	139	39	100	3/4	10
27790-11080A7X150	A	80	3/4-10	25	189	39	150	3/4	10
27790-11080A7X200	A	80	3/4-10	25	239	39	200	3/4	10
27790-11080A7X250	A	80	3/4-10	25	289	39	250	3/4	10
27790-11080A8X75	A	80	1-8	25	114	39	75	1	10
27790-11080A8X100	A	80	1-8	25	139	39	100	1	10
27790-11080A8X150	A	80	1-8	25	189	39	150	1	10
27790-11080A8X200	A	80	1-8	25	239	39	200	1	10
27790-11080A8X250	A	80	1-8	25	289	39	250	1	10
27790-11100A6X75	A	100	5/8-11	28	112,5	37,5	75	5/8	15

Overview of items

Order No.	Form	D	D1	H	H1	H2	L	SW	Load rating max. kN (static load only)
27790-11100A6X100	A	100	5/8-11	28	137,5	37,5	100	5/8	15
27790-11100A6X150	A	100	5/8-11	28	187,5	37,5	150	5/8	15
27790-11100A6X200	A	100	5/8-11	28	237,5	37,5	200	5/8	15
27790-11100A7X75	A	100	3/4-10	28	117	42	75	3/4	15
27790-11100A7X100	A	100	3/4-10	28	142	42	100	3/4	15
27790-11100A7X150	A	100	3/4-10	28	192	42	150	3/4	15
27790-11100A7X200	A	100	3/4-10	28	242	42	200	3/4	15
27790-11100A7X250	A	100	3/4-10	28	292	42	250	3/4	15
27790-11100A8X100	A	100	1-8	28	142	42	100	1	15
27790-11100A8X150	A	100	1-8	28	192	42	150	1	15
27790-11100A8X200	A	100	1-8	28	242	42	200	1	15
27790-11100A8X250	A	100	1-8	28	292	42	250	1	15
27790-11100AFX100	A	100	1 1/4-7	28	143	43	100	1 1/4	15
27790-11100AFX150	A	100	1 1/4-7	28	193	43	150	1 1/4	15
27790-11100AFX200	A	100	1 1/4-7	28	243	43	200	1 1/4	15
27790-11100AFX250	A	100	1 1/4-7	28	293	43	250	1 1/4	15
27790-11120A6X75	A	120	5/8-11	32	116,5	41,5	75	5/8	30
27790-11120A6X100	A	120	5/8-11	32	141,5	41,5	100	5/8	30
27790-11120A6X150	A	120	5/8-11	32	191,5	41,5	150	5/8	30
27790-11120A6X200	A	120	5/8-11	32	241,5	41,5	200	5/8	30
27790-11120A7X75	A	120	3/4-10	32	121	46	75	3/4	30
27790-11120A7X100	A	120	3/4-10	32	146	46	100	3/4	30
27790-11120A7X150	A	120	3/4-10	32	196	46	150	3/4	30
27790-11120A7X200	A	120	3/4-10	32	246	46	200	3/4	30
27790-11120A7X250	A	120	3/4-10	32	296	46	250	3/4	30
27790-11120A8X100	A	120	1-8	32	146	46	100	1	30
27790-11120A8X150	A	120	1-8	32	196	46	150	1	30
27790-11120A8X200	A	120	1-8	32	246	46	200	1	30
27790-11120A8X250	A	120	1-8	32	296	46	250	1	30
27790-11120AFX100	A	120	1 1/4-7	32	147,5	47,5	100	1 1/4	30
27790-11120AFX150	A	120	1 1/4-7	32	197,5	47,5	150	1 1/4	30
27790-11120AFX200	A	120	1 1/4-7	32	247,5	47,5	200	1 1/4	30
27790-11120AFX250	A	120	1 1/4-7	32	297,5	47,5	250	1 1/4	30
27790-11150A6X75	A	150	5/8-11	35	119,5	44,5	75	5/8	30
27790-11150A6X100	A	150	5/8-11	35	144,5	44,5	100	5/8	30
27790-11150A6X150	A	150	5/8-11	35	194,5	44,5	150	5/8	30
27790-11150A6X200	A	150	5/8-11	35	244,5	44,5	200	5/8	30
27790-11150A7X75	A	150	3/4-10	35	124	49	75	3/4	30
27790-11150A7X100	A	150	3/4-10	35	149	49	100	3/4	30
27790-11150A7X150	A	150	3/4-10	35	199	49	150	3/4	30
27790-11150A7X200	A	150	3/4-10	35	249	49	200	3/4	30
27790-11150A7X250	A	150	3/4-10	35	299	49	250	3/4	30
27790-11150A8X100	A	150	1-8	35	149	49	100	1	40
27790-11150A8X150	A	150	1-8	35	199	49	150	1	40
27790-11150A8X200	A	150	1-8	35	249	49	200	1	40
27790-11150A8X250	A	150	1-8	35	299	49	250	1	40
27790-11150AFX100	A	150	1 1/4-7	35	150,5	50,5	100	1 1/4	40
27790-11150AFX150	A	150	1 1/4-7	35	200,5	50,5	150	1 1/4	40
27790-11150AFX200	A	150	1 1/4-7	35	250,5	50,5	200	1 1/4	40
27790-11150AFX250	A	150	1 1/4-7	35	300,5	50,5	250	1 1/4	40