

Item description/product images



black satin finish RAL 9005	black textured matt RAL 9005	orange textured matt RAL 2004	colza yellow textured matt RAL 1021
traffic red textured matt RAL 3020	signal green textured matt RAL 6032	traffic blue textured matt RAL 5017	light grey textured matt RAL 7035
window grey textured matt RAL 7040	bright unpainted	high-gloss chromed	

Description

Material:

Handle die-cast zinc DIN EN 12844.  
Steel parts grade 5.8.

Version:

Handle powder-coated or high-gloss chromed.  
Steel parts black oxidised.


On request:

Other threads, colours and special versions.  
Dimension "H1" available in other lengths at extra charge.

lift to  
disengage



Drawings

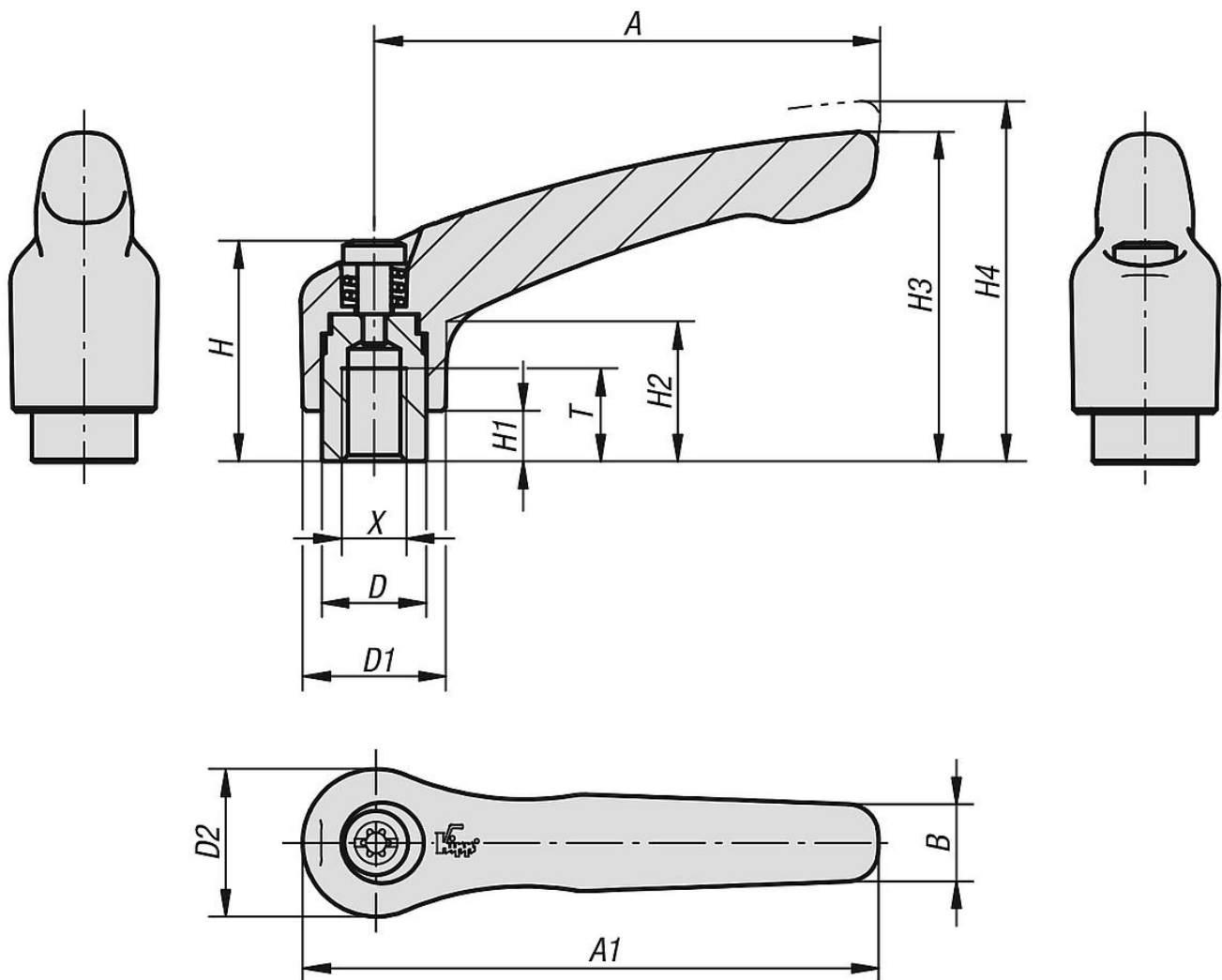

Overview of items

Order No.	Main colour	Surface finish body	Size	X	T	D	D1	D2	H	H1	H2	H3	H4	A	A1	B	No. of teeth
06450-9AD1	jet black RAL 9005	satin finish	9	6-32	6	8	11	11,5	21,4	4	11,9	24	27	22	27,7	6,4	12
06450-9AE1	jet black RAL 9005	satin finish	9	8-32	6	8	11	11,5	21,4	4	11,9	24	27	22	27,7	6,4	12
06450-9A11	jet black RAL 9005	satin finish	9	10-32	6	8	11	11,5	21,4	4	11,9	24	27	22	27,7	6,4	12
06450-0AD1	jet black RAL 9005	satin finish	0	6-32	9	10	13	14	24,5	4	14,5	30	33	30	37	7	16
06450-0AE1	jet black RAL 9005	satin finish	0	8-32	9	10	13	14	24,5	4	14,5	30	33	30	37	7	16
06450-0A01	jet black RAL 9005	satin finish	0	10-24	9	10	13	14	24,5	4	14,5	30	33	30	37	7	16
06450-0A11	jet black RAL 9005	satin finish	0	10-32	9	10	13	14	24,5	4	14,5	30	33	30	37	7	16
06450-0A21	jet black RAL 9005	satin finish	0	1/4-20	9	10	13	14	24,5	4	14,5	30	33	30	37	7	16
06450-1AE1	jet black RAL 9005	satin finish	1	8-32	9	10	13	14	24,5	4	14,5	31	34	40	47	7	16
06450-1A01	jet black RAL 9005	satin finish	1	10-24	9	10	13	14	24,5	4	14,5	31	34	40	47	7	16
06450-1A11	jet black RAL 9005	satin finish	1	10-32	9	10	13	14	24,5	4	14,5	31	34	40	47	7	16
06450-1A21	jet black RAL 9005	satin finish	1	1/4-20	9	10	13	14	24,5	4	14,5	31	34	40	47	7	16
06450-2A21	jet black RAL 9005	satin finish	2	1/4-20	12	13,5	18,5	19	28,5	6,5	17,5	42,5	45,5	65	74,5	9,5	20
06450-2A31	jet black RAL 9005	satin finish	2	5/16-18	12	13,5	18,5	19	28,5	6,5	17,5	42,5	45,5	65	74,5	9,5	20
06450-3A31	jet black RAL 9005	satin finish	3	5/16-18	14	16	21	22	37	10	24	54,5	58,5	80	91	11	22
06450-3A41	jet black RAL 9005	satin finish	3	3/8-16	14	16	21	22	37	10	24	54,5	58,5	80	91	11	22
06450-4A41	jet black RAL 9005	satin finish	4	3/8-16	17	19	27	27,5	43	10	27	63	67,5	95	109	13	24
06450-4A51	jet black RAL 9005	satin finish	4	1/2-13	17	19	27	27,5	43	10	27	63	67,5	95	109	13	24
06450-5A51	jet black RAL 9005	satin finish	5	1/2-13	23	23	31	32	49	12	31,5	73	77,5	110	126	15	26
06450-5A61	jet black RAL 9005	satin finish	5	5/8-11	23	23	31	32	49	12	31,5	73	77,5	110	126	15	26
06450-9AD181	jet black RAL 9005	textured matt	9	6-32	6	8	11	11,5	21,4	4	11,9	24	27	22	27,7	6,4	12

Overview of items

Order No.	Main colour	Surface finish body	Size	X	T	D	D1	D2	H	H1	H2	H3	H4	A	A1	B	No. of teeth
06450-9AE181	jet black RAL 9005	textured matt	9	8-32	6	8	11	11,5	21,4	4	11,9	24	27	22	27,7	6,4	12
06450-9A1181	jet black RAL 9005	textured matt	9	10-32	6	8	11	11,5	21,4	4	11,9	24	27	22	27,7	6,4	12
06450-0AD181	jet black RAL 9005	textured matt	0	6-32	9	10	13	14	24,5	4	14,5	30	33	30	37	7	16
06450-0AE181	jet black RAL 9005	textured matt	0	8-32	9	10	13	14	24,5	4	14,5	30	33	30	37	7	16
06450-0A0181	jet black RAL 9005	textured matt	0	10-24	9	10	13	14	24,5	4	14,5	30	33	30	37	7	16
06450-0A1181	jet black RAL 9005	textured matt	0	10-32	9	10	13	14	24,5	4	14,5	30	33	30	37	7	16
06450-0A2181	jet black RAL 9005	textured matt	0	1/4-20	9	10	13	14	24,5	4	14,5	30	33	30	37	7	16
06450-1AE181	jet black RAL 9005	textured matt	1	8-32	9	10	13	14	24,5	4	14,5	31	34	40	47	7	16
06450-1A0181	jet black RAL 9005	textured matt	1	10-24	9	10	13	14	24,5	4	14,5	31	34	40	47	7	16
06450-1A1181	jet black RAL 9005	textured matt	1	10-32	9	10	13	14	24,5	4	14,5	31	34	40	47	7	16
06450-1A2181	jet black RAL 9005	textured matt	1	1/4-20	9	10	13	14	24,5	4	14,5	31	34	40	47	7	16
06450-2A2181	jet black RAL 9005	textured matt	2	1/4-20	12	13,5	18,5	19	28,5	6,5	17,5	42,5	45,5	65	74,5	9,5	20
06450-2A3181	jet black RAL 9005	textured matt	2	5/16-18	12	13,5	18,5	19	28,5	6,5	17,5	42,5	45,5	65	74,5	9,5	20
06450-3A3181	jet black RAL 9005	textured matt	3	5/16-18	14	16	21	22	37	10	24	54,5	58,5	80	91	11	22
06450-3A4181	jet black RAL 9005	textured matt	3	3/8-16	14	16	21	22	37	10	24	54,5	58,5	80	91	11	22
06450-4A4181	jet black RAL 9005	textured matt	4	3/8-16	17	19	27	27,5	43	10	27	63	67,5	95	109	13	24
06450-4A5181	jet black RAL 9005	textured matt	4	1/2-13	17	19	27	27,5	43	10	27	63	67,5	95	109	13	24
06450-5A5181	jet black RAL 9005	textured matt	5	1/2-13	23	23	31	32	49	12	31,5	73	77,5	110	126	15	26
06450-5A6181	jet black RAL 9005	textured matt	5	5/8-11	23	23	31	32	49	12	31,5	73	77,5	110	126	15	26
06450-9AD182	orange RAL 2004	textured matt	9	6-32	6	8	11	11,5	21,4	4	11,9	24	27	22	27,7	6,4	12
06450-9AE182	orange RAL 2004	textured matt	9	8-32	6	8	11	11,5	21,4	4	11,9	24	27	22	27,7	6,4	12
06450-9A1182	orange RAL 2004	textured matt	9	10-32	6	8	11	11,5	21,4	4	11,9	24	27	22	27,7	6,4	12
06450-0AD182	orange RAL 2004	textured matt	0	6-32	9	10	13	14	24,5	4	14,5	30	33	30	37	7	16
06450-0AE182	orange RAL 2004	textured matt	0	8-32	9	10	13	14	24,5	4	14,5	30	33	30	37	7	16
06450-0A0182	orange RAL 2004	textured matt	0	10-24	9	10	13	14	24,5	4	14,5	30	33	30	37	7	16
06450-0A1182	orange RAL 2004	textured matt	0	10-32	9	10	13	14	24,5	4	14,5	30	33	30	37	7	16
06450-0A2182	orange RAL 2004	textured matt	0	1/4-20	9	10	13	14	24,5	4	14,5	30	33	30	37	7	16
06450-1AE182	orange RAL 2004	textured matt	1	8-32	9	10	13	14	24,5	4	14,5	31	34	40	47	7	16
06450-1A0182	orange RAL 2004	textured matt	1	10-24	9	10	13	14	24,5	4	14,5	31	34	40	47	7	16
06450-1A1182	orange RAL 2004	textured matt	1	10-32	9	10	13	14	24,5	4	14,5	31	34	40	47	7	16
06450-1A2182	orange RAL 2004	textured matt	1	1/4-20	9	10	13	14	24,5	4	14,5	31	34	40	47	7	16
06450-2A2182	orange RAL 2004	textured matt	2	1/4-20	12	13,5	18,5	19	28,5	6,5	17,5	42,5	45,5	65	74,5	9,5	20
06450-2A3182	orange RAL 2004	textured matt	2	5/16-18	12	13,5	18,5	19	28,5	6,5	17,5	42,5	45,5	65	74,5	9,5	20
06450-3A3182	orange RAL 2004	textured matt	3	5/16-18	14	16	21	22	37	10	24	54,5	58,5	80	91	11	22
06450-3A4182	orange RAL 2004	textured matt	3	3/8-16	14	16	21	22	37	10	24	54,5	58,5	80	91	11	22
06450-4A4182	orange RAL 2004	textured matt	4	3/8-16	17	19	27	27,5	43	10	27	63	67,5	95	109	13	24
06450-4A5182	orange RAL 2004	textured matt	4	1/2-13	17	19	27	27,5	43	10	27	63	67,5	95	109	13	24
06450-5A5182	orange RAL 2004	textured matt	5	1/2-13	23	23	31	32	49	12	31,5	73	77,5	110	126	15	26
06450-5A6182	orange RAL 2004	textured matt	5	5/8-11	23	23	31	32	49	12	31,5	73	77,5	110	126	15	26
06450-9AD183	colza yellow RAL 1021	textured matt	9	6-32	6	8	11	11,5	21,4	4	11,9	24	27	22	27,7	6,4	12
06450-9AE183	colza yellow RAL 1021	textured matt	9	8-32	6	8	11	11,5	21,4	4	11,9	24	27	22	27,7	6,4	12
06450-9A1183	colza yellow RAL 1021	textured matt	9	10-32	6	8	11	11,5	21,4	4	11,9	24	27	22	27,7	6,4	12
06450-0AD183	colza yellow RAL 1021	textured matt	0	6-32	9	10	13	14	24,5	4	14,5	30	33	30	37	7	16
06450-0AE183	colza yellow RAL 1021	textured matt	0	8-32	9	10	13	14	24,5	4	14,5	30	33	30	37	7	16
06450-0A0183	colza yellow RAL 1021	textured matt	0	10-24	9	10	13	14	24,5	4	14,5	30	33	30	37	7	16
06450-0A1183	colza yellow RAL 1021	textured matt	0	10-32	9	10	13	14	24,5	4	14,5	30	33	30	37	7	16
06450-0A2183	colza yellow RAL 1021	textured matt	0	1/4-20	9	10	13	14	24,5	4	14,5	30	33	30	37	7	16
06450-1AE183	colza yellow RAL 1021	textured matt	1	8-32	9	10	13	14	24,5	4	14,5	31	34	40	47	7	16
06450-1A0183	colza yellow RAL 1021	textured matt	1	10-24	9	10	13	14	24,5	4	14,5	31	34	40	47	7	16
06450-1A1183	colza yellow RAL 1021	textured matt	1	10-32	9	10	13	14	24,5	4	14,5	31	34	40	47	7	16
06450-1A2183	colza yellow RAL 1021	textured matt	1	1/4-20	9	10	13	14	24,5	4	14,5	31	34	40	47	7	16
06450-2A2183	colza yellow RAL 1021	textured matt	2	1/4-20	12	13,5	18,5	19	28,5	6,5	17,5	42,5	45,5	65	74,5	9,5	20
06450-2A3183	colza yellow RAL 1021	textured matt	2	5/16-18	12	13,5	18,5	19	28,5	6,5	17,5	42,5	45,5	65	74,5	9,5	20
06450-3A3183	colza yellow RAL 1021	textured matt	3	5/16-18	14	16	21	22	37	10	24	54,5	58,5	80	91	11	22
06450-3A4183	colza yellow RAL 1021	textured matt	3	3/8-16	14	16	21	22	37	10	24	54,5	58,5	80	91	11	22
06450-4A4183	colza yellow RAL 1021	textured matt	4	3/8-16	17	19	27	27,5	43	10	27	63	67,5	95	109	13	24
06450-4A5183	colza yellow RAL 1021	textured matt	4	1/2-13	17	19	27	27,5	43	10	27	63	67,5	95	109	13	24
06450-5A5183	colza yellow RAL 1021	textured matt	5	1/2-13	23	23	31	32	49	12	31,5	73	77,5	110	126	15	26
06450-5A6183	colza yellow RAL 1021	textured matt	5	5/8-11	23	23	31	32	49	12	31,5	73	77,5	110	126	15	26
06450-9AD184	traffic red RAL 3020	textured matt	9	6-32	6	8	11	11,5	21,4	4	11,9	24	27	22	27,7	6,4	12
06450-9AE184	traffic red RAL 3020	textured matt	9	8-32	6	8	11	11,5	21,4	4	11,9	24	27	22	27,7	6,4	12
06450-9A1184	traffic red RAL 3020	textured matt	9	10-32	6	8	11	11,5	21,4	4	11,9	24	27	22	27,7	6,4	12
06450-0AD184	traffic red RAL 3020	textured matt	0	6-32	9	10	13	14	24,5	4	14,5	30	33	30	37	7	16
06450-0AE184	traffic red RAL 3020	textured matt	0	8-32	9	10	13	14	24,5	4	14,5	30	33	30	37	7	16
06450-0A0184	traffic red RAL 3020	textured matt	0	10-24	9	10	13	14	24,5	4	14,5	30	33	30	37	7	16

## Overview of items

Order No.	Main colour	Surface finish body	Size	X	T	D	D1	D2	H	H1	H2	H3	H4	A	A1	B	No. of teeth
06450-0A1184	traffic red RAL 3020	textured matt	0	10-32	9	10	13	14	24,5	4	14,5	30	33	30	37	7	16
06450-0A2184	traffic red RAL 3020	textured matt	0	1/4-20	9	10	13	14	24,5	4	14,5	30	33	30	37	7	16
06450-1AE184	traffic red RAL 3020	textured matt	1	8-32	9	10	13	14	24,5	4	14,5	31	34	40	47	7	16
06450-1A0184	traffic red RAL 3020	textured matt	1	10-24	9	10	13	14	24,5	4	14,5	31	34	40	47	7	16
06450-1A1184	traffic red RAL 3020	textured matt	1	10-32	9	10	13	14	24,5	4	14,5	31	34	40	47	7	16
06450-1A2184	traffic red RAL 3020	textured matt	1	1/4-20	9	10	13	14	24,5	4	14,5	31	34	40	47	7	16
06450-2A2184	traffic red RAL 3020	textured matt	2	1/4-20	12	13,5	18,5	19	28,5	6,5	17,5	42,5	45,5	65	74,5	9,5	20
06450-2A3184	traffic red RAL 3020	textured matt	2	5/16-18	12	13,5	18,5	19	28,5	6,5	17,5	42,5	45,5	65	74,5	9,5	20
06450-3A3184	traffic red RAL 3020	textured matt	3	5/16-18	14	16	21	22	37	10	24	54,5	58,5	80	91	11	22
06450-3A4184	traffic red RAL 3020	textured matt	3	3/8-16	14	16	21	22	37	10	24	54,5	58,5	80	91	11	22
06450-4A4184	traffic red RAL 3020	textured matt	4	3/8-16	17	19	27	27,5	43	10	27	63	67,5	95	109	13	24
06450-4A5184	traffic red RAL 3020	textured matt	4	1/2-13	17	19	27	27,5	43	10	27	63	67,5	95	109	13	24
06450-5A5184	traffic red RAL 3020	textured matt	5	1/2-13	23	23	31	32	49	12	31,5	73	77,5	110	126	15	26
06450-5A6184	traffic red RAL 3020	textured matt	5	5/8-11	23	23	31	32	49	12	31,5	73	77,5	110	126	15	26
06450-9AD185	signal green RAL 6032	textured matt	9	6-32	6	8	11	11,5	21,4	4	11,9	24	27	22	27,7	6,4	12
06450-9AE185	signal green RAL 6032	textured matt	9	8-32	6	8	11	11,5	21,4	4	11,9	24	27	22	27,7	6,4	12
06450-9A1185	signal green RAL 6032	textured matt	9	10-32	6	8	11	11,5	21,4	4	11,9	24	27	22	27,7	6,4	12
06450-0AD185	signal green RAL 6032	textured matt	0	6-32	9	10	13	14	24,5	4	14,5	30	33	30	37	7	16
06450-0AE185	signal green RAL 6032	textured matt	0	8-32	9	10	13	14	24,5	4	14,5	30	33	30	37	7	16
06450-0A0185	signal green RAL 6032	textured matt	0	10-24	9	10	13	14	24,5	4	14,5	30	33	30	37	7	16
06450-0A1185	signal green RAL 6032	textured matt	0	10-32	9	10	13	14	24,5	4	14,5	30	33	30	37	7	16
06450-0A2185	signal green RAL 6032	textured matt	0	1/4-20	9	10	13	14	24,5	4	14,5	30	33	30	37	7	16
06450-1AE185	signal green RAL 6032	textured matt	1	8-32	9	10	13	14	24,5	4	14,5	31	34	40	47	7	16
06450-1A0185	signal green RAL 6032	textured matt	1	10-24	9	10	13	14	24,5	4	14,5	31	34	40	47	7	16
06450-1A1185	signal green RAL 6032	textured matt	1	10-32	9	10	13	14	24,5	4	14,5	31	34	40	47	7	16
06450-1A2185	signal green RAL 6032	textured matt	1	1/4-20	9	10	13	14	24,5	4	14,5	31	34	40	47	7	16
06450-2A2185	signal green RAL 6032	textured matt	2	1/4-20	12	13,5	18,5	19	28,5	6,5	17,5	42,5	45,5	65	74,5	9,5	20
06450-2A3185	signal green RAL 6032	textured matt	2	5/16-18	12	13,5	18,5	19	28,5	6,5	17,5	42,5	45,5	65	74,5	9,5	20
06450-3A3185	signal green RAL 6032	textured matt	3	5/16-18	14	16	21	22	37	10	24	54,5	58,5	80	91	11	22
06450-3A4185	signal green RAL 6032	textured matt	3	3/8-16	14	16	21	22	37	10	24	54,5	58,5	80	91	11	22
06450-4A4185	signal green RAL 6032	textured matt	4	3/8-16	17	19	27	27,5	43	10	27	63	67,5	95	109	13	24
06450-4A5185	signal green RAL 6032	textured matt	4	1/2-13	17	19	27	27,5	43	10	27	63	67,5	95	109	13	24
06450-5A5185	signal green RAL 6032	textured matt	5	1/2-13	23	23	31	32	49	12	31,5	73	77,5	110	126	15	26
06450-5A6185	signal green RAL 6032	textured matt	5	5/8-11	23	23	31	32	49	12	31,5	73	77,5	110	126	15	26
06450-9AD186	traffic blue RAL 5017	textured matt	9	6-32	6	8	11	11,5	21,4	4	11,9	24	27	22	27,7	6,4	12
06450-9AE186	traffic blue RAL 5017	textured matt	9	8-32	6	8	11	11,5	21,4	4	11,9	24	27	22	27,7	6,4	12
06450-9A1186	traffic blue RAL 5017	textured matt	9	10-32	6	8	11	11,5	21,4	4	11,9	24	27	22	27,7	6,4	12
06450-0AD186	traffic blue RAL 5017	textured matt	0	6-32	9	10	13	14	24,5	4	14,5	30	33	30	37	7	16
06450-0AE186	traffic blue RAL 5017	textured matt	0	8-32	9	10	13	14	24,5	4	14,5	30	33	30	37	7	16
06450-0A0186	traffic blue RAL 5017	textured matt	0	10-24	9	10	13	14	24,5	4	14,5	30	33	30	37	7	16
06450-0A1186	traffic blue RAL 5017	textured matt	0	10-32	9	10	13	14	24,5	4	14,5	30	33	30	37	7	16
06450-0A2186	traffic blue RAL 5017	textured matt	0	1/4-20	9	10	13	14	24,5	4	14,5	30	33	30	37	7	16
06450-1AE186	traffic blue RAL 5017	textured matt	1	8-32	9	10	13	14	24,5	4	14,5	31	34	40	47	7	16
06450-1A0186	traffic blue RAL 5017	textured matt	1	10-24	9	10	13	14	24,5	4	14,5	31	34	40	47	7	16
06450-1A1186	traffic blue RAL 5017	textured matt	1	10-32	9	10	13	14	24,5	4	14,5	31	34	40	47	7	16
06450-1A2186	traffic blue RAL 5017	textured matt	1	1/4-20	9	10	13	14	24,5	4	14,5	31	34	40	47	7	16
06450-2A2186	traffic blue RAL 5017	textured matt	2	1/4-20	12	13,5	18,5	19	28,5	6,5	17,5	42,5	45,5	65	74,5	9,5	20
06450-2A3186	traffic blue RAL 5017	textured matt	2	5/16-18	12	13,5	18,5	19	28,5	6,5	17,5	42,5	45,5	65	74,5	9,5	20
06450-3A3186	traffic blue RAL 5017	textured matt	3	5/16-18	14	16	21	22	37	10	24	54,5	58,5	80	91	11	22
06450-3A4186	traffic blue RAL 5017	textured matt	3	3/8-16	14	16	21	22	37	10	24	54,5	58,5	80	91	11	22
06450-4A4186	traffic blue RAL 5017	textured matt	4	3/8-16	17	19	27	27,5	43	10	27	63	67,5	95	109	13	24
06450-4A5186	traffic blue RAL 5017	textured matt	4	1/2-13	17	19	27	27,5	43	10	27	63	67,5	95	109	13	24
06450-5A5186	traffic blue RAL 5017	textured matt	5	1/2-13	23	23	31	32	49	12	31,5	73	77,5	110	126	15	26
06450-5A6186	traffic blue RAL 5017	textured matt	5	5/8-11	23	23	31	32	49	12	31,5	73	77,5	110	126	15	26
06450-9AD187	light grey RAL 7035	textured matt	9	6-32	6	8	11	11,5	21,4	4	11,9	24	27	22	27,7	6,4	12
06450-9AE187	light grey RAL 7035	textured matt	9	8-32	6	8	11	11,5	21,4	4	11,9	24	27	22	27,7	6,4	12
06450-9A1187	light grey RAL 7035	textured matt	9	10-32	6	8	11	11,5	21,4	4	11,9	24	27	22	27,7	6,4	12
06450-0AD187	light grey RAL 7035	textured matt	0	6-32	9	10	13	14	24,5	4	14,5	30	33	30	37	7	16
06450-0AE187	light grey RAL 7035	textured matt	0	8-32	9	10	13	14	24,5	4	14,5	30	33	30	37	7	16
06450-0A0187	light grey RAL 7035	textured matt	0	10-24	9	10	13	14	24,5	4	14,5	30	33	30	37	7	16
06450-0A1187	light grey RAL 7035	textured matt	0	10-32	9	10	13	14	24,5	4	14,5	30	33	30	37	7	16
06450-0A2187	light grey RAL 7035	textured matt	0	1/4-20	9	10	13	14	24,5	4	14,5	30	33	30	37	7	16
06450-1AE187	light grey RAL 7035	textured matt	1	8-32	9	10	13	14	24,5	4	14,5	31	34	40	47	7	16
06450-1A0187	light grey RAL 7035	textured matt	1	10-24	9	10	13	14	24,5	4	14,5	31	34	40	47	7	16
06450-1A1187	light grey RAL 7035	textured matt	1	10-32	9	10	13	14	24,5	4	14,5	31	34	40	47	7	16

Overview of items

Order No.	Main colour	Surface finish body	Size	X	T	D	D1	D2	H	H1	H2	H3	H4	A	A1	B	No. of teeth
06450-1A2187	light grey RAL 7035	textured matt	1	1/4-20	9	10	13	14	24,5	4	14,5	31	34	40	47	7	16
06450-2A2187	light grey RAL 7035	textured matt	2	1/4-20	12	13,5	18,5	19	28,5	6,5	17,5	42,5	45,5	65	74,5	9,5	20
06450-2A3187	light grey RAL 7035	textured matt	2	5/16-18	12	13,5	18,5	19	28,5	6,5	17,5	42,5	45,5	65	74,5	9,5	20
06450-3A3187	light grey RAL 7035	textured matt	3	5/16-18	14	16	21	22	37	10	24	54,5	58,5	80	91	11	22
06450-3A4187	light grey RAL 7035	textured matt	3	3/8-16	14	16	21	22	37	10	24	54,5	58,5	80	91	11	22
06450-4A4187	light grey RAL 7035	textured matt	4	3/8-16	17	19	27	27,5	43	10	27	63	67,5	95	109	13	24
06450-4A5187	light grey RAL 7035	textured matt	4	1/2-13	17	19	27	27,5	43	10	27	63	67,5	95	109	13	24
06450-5A5187	light grey RAL 7035	textured matt	5	1/2-13	23	23	31	32	49	12	31,5	73	77,5	110	126	15	26
06450-5A6187	light grey RAL 7035	textured matt	5	5/8-11	23	23	31	32	49	12	31,5	73	77,5	110	126	15	26
06450-9AD188	window grey RAL 7040	textured matt	9	6-32	6	8	11	11,5	21,4	4	11,9	24	27	22	27,7	6,4	12
06450-9AE188	window grey RAL 7040	textured matt	9	8-32	6	8	11	11,5	21,4	4	11,9	24	27	22	27,7	6,4	12
06450-9A1188	window grey RAL 7040	textured matt	9	10-32	6	8	11	11,5	21,4	4	11,9	24	27	22	27,7	6,4	12
06450-0AD188	window grey RAL 7040	textured matt	0	6-32	9	10	13	14	24,5	4	14,5	30	33	30	37	7	16
06450-0AE188	window grey RAL 7040	textured matt	0	8-32	9	10	13	14	24,5	4	14,5	30	33	30	37	7	16
06450-0A0188	window grey RAL 7040	textured matt	0	10-24	9	10	13	14	24,5	4	14,5	30	33	30	37	7	16
06450-0A1188	window grey RAL 7040	textured matt	0	10-32	9	10	13	14	24,5	4	14,5	30	33	30	37	7	16
06450-0A2188	window grey RAL 7040	textured matt	0	1/4-20	9	10	13	14	24,5	4	14,5	30	33	30	37	7	16
06450-1AE188	window grey RAL 7040	textured matt	1	8-32	9	10	13	14	24,5	4	14,5	31	34	40	47	7	16
06450-1A0188	window grey RAL 7040	textured matt	1	10-24	9	10	13	14	24,5	4	14,5	31	34	40	47	7	16
06450-1A1188	window grey RAL 7040	textured matt	1	10-32	9	10	13	14	24,5	4	14,5	31	34	40	47	7	16
06450-1A2188	window grey RAL 7040	textured matt	1	1/4-20	9	10	13	14	24,5	4	14,5	31	34	40	47	7	16
06450-2A2188	window grey RAL 7040	textured matt	2	1/4-20	12	13,5	18,5	19	28,5	6,5	17,5	42,5	45,5	65	74,5	9,5	20
06450-2A3188	window grey RAL 7040	textured matt	2	5/16-18	12	13,5	18,5	19	28,5	6,5	17,5	42,5	45,5	65	74,5	9,5	20
06450-3A3188	window grey RAL 7040	textured matt	3	5/16-18	14	16	21	22	37	10	24	54,5	58,5	80	91	11	22
06450-3A4188	window grey RAL 7040	textured matt	3	3/8-16	14	16	21	22	37	10	24	54,5	58,5	80	91	11	22
06450-4A4188	window grey RAL 7040	textured matt	4	3/8-16	17	19	27	27,5	43	10	27	63	67,5	95	109	13	24
06450-4A5188	window grey RAL 7040	textured matt	4	1/2-13	17	19	27	27,5	43	10	27	63	67,5	95	109	13	24
06450-5A5188	window grey RAL 7040	textured matt	5	1/2-13	23	23	31	32	49	12	31,5	73	77,5	110	126	15	26
06450-5A6188	window grey RAL 7040	textured matt	5	5/8-11	23	23	31	32	49	12	31,5	73	77,5	110	126	15	26
06450-9AD008	-	bright	9	6-32	6	8	11	11,5	21,4	4	11,9	24	27	22	27,7	6,4	12
06450-9AE008	-	bright	9	8-32	6	8	11	11,5	21,4	4	11,9	24	27	22	27,7	6,4	12
06450-9A1008	-	bright	9	10-32	6	8	11	11,5	21,4	4	11,9	24	27	22	27,7	6,4	12
06450-0AD008	-	bright	0	6-32	9	10	13	14	24,5	4	14,5	30	33	30	37	7	16
06450-0AE008	-	bright	0	8-32	9	10	13	14	24,5	4	14,5	30	33	30	37	7	16
06450-0A0008	-	bright	0	10-24	9	10	13	14	24,5	4	14,5	30	33	30	37	7	16
06450-0A1008	-	bright	0	10-32	9	10	13	14	24,5	4	14,5	30	33	30	37	7	16
06450-0A2008	-	bright	0	1/4-20	9	10	13	14	24,5	4	14,5	30	33	30	37	7	16
06450-1AE008	-	bright	1	8-32	9	10	13	14	24,5	4	14,5	31	34	40	47	7	16
06450-1A0008	-	bright	1	10-24	9	10	13	14	24,5	4	14,5	31	34	40	47	7	16
06450-1A1008	-	bright	1	10-32	9	10	13	14	24,5	4	14,5	31	34	40	47	7	16
06450-1A2008	-	bright	1	1/4-20	9	10	13	14	24,5	4	14,5	31	34	40	47	7	16
06450-2A2008	-	bright	2	1/4-20	12	13,5	18,5	19	28,5	6,5	17,5	42,5	45,5	65	74,5	9,5	20
06450-2A3008	-	bright	2	5/16-18	12	13,5	18,5	19	28,5	6,5	17,5	42,5	45,5	65	74,5	9,5	20
06450-3A3008	-	bright	3	5/16-18	14	16	21	22	37	10	24	54,5	58,5	80	91	11	22
06450-3A4008	-	bright	3	3/8-16	14	16	21	22	37	10	24	54,5	58,5	80	91	11	22
06450-4A4008	-	bright	4	3/8-16	17	19	27	27,5	43	10	27	63	67,5	95	109	13	24
06450-4A5008	-	bright	4	1/2-13	17	19	27	27,5	43	10	27	63	67,5	95	109	13	24
06450-5A5008	-	bright	5	1/2-13	23	23	31	32	49	12	31,5	73	77,5	110	126	15	26
06450-5A6008	-	bright	5	5/8-11	23	23	31	32	49	12	31,5	73	77,5	110	126	15	26
06450-9AD6	silver	high-gloss chromed	9	6-32	6	8	11	11,5	21,4	4	11,9	24	27	22	27,7	6,4	12
06450-9AE6	silver	high-gloss chromed	9	8-32	6	8	11	11,5	21,4	4	11,9	24	27	22	27,7	6,4	12
06450-9A16	silver	high-gloss chromed	9	10-32	6	8	11	11,5	21,4	4	11,9	24	27	22	27,7	6,4	12
06450-0AD6	silver	high-gloss chromed	0	6-32	9	10	13	14	24,5	4	14,5	30	33	30	37	7	16
06450-0AE6	silver	high-gloss chromed	0	8-32	9	10	13	14	24,5	4	14,5	30	33	30	37	7	16
06450-0A06	silver	high-gloss chromed	0	10-24	9	10	13	14	24,5	4	14,5	30	33	30	37	7	16
06450-0A16	silver	high-gloss chromed	0	10-32	9	10	13	14	24,5	4	14,5	30	33	30	37	7	16
06450-0A26	silver	high-gloss chromed	0	1/4-20	9	10	13	14	24,5	4	14,5	30	33	30	37	7	16
06450-1AE6	silver	high-gloss chromed	1	8-32	9	10	13	14	24,5	4	14,5	31	34	40	47	7	16
06450-1A06	silver	high-gloss chromed	1	10-24	9	10	13	14	24,5	4	14,5	31	34	40	47	7	16
06450-1A16	silver	high-gloss chromed	1	10-32	9	10	13	14	24,5	4	14,5	31	34	40	47	7	16
06450-1A26	silver	high-gloss chromed	1	1/4-20	9	10	13	14	24,5	4	14,5	31	34	40	47	7	16
06450-2A26	silver	high-gloss chromed	2	1/4-20	12	13,5	18,5	19	28,5	6,5	17,5	42,5	45,5	65	74,5	9,5	20
06450-2A36	silver	high-gloss chromed	2	5/16-18	12	13,5	18,5	19	28,5	6,5	17,5	42,5	45,5	65	74,5	9,5	20
06450-3A36	silver	high-gloss chromed	3	5/16-18	14	16	21	22	37	10	24	54,5	58,5	80	91	11	22
06450-3A46	silver	high-gloss chromed	3	3/8-16	14	16	21	22	37	10	24	54,5	58,5	80	91	11	22

## Overview of items

Order No.	Main colour	Surface finish body	Size	X	T	D	D1	D2	H	H1	H2	H3	H4	A	A1	B	No. of teeth
06450-4A46	silver	high-gloss chromed	4	3/8-16	17	19	27	27,5	43	10	27	63	67,5	95	109	13	24
06450-4A56	silver	high-gloss chromed	4	1/2-13	17	19	27	27,5	43	10	27	63	67,5	95	109	13	24
06450-5A56	silver	high-gloss chromed	5	1/2-13	23	23	31	32	49	12	31,5	73	77,5	110	126	15	26
06450-5A66	silver	high-gloss chromed	5	5/8-11	23	23	31	32	49	12	31,5	73	77,5	110	126	15	26