

Item description/product images



Description

Material:

Disc handwheel in aluminium.

Version:


Wheel rim turned and polished.
Radial and axial run-out of rim < IT 12.

On request:

Hubs with square socket or powder-coated handwheels.

Drawings

without cylindrical grip

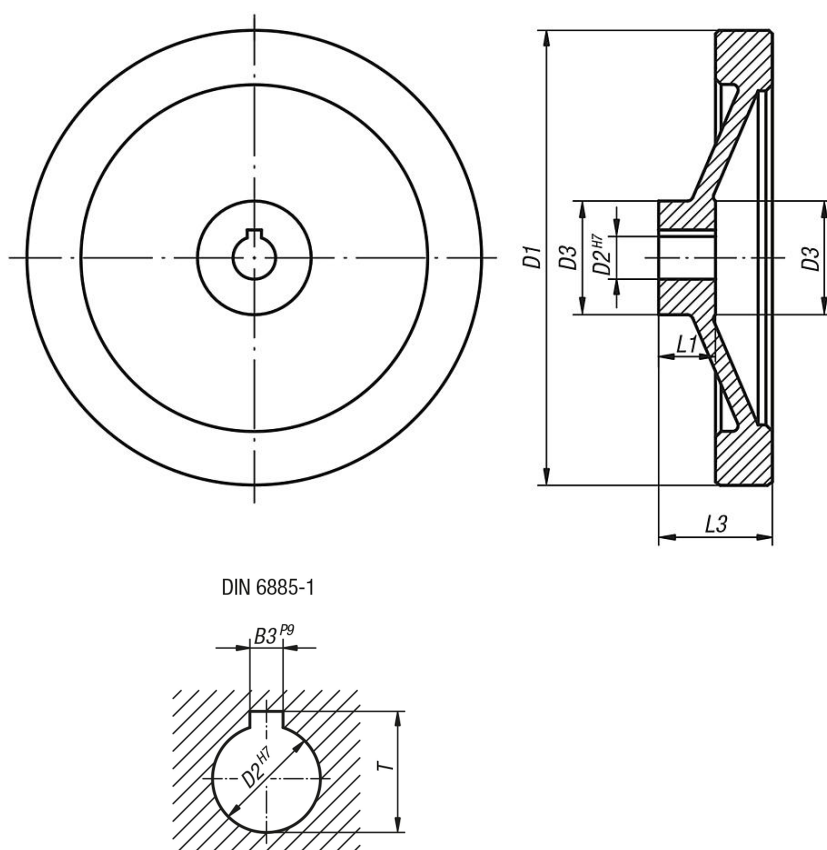

Overview of items

Order No.	Version 1	D1	D2	D3	L1	L3	B3	T
06275-0080X10	Cam screw	80	10H7	26	16	31	-	-
06275-0080X12	Cam screw	80	12H7	26	16	31	-	-
06275-0100X10	Cam screw	100	10H7	31	17	34	-	-
06275-0100X12	Cam screw	100	12H7	31	17	34	-	-
06275-0125X12	Cam screw	125	12H7	30	18	37	-	-
06275-0125X14	Cam screw	125	14H7	30	18	37	-	-
06275-0140X14	Cam screw	140	14H7	34	19	34	-	-

Overview of items

Order No.	Version 1	D1	D2	D3	L1	L3	B3	T
06275-0140X15	Cam screw	140	15H7	34	19	34	-	-
06275-0160X15	Cam screw	160	15H7	40	20	40	-	-
06275-0160X16	Cam screw	160	16H7	40	20	40	-	-
06275-0200X18	Cam screw	200	18H7	50	24	46	-	-
06275-0200X20	Cam screw	200	20H7	50	24	46	-	-
06275-0250X22	Cam screw	250	22H7	50	28	49	-	-
06275-0250X24	Cam screw	250	24H7	50	28	49	-	-
06275-1080X10	1 kg can	80	10H7	26	16	31	3	11,4
06275-1080X12	1 kg can	80	12H7	26	16	31	4	13,8
06275-1100X10	1 kg can	100	10H7	31	17	34	3	11,4
06275-1100X12	1 kg can	100	12H7	31	17	34	4	13,8
06275-1125X12	1 kg can	125	12H7	30	18	37	4	13,8
06275-1125X14	1 kg can	125	14H7	30	18	37	5	16,3
06275-1140X14	1 kg can	140	14H7	34	19	34	5	16,3
06275-1140X15	1 kg can	140	15H7	34	19	34	5	17,3
06275-1160X15	1 kg can	160	15H7	40	20	40	5	17,3
06275-1160X16	1 kg can	160	16H7	40	20	40	5	18,3
06275-1200X18	1 kg can	200	18H7	50	24	46	6	20,8
06275-1200X20	1 kg can	200	20H7	50	24	46	6	22,8
06275-1250X22	1 kg can	250	22H7	50	28	49	6	24,8
06275-1250X24	1 kg can	250	24H7	50	28	49	8	27,3