

## Item description/product images



## Description

**Material:**

Aluminium.

Grub screw stainless steel 1.4305.

Pin stainless steel 1.4310.

**Version:**

Vibratory ground or ground and polished.

Grub screw and pin bright.

**On request:**

Blank star grips (not tumbled).

**Drawing reference:**

Form A: blank

Form B: drilled through


Form C: blind hole

Form D: tapped and counterbored

Form E: tapped blind hole

Form L: external thread

## Drawings

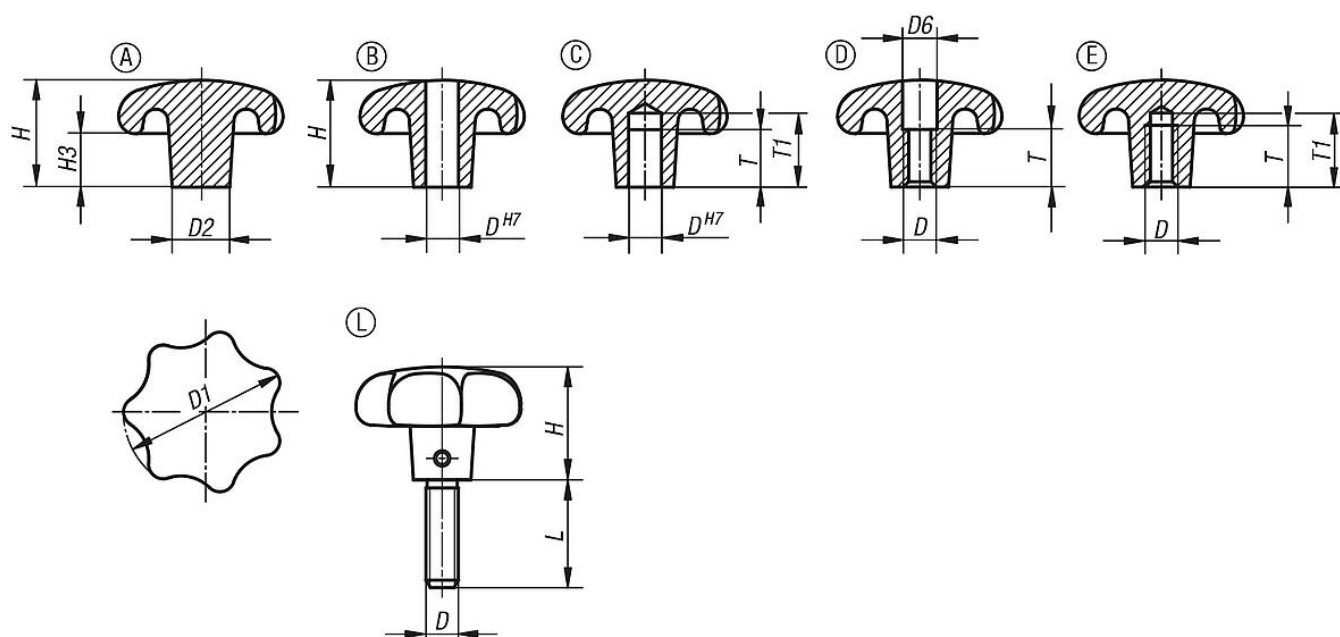

## Overview of items

| Order No.    | Form | Surface finish<br>body | D  | D1 | D2 | D6 | H  | H3 | L | T | T1 |
|--------------|------|------------------------|----|----|----|----|----|----|---|---|----|
| 06192-14008  | A    | Kipp                   | -  | 40 | 14 | -  | 26 | 13 | - | - | -  |
| 06192-15010  | A    | Kipp                   | -  | 50 | 18 | -  | 34 | 17 | - | - | -  |
| 06192-16312  | A    | Kipp                   | -  | 63 | 20 | -  | 42 | 21 | - | - | -  |
| 06192-18016  | A    | Kipp                   | -  | 80 | 25 | -  | 52 | 25 | - | - | -  |
| 06192-24008  | B    | Kipp                   | 8  | 40 | 14 | -  | 25 | 13 | - | - | -  |
| 06192-25010  | B    | Kipp                   | 10 | 50 | 18 | -  | 32 | 17 | - | - | -  |
| 06192-26312  | B    | Kipp                   | 12 | 63 | 20 | -  | 40 | 21 | - | - | -  |
| 06192-28016  | B    | Kipp                   | 16 | 80 | 25 | -  | 50 | 25 | - | - | -  |
| 06192-240082 | B    | from 18.5 to 22.0      | 8  | 40 | 14 | -  | 25 | 13 | - | - | -  |

## Overview of items

| Order No.      | Form | Surface finish<br>body | D   | D1 | D2 | D6   | H  | H3 | L  | T  | T1 |
|----------------|------|------------------------|-----|----|----|------|----|----|----|----|----|
| 06192-250102   | B    | from 18.5 to 22.0      | 10  | 50 | 18 | -    | 32 | 17 | -  | -  | -  |
| 06192-263122   | B    | from 18.5 to 22.0      | 12  | 63 | 20 | -    | 40 | 21 | -  | -  | -  |
| 06192-280162   | B    | from 18.5 to 22.0      | 16  | 80 | 25 | -    | 50 | 25 | -  | -  | -  |
| 06192-34008    | C    | Kipp                   | 8   | 40 | 14 | -    | 25 | 13 | -  | 15 | 18 |
| 06192-35010    | C    | Kipp                   | 10  | 50 | 18 | -    | 32 | 17 | -  | 18 | 21 |
| 06192-36312    | C    | Kipp                   | 12  | 63 | 20 | -    | 40 | 21 | -  | 22 | 25 |
| 06192-38016    | C    | Kipp                   | 16  | 80 | 25 | -    | 50 | 25 | -  | 28 | 32 |
| 06192-340082   | C    | from 18.5 to 22.0      | 8   | 40 | 14 | -    | 25 | 13 | -  | 15 | 18 |
| 06192-350102   | C    | from 18.5 to 22.0      | 10  | 50 | 18 | -    | 32 | 17 | -  | 18 | 21 |
| 06192-363122   | C    | from 18.5 to 22.0      | 12  | 63 | 20 | -    | 40 | 21 | -  | 22 | 25 |
| 06192-380162   | C    | from 18.5 to 22.0      | 16  | 80 | 25 | -    | 50 | 25 | -  | 28 | 32 |
| 06192-44008    | D    | Kipp                   | M8  | 40 | 14 | 8,4  | 25 | 13 | -  | 12 | -  |
| 06192-45010    | D    | Kipp                   | M10 | 50 | 18 | 10,5 | 32 | 17 | -  | 16 | -  |
| 06192-46312    | D    | Kipp                   | M12 | 63 | 20 | 13   | 40 | 21 | -  | 20 | -  |
| 06192-48016    | D    | Kipp                   | M16 | 80 | 25 | 17   | 50 | 25 | -  | 30 | -  |
| 06192-440082   | D    | from 18.5 to 22.0      | M8  | 40 | 14 | 8,4  | 25 | 13 | -  | 12 | -  |
| 06192-450102   | D    | from 18.5 to 22.0      | M10 | 50 | 18 | 10,5 | 32 | 17 | -  | 16 | -  |
| 06192-463122   | D    | from 18.5 to 22.0      | M12 | 63 | 20 | 13   | 40 | 21 | -  | 20 | -  |
| 06192-480162   | D    | from 18.5 to 22.0      | M16 | 80 | 25 | 17   | 50 | 25 | -  | 30 | -  |
| 06192-54008    | E    | Kipp                   | M8  | 40 | 16 | -    | 25 | 13 | -  | 15 | 18 |
| 06192-55010    | E    | Kipp                   | M10 | 50 | 18 | -    | 32 | 17 | -  | 18 | 21 |
| 06192-56312    | E    | Kipp                   | M12 | 63 | 20 | -    | 40 | 21 | -  | 22 | 25 |
| 06192-58016    | E    | Kipp                   | M16 | 80 | 25 | -    | 50 | 25 | -  | 28 | 32 |
| 06192-540082   | E    | from 18.5 to 22.0      | M8  | 40 | 14 | -    | 25 | 13 | -  | 15 | 18 |
| 06192-550102   | E    | from 18.5 to 22.0      | M10 | 50 | 18 | -    | 32 | 17 | -  | 18 | 21 |
| 06192-563122   | E    | from 18.5 to 22.0      | M12 | 63 | 20 | -    | 40 | 21 | -  | 22 | 25 |
| 06192-580162   | E    | from 18.5 to 22.0      | M16 | 80 | 25 | -    | 50 | 25 | -  | 28 | 32 |
| 06192-64008X20 | L    | Kipp                   | M8  | 40 | 14 | -    | 25 | -  | 20 | -  | -  |
| 06192-64008X25 | L    | Kipp                   | M8  | 40 | 14 | -    | 25 | -  | 25 | -  | -  |
| 06192-64008X30 | L    | Kipp                   | M8  | 40 | 14 | -    | 25 | -  | 30 | -  | -  |
| 06192-64008X40 | L    | Kipp                   | M8  | 40 | 14 | -    | 25 | -  | 40 | -  | -  |
| 06192-65010X25 | L    | Kipp                   | M10 | 50 | 18 | -    | 32 | -  | 25 | -  | -  |
| 06192-65010X30 | L    | Kipp                   | M10 | 50 | 18 | -    | 32 | -  | 30 | -  | -  |
| 06192-65010X50 | L    | Kipp                   | M10 | 50 | 18 | -    | 32 | -  | 50 | -  | -  |
| 06192-65010X40 | L    | Kipp                   | M10 | 50 | 18 | -    | 32 | -  | 40 | -  | -  |
| 06192-66312X30 | L    | Kipp                   | M12 | 63 | 20 | -    | 40 | -  | 30 | -  | -  |
| 06192-66312X40 | L    | Kipp                   | M12 | 63 | 20 | -    | 40 | -  | 40 | -  | -  |
| 06192-66312X50 | L    | Kipp                   | M12 | 63 | 20 | -    | 40 | -  | 50 | -  | -  |
| 06192-66312X60 | L    | Kipp                   | M12 | 63 | 20 | -    | 40 | -  | 60 | -  | -  |