

Item description/product images




Description

Version:

Bright (black) or electro zinc-plated.
Surface hardened to min. 550 HV.

Drawings

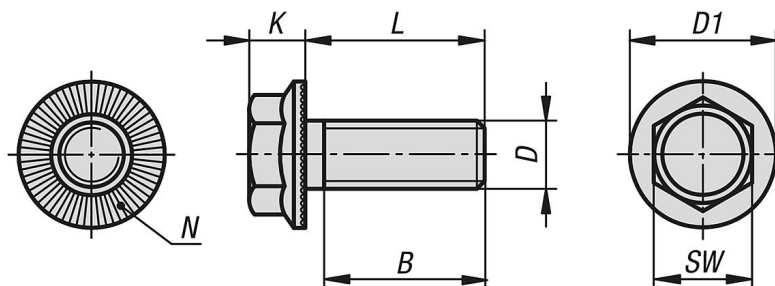

Overview of items

Order No.	Grade	Surface finish body	B	D	L	D1	K	SW	N (number)
07173-305X10	100	bright (black)	8,4	M5	10	11,2	4,3	8	28
07173-305X12	100	bright (black)	10,4	M5	12	11,2	4,3	8	28
07173-305X16	100	bright (black)	14,4	M5	16	11,2	4,3	8	28
07173-305X20	100	bright (black)	18,4	M5	20	11,2	4,3	8	28
07173-306X10	100	bright (black)	8	M6	10	14,2	5,5	10	36
07173-306X12	100	bright (black)	10	M6	12	14,2	5,5	10	36
07173-306X16	100	bright (black)	14	M6	16	14,2	5,5	10	36
07173-306X20	100	bright (black)	18	M6	20	14,2	5,5	10	36
07173-306X25	100	bright (black)	23	M6	25	14,2	5,5	10	36
07173-308X12	100	bright (black)	9,5	M8	12	18,2	7	13	48
07173-308X16	100	bright (black)	13,5	M8	16	18,2	7	13	48
07173-308X20	100	bright (black)	17,5	M8	20	18,2	7	13	48
07173-308X25	100	bright (black)	22,5	M8	25	18,2	7	13	48
07173-308X30	100	bright (black)	27,5	M8	30	18,2	7	13	48
07173-308X35	100	bright (black)	32,5	M8	35	18,2	7	13	48
07173-308X40	100	bright (black)	37,5	M8	40	18,2	7	13	48
07173-310X16	100	bright (black)	13	M10	16	21	8,5	15	48
07173-310X20	100	bright (black)	17	M10	20	21	8,5	15	48
07173-310X25	100	bright (black)	22	M10	25	21	8,5	15	48
07173-310X30	100	bright (black)	27	M10	30	21	8,5	15	48
07173-310X35	100	bright (black)	32	M10	35	21	8,5	15	48
07173-310X40	100	bright (black)	37	M10	40	21	8,5	15	48
07173-310X45	100	bright (black)	42	M10	45	21	8,5	15	48
07173-310X50	100	bright (black)	47	M10	50	21	8,5	15	48
07173-312X20	100	bright (black)	16,5	M12	20	24	10	17	60
07173-312X25	100	bright (black)	21,5	M12	25	24	10	17	60
07173-312X30	100	bright (black)	26,5	M12	30	24	10	17	60
07173-312X35	100	bright (black)	31,5	M12	35	24	10	17	60
07173-312X40	100	bright (black)	36,5	M12	40	24	10	17	60
07173-312X45	100	bright (black)	41,5	M12	45	24	10	17	60
07173-312X50	100	bright (black)	46,5	M12	50	24	10	17	60
07173-312X55	100	bright (black)	51,5	M12	55	24	10	17	60
07173-312X60	100	bright (black)	56,5	M12	60	24	10	17	60
07173-312X75	100	bright (black)	71,5	M12	75	24	10	17	60
07173-316X25	100	bright (black)	21	M16	25	31	14	22	72
07173-316X30	100	bright (black)	26	M16	30	31	14	22	72

Overview of items

Order No.	Grade	Surface finish body	B	D	L	D1	K	SW	N (number)
07173-316X35	100	bright (black)	31	M16	35	31	14	22	72
07173-316X40	100	bright (black)	36	M16	40	31	14	22	72
07173-316X45	100	bright (black)	41	M16	45	31	14	22	72
07173-316X50	100	bright (black)	46	M16	50	31	14	22	72
07173-316X55	100	bright (black)	51	M16	55	31	14	22	72
07173-316X60	100	bright (black)	56	M16	60	31	14	22	72
07173-316X65	100	bright (black)	61	M16	65	31	14	22	72
07173-316X70	100	bright (black)	66	M16	70	31	14	22	72
07173-505X10	100	galvanised	8,4	M5	10	11,2	4,3	8	28
07173-505X12	100	galvanised	10,4	M5	12	11,2	4,3	8	28
07173-505X16	100	galvanised	14,4	M5	16	11,2	4,3	8	28
07173-505X20	100	galvanised	18,4	M5	20	11,2	4,3	8	28
07173-506X10	100	galvanised	8	M6	10	14,2	5,5	10	36
07173-506X12	100	galvanised	10	M6	12	14,2	5,5	10	36
07173-506X16	100	galvanised	14	M6	16	14,2	5,5	10	36
07173-506X20	100	galvanised	18	M6	20	14,2	5,5	10	36
07173-506X25	100	galvanised	23	M6	25	14,2	5,5	10	36
07173-508X12	100	galvanised	9,5	M8	12	18,2	7	13	48
07173-508X16	100	galvanised	13,5	M8	16	18,2	7	13	48
07173-508X20	100	galvanised	17,5	M8	20	18,2	7	13	48
07173-508X25	100	galvanised	22,5	M8	25	18,2	7	13	48
07173-508X30	100	galvanised	27,5	M8	30	18,2	7	13	48
07173-508X40	100	galvanised	37,5	M8	40	18,2	7	13	48
07173-510X16	100	galvanised	13	M10	16	21	8,5	15	48
07173-510X20	100	galvanised	17	M10	20	21	8,5	15	48
07173-510X25	100	galvanised	22	M10	25	21	8,5	15	48
07173-510X30	100	galvanised	27	M10	30	21	8,5	15	48
07173-510X35	100	galvanised	32	M10	35	21	8,5	15	48
07173-510X40	100	galvanised	37	M10	40	21	8,5	15	48
07173-510X50	100	galvanised	47	M10	50	21	8,5	15	48
07173-512X20	100	galvanised	16,5	M12	20	24	10	17	60
07173-512X25	100	galvanised	21,5	M12	25	24	10	17	60
07173-512X30	100	galvanised	26,5	M12	30	24	10	17	60
07173-512X35	100	galvanised	31,5	M12	35	24	10	17	60
07173-512X40	100	galvanised	36,5	M12	40	24	10	17	60
07173-512X45	100	galvanised	41,5	M12	45	24	10	17	60
07173-512X50	100	galvanised	46,5	M12	50	24	10	17	60
07173-512X60	100	galvanised	56,5	M12	60	24	10	17	60
07173-512X75	100	galvanised	71,5	M12	75	24	10	17	60
07173-516X25	100	galvanised	21	M16	25	31	14	22	72
07173-516X35	100	galvanised	31	M16	35	31	14	22	72
07173-516X40	100	galvanised	36	M16	40	31	14	22	72
07173-516X45	100	galvanised	41	M16	45	31	14	22	72
07173-516X50	100	galvanised	46	M16	50	31	14	22	72
07173-516X55	100	galvanised	51	M16	55	31	14	22	72
07173-516X60	100	galvanised	56	M16	60	31	14	22	72
07173-516X70	100	galvanised	66	M16	70	31	14	22	72