

Item description/product images



Description

Material:

Steel.

Version:

Grade 10.

Plastic-coated, red.

Note:

The shortening hook is for incorporating into single or multiple strand chains and is used to shorten the chain.

Shortening hooks are permissible for lifting, but not for lashing since they do not have a latch to prevent unintentional unhooking.

The shortening hooks correspond to the Machinery Directive and are BG certified (H stamp).

Temperature range:

From -40°C to 200°C = 100% permissible load

Up to 300°C = 90% permissible load


Up to 400°C = 75% permissible load

Drawing reference:

Form A: eye hook.

Form B: clevis hook.

Drawings

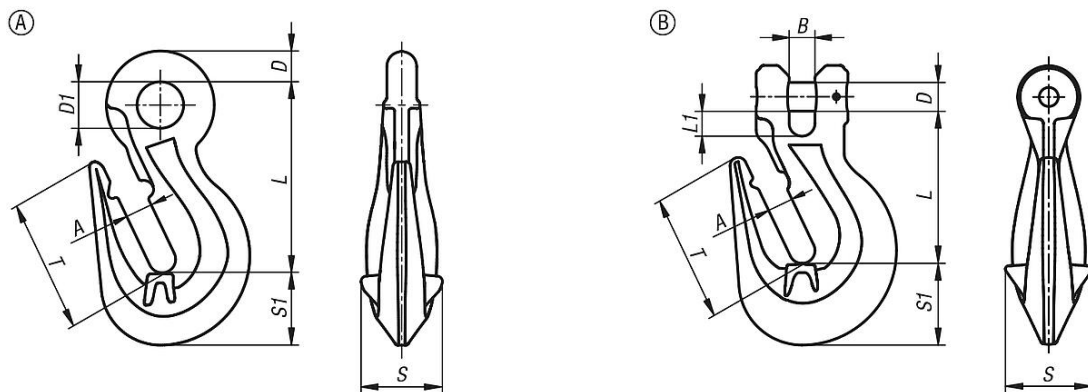

Overview of items

Order No.	Version 1	Form	for chain mm	A	B	D	D1	L	L1	S	S1	T	Permissible load kg
-	eye hook	A	6	8	-	8,5	12	51,5	-	22	22	35,5	1400
-	eye hook	A	7-8	10	-	11	17	69	-	30	28	47	2500
-	eye hook	A	10	13	-	15	22	86,5	-	44	34	55	4000
-	eye hook	A	13	17	-	18	26	110,5	-	53	47	81	6700
-	eye hook	A	16	19	-	21	32	129	-	64	60	92	10000
-	clevis hook	B	6	8	8	7,5	-	51	8,8	22	22	36	1400
-	clevis hook	B	7	10	10	9	-	66	11	30	28	47	1900
-	clevis hook	B	8	10	10	10	-	65	11	30	28	47	2500
-	clevis hook	B	10	13	13	13	-	80	15	44	34	55	4000
-	clevis hook	B	13	17	17	16	-	105	18	53	47	81	6700

Overview of items

Order No.	Version 1	Form	for chain mm	A	B	D	D1	L	L1	S	S1	T	Permissible load kg
-	clevis hook	B	16	19	19	21	-	112	18	64	60	92	10000