

## Item description/product images



## Description

**Material:**

Steel 1.0503 (C45).

**Version:**


Milled tothing, straight teeth  
 Tothing inductively hardened to 50 +4 HRC.  
 engagement angle 20°, bright.

**Note:**


The gear racks are suitable for consecutive mounting.

Hardening changes the tothing quality to ca. 10-11.

## Drawings

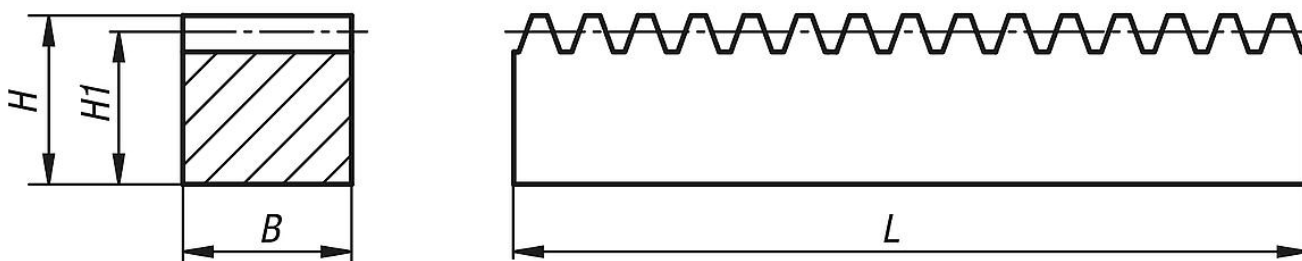

mounting in series

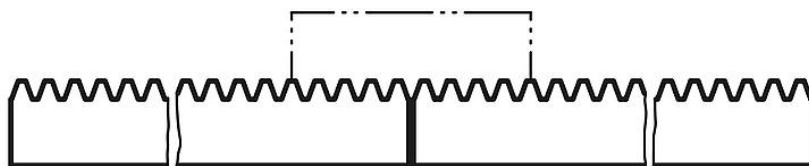

## Overview of items

Order No.	Module	B	H	H1	L Nom. length	L Actual length
22421-020200X1000	2	20	20	18	1000	1005,31
22421-020200X2000	2	20	20	18	2000	2004,34
22421-025250X1000	2,5	25	25	22,5	1000	1005,31
22421-025250X2000	2,5	25	25	22,5	2000	2002,77
22421-030300X1000	3	30	30	27	1000	1008,45
22421-030300X2000	3	30	30	27	2000	2007,48
22421-040400X1000	4	40	40	36	1000	1005,31
22421-040400X2000	4	40	40	36	2000	2010,62
22421-050500X1000	5	50	50	45	1000	1005,31
22421-050500X2000	5	50	50	45	2000	2010,62
22421-060600X1000	6	60	60	54	1000	1017,88

## Overview of items

Order No.	Module	B	H	H1	L Nom. length	L Actual length
22421-060600X2000	6	60	60	54	2000	2016,9