

Item description/product images



Description

Material:

Roller rim polyurethane (PUR).
Bearing steel.

Version:

Roller rim dark brown.

Note:

The roller rim is firmly bonded onto a ball bearing. From diameter $D = 40$ mm, the roller rim has a double-layer

The advantage of a PUR roller rim is quiet running.


These guide rollers are not suitable for high temperatures, high humidity or exposure to water. The guide rollers are resistant to solvent-free oils. Oils with solvent content can cause swelling or strength deterioration.

The radial load was tested over one million revolutions at 300 rpm. These results may vary depending on operating conditions and environment.

Accessory:

Matching pins 95102.

Drawings

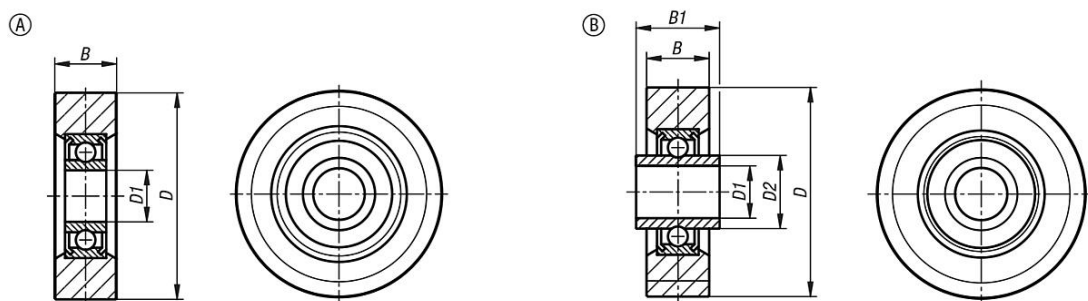

Overview of items

Guide rollers, plastic, cylindrical without pins

Order No.	B	B1	D	D1	D2	Form	Form definition	Ball bearing	Radial load N	Suitable for
95101-002008	8	-	20	6	-	A	no collar	696-2RS	63	95102-3006055
95101-002509	9	-	25	6	-	A	no collar	626-2RS	93	95102-3006060
95101-003011	11	-	30	8	-	A	no collar	608-2RS	167	95102-3008070
95101-003511	11	-	35	8	-	A	no collar	608-2RS	225	95102-3008070
95101-004012	12	-	40	10	-	A	no collar	6000-2RS	314	95102-3010080
95101-004514	14	-	45	12	-	A	no collar	6201-2RS	402	95102-3012100
95101-005014	14	-	50	12	-	A	no collar	6201-2RS	470	95102-3012100
95101-005515	15	-	55	15	-	A	no collar	6202-2RS	510	95102-3015110
95101-006015	15	-	60	15	-	A	no collar	6202-2RS	539	95102-3015110
95101-102008	8	11	20	6	8,6	B	with collar	696-2RS	63	95102-3006110
95101-102509	9	12	25	6	9,3	B	with collar	626-2RS	93	95102-3006110
95101-103011	11	15	30	8	12	B	with collar	608-2RS	167	95102-3008130
95101-103511	11	15	35	8	12	B	with collar	608-2RS	225	95102-3008130
95101-104012	12	16	40	10	14	B	with collar	6000-2RS	314	95102-3010160

Overview of items

Order No.	B	B1	D	D1	D2	Form	Form definition	Ball bearing	Radial load N	Suitable for
95101-104514	14	18	45	12	18,3	B	with collar	6201-2RS	402	95102-3012160
95101-105014	14	18	50	12	18,3	B	with collar	6201-2RS	470	95102-3012160
95101-105515	15	19	55	15	21,6	B	with collar	6202-2RS	510	95102-3015170
95101-106015	15	19	60	15	21,6	B	with collar	6202-2RS	539	95102-3015170