

Item description/product images



Description

Material:

Steel.

Version:

Roller rim nickel-plated.

Note:

The roller rim and ball bearing are held firmly held together by a circlip.

The load ratings refer to the ball bearing.

On request:


Heavy-duty versions.

Black polyacetal roller rims.

Accessory:

Matching pins 95102.

Drawings

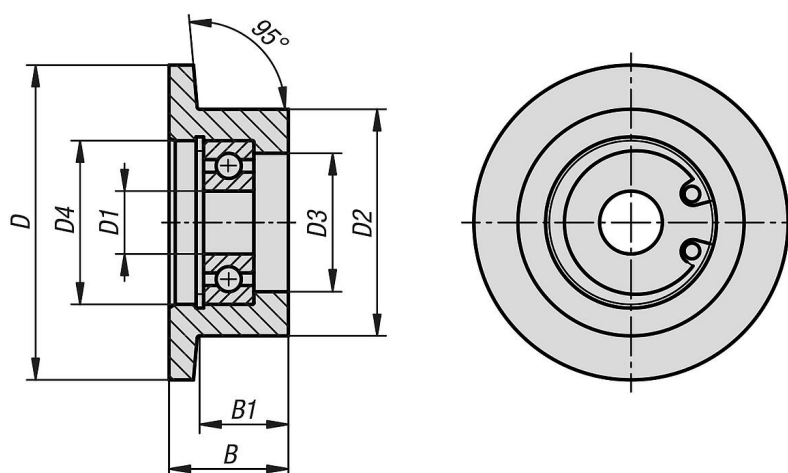

Overview of items

Guide rollers, steel with flange one side

Order No.	B	B1	D	D1	D2	D3	D4	Ball bearing	Dynamic load rating N	Static load rating N
95101-20-003012	12	8,5	30	6	22	13	17	606-ZZ	2260	840
95101-20-004016	16	11,5	40	8	30	18	22	608-ZZ	3300	1360
95101-20-005019	19	14,5	50	10	36	22	26	6000-ZZ	4550	1970
95101-20-006023	23	18	60	12	42	26	32	6201-ZZ	6800	3050
95101-20-007028	28	22,5	70	15	46	29	35	6202-ZZ	7650	3700

