


Item description/product images

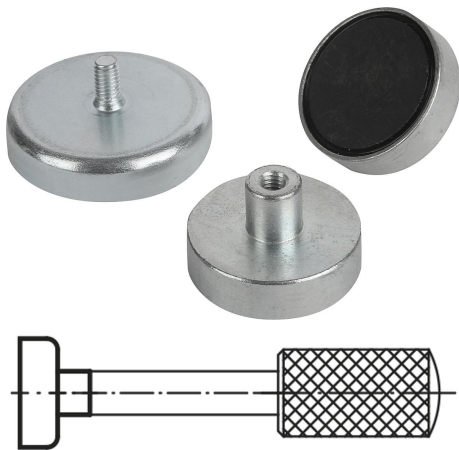

Description

Material:
Housing, steel.
Magnetic core hard ferrite.

Version:
Housing, electro zinc-plated.


Note:
Shallow pot magnets, shielded system.

Hairline cracks in the magnetic material are unavoidable for technical reasons in D=80, D=100 and D=125 versions. They do not impair the attracting function of the magnets in any way.

Temperature range:
max. 200°C.

Drawing reference:
1) magnetic face

Drawings

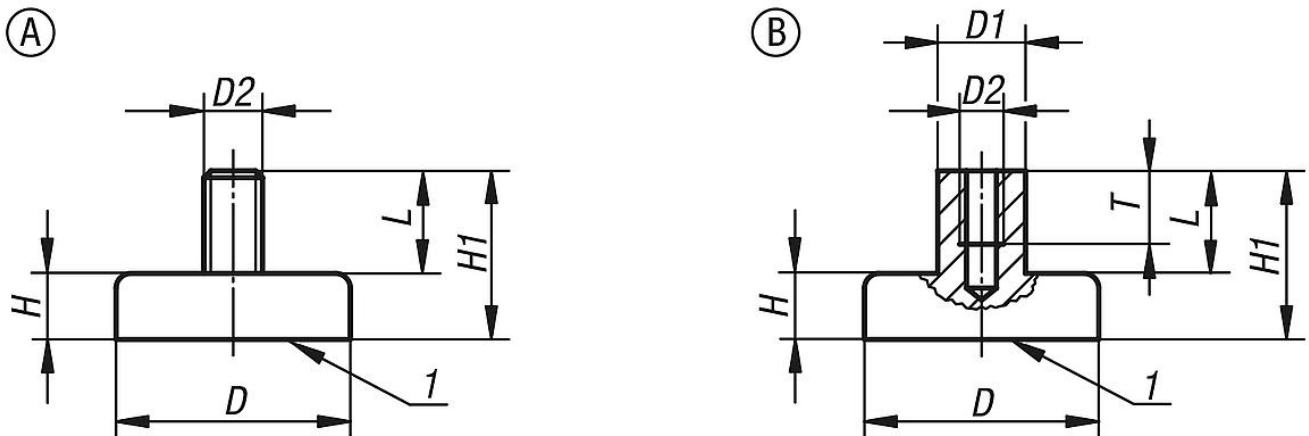

Overview of items

| Order No. Form A | Order No. Form B | D | D1 | D2 | L | H | H1 | T | Magnetic force N |
|------------------|------------------|-----------|-----|-----|----|-----|------|-----|------------------|
| 09065-21 | 09065-01 | 10 ±0,15 | -/6 | M3 | 7 | 4,5 | 11,5 | -/5 | 4 |
| 09065-22 | 09065-02 | 13 ±0,15 | -/6 | M3 | 7 | 4,5 | 11,5 | -/5 | 10 |
| 09065-23 | 09065-03 | 16 ±0,15 | -/6 | M3 | 7 | 4,5 | 11,5 | -/5 | 18 |
| 09065-24 | 09065-04 | 20 ±0,15 | -/6 | M3 | 7 | 6 | 13 | -/5 | 30 |
| 09065-25 | 09065-05 | 25 ±0,15 | -/8 | M4 | 8 | 7 | 15 | -/6 | 40 |
| 09065-26 | 09065-06 | 32 ±0,20 | -/8 | M4 | 8 | 7 | 15 | -/6 | 80 |
| - | 09065-07 | 40 ±0,20 | 10 | M5 | 10 | 8 | 18 | 8 | 125 |
| - | 09065-08 | 50 ±0,20 | 12 | M6 | 12 | 10 | 22 | 10 | 220 |
| - | 09065-09 | 63 ±0,20 | 15 | M8 | 16 | 14 | 30 | 14 | 350 |
| - | 09065-10 | 80 ±0,25 | 20 | M10 | 16 | 18 | 34 | 14 | 600 |
| - | 09065-11 | 99 ±0,25 | 22 | M12 | 20 | 22 | 42 | 17 | 900 |
| - | 09065-12 | 125 ±0,25 | 25 | M14 | 24 | 26 | 50 | 20 | 1300 |

