

Item description/product images




Description

Material:


GJL 250 annealed or EN AW-7075

Note:

The length L is cut by saw and is always supplied overlong.

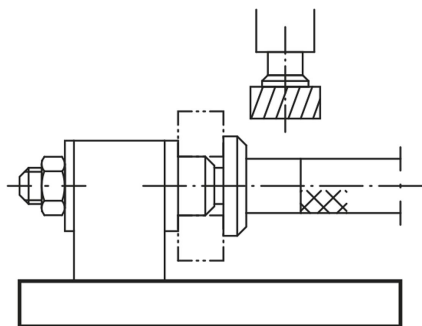

Drawings

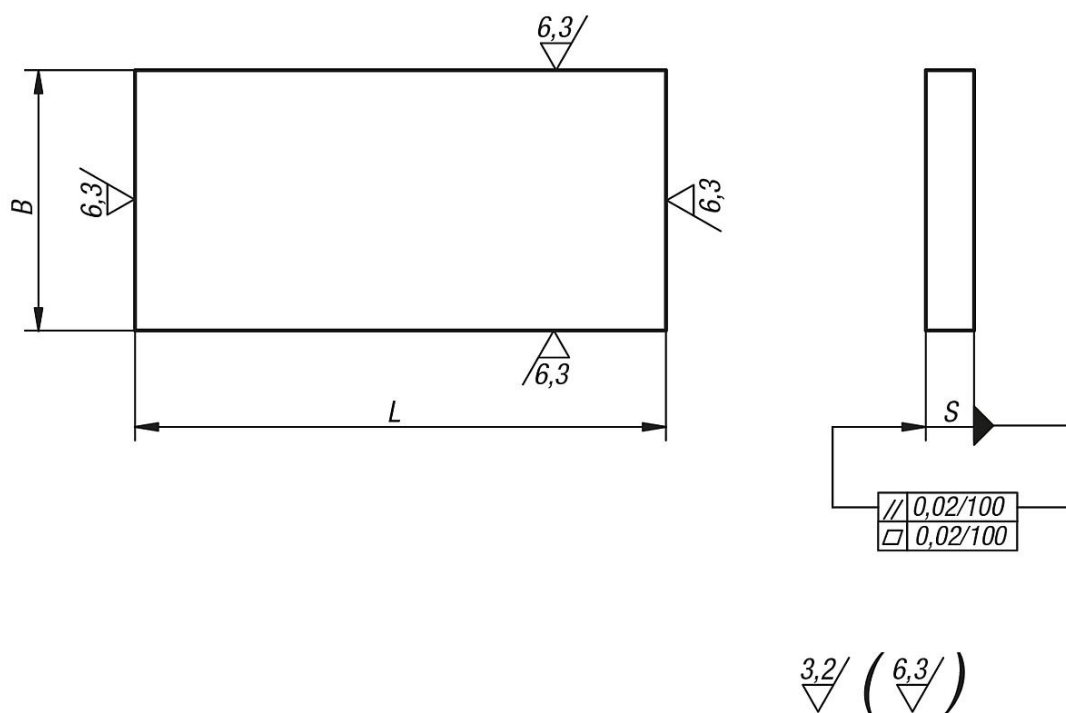

Overview of items

Order No.	Main material	L = length	B	S
01140-01X300	grey cast iron	300	40	10
01140-02X300	grey cast iron	300	50	12
01140-03X300	grey cast iron	300	63	16
01140-04X200	grey cast iron	200	80	20
01140-04X300	grey cast iron	300	80	20
01140-04X400	grey cast iron	400	80	20

Overview of items

Order No.	Main material	L = length	B	S
01140-04X600	grey cast iron	600	80	20
01140-04X800	grey cast iron	800	80	20
01140-05X200	grey cast iron	200	100	20
01140-05X300	grey cast iron	300	100	20
01140-05X400	grey cast iron	400	100	20
01140-05X600	grey cast iron	600	100	20
01140-05X800	grey cast iron	800	100	20
01140-06X200	grey cast iron	200	160	20
01140-06X300	grey cast iron	300	160	20
01140-06X400	grey cast iron	400	160	20
01140-06X600	grey cast iron	600	160	20
01140-06X800	grey cast iron	800	160	20
01140-061X200	grey cast iron	200	200	20
01140-061X300	grey cast iron	300	200	20
01140-061X400	grey cast iron	400	200	20
01140-061X600	grey cast iron	600	200	20
01140-061X800	grey cast iron	800	200	20
01140-062X200	grey cast iron	200	250	20
01140-062X300	grey cast iron	300	250	20
01140-062X400	grey cast iron	400	250	20
01140-062X600	grey cast iron	600	250	20
01140-062X800	grey cast iron	800	250	20
01140-07X200	grey cast iron	200	125	25
01140-07X300	grey cast iron	300	125	25
01140-07X400	grey cast iron	400	125	25
01140-07X600	grey cast iron	600	125	25
01140-07X800	grey cast iron	800	125	25
01140-07X1200	grey cast iron	1200	125	25
01140-08X200	grey cast iron	200	200	25
01140-08X300	grey cast iron	300	200	25
01140-08X400	grey cast iron	400	200	25
01140-08X600	grey cast iron	600	200	25
01140-08X800	grey cast iron	800	200	25
01140-08X1200	grey cast iron	1200	200	25
01140-081X200	grey cast iron	200	250	25
01140-081X300	grey cast iron	300	250	25
01140-081X400	grey cast iron	400	250	25
01140-081X600	grey cast iron	600	250	25
01140-081X800	grey cast iron	800	250	25
01140-081X1200	grey cast iron	1200	250	25
01140-082X200	grey cast iron	200	315	25
01140-082X300	grey cast iron	300	315	25
01140-082X400	grey cast iron	400	315	25
01140-082X600	grey cast iron	600	315	25
01140-082X800	grey cast iron	800	315	25
01140-082X1200	grey cast iron	1200	315	25
01140-09X200	grey cast iron	200	160	32
01140-09X300	grey cast iron	300	160	32
01140-09X400	grey cast iron	400	160	32
01140-09X600	grey cast iron	600	160	32
01140-09X800	grey cast iron	800	160	32
01140-09X1200	grey cast iron	1200	160	32
01140-10X200	grey cast iron	200	250	32
01140-10X300	grey cast iron	300	250	32
01140-10X400	grey cast iron	400	250	32
01140-10X600	grey cast iron	600	250	32
01140-10X800	grey cast iron	800	250	32
01140-10X1200	grey cast iron	1200	250	32
01140-101X200	grey cast iron	200	315	32
01140-101X400	grey cast iron	400	315	32
01140-101X600	grey cast iron	600	315	32
01140-101X800	grey cast iron	800	315	32
01140-101X1200	grey cast iron	1200	315	32
01140-102X200	grey cast iron	200	400	32
01140-102X300	grey cast iron	300	400	32

Overview of items

Order No.	Main material	L = length	B	S
01140-102X400	grey cast iron	400	400	32
01140-102X600	grey cast iron	600	400	32
01140-102X800	grey cast iron	800	400	32
01140-102X1200	grey cast iron	1200	400	32
01140-11X200	grey cast iron	200	200	40
01140-11X400	grey cast iron	400	200	40
01140-11X600	grey cast iron	600	200	40
01140-11X800	grey cast iron	800	200	40
01140-11X1200	grey cast iron	1200	200	40
01140-12X200	grey cast iron	200	250	40
01140-12X400	grey cast iron	400	250	40
01140-12X600	grey cast iron	600	250	40
01140-12X800	grey cast iron	800	250	40
01140-12X1200	grey cast iron	1200	250	40
01140-120X200	grey cast iron	200	315	40
01140-120X400	grey cast iron	400	315	40
01140-120X600	grey cast iron	600	315	40
01140-120X800	grey cast iron	800	315	40
01140-120X1200	grey cast iron	1200	315	40
01140-121X200	grey cast iron	200	400	40
01140-121X300	grey cast iron	300	400	40
01140-121X400	grey cast iron	400	400	40
01140-121X600	grey cast iron	600	400	40
01140-121X800	grey cast iron	800	400	40
01140-121X1200	grey cast iron	1200	400	40
01140-13X200	grey cast iron	200	315	50
01140-13X400	grey cast iron	400	315	50
01140-13X600	grey cast iron	600	315	50
01140-13X800	grey cast iron	800	315	50
01140-13X1200	grey cast iron	1200	315	50
01140-131X200	grey cast iron	200	500	50
01140-131X300	grey cast iron	300	500	50
01140-131X400	grey cast iron	400	500	50
01140-131X600	grey cast iron	600	500	50
01140-131X800	grey cast iron	800	500	50
01140-131X1200	grey cast iron	1200	500	50
01140-201X300	aluminium	300	40	10
01140-202X300	aluminium	300	50	12
01140-203X300	aluminium	300	63	16
01140-204X200	aluminium	200	80	20
01140-204X300	aluminium	300	80	20
01140-204X400	aluminium	400	80	20
01140-204X600	aluminium	600	80	20
01140-204X800	aluminium	800	80	20
01140-205X200	aluminium	200	100	20
01140-205X300	aluminium	300	100	20
01140-205X400	aluminium	400	100	20
01140-205X600	aluminium	600	100	20
01140-205X800	aluminium	800	100	20
01140-206X200	aluminium	200	160	20
01140-206X300	aluminium	300	160	20
01140-206X400	aluminium	400	160	20
01140-206X600	aluminium	600	160	20
01140-206X800	aluminium	800	160	20
01140-2061X200	aluminium	200	200	20
01140-2061X300	aluminium	300	200	20
01140-2061X400	aluminium	400	200	20
01140-2061X600	aluminium	600	200	20
01140-2061X800	aluminium	800	200	20
01140-2062X200	aluminium	200	250	20
01140-2062X300	aluminium	300	250	20
01140-2062X400	aluminium	400	250	20
01140-2062X600	aluminium	600	250	20
01140-2062X800	aluminium	800	250	20
01140-207X200	aluminium	200	125	25

Overview of items

Order No.	Main material	L = length	B	S
01140-207X300	aluminium	300	125	25
01140-207X400	aluminium	400	125	25
01140-207X600	aluminium	600	125	25
01140-207X800	aluminium	800	125	25
01140-207X1200	aluminium	1200	125	25
01140-208X200	aluminium	200	200	25
01140-208X300	aluminium	300	200	25
01140-208X400	aluminium	400	200	25
01140-208X600	aluminium	600	200	25
01140-208X800	aluminium	800	200	25
01140-208X1200	aluminium	1200	200	25
01140-2081X200	aluminium	200	250	25
01140-2081X300	aluminium	300	250	25
01140-2081X400	aluminium	400	250	25
01140-2081X600	aluminium	600	250	25
01140-2081X800	aluminium	800	250	25
01140-2081X1200	aluminium	1200	250	25
01140-2082X200	aluminium	200	315	25
01140-2082X300	aluminium	300	315	25
01140-2082X400	aluminium	400	315	25
01140-2082X600	aluminium	600	315	25
01140-2082X800	aluminium	800	315	25
01140-2082X1200	aluminium	1200	315	25
01140-209X200	aluminium	200	160	32
01140-209X300	aluminium	300	160	32
01140-209X400	aluminium	400	160	32
01140-209X600	aluminium	600	160	32
01140-209X800	aluminium	800	160	32
01140-209X1200	aluminium	1200	160	32
01140-210X200	aluminium	200	250	32
01140-210X300	aluminium	300	250	32
01140-210X400	aluminium	400	250	32
01140-210X600	aluminium	600	250	32
01140-210X800	aluminium	800	250	32
01140-210X1200	aluminium	1200	250	32
01140-2101X200	aluminium	200	315	32
01140-2101X400	aluminium	400	315	32
01140-2101X600	aluminium	600	315	32
01140-2101X800	aluminium	800	315	32
01140-2101X1200	aluminium	1200	315	32
01140-2102X200	aluminium	200	400	32
01140-2102X300	aluminium	300	400	32
01140-2102X400	aluminium	400	400	32
01140-2102X600	aluminium	600	400	32
01140-2102X800	aluminium	800	400	32
01140-2102X1200	aluminium	1200	400	32
01140-211X200	aluminium	200	200	40
01140-211X400	aluminium	400	200	40
01140-211X600	aluminium	600	200	40
01140-211X800	aluminium	800	200	40
01140-211X1200	aluminium	1200	200	40
01140-212X200	aluminium	200	250	40
01140-212X400	aluminium	400	250	40
01140-212X600	aluminium	600	250	40
01140-212X800	aluminium	800	250	40
01140-212X1200	aluminium	1200	250	40

