

Item description/product images



Description

Material:

Rails steel.
Screws steel.
Parallel key stainless steel.
Plug plastic.

Version:

Rails bright and hardened.
Screws electro zinc-plated steel.

Note:

The linear guide rails are screwed down from above. One or more roller guide carriages can be mounted on these. The linear guide rails with a slot on both sides are suitable for assembling several linear guide rails. This makes for easy assembly of the rails using parallel keys.

As standard, the plugs are always supplied in blue RAL 5002.

Other items suitable for this system:

Roller carriage for straight linear guide rails 21350.

Roller carriage for linear guide rails 21351.

Curved linear guide rails 21356.

Cap screws 07160 M5 for size 2 or M8 for size 3.

Advantages:

Complex geometries consisting of straight and curved linear guide rails can be constructed.

On request:

Slot one side.

Plug in other colours. Other lengths. (L max = 4000 mm).

Diamond coating.

Supplied with:


Plug blue RAL 5002.

Parallel keys (for versions with slots).

Accessory:

Parallel keys 03288-06X22 and 03288-106X22 for size 2, 03288-08X28 and 03288-108X28 for size 3.

Drawings

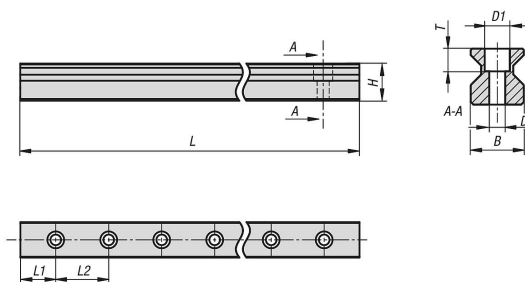

Overview of items

Order No.	Version 2	Size	B	D	D1	H	L	L1	L2	T
21355-210X0500	without slot	2	20	6	9,5	21	500	25	30	8,5
21355-210X1000	without slot	2	20	6	9,5	21	1000	20	30	8,5
21355-210X2000	without slot	2	20	6	9,5	21	2000	25	30	8,5
21355-310X0500	without slot	3	28	9	14	28	500	30	40	12
21355-310X1000	without slot	3	28	9	14	28	1000	20	40	12
21355-310X2000	without slot	3	28	9	14	28	2000	20	40	12
21355-212X0500	with slot	2	20	6	9,5	21	500	25	30	8,5
21355-212X1000	with slot	2	20	6	9,5	21	1000	20	30	8,5
21355-212X2000	with slot	2	20	6	9,5	21	2000	25	30	8,5
21355-312X0500	with slot	3	28	9	14	28	500	30	40	12
21355-312X1000	with slot	3	28	9	14	28	1000	20	40	12
21355-312X2000	with slot	3	28	9	14	28	2000	20	40	12

Information about this article

If your desired length is not shown, please contact our professional personal. The maximum length we can supply is 4000mm. Order now [here](#).