

## Item description/product images



## Description

## Material:

Steel, stainless steel A2 or stainless steel A4.


## Version:

Steel grade 8.8, bright (blackened) or electro zinc-plated.

Stainless steel A2-70, bright

Stainless steel A4-70, bright

## Drawings

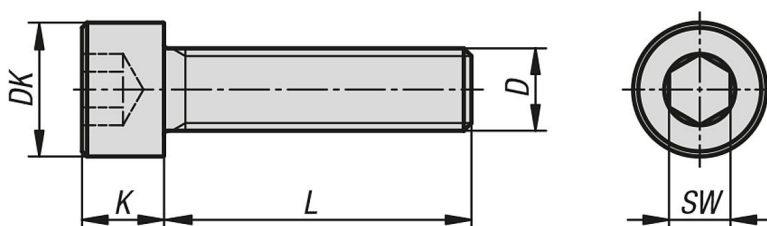

## Overview of items

Order No.	Main material	Grade	Surface finish body	D	L	DK	K	SW
07159-05X40	steel	8.8	bright (black)	M5	40	8,5	5	4
07159-05X50	steel	8.8	bright (black)	M5	50	8,5	5	4
07159-05X60	steel	8.8	bright (black)	M5	60	8,5	5	4
07159-05X80	steel	8.8	bright (black)	M5	80	8,5	5	4
07159-06X40	steel	8.8	bright (black)	M6	40	10	6	5
07159-06X50	steel	8.8	bright (black)	M6	50	10	6	5
07159-06X60	steel	8.8	bright (black)	M6	60	10	6	5
07159-06X70	steel	8.8	bright (black)	M6	70	10	6	5
07159-06X90	steel	8.8	bright (black)	M6	90	10	6	5
07159-06X100	steel	8.8	bright (black)	M6	100	10	6	5
07159-08X50	steel	8.8	bright (black)	M8	50	13	8	6
07159-08X60	steel	8.8	bright (black)	M8	60	13	8	6
07159-08X70	steel	8.8	bright (black)	M8	70	13	8	6
07159-08X80	steel	8.8	bright (black)	M8	80	13	8	6
07159-08X90	steel	8.8	bright (black)	M8	90	13	8	6
07159-10X50	steel	8.8	bright (black)	M10	50	16	10	8
07159-10X60	steel	8.8	bright (black)	M10	60	16	10	8
07159-10X70	steel	8.8	bright (black)	M10	70	16	10	8
07159-10X80	steel	8.8	bright (black)	M10	80	16	10	8
07159-10X90	steel	8.8	bright (black)	M10	90	16	10	8
07159-10X100	steel	8.8	bright (black)	M10	100	16	10	8
07159-12X80	steel	8.8	bright (black)	M12	80	18	12	10
07159-12X90	steel	8.8	bright (black)	M12	90	18	12	10
07159-12X100	steel	8.8	bright (black)	M12	100	18	12	10
07159-405X40	steel	8.8	galvanised	M5	40	8,5	5	4
07159-405X70	steel	8.8	galvanised	M5	70	8,5	5	4
07159-405X80	steel	8.8	galvanised	M5	80	8,5	5	4
07159-406X40	steel	8.8	galvanised	M6	40	10	6	5
07159-406X50	steel	8.8	galvanised	M6	50	10	6	5
07159-406X60	steel	8.8	galvanised	M6	60	10	6	5
07159-406X70	steel	8.8	galvanised	M6	70	10	6	5
07159-406X80	steel	8.8	galvanised	M6	80	10	6	5
07159-406X90	steel	8.8	galvanised	M6	90	10	6	5
07159-406X100	steel	8.8	galvanised	M6	100	10	6	5

## Overview of items

Order No.	Main material	Grade	Surface finish body	D	L	DK	K	SW
07159-408X50	steel	8.8	galvanised	M8	50	13	8	6
07159-408X60	steel	8.8	galvanised	M8	60	13	8	6
07159-408X70	steel	8.8	galvanised	M8	70	13	8	6
07159-408X80	steel	8.8	galvanised	M8	80	13	8	6
07159-408X90	steel	8.8	galvanised	M8	90	13	8	6
07159-408X100	steel	8.8	galvanised	M8	100	13	8	6
07159-410X50	steel	8.8	galvanised	M10	50	16	10	8
07159-410X60	steel	8.8	galvanised	M10	60	16	10	8
07159-410X70	steel	8.8	galvanised	M10	70	16	10	8
07159-410X80	steel	8.8	galvanised	M10	80	16	10	8
07159-410X90	steel	8.8	galvanised	M10	90	16	10	8
07159-410X100	steel	8.8	galvanised	M10	100	16	10	8
07159-412X70	steel	8.8	galvanised	M12	70	18	12	10
07159-412X80	steel	8.8	galvanised	M12	80	18	12	10
07159-412X90	steel	8.8	galvanised	M12	90	18	12	10
07159-412X100	steel	8.8	galvanised	M12	100	18	12	10
07159-105X40	stainless steel A2	70	bright	M5	40	8,5	5	4
07159-105X70	stainless steel A2	70	bright	M5	70	8,5	5	4
07159-106X40	stainless steel A2	70	bright	M6	40	10	6	5
07159-106X50	stainless steel A2	70	bright	M6	50	10	6	5
07159-106X60	stainless steel A2	70	bright	M6	60	10	6	5
07159-106X70	stainless steel A2	70	bright	M6	70	10	6	5
07159-106X80	stainless steel A2	70	bright	M6	80	10	6	5
07159-106X90	stainless steel A2	70	bright	M6	90	10	6	5
07159-106X100	stainless steel A2	70	bright	M6	100	10	6	5
07159-108X50	stainless steel A2	70	bright	M8	50	13	8	6
07159-108X60	stainless steel A2	70	bright	M8	60	13	8	6
07159-108X70	stainless steel A2	70	bright	M8	70	13	8	6
07159-108X80	stainless steel A2	70	bright	M8	80	13	8	6
07159-108X90	stainless steel A2	70	bright	M8	90	13	8	6
07159-108X100	stainless steel A2	70	bright	M8	100	13	8	6
07159-110X50	stainless steel A2	70	bright	M10	50	16	10	8
07159-110X60	stainless steel A2	70	bright	M10	60	16	10	8
07159-110X70	stainless steel A2	70	bright	M10	70	16	10	8
07159-110X80	stainless steel A2	70	bright	M10	80	16	10	8
07159-110X90	stainless steel A2	70	bright	M10	90	16	10	8
07159-110X100	stainless steel A2	70	bright	M10	100	16	10	8
07159-112X70	stainless steel A2	70	bright	M12	70	18	12	10
07159-112X80	stainless steel A2	70	bright	M12	80	18	12	10
07159-112X90	stainless steel A2	70	bright	M12	90	18	12	10
07159-112X100	stainless steel A2	70	bright	M12	100	18	12	10
07159-605X40	stainless steel A4	70	bright	M5	40	8,5	5	4
07159-605X70	stainless steel A4	70	bright	M5	70	8,5	5	4
07159-605X80	stainless steel A4	70	bright	M5	80	8,5	5	4
07159-606X40	stainless steel A4	70	bright	M6	40	10	6	5
07159-606X50	stainless steel A4	70	bright	M6	50	10	6	5
07159-606X60	stainless steel A4	70	bright	M6	60	10	6	5
07159-606X70	stainless steel A4	70	bright	M6	70	10	6	5
07159-606X80	stainless steel A4	70	bright	M6	80	10	6	5
07159-606X90	stainless steel A4	70	bright	M6	90	10	6	5
07159-606X100	stainless steel A4	70	bright	M6	100	10	6	5
07159-608X50	stainless steel A4	70	bright	M8	50	13	8	6
07159-608X60	stainless steel A4	70	bright	M8	60	13	8	6
07159-608X70	stainless steel A4	70	bright	M8	70	13	8	6
07159-608X80	stainless steel A4	70	bright	M8	80	13	8	6
07159-608X90	stainless steel A4	70	bright	M8	90	13	8	6
07159-608X100	stainless steel A4	70	bright	M8	100	13	8	6
07159-610X50	stainless steel A4	70	bright	M10	50	16	10	8
07159-610X60	stainless steel A4	70	bright	M10	60	16	10	8
07159-610X70	stainless steel A4	70	bright	M10	70	16	10	8
07159-610X80	stainless steel A4	70	bright	M10	80	16	10	8
07159-610X90	stainless steel A4	70	bright	M10	90	16	10	8
07159-610X100	stainless steel A4	70	bright	M10	100	16	10	8
07159-612X80	stainless steel A4	70	bright	M12	80	18	12	10
07159-612X100	stainless steel A4	70	bright	M12	100	18	12	10

