

Item description/product images



Description

**Material:**  
Steel or stainless steel A2.


**Version:**  
Electro zinc-plated steel.  
Bright stainless steel.

**Note:**  
Hexagon nuts with thread lock DIN 980, Form V (all-metal nut, one piece).

The maximum nut height H max. is shown in the table.  
The form and dimensions of the stainless steel versions are the same as for DIN 934 with additional crimping.

**Drawing reference:**  
a) Steel  
b) Stainless steel

Drawings

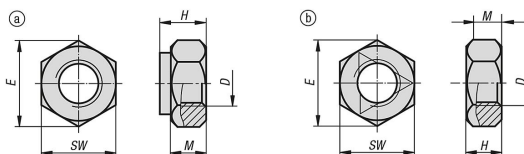

Overview of items

Order No.	Main material	Grade	D	E	H	M	SW
07215-204	steel	8	M4	7,66	4,2	2,2	7
07215-205	steel	8	M5	8,79	5,1	2,75	8
07215-206	steel	8	M6	11,05	6	3,3	10
07215-208	steel	8	M8	14,38	8	4,4	13
07215-210	steel	8	M10	18,9	10	5,5	17
07215-212	steel	8	M12	21,1	12	6,6	19
07215-214	steel	8	M14	23,9	14	7,7	22
07215-216	steel	8	M16	26,76	16	8,8	24
07215-220	steel	8	M20	32,95	20	11	30
07215-224	steel	8	M24	39,55	24	13,2	36
07215-227	steel	8	M27	45,2	27	14,8	41
07215-230	steel	8	M30	50,85	30	16,5	46
07215-308	steel	10	M8	14,38	8	4,4	13
07215-310	steel	10	M10	18,9	10	5,5	17
07215-312	steel	10	M12	21,1	12	6,6	19
07215-314	steel	10	M14	23,9	14	7,7	22
07215-316	steel	10	M16	26,76	16	8,8	24
07215-320	steel	10	M20	32,95	20	11	30
07215-324	steel	10	M24	35	24	13,2	36
07215-327	steel	10	M27	45,2	27	14,8	41
07215-330	steel	10	M30	50,85	30	16,5	46
07215-104	stainless steel A2	70	M4	7,66	4,2	2,2	7
07215-105	stainless steel A2	70	M5	8,79	5,1	2,75	8
07215-106	stainless steel A2	70	M6	11,05	6	3,3	10
07215-108	stainless steel A2	70	M8	14,38	8	4,4	13
07215-110	stainless steel A2	70	M10	18,9	10	5,5	17
07215-112	stainless steel A2	70	M12	21,1	12	6,6	19
07215-114	stainless steel A2	70	M14	23,9	14	7,7	22

## Overview of items

Order No.	Main material	Grade	D	E	H	M	SW
07215-116	stainless steel A2	70	M16	26,76	16	8,8	24
07215-120	stainless steel A2	70	M20	32,95	20	11	30
07215-124	stainless steel A2	70	M24	39,55	24	13,2	36