


## Item description/product images

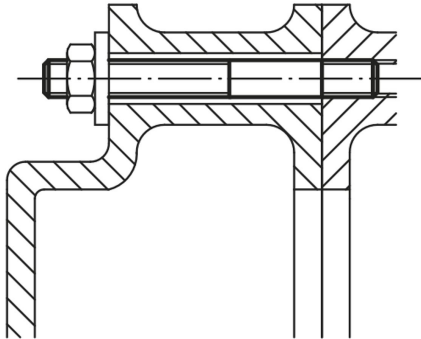

## Description

**Material:**

Carbon steel.

**Version:**

Thread rolled.


M6-M12 tempered to 10.9, black.

M14-M36 tempered to 8.8, black.

**Note:**

Permissible load: see Technical Information.

## Drawings

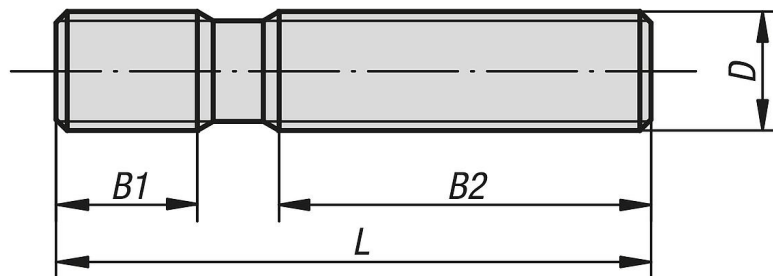

## Overview of items

| Order No.   | D   | L   | B1 | B2  |
|-------------|-----|-----|----|-----|
| 07030-0632  | M6  | 32  | 9  | 16  |
| 07030-0640  | M6  | 40  | 9  | 20  |
| 07030-0650  | M6  | 50  | 9  | 30  |
| 07030-0663  | M6  | 63  | 9  | 40  |
| 07030-0680  | M6  | 80  | 9  | 50  |
| 07030-06100 | M6  | 100 | 9  | 63  |
| 07030-0840  | M8  | 40  | 11 | 20  |
| 07030-0863  | M8  | 63  | 11 | 40  |
| 07030-0880  | M8  | 80  | 11 | 50  |
| 07030-08100 | M8  | 100 | 11 | 63  |
| 07030-08125 | M8  | 125 | 11 | 75  |
| 07030-08160 | M8  | 160 | 11 | 100 |
| 07030-1050  | M10 | 50  | 13 | 25  |
| 07030-1080  | M10 | 80  | 13 | 50  |
| 07030-10100 | M10 | 100 | 13 | 75  |
| 07030-10125 | M10 | 125 | 13 | 75  |
| 07030-10160 | M10 | 160 | 13 | 100 |
| 07030-10200 | M10 | 200 | 13 | 125 |
| 07030-1250  | M12 | 50  | 15 | 25  |
| 07030-1263  | M12 | 63  | 15 | 32  |
| 07030-1280  | M12 | 80  | 15 | 50  |
| 07030-12100 | M12 | 100 | 15 | 63  |
| 07030-12125 | M12 | 125 | 15 | 75  |
| 07030-12160 | M12 | 160 | 15 | 100 |
| 07030-12200 | M12 | 200 | 15 | 125 |

## Overview of items

| Order No.    | D   | L    | B1 | B2  |
|--------------|-----|------|----|-----|
| 07030-1463   | M14 | 63   | 17 | 32  |
| 07030-1480   | M14 | 80   | 17 | 50  |
| 07030-14100  | M14 | 100  | 17 | 63  |
| 07030-14125  | M14 | 125  | 17 | 75  |
| 07030-14160  | M14 | 160  | 17 | 100 |
| 07030-14200  | M14 | 200  | 17 | 125 |
| 07030-14250  | M14 | 250  | 17 | 160 |
| 07030-1663   | M16 | 63   | 19 | 32  |
| 07030-1680   | M16 | 80   | 19 | 50  |
| 07030-16100  | M16 | 100  | 19 | 63  |
| 07030-16125  | M16 | 125  | 19 | 75  |
| 07030-16160  | M16 | 160  | 19 | 100 |
| 07030-16200  | M16 | 200  | 19 | 125 |
| 07030-16250  | M16 | 250  | 19 | 160 |
| 07030-16315  | M16 | 315  | 19 | 180 |
| 07030-16350  | M16 | 350  | 19 | 200 |
| 07030-16500  | M16 | 500  | 20 | 315 |
| 07030-1880   | M18 | 80   | 23 | 50  |
| 07030-18125  | M18 | 125  | 23 | 75  |
| 07030-18160  | M18 | 160  | 23 | 100 |
| 07030-18200  | M18 | 200  | 23 | 125 |
| 07030-18250  | M18 | 250  | 23 | 150 |
| 07030-18315  | M18 | 315  | 23 | 180 |
| 07030-2080   | M20 | 80   | 27 | 32  |
| 07030-20125  | M20 | 125  | 27 | 70  |
| 07030-20160  | M20 | 160  | 27 | 100 |
| 07030-20200  | M20 | 200  | 27 | 125 |
| 07030-20250  | M20 | 250  | 27 | 160 |
| 07030-20315  | M20 | 315  | 27 | 200 |
| 07030-20400  | M20 | 400  | 27 | 250 |
| 07030-20500  | M20 | 500  | 27 | 315 |
| 07030-22100  | M22 | 100  | 31 | 45  |
| 07030-22160  | M22 | 160  | 31 | 100 |
| 07030-22200  | M22 | 200  | 31 | 125 |
| 07030-22250  | M22 | 250  | 31 | 160 |
| 07030-22315  | M22 | 315  | 31 | 180 |
| 07030-22400  | M22 | 400  | 31 | 250 |
| 07030-24100  | M24 | 100  | 35 | 45  |
| 07030-24125  | M24 | 125  | 35 | 63  |
| 07030-24160  | M24 | 160  | 35 | 100 |
| 07030-24200  | M24 | 200  | 35 | 125 |
| 07030-24250  | M24 | 250  | 35 | 160 |
| 07030-24315  | M24 | 315  | 35 | 200 |
| 07030-24400  | M24 | 400  | 35 | 250 |
| 07030-24500  | M24 | 500  | 35 | 315 |
| 07030-24630  | M24 | 630  | 35 | 315 |
| 07030-27125  | M27 | 125  | 39 | 56  |
| 07030-27200  | M27 | 200  | 39 | 125 |
| 07030-27315  | M27 | 315  | 39 | 200 |
| 07030-27400  | M27 | 400  | 39 | 250 |
| 07030-27500  | M27 | 500  | 39 | 315 |
| 07030-30125  | M30 | 125  | 43 | 56  |
| 07030-30200  | M30 | 200  | 43 | 125 |
| 07030-30315  | M30 | 315  | 43 | 200 |
| 07030-30500  | M30 | 500  | 43 | 315 |
| 07030-30700  | M30 | 700  | 43 | 400 |
| 07030-301000 | M30 | 1000 | 44 | 400 |
| 07030-36160  | M36 | 160  | 51 | 80  |
| 07030-36200  | M36 | 200  | 51 | 125 |
| 07030-36250  | M36 | 250  | 51 | 160 |
| 07030-36315  | M36 | 315  | 51 | 200 |
| 07030-36400  | M36 | 400  | 51 | 250 |
| 07030-36500  | M36 | 500  | 51 | 315 |
| 07030-36700  | M36 | 700  | 51 | 400 |

