

Item description/product images



Description

Product description:

These slanted pull handles are particularly suitable for mounting in places where space is limited.

The grips are very stable and can also be used where robust handling and corrosion resistance are required.

Material:

1.4308 stainless steel precision casting 316L.

Version:

Bright.

Note:

Due to the manufacturing process, the grips may show surface irregularities.

Application:

Where space is limited in machine and plant construction, toolmaking or the foodstuff and pharmaceutical industries.

Assembly:

From the rear.

Advantages:


Good access where space is limited.

Very stable and robust.

Corrosion resistant.

Retaining element for opening and closing covers, panels and hoods.

Drawings

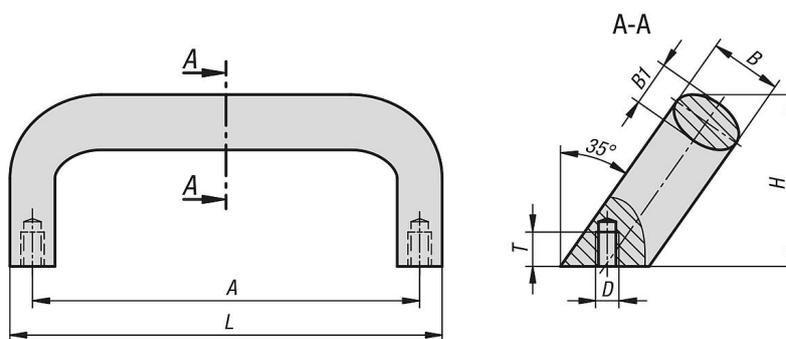

Overview of items

Order No.	Steel code	A	B	B1	D	H	L	T	Load capacity N
06920-15-100008061	1.4308	100	21	13	M6	50	113	10	1000
06920-15-112008061	1.4308	112	21	13	M6	50	125	10	1000
06920-15-120008061	1.4308	120	21	13	M6	50	133	10	1000
06920-15-128008061	1.4308	128	21	13	M6	50	141	10	1000
06920-15-160008061	1.4308	160	21	13	M6	50	173	10	1000
06920-15-100008062	1.4404	100	21	13	M6	50	113	10	1000
06920-15-112008062	1.4404	112	21	13	M6	50	125	10	1000
06920-15-120008062	1.4404	120	21	13	M6	50	133	10	1000
06920-15-128008062	1.4404	128	21	13	M6	50	141	10	1000

Overview of items

Order No.	Steel code	A	B	B1	D	H	L	T	Load capacity N
06920-15-160008062	1.4404	160	21	13	M6	50	173	10	1000