

Item description/product images

INCH
Partslift to
disengage

Description

Material:

Handle die-cast zinc DIN EN 12844.
Steel parts grade 5.8.

Version:

Handle powder-coated.
Steel parts black oxidised.

Note for ordering:

Screws from 70 mm long have 60 mm long threads.

Note:

Where $L \geq 60$ mm the thread length is always 60 mm.


On request:

Other threads, screw lengths, colours and special versions.
Dimension "H1" available in other lengths at extra charge.

Drawing reference:

1) flat point DIN EN ISO 4753

Drawings

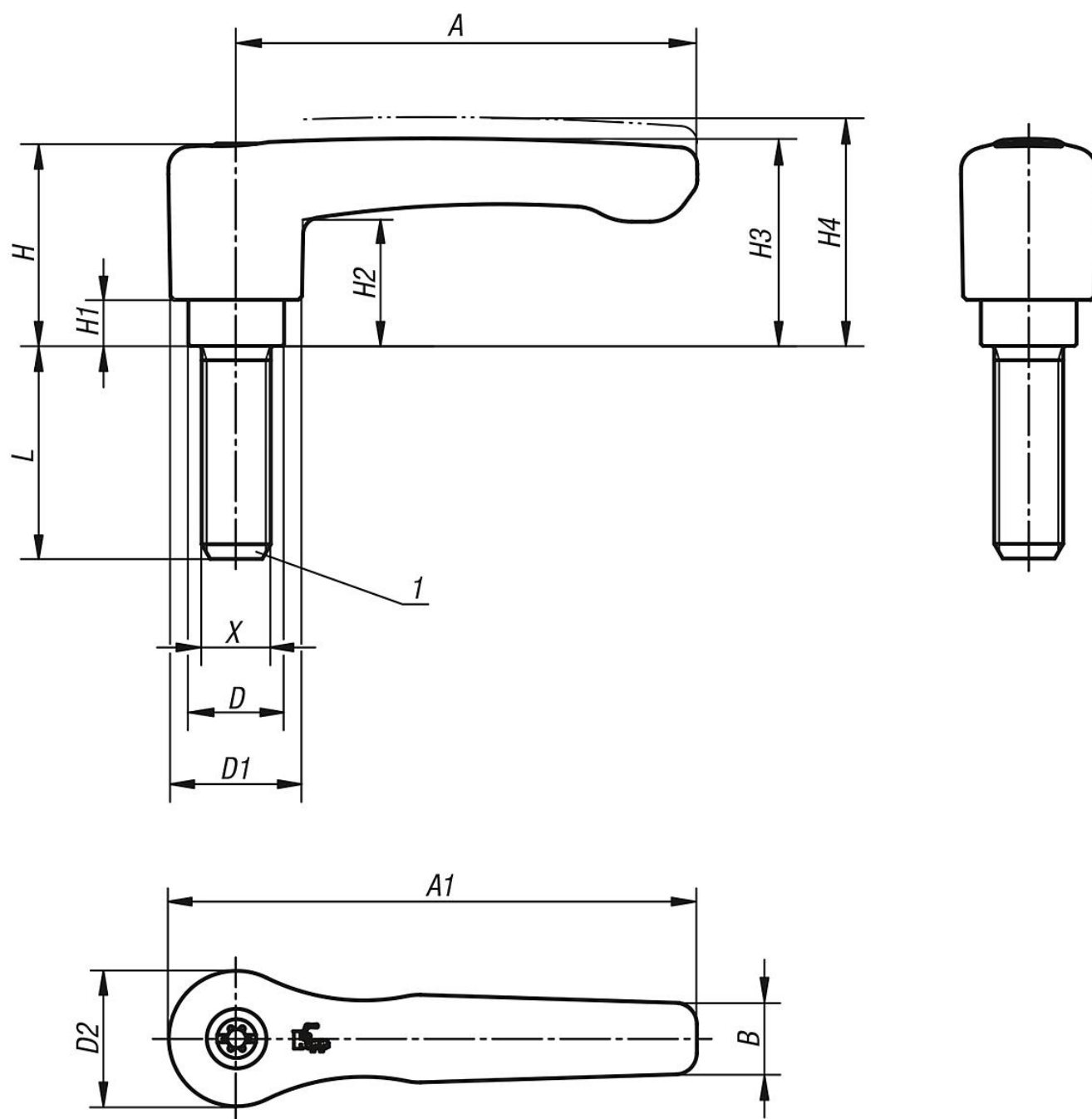

Overview of items

Order No.	Main colour	Surface finish body	Size	X	D	D1	D2	H	H1	H2	H3	H4	A	A1	B	No. of teeth	L
06458-2A21X15	jet black RAL 9005	satin finish	2	1/4-20	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	15
06458-2A21X20	jet black RAL 9005	satin finish	2	1/4-20	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	20
06458-2A21X25	jet black RAL 9005	satin finish	2	1/4-20	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	25
06458-2A21X30	jet black RAL 9005	satin finish	2	1/4-20	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	30
06458-2A21X35	jet black RAL 9005	satin finish	2	1/4-20	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	35
06458-2A21X40	jet black RAL 9005	satin finish	2	1/4-20	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	40
06458-2A21X45	jet black RAL 9005	satin finish	2	1/4-20	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	45
06458-2A21X50	jet black RAL 9005	satin finish	2	1/4-20	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	50
06458-2A21X55	jet black RAL 9005	satin finish	2	1/4-20	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	55
06458-2A21X60	jet black RAL 9005	satin finish	2	1/4-20	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	60
06458-2A31X15	jet black RAL 9005	satin finish	2	5/16-18	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	15

Order No.	Main colour	Surface finish body	Size	X	D	D1	D2	H	H1	H2	H3	H4	A	A1	B	No. of teeth	L
06458-2A31X20	jet black RAL 9005	satin finish	2	5/16-18	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	20
06458-2A31X25	jet black RAL 9005	satin finish	2	5/16-18	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	25
06458-2A31X30	jet black RAL 9005	satin finish	2	5/16-18	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	30
06458-2A31X35	jet black RAL 9005	satin finish	2	5/16-18	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	35
06458-2A31X40	jet black RAL 9005	satin finish	2	5/16-18	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	40
06458-2A31X45	jet black RAL 9005	satin finish	2	5/16-18	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	45
06458-2A31X50	jet black RAL 9005	satin finish	2	5/16-18	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	50
06458-2A31X55	jet black RAL 9005	satin finish	2	5/16-18	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	55
06458-2A31X60	jet black RAL 9005	satin finish	2	5/16-18	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	60
06458-2A41X15	jet black RAL 9005	satin finish	2	3/8-16	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	
06458-2A41X20	jet black RAL 9005	satin finish	2	3/8-16	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	20
06458-2A41X25	jet black RAL 9005	satin finish	2	3/8-16	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	25
06458-2A41X30	jet black RAL 9005	satin finish	2	3/8-16	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	30
06458-2A41X35	jet black RAL 9005	satin finish	2	3/8-16	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	35
06458-2A41X40	jet black RAL 9005	satin finish	2	3/8-16	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	40
06458-2A41X45	jet black RAL 9005	satin finish	2	3/8-16	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	45
06458-2A41X50	jet black RAL 9005	satin finish	2	3/8-16	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	50
06458-2A41X55	jet black RAL 9005	satin finish	2	3/8-16	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	55
06458-2A41X60	jet black RAL 9005	satin finish	2	3/8-16	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	60
06458-3A31X15	jet black RAL 9005	satin finish	3	5/16-18	16	21,2	22	37	10	23,8	38	42	80	91	11,7	22	15
06458-3A31X20	jet black RAL 9005	satin finish	3	5/16-18	16	21,2	22	37	10	23,8	38	42	80	91	11,7	22	20
06458-3A31X25	jet black RAL 9005	satin finish	3	5/16-18	16	21,2	22	37	10	23,8	38	42	80	91	11,7	22	25
06458-3A31X30	jet black RAL 9005	satin finish	3	5/16-18	16	21,2	22	37	10	23,8	38	42	80	91	11,7	22	30
06458-3A31X35	jet black RAL 9005	satin finish	3	5/16-18	16	21,2	22	37	10	23,8	38	4					

Order No.	Main colour	Surface finish body	Size	X	D	D1	D2	H	H1	H2	H3	H4	A	A1	B	No. of teeth	L
06458-2A4181X45	jet black RAL 9005	textured matt	2	3/8-16	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	45
06458-2A4181X50	jet black RAL 9005	textured matt	2	3/8-16	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	50
06458-2A4181X55	jet black RAL 9005	textured matt	2	3/8-16	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	55
06458-2A4181X60	jet black RAL 9005	textured matt	2	3/8-16	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	60
06458-3A3181X15	jet black RAL 9005	textured matt	3	5/16-18	16	21,2	22	37	10	23,8	38	42	80	91	11,7	22	15
06458-3A3181X20	jet black RAL 9005	textured matt	3	5/16-18	16	21,2	22	37	10	23,8	38	42	80	91	11,7	22	20
06458-3A3181X25	jet black RAL 9005	textured matt	3	5/16-18	16	21,2	22	37	10	23,8	38	42	80	91	11,7	22	25
06458-3A3181X30	jet black RAL 9005	textured matt	3	5/16-18	16	21,2	22	37	10	23,8	38	42	80	91	11,7	22	30
06458-3A3181X35	jet black RAL 9005	textured matt	3	5/16-18	16	21,2	22	37	10	23,8	38	42	80	91	11,7	22	35
06458-3A3181X40	jet black RAL 9005	textured matt	3	5/16-18	16	21,2	22	37	10	23,8	38	42	80	91	11,7	22	40
06458-3A3181X45	jet black RAL 9005	textured matt	3	5/16-18	16	21,2	22	37	10	23,8	38	42	80	91	11,7	22	45
06458-3A3181X50	jet black RAL 9005	textured matt	3	5/16-18	16	21,2	22	37	10	23,8	38	42	80	91	11,7	22	50
06458-3A3181X55	jet black RAL 9005	textured matt	3	5/16-18	16	21,2	22	37	10	23,8	38	42	80	91	11,7	22	55
06458-3A3181X60	jet black RAL 9005	textured matt	3	5/16-18	16	21,2	22	37	10	23,8	38	42	80	91	11,7	22	60
06458-3A4181X15	jet black RAL 9005	textured matt	3	3/8-16	16	21,2	22	37	10	23,8	38	42	80	91	11,7	22	15
06458-3A4181X20	jet black RAL 9005	textured matt	3	3/8-16	16	21,2	22	37	10	23,8	38	42	80	91	11,7	22	20
06458-3A4181X25	jet black RAL 9005	textured matt	3	3/8-16	16	21,2	22	37	10	23,8	38	42	80	91	11,7	22	25
06458-3A4181X30	jet black RAL 9005	textured matt	3	3/8-16	16	21,2	22	37	10	23,8	38	42	80	91	11,7	22	30
06458-3A4181X35	jet black RAL 9005	textured matt	3	3/8-16	16	21,2	22	37	10	23,8	38	42	80	91	11,7	22	35
06458-3A4181X40	jet black RAL 9005	textured matt	3	3/8-16	16	21,2	22	37	10	23,8	38	42	80	91	11,7	22	40
06458-3A4181X45	jet black RAL 9005	textured matt	3	3/8-16	16	21,2	22	37	10	23,8	38	42	80	91	11,7	22	45
06458-3A4181X50	jet black RAL 9005	textured matt	3	3/8-16	16	21,2	22	37	10	23,8	38	42	80	91	11,7	22	50
06458-3A4181X55	jet black RAL 9005	textured matt	3	3/8-16	16	21,2	22	37	10	23,8	38	42	80	91	11,7	22	55
06458-3A4181X60	jet black RAL 9005	textured matt	3	3/8-16	16	21,2	22	37	10	23,8	38	42	80	91	11,7	22	60
06458-2A2182X15	orange RAL 2004	textured matt	2	1/4-20	13,5	18,5	1										

