

Item description/product images



Description


Material:

Steel 1.1192 or stainless steel 1.4571.


Version:

Bright.

Application example:

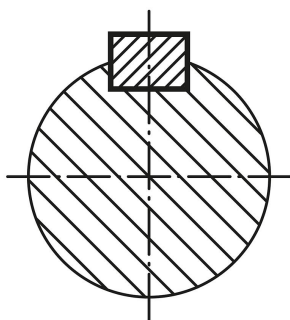

Drawings

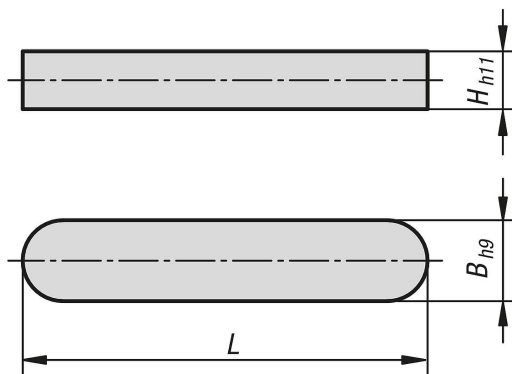

Overview of items

Order No.	Main material	B	H	L = length
03288-03X8	0.004	3	3	8
03288-03X10	0.004	3	3	10
03288-03X12	0.004	3	3	12
03288-03X14	0.004	3	3	14
03288-03X16	0.004	3	3	16
03288-03X18	0.004	3	3	18
03288-03X20	0.004	3	3	20
03288-03X22	0.004	3	3	22
03288-03X25	0.004	3	3	25
03288-03X28	0.004	3	3	28
03288-04X8	0.004	4	4	8
03288-04X10	0.004	4	4	10
03288-04X12	0.004	4	4	12
03288-04X14	0.004	4	4	14

Overview of items

Order No.	Main material	B	H	L = length
03288-04X16	0.004	4	4	16
03288-04X18	0.004	4	4	18
03288-04X20	0.004	4	4	20
03288-04X22	0.004	4	4	22
03288-04X25	0.004	4	4	25
03288-04X28	0.004	4	4	28
03288-05X12	0.004	5	5	12
03288-05X14	0.004	5	5	14
03288-05X16	0.004	5	5	16
03288-05X18	0.004	5	5	18
03288-05X20	0.004	5	5	20
03288-05X22	0.004	5	5	22
03288-05X25	0.004	5	5	25
03288-05X28	0.004	5	5	28
03288-05X32	0.004	5	5	32
03288-05X36	0.004	5	5	36
03288-05X40	0.004	5	5	40
03288-06X12	0.004	6	6	12
03288-06X14	0.004	6	6	14
03288-06X16	0.004	6	6	16
03288-06X18	0.004	6	6	18
03288-06X20	0.004	6	6	20
03288-06X22	0.004	6	6	22
03288-06X25	0.004	6	6	25
03288-06X28	0.004	6	6	28
03288-06X32	0.004	6	6	32
03288-06X36	0.004	6	6	36
03288-06X40	0.004	6	6	40
03288-06X45	0.004	6	6	45
03288-08X14	0.004	8	7	14
03288-08X16	0.004	8	7	16
03288-08X18	0.004	8	7	18
03288-08X20	0.004	8	7	20
03288-08X22	0.004	8	7	22
03288-08X25	0.004	8	7	25
03288-08X28	0.004	8	7	28
03288-08X32	0.004	8	7	32
03288-08X36	0.004	8	7	36
03288-08X40	0.004	8	7	40
03288-08X45	0.004	8	7	45
03288-08X50	0.004	8	7	50
03288-08X70	0.004	8	7	70
03288-10X22	0.004	10	8	22
03288-10X25	0.004	10	8	25
03288-10X28	0.004	10	8	28
03288-10X32	0.004	10	8	32
03288-10X36	0.004	10	8	36
03288-10X40	0.004	10	8	40
03288-10X45	0.004	10	8	45
03288-10X50	0.004	10	8	50
03288-10X56	0.004	10	8	56
03288-10X70	0.004	10	8	70
03288-10X80	0.004	10	8	80
03288-12X25	0.004	12	8	25
03288-12X28	0.004	12	8	28
03288-12X32	0.004	12	8	32
03288-12X36	0.004	12	8	36
03288-12X40	0.004	12	8	40
03288-12X45	0.004	12	8	45
03288-12X50	0.004	12	8	50
03288-12X56	0.004	12	8	56
03288-12X70	0.004	12	8	70
03288-12X80	0.004	12	8	80
03288-14X25	0.004	14	9	25
03288-14X28	0.004	14	9	28

Overview of items

Order No.	Main material	B	H	L = length
03288-14X32	0.004	14	9	32
03288-14X36	0.004	14	9	36
03288-14X40	0.004	14	9	40
03288-14X45	0.004	14	9	45
03288-14X50	0.004	14	9	50
03288-14X56	0.004	14	9	56
03288-14X70	0.004	14	9	70
03288-14X80	0.004	14	9	80
03288-16X50	0.004	16	10	50
03288-16X56	0.004	16	10	56
03288-16X63	0.004	16	10	63
03288-16X70	0.004	16	10	70
03288-16X80	0.004	16	10	80
03288-16X90	0.004	16	10	90
03288-16X100	0.004	16	10	100
03288-103X10	250 ml tube	3	3	10
03288-103X12	250 ml tube	3	3	12
03288-103X16	250 ml tube	3	3	16
03288-103X20	250 ml tube	3	3	20
03288-104X10	250 ml tube	4	4	10
03288-104X12	250 ml tube	4	4	12
03288-104X14	250 ml tube	4	4	14
03288-104X16	250 ml tube	4	4	16
03288-104X18	250 ml tube	4	4	18
03288-104X20	250 ml tube	4	4	20
03288-104X22	250 ml tube	4	4	22
03288-105X12	250 ml tube	5	5	12
03288-105X14	250 ml tube	5	5	14
03288-105X16	250 ml tube	5	5	16
03288-105X18	250 ml tube	5	5	18
03288-105X20	250 ml tube	5	5	20
03288-105X22	250 ml tube	5	5	22
03288-105X25	250 ml tube	5	5	25
03288-105X28	250 ml tube	5	5	28
03288-105X36	250 ml tube	5	5	36
03288-105X40	250 ml tube	5	5	40
03288-106X12	250 ml tube	6	6	12
03288-106X14	250 ml tube	6	6	14
03288-106X16	250 ml tube	6	6	16
03288-106X18	250 ml tube	6	6	18
03288-106X20	250 ml tube	6	6	20
03288-106X22	250 ml tube	6	6	22
03288-106X25	250 ml tube	6	6	25
03288-106X28	250 ml tube	6	6	28
03288-106X32	250 ml tube	6	6	32
03288-106X36	250 ml tube	6	6	36
03288-106X40	250 ml tube	6	6	40
03288-108X16	250 ml tube	8	7	16
03288-108X18	250 ml tube	8	7	18
03288-108X20	250 ml tube	8	7	20
03288-108X22	250 ml tube	8	7	22
03288-108X25	250 ml tube	8	7	25
03288-108X28	250 ml tube	8	7	28
03288-108X32	250 ml tube	8	7	32
03288-108X36	250 ml tube	8	7	36
03288-108X40	250 ml tube	8	7	40
03288-108X45	250 ml tube	8	7	45
03288-108X50	250 ml tube	8	7	50
03288-108X70	250 ml tube	8	7	70
03288-110X22	250 ml tube	10	8	22
03288-110X25	250 ml tube	10	8	25
03288-110X28	250 ml tube	10	8	28
03288-110X32	250 ml tube	10	8	32
03288-110X36	250 ml tube	10	8	36
03288-110X40	250 ml tube	10	8	40

Overview of items

Order No.	Main material	B	H	L = length
03288-110X45	250 ml tube	10	8	45
03288-110X50	250 ml tube	10	8	50
03288-110X56	250 ml tube	10	8	56
03288-110X70	250 ml tube	10	8	70
03288-110X80	250 ml tube	10	8	80
03288-112X28	250 ml tube	12	8	28
03288-112X32	250 ml tube	12	8	32
03288-112X36	250 ml tube	12	8	36
03288-112X40	250 ml tube	12	8	40
03288-112X45	250 ml tube	12	8	45
03288-112X50	250 ml tube	12	8	50
03288-112X56	250 ml tube	12	8	56
03288-112X70	250 ml tube	12	8	70
03288-112X80	250 ml tube	12	8	80
03288-114X32	250 ml tube	14	9	32
03288-114X40	250 ml tube	14	9	40
03288-114X45	250 ml tube	14	9	45
03288-114X50	250 ml tube	14	9	50
03288-114X56	250 ml tube	14	9	56
03288-114X70	250 ml tube	14	9	70
03288-114X80	250 ml tube	14	9	80
03288-116X50	250 ml tube	16	10	50
03288-116X63	250 ml tube	16	10	63
03288-116X70	250 ml tube	16	10	70
03288-116X80	250 ml tube	16	10	80
03288-116X90	250 ml tube	16	10	90
03288-116X100	250 ml tube	16	10	100