

Item description/product images



lift to
disengage

**Description****Material:**

Handle die-cast zinc DIN EN 12844.
Steel parts grade 5.8.


Version:

Handle powder-coated.
Steel parts black oxidised.

On request:

Other threads, colours and special versions.
Dimension "H1" available in other lengths at extra charge.

Drawings

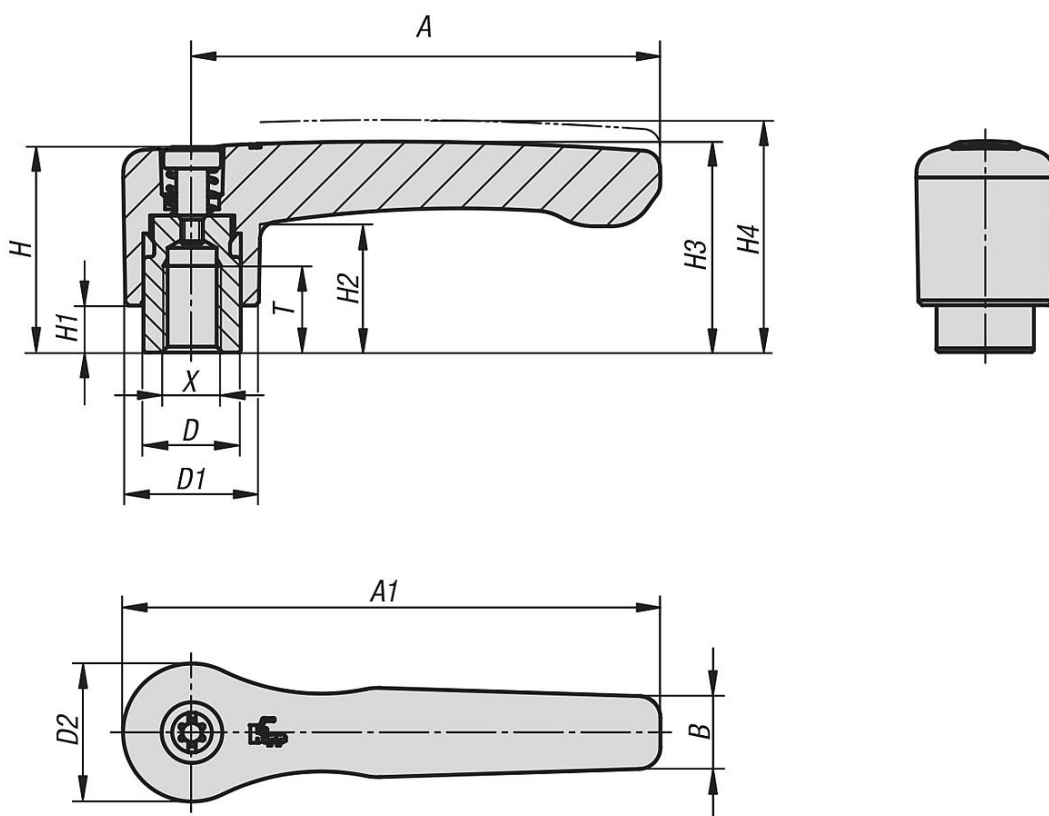

Overview of items

Order No.	Main colour	Surface finish body	Size	X	T	D	D1	D2	H	H1	H2	H3	H4	A	A1	B	No. of teeth
06448-2A21	jet black RAL 9005	satin finish	2	1/4-20	12	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20
06448-2A31	jet black RAL 9005	satin finish	2	5/16-18	12	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20
06448-3A31	jet black RAL 9005	satin finish	3	5/16-18	14	16	21,2	22	37	10	23,8	38	42	80	91	11,7	22
06448-3A41	jet black RAL 9005	satin finish	3	3/8-16	14	16	21,2	22	37	10	23,8	38	42	80	91	11,7	22
06448-2A2181	jet black RAL 9005	textured matt	2	1/4-20	12	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20
06448-2A3181	jet black RAL 9005	textured matt	2	5/16-18	12	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20
06448-3A3181	jet black RAL 9005	textured matt	3	5/16-18	14	16	21,2	22	37	10	23,8	38	42	80	91	11,7	22
06448-3A4181	jet black RAL 9005	textured matt	3	3/8-16	14	16	21,2	22	37	10	23,8	38	42	80	91	11,7	22
06448-2A2182	orange RAL 2004	textured matt	2	1/4-20	12	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20
06448-2A3182	orange RAL 2004	textured matt	2	5/16-18	12	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20
06448-3A3182	orange RAL 2004	textured matt	3	5/16-18	14	16	21,2	22	37	10	23,8	38	42	80	91	11,7	22
06448-3A4182	orange RAL 2004	textured matt	3	3/8-16	14	16	21,2	22	37	10	23,8	38	42	80	91	11,7	22
06448-2A2184	traffic red RAL 3020	textured matt	2	1/4-20	12	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20
06448-2A3184	traffic red RAL 3020	textured matt	2	5/16-18	12	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20
06448-3A3184	traffic red RAL 3020	textured matt	3	5/16-18	14	16	21,2	22	37	10	23,8	38	42	80	91	11,7	22
06448-3A4184	traffic red RAL 3020	textured matt	3	3/8-16	14	16	21,2	22	37	10	23,8	38	42	80	91	11,7	22