

Item description/product images



Description

Material:

Steel or 1.4305 stainless steel.

Stainless steel versions have Neoprene seals.

Version:

Trivalent passivated.

Stainless steel version bright.

Note:


Protected against dust, dirt, water spray and vapour.

Applicable temperature range from -30 °C to +110 °C.

On request:

Axial joints with greater extraction force and left-hand thread available.

Drawings

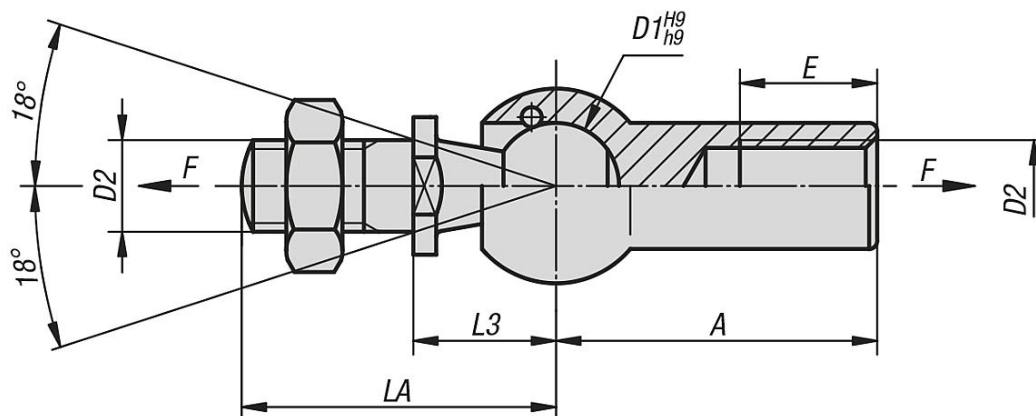

Overview of items

Order No.	Main material	D1	D2	A	LA	L3	E	Extraction force F N
27665-08	0.0041	8	M5	22	19,2	9	10,2	30
27665-10	0.0041	10	M6	25	23,5	11	11,5	40
27665-13	0.0041	13	M8	30	29,5	13	14	60
27665-16	0.0041	16	M10	35	36	16	15,5	80
27665-19	0.0041	19	M14x1,5	45	48	20	21,5	100
27665-108	250 V	8	M5	22	19,2	9	10,2	30
27665-110	250 V	10	M6	25	23,5	11	11,5	40
27665-113	250 V	13	M8	30	29,5	13	14	60
27665-116	250 V	16	M10	35	36	16	15,5	80