

Item description/product images



Description

Material:

Carbon steel or stainless steel A2.

Version:

Steel version:


tempered to 900 N/mm², black oxidised.

Stainless steel version:


tempered to 900 N/mm², bright.

Note:

Captive components (one-piece).

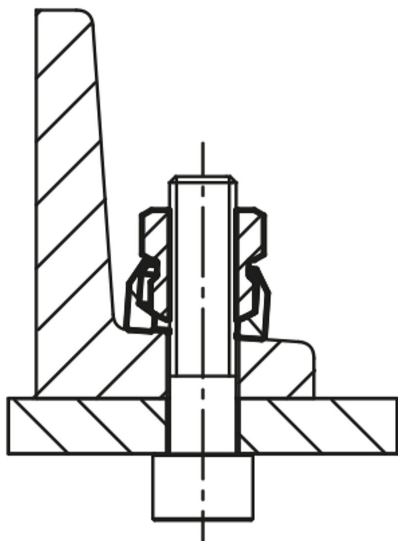

Drawings

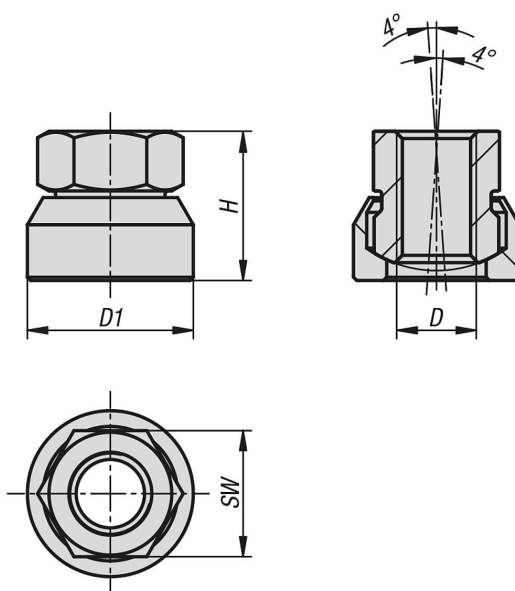

Overview of items

Order No.	Main material	D	D1	H	SW
07265-08	0.0061	M8	18	15	13

Overview of items

Order No.	Main material	D	D1	H	SW
07265-10	0.0061	M10	22	18,5	17
07265-12	0.0061	M12	25	22,5	19
07265-16	0.0061	M16	31	29	24
07265-808	Additional Hinge	M8	18	15	13
07265-810	Additional Hinge	M10	22	18,5	17
07265-812	Additional Hinge	M12	25	22,5	19
07265-816	Additional Hinge	M16	31	29	24