


Item description/product images

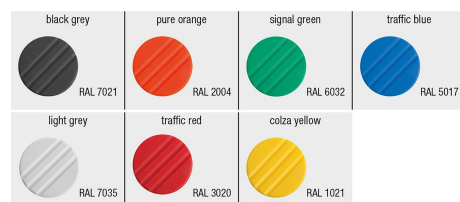

Description

Material:

Black thermoplastic.


Bush and screw 5.8 steel or 1.4305 stainless steel.

Version:

Steel trivalent blue passivated.

Stainless steel, bright.

Drawings

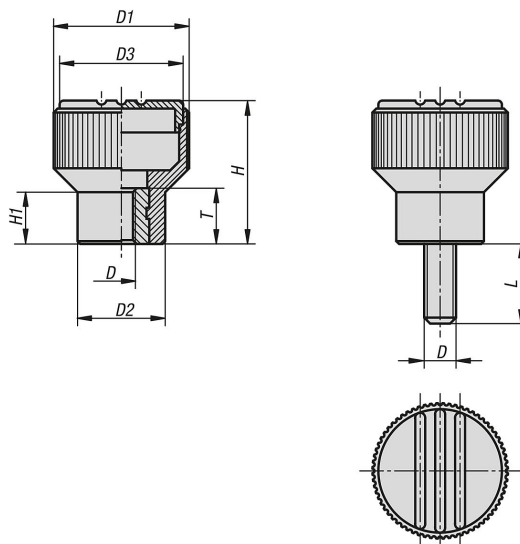

Overview of items

Knurled knobs with internal thread

Order No.	Bush material	Colour Cap	D	D1	D2	D3	H	H1	T	L
06092-104	steel	black grey RAL 7021	M4	21	14	19	22	8	10	-
06092-1041	steel	orange RAL 2004	M4	21	14	19	22	8	10	-
06092-1042	steel	signal green RAL 6032	M4	21	14	19	22	8	10	-
06092-1043	steel	blue RAL5017	M4	21	14	19	22	8	10	-
06092-1045	steel	light grey RAL 7035	M4	21	14	19	22	8	10	-
06092-1046	steel	traffic red RAL 3020	M4	21	14	19	22	8	10	-
06092-1047	steel	colza yellow RAL 1021	M4	21	14	19	22	8	10	-
06092-105	steel	black grey RAL 7021	M5	21	14	19	22	8	10	-
06092-1051	steel	orange RAL 2004	M5	21	14	19	22	8	10	-
06092-1052	steel	signal green RAL 6032	M5	21	14	19	22	8	10	-
06092-1053	steel	blue RAL5017	M5	21	14	19	22	8	10	-
06092-1055	steel	light grey RAL 7035	M5	21	14	19	22	8	10	-
06092-1056	steel	traffic red RAL 3020	M5	21	14	19	22	8	10	-
06092-1057	steel	colza yellow RAL 1021	M5	21	14	19	22	8	10	-

Overview of items

Order No.	Bush material	Colour Cap	D	D1	D2	D3	H	H1	T	L
06092-106	steel	black grey RAL 7021	M6	21	14	19	22	8	10	-
06092-1061	steel	orange RAL 2004	M6	21	14	19	22	8	10	-
06092-1062	steel	signal green RAL 6032	M6	21	14	19	22	8	10	-
06092-1063	steel	blue RAL5017	M6	21	14	19	22	8	10	-
06092-1065	steel	light grey RAL 7035	M6	21	14	19	22	8	10	-
06092-1066	steel	traffic red RAL 3020	M6	21	14	19	22	8	10	-
06092-1067	steel	colza yellow RAL 1021	M6	21	14	19	22	8	10	-
06092-208	steel	black grey RAL 7021	M8	26	18	23	26	9,5	14	-
06092-2081	steel	orange RAL 2004	M8	26	18	23	26	9,5	14	-
06092-2082	steel	signal green RAL 6032	M8	26	18	23	26	9,5	14	-
06092-2083	steel	blue RAL5017	M8	26	18	23	26	9,5	14	-
06092-2085	steel	light grey RAL 7035	M8	26	18	23	26	9,5	14	-
06092-2086	steel	traffic red RAL 3020	M8	26	18	23	26	9,5	14	-
06092-2087	steel	colza yellow RAL 1021	M8	26	18	23	26	9,5	14	-
06092-308	steel	black grey RAL 7021	M8	34	22	31	36	13	14	-
06092-3081	steel	orange RAL 2004	M8	34	22	31	36	13	14	-
06092-3082	steel	signal green RAL 6032	M8	34	22	31	36	13	14	-
06092-3083	steel	blue RAL5017	M8	34	22	31	36	13	14	-
06092-3085	steel	light grey RAL 7035	M8	34	22	31	36	13	14	-
06092-3086	steel	traffic red RAL 3020	M8	34	22	31	36	13	14	-
06092-3087	steel	colza yellow RAL 1021	M8	34	22	31	36	13	14	-
06092-310	steel	black grey RAL 7021	M10	34	22	31	36	13	14	-
06092-3101	steel	orange RAL 2004	M10	34	22	31	36	13	14	-
06092-3102	steel	signal green RAL 6032	M10	34	22	31	36	13	14	-
06092-3103	steel	blue RAL5017	M10	34	22	31	36	13	14	-
06092-3105	steel	light grey RAL 7035	M10	34	22	31	36	13	14	-
06092-3106	steel	traffic red RAL 3020	M10	34	22	31	36	13	14	-
06092-3107	steel	colza yellow RAL 1021	M10	34	22	31	36	13	14	-
06092-0104	stainless steel	black grey RAL 7021	M4	21	14	19	22	8	10	-
06092-01041	stainless steel	orange RAL 2004	M4	21	14	19	22	8	10	-
06092-01042	stainless steel	signal green RAL 6032	M4	21	14	19	22	8	10	-
06092-01043	stainless steel	blue RAL5017	M4	21	14	19	22	8	10	-
06092-01045	stainless steel	light grey RAL 7035	M4	21	14	19	22	8	10	-
06092-01046	stainless steel	traffic red RAL 3020	M4	21	14	19	22	8	10	-
06092-01047	stainless steel	colza yellow RAL 1021	M4	21	14	19	22	8	10	-
06092-0105	stainless steel	black grey RAL 7021	M5	21	14	19	22	8	10	-
06092-01051	stainless steel	orange RAL 2004	M5	21	14	19	22	8	10	-
06092-01052	stainless steel	signal green RAL 6032	M5	21	14	19	22	8	10	-
06092-01053	stainless steel	blue RAL5017	M5	21	14	19	22	8	10	-
06092-01055	stainless steel	light grey RAL 7035	M5	21	14	19	22	8	10	-
06092-01056	stainless steel	traffic red RAL 3020	M5	21	14	19	22	8	10	-
06092-01057	stainless steel	colza yellow RAL 1021	M5	21	14	19	22	8	10	-
06092-0106	stainless steel	black grey RAL 7021	M6	21	14	19	22	8	10	-
06092-01061	stainless steel	orange RAL 2004	M6	21	14	19	22	8	10	-
06092-01062	stainless steel	signal green RAL 6032	M6	21	14	19	22	8	10	-
06092-01063	stainless steel	blue RAL5017	M6	21	14	19	22	8	10	-
06092-01065	stainless steel	light grey RAL 7035	M6	21	14	19	22	8	10	-
06092-01066	stainless steel	traffic red RAL 3020	M6	21	14	19	22	8	10	-
06092-01067	stainless steel	colza yellow RAL 1021	M6	21	14	19	22	8	10	-
06092-0208	stainless steel	black grey RAL 7021	M8	26	18	23	26	9,5	14	-
06092-02081	stainless steel	orange RAL 2004	M8	26	18	23	26	9,5	14	-
06092-02082	stainless steel	signal green RAL 6032	M8	26	18	23	26	9,5	14	-
06092-02083	stainless steel	blue RAL5017	M8	26	18	23	26	9,5	14	-
06092-02085	stainless steel	light grey RAL 7035	M8	26	18	23	26	9,5	14	-
06092-02086	stainless steel	traffic red RAL 3020	M8	26	18	23	26	9,5	14	-
06092-02087	stainless steel	colza yellow RAL 1021	M8	26	18	23	26	9,5	14	-
06092-0308	stainless steel	black grey RAL 7021	M8	34	22	31	36	13	14	-
06092-03081	stainless steel	orange RAL 2004	M8	34	22	31	36	13	14	-
06092-03082	stainless steel	signal green RAL 6032	M8	34	22	31	36	13	14	-
06092-03083	stainless steel	blue RAL5017	M8	34	22	31	36	13	14	-
06092-03085	stainless steel	light grey RAL 7035	M8	34	22	31	36	13	14	-
06092-03086	stainless steel	traffic red RAL 3020	M8	34	22	31	36	13	14	-
06092-03087	stainless steel	colza yellow RAL 1021	M8	34	22	31	36	13	14	-
06092-0310	stainless steel	black grey RAL 7021	M10	34	22	31	36	13	14	-
06092-03101	stainless steel	orange RAL 2004	M10	34	22	31	36	13	14	-

Overview of items

Order No.	Bush material	Colour Cap	D	D1	D2	D3	H	H1	T	L
06092-03102	stainless steel	signal green RAL 6032	M10	34	22	31	36	13	14	-
06092-03103	stainless steel	blue RAL5017	M10	34	22	31	36	13	14	-
06092-03105	stainless steel	light grey RAL 7035	M10	34	22	31	36	13	14	-
06092-03106	stainless steel	traffic red RAL 3020	M10	34	22	31	36	13	14	-
06092-03107	stainless steel	colza yellow RAL 1021	M10	34	22	31	36	13	14	-
06092-105X10	steel	black grey RAL 7021	M5	21	14	19	22	8	-	10
06092-1051X10	steel	orange RAL 2004	M5	21	14	19	22	8	-	10
06092-1052X10	steel	signal green RAL 6032	M5	21	14	19	22	8	-	10
06092-1053X10	steel	blue RAL5017	M5	21	14	19	22	8	-	10
06092-1055X10	steel	light grey RAL 7035	M5	21	14	19	22	8	-	10
06092-1056X10	steel	traffic red RAL 3020	M5	21	14	19	22	8	-	10
06092-1057X10	steel	colza yellow RAL 1021	M5	21	14	19	22	8	-	10
06092-105X12	steel	black grey RAL 7021	M5	21	14	19	22	8	-	12
06092-1051X12	steel	orange RAL 2004	M5	21	14	19	22	8	-	12
06092-1052X12	steel	signal green RAL 6032	M5	21	14	19	22	8	-	12
06092-1053X12	steel	blue RAL5017	M5	21	14	19	22	8	-	12
06092-1055X12	steel	light grey RAL 7035	M5	21	14	19	22	8	-	12
06092-1056X12	steel	traffic red RAL 3020	M5	21	14	19	22	8	-	12
06092-1057X12	steel	colza yellow RAL 1021	M5	21	14	19	22	8	-	12
06092-105X15	steel	black grey RAL 7021	M5	21	14	19	22	8	-	15
06092-1051X15	steel	orange RAL 2004	M5	21	14	19	22	8	-	15
06092-1052X15	steel	signal green RAL 6032	M5	21	14	19	22	8	-	15
06092-1053X15	steel	blue RAL5017	M5	21	14	19	22	8	-	15
06092-1055X15	steel	light grey RAL 7035	M5	21	14	19	22	8	-	15
06092-1056X15	steel	traffic red RAL 3020	M5	21	14	19	22	8	-	15
06092-1057X15	steel	colza yellow RAL 1021	M5	21	14	19	22	8	-	15
06092-105X20	steel	black grey RAL 7021	M5	21	14	19	22	8	-	20
06092-1051X20	steel	orange RAL 2004	M5	21	14	19	22	8	-	20
06092-1052X20	steel	signal green RAL 6032	M5	21	14	19	22	8	-	20
06092-1053X20	steel	blue RAL5017	M5	21	14	19	22	8	-	20
06092-1055X20	steel	light grey RAL 7035	M5	21	14	19	22	8	-	20
06092-1056X20	steel	traffic red RAL 3020	M5	21	14	19	22	8	-	20
06092-1057X20	steel	colza yellow RAL 1021	M5	21	14	19	22	8	-	20
06092-105X25	steel	black grey RAL 7021	M5	21	14	19	22	8	-	25
06092-1051X25	steel	orange RAL 2004	M5	21	14	19	22	8	-	25
06092-1052X25	steel	signal green RAL 6032	M5	21	14	19	22	8	-	25
06092-1053X25	steel	blue RAL5017	M5	21	14	19	22	8	-	25
06092-1055X25	steel	light grey RAL 7035	M5	21	14	19	22	8	-	25
06092-1056X25	steel	traffic red RAL 3020	M5	21	14	19	22	8	-	25
06092-1057X25	steel	colza yellow RAL 1021	M5	21	14	19	22	8	-	25
06092-106X15	steel	black grey RAL 7021	M6	21	14	19	22	8	-	15
06092-1061X15	steel	orange RAL 2004	M6	21	14	19	22	8	-	15
06092-1062X15	steel	signal green RAL 6032	M6	21	14	19	22	8	-	15
06092-1063X15	steel	blue RAL5017	M6	21	14	19	22	8	-	15
06092-1065X15	steel	light grey RAL 7035	M6	21	14	19	22	8	-	15
06092-1066X15	steel	traffic red RAL 3020	M6	21	14	19	22	8	-	15
06092-1067X15	steel	colza yellow RAL 1021	M6	21	14	19	22	8	-	15
06092-106X20	steel	black grey RAL 7021	M6	21	14	19	22	8	-	20
06092-1061X20	steel	orange RAL 2004	M6	21	14	19	22	8	-	20
06092-1062X20	steel	signal green RAL 6032	M6	21	14	19	22	8	-	20
06092-1063X20	steel	blue RAL5017	M6	21	14	19	22	8	-	20
06092-1065X20	steel	light grey RAL 7035	M6	21	14	19	22	8	-	20
06092-1066X20	steel	traffic red RAL 3020	M6	21	14	19	22	8	-	20
06092-1067X20	steel	colza yellow RAL 1021	M6	21	14	19	22	8	-	20
06092-106X25	steel	black grey RAL 7021	M6	21	14	19	22	8	-	25
06092-1061X25	steel	orange RAL 2004	M6	21	14	19	22	8	-	25
06092-1062X25	steel	signal green RAL 6032	M6	21	14	19	22	8	-	25
06092-1063X25	steel	blue RAL5017	M6	21	14	19	22	8	-	25
06092-1065X25	steel	light grey RAL 7035	M6	21	14	19	22	8	-	25
06092-1066X25	steel	traffic red RAL 3020	M6	21	14	19	22	8	-	25
06092-1067X25	steel	colza yellow RAL 1021	M6	21	14	19	22	8	-	25
06092-106X30	steel	black grey RAL 7021	M6	21	14	19	22	8	-	30
06092-1061X30	steel	orange RAL 2004	M6	21	14	19	22	8	-	30
06092-1062X30	steel	signal green RAL 6032	M6	21	14	19	22	8	-	30
06092-1063X30	steel	blue RAL5017	M6	21	14	19	22	8	-	30

Overview of items

Order No.	Bush material	Colour Cap	D	D1	D2	D3	H	H1	T	L
06092-1065X30	steel	light grey RAL 7035	M6	21	14	19	22	8	-	30
06092-1066X30	steel	traffic red RAL 3020	M6	21	14	19	22	8	-	30
06092-1067X30	steel	colza yellow RAL 1021	M6	21	14	19	22	8	-	30
06092-208X20	steel	black grey RAL 7021	M8	26	18	23	26	9,5	-	20
06092-2081X20	steel	orange RAL 2004	M8	26	18	23	26	9,5	-	20
06092-2082X20	steel	signal green RAL 6032	M8	26	18	23	26	9,5	-	20
06092-2083X20	steel	blue RAL5017	M8	26	18	23	26	9,5	-	20
06092-2085X20	steel	light grey RAL 7035	M8	26	18	23	26	9,5	-	20
06092-2086X20	steel	traffic red RAL 3020	M8	26	18	23	26	9,5	-	20
06092-2087X20	steel	colza yellow RAL 1021	M8	26	18	23	26	9,5	-	20
06092-208X25	steel	black grey RAL 7021	M8	26	18	23	26	9,5	-	25
06092-2081X25	steel	orange RAL 2004	M8	26	18	23	26	9,5	-	25
06092-2082X25	steel	signal green RAL 6032	M8	26	18	23	26	9,5	-	25
06092-2083X25	steel	blue RAL5017	M8	26	18	23	26	9,5	-	25
06092-2085X25	steel	light grey RAL 7035	M8	26	18	23	26	9,5	-	25
06092-2086X25	steel	traffic red RAL 3020	M8	26	18	23	26	9,5	-	25
06092-2087X25	steel	colza yellow RAL 1021	M8	26	18	23	26	9,5	-	25
06092-208X30	steel	black grey RAL 7021	M8	26	18	23	26	9,5	-	30
06092-2081X30	steel	orange RAL 2004	M8	26	18	23	26	9,5	-	30
06092-2082X30	steel	signal green RAL 6032	M8	26	18	23	26	9,5	-	30
06092-2083X30	steel	blue RAL5017	M8	26	18	23	26	9,5	-	30
06092-2085X30	steel	light grey RAL 7035	M8	26	18	23	26	9,5	-	30
06092-2086X30	steel	traffic red RAL 3020	M8	26	18	23	26	9,5	-	30
06092-2087X30	steel	colza yellow RAL 1021	M8	26	18	23	26	9,5	-	30
06092-208X40	steel	black grey RAL 7021	M8	26	18	23	26	9,5	-	40
06092-2081X40	steel	orange RAL 2004	M8	26	18	23	26	9,5	-	40
06092-2082X40	steel	signal green RAL 6032	M8	26	18	23	26	9,5	-	40
06092-2083X40	steel	blue RAL5017	M8	26	18	23	26	9,5	-	40
06092-2085X40	steel	light grey RAL 7035	M8	26	18	23	26	9,5	-	40
06092-2086X40	steel	traffic red RAL 3020	M8	26	18	23	26	9,5	-	40
06092-2087X40	steel	colza yellow RAL 1021	M8	26	18	23	26	9,5	-	40
06092-310X20	steel	black grey RAL 7021	M10	34	22	31	36	13	-	20
06092-3101X20	steel	orange RAL 2004	M10	34	22	31	36	13	-	20
06092-3102X20	steel	signal green RAL 6032	M10	34	22	31	36	13	-	20
06092-3103X20	steel	blue RAL5017	M10	34	22	31	36	13	-	20
06092-3105X20	steel	light grey RAL 7035	M10	34	22	31	36	13	-	20
06092-3106X20	steel	traffic red RAL 3020	M10	34	22	31	36	13	-	20
06092-3107X20	steel	colza yellow RAL 1021	M10	34	22	31	36	13	-	20
06092-310X30	steel	black grey RAL 7021	M10	34	22	31	36	13	-	30
06092-3101X30	steel	orange RAL 2004	M10	34	22	31	36	13	-	30
06092-3102X30	steel	signal green RAL 6032	M10	34	22	31	36	13	-	30
06092-3103X30	steel	blue RAL5017	M10	34	22	31	36	13	-	30
06092-3105X30	steel	light grey RAL 7035	M10	34	22	31	36	13	-	30
06092-3106X30	steel	traffic red RAL 3020	M10	34	22	31	36	13	-	30
06092-3107X30	steel	colza yellow RAL 1021	M10	34	22	31	36	13	-	30
06092-310X40	steel	black grey RAL 7021	M10	34	22	31	36	13	-	40
06092-3101X40	steel	orange RAL 2004	M10	34	22	31	36	13	-	40
06092-3102X40	steel	signal green RAL 6032	M10	34	22	31	36	13	-	40
06092-3103X40	steel	blue RAL5017	M10	34	22	31	36	13	-	40
06092-3105X40	steel	light grey RAL 7035	M10	34	22	31	36	13	-	40
06092-3106X40	steel	traffic red RAL 3020	M10	34	22	31	36	13	-	40
06092-3107X40	steel	colza yellow RAL 1021	M10	34	22	31	36	13	-	40
06092-0105X10	stainless steel	black grey RAL 7021	M5	21	14	19	22	8	-	10
06092-01051X10	stainless steel	orange RAL 2004	M5	21	14	19	22	8	-	10
06092-01052X10	stainless steel	signal green RAL 6032	M5	21	14	19	22	8	-	10
06092-01053X10	stainless steel	blue RAL5017	M5	21	14	19	22	8	-	10
06092-01055X10	stainless steel	light grey RAL 7035	M5	21	14	19	22	8	-	10
06092-01056X10	stainless steel	traffic red RAL 3020	M5	21	14	19	22	8	-	10
06092-01057X10	stainless steel	colza yellow RAL 1021	M5	21	14	19	22	8	-	10
06092-0105X12	stainless steel	black grey RAL 7021	M5	21	14	19	22	8	-	12
06092-01051X12	stainless steel	orange RAL 2004	M5	21	14	19	22	8	-	12
06092-01052X12	stainless steel	signal green RAL 6032	M5	21	14	19	22	8	-	12
06092-01053X12	stainless steel	blue RAL5017	M5	21	14	19	22	8	-	12
06092-01055X12	stainless steel	light grey RAL 7035	M5	21	14	19	22	8	-	12
06092-01056X12	stainless steel	traffic red RAL 3020	M5	21	14	19	22	8	-	12

Overview of items

Order No.	Bush material	Colour Cap	D	D1	D2	D3	H	H1	T	L
06092-01057X12	stainless steel	colza yellow RAL 1021	M5	21	14	19	22	8	-	12
06092-0105X15	stainless steel	black grey RAL 7021	M5	21	14	19	22	8	-	15
06092-01051X15	stainless steel	orange RAL 2004	M5	21	14	19	22	8	-	15
06092-01052X15	stainless steel	signal green RAL 6032	M5	21	14	19	22	8	-	15
06092-01053X15	stainless steel	blue RAL5017	M5	21	14	19	22	8	-	15
06092-01055X15	stainless steel	light grey RAL 7035	M5	21	14	19	22	8	-	15
06092-01056X15	stainless steel	traffic red RAL 3020	M5	21	14	19	22	8	-	15
06092-01057X15	stainless steel	colza yellow RAL 1021	M5	21	14	19	22	8	-	15
06092-0105X20	stainless steel	black grey RAL 7021	M5	21	14	19	22	8	-	20
06092-01051X20	stainless steel	orange RAL 2004	M5	21	14	19	22	8	-	20
06092-01052X20	stainless steel	signal green RAL 6032	M5	21	14	19	22	8	-	20
06092-01053X20	stainless steel	blue RAL5017	M5	21	14	19	22	8	-	20
06092-01055X20	stainless steel	light grey RAL 7035	M5	21	14	19	22	8	-	20
06092-01056X20	stainless steel	traffic red RAL 3020	M5	21	14	19	22	8	-	20
06092-01057X20	stainless steel	colza yellow RAL 1021	M5	21	14	19	22	8	-	20
06092-0105X25	stainless steel	black grey RAL 7021	M5	21	14	19	22	8	-	25
06092-01051X25	stainless steel	orange RAL 2004	M5	21	14	19	22	8	-	25
06092-01052X25	stainless steel	signal green RAL 6032	M5	21	14	19	22	8	-	25
06092-01053X25	stainless steel	blue RAL5017	M5	21	14	19	22	8	-	25
06092-01055X25	stainless steel	light grey RAL 7035	M5	21	14	19	22	8	-	25
06092-01056X25	stainless steel	traffic red RAL 3020	M5	21	14	19	22	8	-	25
06092-01057X25	stainless steel	colza yellow RAL 1021	M5	21	14	19	22	8	-	25
06092-0106X15	stainless steel	black grey RAL 7021	M6	21	14	19	22	8	-	15
06092-01061X15	stainless steel	orange RAL 2004	M6	21	14	19	22	8	-	15
06092-01062X15	stainless steel	signal green RAL 6032	M6	21	14	19	22	8	-	15
06092-01063X15	stainless steel	blue RAL5017	M6	21	14	19	22	8	-	15
06092-01065X15	stainless steel	light grey RAL 7035	M6	21	14	19	22	8	-	15
06092-01066X15	stainless steel	traffic red RAL 3020	M6	21	14	19	22	8	-	15
06092-01067X15	stainless steel	colza yellow RAL 1021	M6	21	14	19	22	8	-	15
06092-0106X20	stainless steel	black grey RAL 7021	M6	21	14	19	22	8	-	20
06092-01061X20	stainless steel	orange RAL 2004	M6	21	14	19	22	8	-	20
06092-01062X20	stainless steel	signal green RAL 6032	M6	21	14	19	22	8	-	20
06092-01063X20	stainless steel	blue RAL5017	M6	21	14	19	22	8	-	20
06092-01065X20	stainless steel	light grey RAL 7035	M6	21	14	19	22	8	-	20
06092-01066X20	stainless steel	traffic red RAL 3020	M6	21	14	19	22	8	-	20
06092-01067X20	stainless steel	colza yellow RAL 1021	M6	21	14	19	22	8	-	20
06092-0106X25	stainless steel	black grey RAL 7021	M6	21	14	19	22	8	-	25
06092-01061X25	stainless steel	orange RAL 2004	M6	21	14	19	22	8	-	25
06092-01062X25	stainless steel	signal green RAL 6032	M6	21	14	19	22	8	-	25
06092-01063X25	stainless steel	blue RAL5017	M6	21	14	19	22	8	-	25
06092-01065X25	stainless steel	light grey RAL 7035	M6	21	14	19	22	8	-	25
06092-01066X25	stainless steel	traffic red RAL 3020	M6	21	14	19	22	8	-	25
06092-01067X25	stainless steel	colza yellow RAL 1021	M6	21	14	19	22	8	-	25
06092-0106X30	stainless steel	black grey RAL 7021	M6	21	14	19	22	8	-	30
06092-01061X30	stainless steel	orange RAL 2004	M6	21	14	19	22	8	-	30
06092-01062X30	stainless steel	signal green RAL 6032	M6	21	14	19	22	8	-	30
06092-01063X30	stainless steel	blue RAL5017	M6	21	14	19	22	8	-	30
06092-01065X30	stainless steel	light grey RAL 7035	M6	21	14	19	22	8	-	30
06092-01066X30	stainless steel	traffic red RAL 3020	M6	21	14	19	22	8	-	30
06092-01067X30	stainless steel	colza yellow RAL 1021	M6	21	14	19	22	8	-	30
06092-0208X20	stainless steel	black grey RAL 7021	M8	26	18	23	26	9,5	-	20
06092-02081X20	stainless steel	orange RAL 2004	M8	26	18	23	26	9,5	-	20
06092-02082X20	stainless steel	signal green RAL 6032	M8	26	18	23	26	9,5	-	20
06092-02083X20	stainless steel	blue RAL5017	M8	26	18	23	26	9,5	-	20
06092-02085X20	stainless steel	light grey RAL 7035	M8	26	18	23	26	9,5	-	20
06092-02086X20	stainless steel	traffic red RAL 3020	M8	26	18	23	26	9,5	-	20
06092-02087X20	stainless steel	colza yellow RAL 1021	M8	26	18	23	26	9,5	-	20
06092-0208X25	stainless steel	black grey RAL 7021	M8	26	18	23	26	9,5	-	25
06092-02081X25	stainless steel	orange RAL 2004	M8	26	18	23	26	9,5	-	25
06092-02082X25	stainless steel	signal green RAL 6032	M8	26	18	23	26	9,5	-	25
06092-02083X25	stainless steel	blue RAL5017	M8	26	18	23	26	9,5	-	25
06092-02085X25	stainless steel	light grey RAL 7035	M8	26	18	23	26	9,5	-	25
06092-02086X25	stainless steel	traffic red RAL 3020	M8	26	18	23	26	9,5	-	25
06092-02087X25	stainless steel	colza yellow RAL 1021	M8	26	18	23	26	9,5	-	25
06092-0208X30	stainless steel	black grey RAL 7021	M8	26	18	23	26	9,5	-	30

Overview of items

Order No.	Bush material	Colour Cap	D	D1	D2	D3	H	H1	T	L
06092-02081X30	stainless steel	orange RAL 2004	M8	26	18	23	26	9,5	-	30
06092-02082X30	stainless steel	signal green RAL 6032	M8	26	18	23	26	9,5	-	30
06092-02083X30	stainless steel	blue RAL5017	M8	26	18	23	26	9,5	-	30
06092-02085X30	stainless steel	light grey RAL 7035	M8	26	18	23	26	9,5	-	30
06092-02086X30	stainless steel	traffic red RAL 3020	M8	26	18	23	26	9,5	-	30
06092-02087X30	stainless steel	colza yellow RAL 1021	M8	26	18	23	26	9,5	-	30
06092-0208X40	stainless steel	black grey RAL 7021	M8	26	18	23	26	9,5	-	40
06092-02081X40	stainless steel	orange RAL 2004	M8	26	18	23	26	9,5	-	40
06092-02082X40	stainless steel	signal green RAL 6032	M8	26	18	23	26	9,5	-	40
06092-02083X40	stainless steel	blue RAL5017	M8	26	18	23	26	9,5	-	40
06092-02085X40	stainless steel	light grey RAL 7035	M8	26	18	23	26	9,5	-	40
06092-02086X40	stainless steel	traffic red RAL 3020	M8	26	18	23	26	9,5	-	40
06092-02087X40	stainless steel	colza yellow RAL 1021	M8	26	18	23	26	9,5	-	40
06092-0310X20	stainless steel	black grey RAL 7021	M10	34	22	31	36	13	-	20
06092-03101X20	stainless steel	orange RAL 2004	M10	34	22	31	36	13	-	20
06092-03102X20	stainless steel	signal green RAL 6032	M10	34	22	31	36	13	-	20
06092-03103X20	stainless steel	blue RAL5017	M10	34	22	31	36	13	-	20
06092-03105X20	stainless steel	light grey RAL 7035	M10	34	22	31	36	13	-	20
06092-03106X20	stainless steel	traffic red RAL 3020	M10	34	22	31	36	13	-	20
06092-03107X20	stainless steel	colza yellow RAL 1021	M10	34	22	31	36	13	-	20
06092-0310X30	stainless steel	black grey RAL 7021	M10	34	22	31	36	13	-	30
06092-03101X30	stainless steel	orange RAL 2004	M10	34	22	31	36	13	-	30
06092-03102X30	stainless steel	signal green RAL 6032	M10	34	22	31	36	13	-	30
06092-03103X30	stainless steel	blue RAL5017	M10	34	22	31	36	13	-	30
06092-03105X30	stainless steel	light grey RAL 7035	M10	34	22	31	36	13	-	30
06092-03106X30	stainless steel	traffic red RAL 3020	M10	34	22	31	36	13	-	30
06092-03107X30	stainless steel	colza yellow RAL 1021	M10	34	22	31	36	13	-	30
06092-0310X40	stainless steel	black grey RAL 7021	M10	34	22	31	36	13	-	40
06092-03101X40	stainless steel	orange RAL 2004	M10	34	22	31	36	13	-	40
06092-03102X40	stainless steel	signal green RAL 6032	M10	34	22	31	36	13	-	40
06092-03103X40	stainless steel	blue RAL5017	M10	34	22	31	36	13	-	40
06092-03105X40	stainless steel	light grey RAL 7035	M10	34	22	31	36	13	-	40
06092-03106X40	stainless steel	traffic red RAL 3020	M10	34	22	31	36	13	-	40
06092-03107X40	stainless steel	colza yellow RAL 1021	M10	34	22	31	36	13	-	40