

Item description/product images



Description

Material:

Steel, 1.4305 stainless steel, 1.4404 stainless steel or aluminium.

Version:

Steel electro zinc-plated and trivalent blue passivated.


Stainless steel, fine turned or abrasive blasted.

Aluminium natural tone anodised.

On request:

With external threads.

Drawings

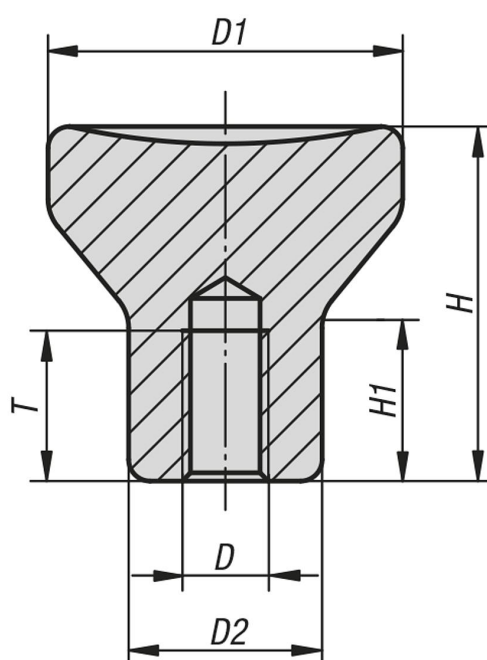

Overview of items

Order No.	Main material	Steel code	Surface finish body	D	D1	D2	H	H1	T
06240-0902	steel	-	blue-passivated	M2	14	8	14	6,7	4
06240-0003	steel	-	blue-passivated	M3	18	10	18	8,6	7,5
06240-0104	steel	-	blue-passivated	M4	21	12	21	10	10
06240-0105	steel	-	blue-passivated	M5	21	12	21	10	12,5
06240-0206	steel	-	blue-passivated	M6	25	14	25	12	12
06240-0308	steel	-	blue-passivated	M8	33	18	33	16	16
06240-0410	steel	-	blue-passivated	M10	40	24	40	18,7	20
06240-902	stainless steel	1.4305	-	M2	14	8	14	6,7	4
06240-003	stainless steel	1.4305	-	M3	18	10	18	8,6	7,5
06240-104	stainless steel	1.4305	-	M4	21	12	21	10	10
06240-105	stainless steel	1.4305	-	M5	21	12	21	10	12,5
06240-206	stainless steel	1.4305	-	M6	25	14	25	12	12
06240-308	stainless steel	1.4305	-	M8	33	18	33	16	16
06240-410	stainless steel	1.4305	-	M10	40	24	40	18,7	20
06240-2902	stainless steel	1.4305	blasted	M2	14	8	14	6,7	4
06240-2003	stainless steel	1.4305	blasted	M3	18	10	18	8,6	7,5
06240-2104	stainless steel	1.4305	blasted	M4	21	12	21	10	10

Overview of items

Order No.	Main material	Steel code	Surface finish body	D	D1	D2	H	H1	T
06240-2105	stainless steel	1.4305	blasted	M5	21	12	21	10	12,5
06240-2206	stainless steel	1.4305	blasted	M6	25	14	25	12	12
06240-2308	stainless steel	1.4305	blasted	M8	33	18	33	16	16
06240-2410	stainless steel	1.4305	blasted	M10	40	24	40	18,7	20
06240-3902	stainless steel	1.4404	-	M2	14	8	14	6,7	4
06240-3003	stainless steel	1.4404	-	M3	18	10	18	8,6	7,5
06240-3104	stainless steel	1.4404	-	M4	21	12	21	10	10
06240-3105	stainless steel	1.4404	-	M5	21	12	21	10	12,5
06240-3206	stainless steel	1.4404	-	M6	25	14	25	12	12
06240-3308	stainless steel	1.4404	-	M8	33	18	33	16	16
06240-3410	stainless steel	1.4404	-	M10	40	24	40	18,7	20
06240-4902	stainless steel	1.4404	blasted	M2	14	8	14	6,7	4
06240-4003	stainless steel	1.4404	blasted	M3	18	10	18	8,6	7,5
06240-4104	stainless steel	1.4404	blasted	M4	21	12	21	10	10
06240-4105	stainless steel	1.4404	blasted	M5	21	12	21	10	12,5
06240-4206	stainless steel	1.4404	blasted	M6	25	14	25	12	12
06240-4308	stainless steel	1.4404	blasted	M8	33	18	33	16	16
06240-4410	stainless steel	1.4404	blasted	M10	40	24	40	18,7	20
06240-1902	aluminium	-	anodised	M2	14	8	14	6,7	4
06240-1003	aluminium	-	anodised	M3	18	10	18	8,6	7,5
06240-1104	aluminium	-	anodised	M4	21	12	21	10	10
06240-1105	aluminium	-	anodised	M5	21	12	21	10	12,5
06240-1206	aluminium	-	anodised	M6	25	14	25	12	12
06240-1308	aluminium	-	anodised	M8	33	18	33	16	16
06240-1410	aluminium	-	anodised	M10	40	24	40	18,7	20