

Item description/product images



Description


Material:

Black thermoplastic.


Screw grade 5.8 steel or 1.4305 stainless steel.

Version:

Steel trivalent blue passivated, stainless steel bright.

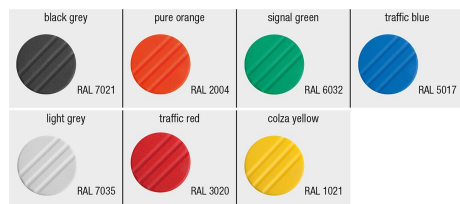

Drawings

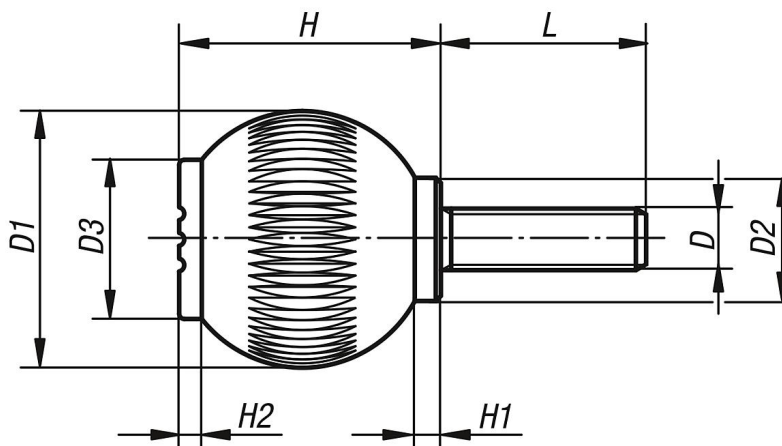

Overview of items

Order No.	Component material	Colour Cap	D	D1	D2	D3	H	H1	H2	L
06245-106X15	steel	black grey RAL 7021	M6	25	12	17	25	3	2	15
06245-1061X15	steel	orange RAL 2004	M6	25	12	17	25	3	2	15
06245-1062X15	steel	signal green RAL 6032	M6	25	12	17	25	3	2	15
06245-1063X15	steel	blue RAL5017	M6	25	12	17	25	3	2	15
06245-1065X15	steel	light grey RAL 7035	M6	25	12	17	25	3	2	15
06245-1066X15	steel	traffic red RAL 3020	M6	25	12	17	25	3	2	15
06245-1067X15	steel	colza yellow RAL 1021	M6	25	12	17	25	3	2	15
06245-106X20	steel	black grey RAL 7021	M6	25	12	17	25	3	2	20
06245-1061X20	steel	orange RAL 2004	M6	25	12	17	25	3	2	20
06245-1062X20	steel	signal green RAL 6032	M6	25	12	17	25	3	2	20
06245-1063X20	steel	blue RAL5017	M6	25	12	17	25	3	2	20
06245-1065X20	steel	light grey RAL 7035	M6	25	12	17	25	3	2	20
06245-1066X20	steel	traffic red RAL 3020	M6	25	12	17	25	3	2	20
06245-1067X20	steel	colza yellow RAL 1021	M6	25	12	17	25	3	2	20
06245-106X25	steel	black grey RAL 7021	M6	25	12	17	25	3	2	25
06245-1061X25	steel	orange RAL 2004	M6	25	12	17	25	3	2	25
06245-1062X25	steel	signal green RAL 6032	M6	25	12	17	25	3	2	25
06245-1063X25	steel	blue RAL5017	M6	25	12	17	25	3	2	25
06245-1065X25	steel	light grey RAL 7035	M6	25	12	17	25	3	2	25
06245-1066X25	steel	traffic red RAL 3020	M6	25	12	17	25	3	2	25

Overview of items

Order No.	Component material	Colour Cap	D	D1	D2	D3	H	H1	H2	L
06245-1067X25	steel	colza yellow RAL 1021	M6	25	12	17	25	3	2	25
06245-106X30	steel	black grey RAL 7021	M6	25	12	17	25	3	2	30
06245-1061X30	steel	orange RAL 2004	M6	25	12	17	25	3	2	30
06245-1062X30	steel	signal green RAL 6032	M6	25	12	17	25	3	2	30
06245-1063X30	steel	blue RAL5017	M6	25	12	17	25	3	2	30
06245-1065X30	steel	light grey RAL 7035	M6	25	12	17	25	3	2	30
06245-1066X30	steel	traffic red RAL 3020	M6	25	12	17	25	3	2	30
06245-1067X30	steel	colza yellow RAL 1021	M6	25	12	17	25	3	2	30
06245-208X20	steel	black grey RAL 7021	M8	32	15,5	19	33	3,5	2,6	20
06245-2081X20	steel	orange RAL 2004	M8	32	15,5	19	33	3,5	2,6	20
06245-2082X20	steel	signal green RAL 6032	M8	32	15,5	19	33	3,5	2,6	20
06245-2083X20	steel	blue RAL5017	M8	32	15,5	19	33	3,5	2,6	20
06245-2085X20	steel	light grey RAL 7035	M8	32	15,5	19	33	3,5	2,6	20
06245-2086X20	steel	traffic red RAL 3020	M8	32	15,5	19	33	3,5	2,6	20
06245-2087X20	steel	colza yellow RAL 1021	M8	32	15,5	19	33	3,5	2,6	20
06245-208X25	steel	black grey RAL 7021	M8	32	15,5	19	33	3,5	2,6	25
06245-2081X25	steel	orange RAL 2004	M8	32	15,5	19	33	3,5	2,6	25
06245-2082X25	steel	signal green RAL 6032	M8	32	15,5	19	33	3,5	2,6	25
06245-2083X25	steel	blue RAL5017	M8	32	15,5	19	33	3,5	2,6	25
06245-2085X25	steel	light grey RAL 7035	M8	32	15,5	19	33	3,5	2,6	25
06245-2086X25	steel	traffic red RAL 3020	M8	32	15,5	19	33	3,5	2,6	25
06245-2087X25	steel	colza yellow RAL 1021	M8	32	15,5	19	33	3,5	2,6	25
06245-208X30	steel	black grey RAL 7021	M8	32	15,5	19	33	3,5	2,6	30
06245-2081X30	steel	orange RAL 2004	M8	32	15,5	19	33	3,5	2,6	30
06245-2082X30	steel	signal green RAL 6032	M8	32	15,5	19	33	3,5	2,6	30
06245-2083X30	steel	blue RAL5017	M8	32	15,5	19	33	3,5	2,6	30
06245-2085X30	steel	light grey RAL 7035	M8	32	15,5	19	33	3,5	2,6	30
06245-2086X30	steel	traffic red RAL 3020	M8	32	15,5	19	33	3,5	2,6	30
06245-2087X30	steel	colza yellow RAL 1021	M8	32	15,5	19	33	3,5	2,6	30
06245-208X40	steel	black grey RAL 7021	M8	32	15,5	19	33	3,5	2,6	40
06245-2081X40	steel	orange RAL 2004	M8	32	15,5	19	33	3,5	2,6	40
06245-2082X40	steel	signal green RAL 6032	M8	32	15,5	19	33	3,5	2,6	40
06245-2083X40	steel	blue RAL5017	M8	32	15,5	19	33	3,5	2,6	40
06245-2085X40	steel	light grey RAL 7035	M8	32	15,5	19	33	3,5	2,6	40
06245-2086X40	steel	traffic red RAL 3020	M8	32	15,5	19	33	3,5	2,6	40
06245-2087X40	steel	colza yellow RAL 1021	M8	32	15,5	19	33	3,5	2,6	40
06245-310X20	steel	black grey RAL 7021	M10	40	19	23	41	4	3	20
06245-3101X20	steel	orange RAL 2004	M10	40	19	23	41	4	3	20
06245-3102X20	steel	signal green RAL 6032	M10	40	19	23	41	4	3	20
06245-3103X20	steel	blue RAL5017	M10	40	19	23	41	4	3	20
06245-3105X20	steel	light grey RAL 7035	M10	40	19	23	41	4	3	20
06245-3106X20	steel	traffic red RAL 3020	M10	40	19	23	41	4	3	20
06245-3107X20	steel	colza yellow RAL 1021	M10	40	19	23	41	4	3	20
06245-310X30	steel	black grey RAL 7021	M10	40	19	23	41	4	3	30
06245-3101X30	steel	orange RAL 2004	M10	40	19	23	41	4	3	30
06245-3102X30	steel	signal green RAL 6032	M10	40	19	23	41	4	3	30
06245-3103X30	steel	blue RAL5017	M10	40	19	23	41	4	3	30
06245-3105X30	steel	light grey RAL 7035	M10	40	19	23	41	4	3	30
06245-3106X30	steel	traffic red RAL 3020	M10	40	19	23	41	4	3	30
06245-3107X30	steel	colza yellow RAL 1021	M10	40	19	23	41	4	3	30
06245-310X40	steel	black grey RAL 7021	M10	40	19	23	41	4	3	40
06245-3101X40	steel	orange RAL 2004	M10	40	19	23	41	4	3	40
06245-3102X40	steel	signal green RAL 6032	M10	40	19	23	41	4	3	40
06245-3103X40	steel	blue RAL5017	M10	40	19	23	41	4	3	40
06245-3105X40	steel	light grey RAL 7035	M10	40	19	23	41	4	3	40
06245-3106X40	steel	traffic red RAL 3020	M10	40	19	23	41	4	3	40
06245-3107X40	steel	colza yellow RAL 1021	M10	40	19	23	41	4	3	40
06245-410X20	steel	black grey RAL 7021	M10	50	24	31	51	5,5	4,5	20
06245-4101X20	steel	orange RAL 2004	M10	50	24	31	51	5,5	4,5	20
06245-4102X20	steel	signal green RAL 6032	M10	50	24	31	51	5,5	4,5	20
06245-4103X20	steel	blue RAL5017	M10	50	24	31	51	5,5	4,5	20
06245-4105X20	steel	light grey RAL 7035	M10	50	24	31	51	5,5	4,5	20
06245-4106X20	steel	traffic red RAL 3020	M10	50	24	31	51	5,5	4,5	20
06245-4107X20	steel	colza yellow RAL 1021	M10	50	24	31	51	5,5	4,5	20
06245-410X30	steel	black grey RAL 7021	M10	50	24	31	51	5,5	4,5	30

Overview of items

Order No.	Component material	Colour Cap	D	D1	D2	D3	H	H1	H2	L
06245-4101X30	steel	orange RAL 2004	M10	50	24	31	51	5,5	4,5	30
06245-4102X30	steel	signal green RAL 6032	M10	50	24	31	51	5,5	4,5	30
06245-4103X30	steel	blue RAL5017	M10	50	24	31	51	5,5	4,5	30
06245-4105X30	steel	light grey RAL 7035	M10	50	24	31	51	5,5	4,5	30
06245-4106X30	steel	traffic red RAL 3020	M10	50	24	31	51	5,5	4,5	30
06245-4107X30	steel	colza yellow RAL 1021	M10	50	24	31	51	5,5	4,5	30
06245-410X40	steel	black grey RAL 7021	M10	50	24	31	51	5,5	4,5	40
06245-4101X40	steel	orange RAL 2004	M10	50	24	31	51	5,5	4,5	40
06245-4102X40	steel	signal green RAL 6032	M10	50	24	31	51	5,5	4,5	40
06245-4103X40	steel	blue RAL5017	M10	50	24	31	51	5,5	4,5	40
06245-4105X40	steel	light grey RAL 7035	M10	50	24	31	51	5,5	4,5	40
06245-4106X40	steel	traffic red RAL 3020	M10	50	24	31	51	5,5	4,5	40
06245-4107X40	steel	colza yellow RAL 1021	M10	50	24	31	51	5,5	4,5	40
06245-412X20	steel	black grey RAL 7021	M12	50	24	31	51	5,5	4,5	20
06245-4121X20	steel	orange RAL 2004	M12	50	24	31	51	5,5	4,5	20
06245-4122X20	steel	signal green RAL 6032	M12	50	24	31	51	5,5	4,5	20
06245-4123X20	steel	blue RAL5017	M12	50	24	31	51	5,5	4,5	20
06245-4125X20	steel	light grey RAL 7035	M12	50	24	31	51	5,5	4,5	20
06245-4126X20	steel	traffic red RAL 3020	M12	50	24	31	51	5,5	4,5	20
06245-4127X20	steel	colza yellow RAL 1021	M12	50	24	31	51	5,5	4,5	20
06245-412X30	steel	black grey RAL 7021	M12	50	24	31	51	5,5	4,5	30
06245-4121X30	steel	orange RAL 2004	M12	50	24	31	51	5,5	4,5	30
06245-4122X30	steel	signal green RAL 6032	M12	50	24	31	51	5,5	4,5	30
06245-4123X30	steel	blue RAL5017	M12	50	24	31	51	5,5	4,5	30
06245-4125X30	steel	light grey RAL 7035	M12	50	24	31	51	5,5	4,5	30
06245-4126X30	steel	traffic red RAL 3020	M12	50	24	31	51	5,5	4,5	30
06245-4127X30	steel	colza yellow RAL 1021	M12	50	24	31	51	5,5	4,5	30
06245-412X40	steel	black grey RAL 7021	M12	50	24	31	51	5,5	4,5	40
06245-4121X40	steel	orange RAL 2004	M12	50	24	31	51	5,5	4,5	40
06245-4122X40	steel	signal green RAL 6032	M12	50	24	31	51	5,5	4,5	40
06245-4123X40	steel	blue RAL5017	M12	50	24	31	51	5,5	4,5	40
06245-4125X40	steel	light grey RAL 7035	M12	50	24	31	51	5,5	4,5	40
06245-4126X40	steel	traffic red RAL 3020	M12	50	24	31	51	5,5	4,5	40
06245-4127X40	steel	colza yellow RAL 1021	M12	50	24	31	51	5,5	4,5	40
06245-0106X15	stainless steel	black grey RAL 7021	M6	25	12	17	25	3	2	15
06245-01061X15	stainless steel	orange RAL 2004	M6	25	12	17	25	3	2	15
06245-01062X15	stainless steel	signal green RAL 6032	M6	25	12	17	25	3	2	15
06245-01063X15	stainless steel	blue RAL5017	M6	25	12	17	25	3	2	15
06245-01065X15	stainless steel	light grey RAL 7035	M6	25	12	17	25	3	2	15
06245-01066X15	stainless steel	traffic red RAL 3020	M6	25	12	17	25	3	2	15
06245-01067X15	stainless steel	colza yellow RAL 1021	M6	25	12	17	25	3	2	15
06245-0106X20	stainless steel	black grey RAL 7021	M6	25	12	17	25	3	2	20
06245-01061X20	stainless steel	orange RAL 2004	M6	25	12	17	25	3	2	20
06245-01062X20	stainless steel	signal green RAL 6032	M6	25	12	17	25	3	2	20
06245-01063X20	stainless steel	blue RAL5017	M6	25	12	17	25	3	2	20
06245-01065X20	stainless steel	light grey RAL 7035	M6	25	12	17	25	3	2	20
06245-01066X20	stainless steel	traffic red RAL 3020	M6	25	12	17	25	3	2	20
06245-01067X20	stainless steel	colza yellow RAL 1021	M6	25	12	17	25	3	2	20
06245-0106X25	stainless steel	black grey RAL 7021	M6	25	12	17	25	3	2	25
06245-01061X25	stainless steel	orange RAL 2004	M6	25	12	17	25	3	2	25
06245-01062X25	stainless steel	signal green RAL 6032	M6	25	12	17	25	3	2	25
06245-01063X25	stainless steel	blue RAL5017	M6	25	12	17	25	3	2	25
06245-01065X25	stainless steel	light grey RAL 7035	M6	25	12	17	25	3	2	25
06245-01066X25	stainless steel	traffic red RAL 3020	M6	25	12	17	25	3	2	25
06245-01067X25	stainless steel	colza yellow RAL 1021	M6	25	12	17	25	3	2	25
06245-0106X30	stainless steel	black grey RAL 7021	M6	25	12	17	25	3	2	30
06245-01061X30	stainless steel	orange RAL 2004	M6	25	12	17	25	3	2	30
06245-01062X30	stainless steel	signal green RAL 6032	M6	25	12	17	25	3	2	30
06245-01063X30	stainless steel	blue RAL5017	M6	25	12	17	25	3	2	30
06245-01065X30	stainless steel	light grey RAL 7035	M6	25	12	17	25	3	2	30
06245-01066X30	stainless steel	traffic red RAL 3020	M6	25	12	17	25	3	2	30
06245-01067X30	stainless steel	colza yellow RAL 1021	M6	25	12	17	25	3	2	30
06245-0208X20	stainless steel	black grey RAL 7021	M8	32	15,5	19	33	3,5	2,6	20
06245-02081X20	stainless steel	orange RAL 2004	M8	32	15,5	19	33	3,5	2,6	20
06245-02082X20	stainless steel	signal green RAL 6032	M8	32	15,5	19	33	3,5	2,6	20

Overview of items

Order No.	Component material	Colour Cap	D	D1	D2	D3	H	H1	H2	L
06245-02083X20	stainless steel	blue RAL5017	M8	32	15,5	19	33	3,5	2,6	20
06245-02085X20	stainless steel	light grey RAL 7035	M8	32	15,5	19	33	3,5	2,6	20
06245-02086X20	stainless steel	traffic red RAL 3020	M8	32	15,5	19	33	3,5	2,6	20
06245-02087X20	stainless steel	colza yellow RAL 1021	M8	32	15,5	19	33	3,5	2,6	20
06245-0208X25	stainless steel	black grey RAL 7021	M8	32	15,5	19	33	3,5	2,6	25
06245-02081X25	stainless steel	orange RAL 2004	M8	32	15,5	19	33	3,5	2,6	25
06245-02082X25	stainless steel	signal green RAL 6032	M8	32	15,5	19	33	3,5	2,6	25
06245-02083X25	stainless steel	blue RAL5017	M8	32	15,5	19	33	3,5	2,6	25
06245-02085X25	stainless steel	light grey RAL 7035	M8	32	15,5	19	33	3,5	2,6	25
06245-02086X25	stainless steel	traffic red RAL 3020	M8	32	15,5	19	33	3,5	2,6	25
06245-02087X25	stainless steel	colza yellow RAL 1021	M8	32	15,5	19	33	3,5	2,6	25
06245-0208X30	stainless steel	black grey RAL 7021	M8	32	15,5	19	33	3,5	2,6	30
06245-02081X30	stainless steel	orange RAL 2004	M8	32	15,5	19	33	3,5	2,6	30
06245-02082X30	stainless steel	signal green RAL 6032	M8	32	15,5	19	33	3,5	2,6	30
06245-02083X30	stainless steel	blue RAL5017	M8	32	15,5	19	33	3,5	2,6	30
06245-02085X30	stainless steel	light grey RAL 7035	M8	32	15,5	19	33	3,5	2,6	30
06245-02086X30	stainless steel	traffic red RAL 3020	M8	32	15,5	19	33	3,5	2,6	30
06245-02087X30	stainless steel	colza yellow RAL 1021	M8	32	15,5	19	33	3,5	2,6	30
06245-0208X40	stainless steel	black grey RAL 7021	M8	32	15,5	19	33	3,5	2,6	40
06245-02081X40	stainless steel	orange RAL 2004	M8	32	15,5	19	33	3,5	2,6	40
06245-02082X40	stainless steel	signal green RAL 6032	M8	32	15,5	19	33	3,5	2,6	40
06245-02083X40	stainless steel	blue RAL5017	M8	32	15,5	19	33	3,5	2,6	40
06245-02085X40	stainless steel	light grey RAL 7035	M8	32	15,5	19	33	3,5	2,6	40
06245-02086X40	stainless steel	traffic red RAL 3020	M8	32	15,5	19	33	3,5	2,6	40
06245-02087X40	stainless steel	colza yellow RAL 1021	M8	32	15,5	19	33	3,5	2,6	40
06245-0310X20	stainless steel	black grey RAL 7021	M10	40	19	23	41	4	3	20
06245-03101X20	stainless steel	orange RAL 2004	M10	40	19	23	41	4	3	20
06245-03102X20	stainless steel	signal green RAL 6032	M10	40	19	23	41	4	3	20
06245-03103X20	stainless steel	blue RAL5017	M10	40	19	23	41	4	3	20
06245-03105X20	stainless steel	light grey RAL 7035	M10	40	19	23	41	4	3	20
06245-03106X20	stainless steel	traffic red RAL 3020	M10	40	19	23	41	4	3	20
06245-03107X20	stainless steel	colza yellow RAL 1021	M10	40	19	23	41	4	3	20
06245-0310X30	stainless steel	black grey RAL 7021	M10	40	19	23	41	4	3	30
06245-03101X30	stainless steel	orange RAL 2004	M10	40	19	23	41	4	3	30
06245-03102X30	stainless steel	signal green RAL 6032	M10	40	19	23	41	4	3	30
06245-03103X30	stainless steel	blue RAL5017	M10	40	19	23	41	4	3	30
06245-03105X30	stainless steel	light grey RAL 7035	M10	40	19	23	41	4	3	30
06245-03106X30	stainless steel	traffic red RAL 3020	M10	40	19	23	41	4	3	30
06245-03107X30	stainless steel	colza yellow RAL 1021	M10	40	19	23	41	4	3	30
06245-0310X40	stainless steel	black grey RAL 7021	M10	40	19	23	41	4	3	40
06245-03101X40	stainless steel	orange RAL 2004	M10	40	19	23	41	4	3	40
06245-03102X40	stainless steel	signal green RAL 6032	M10	40	19	23	41	4	3	40
06245-03103X40	stainless steel	blue RAL5017	M10	40	19	23	41	4	3	40
06245-03105X40	stainless steel	light grey RAL 7035	M10	40	19	23	41	4	3	40
06245-03106X40	stainless steel	traffic red RAL 3020	M10	40	19	23	41	4	3	40
06245-03107X40	stainless steel	colza yellow RAL 1021	M10	40	19	23	41	4	3	40
06245-0410X20	stainless steel	black grey RAL 7021	M10	50	24	31	51	5,5	4,5	20
06245-04101X20	stainless steel	orange RAL 2004	M10	50	24	31	51	5,5	4,5	20
06245-04102X20	stainless steel	signal green RAL 6032	M10	50	24	31	51	5,5	4,5	20
06245-04103X20	stainless steel	blue RAL5017	M10	50	24	31	51	5,5	4,5	20
06245-04105X20	stainless steel	light grey RAL 7035	M10	50	24	31	51	5,5	4,5	20
06245-04106X20	stainless steel	traffic red RAL 3020	M10	50	24	31	51	5,5	4,5	20
06245-04107X20	stainless steel	colza yellow RAL 1021	M10	50	24	31	51	5,5	4,5	20
06245-0410X30	stainless steel	black grey RAL 7021	M10	50	24	31	51	5,5	4,5	30
06245-04101X30	stainless steel	orange RAL 2004	M10	50	24	31	51	5,5	4,5	30
06245-04102X30	stainless steel	signal green RAL 6032	M10	50	24	31	51	5,5	4,5	30
06245-04103X30	stainless steel	blue RAL5017	M10	50	24	31	51	5,5	4,5	30
06245-04105X30	stainless steel	light grey RAL 7035	M10	50	24	31	51	5,5	4,5	30
06245-04106X30	stainless steel	traffic red RAL 3020	M10	50	24	31	51	5,5	4,5	30
06245-04107X30	stainless steel	colza yellow RAL 1021	M10	50	24	31	51	5,5	4,5	30
06245-0410X40	stainless steel	black grey RAL 7021	M10	50	24	31	51	5,5	4,5	40
06245-04101X40	stainless steel	orange RAL 2004	M10	50	24	31	51	5,5	4,5	40
06245-04102X40	stainless steel	signal green RAL 6032	M10	50	24	31	51	5,5	4,5	40
06245-04103X40	stainless steel	blue RAL5017	M10	50	24	31	51	5,5	4,5	40
06245-04105X40	stainless steel	light grey RAL 7035	M10	50	24	31	51	5,5	4,5	40

Overview of items

Order No.	Component material	Colour Cap	D	D1	D2	D3	H	H1	H2	L
06245-04106X40	stainless steel	traffic red RAL 3020	M10	50	24	31	51	5,5	4,5	40
06245-04107X40	stainless steel	colza yellow RAL 1021	M10	50	24	31	51	5,5	4,5	40
06245-0412X20	stainless steel	black grey RAL 7021	M12	50	24	31	51	5,5	4,5	20
06245-04121X20	stainless steel	orange RAL 2004	M12	50	24	31	51	5,5	4,5	20
06245-04122X20	stainless steel	signal green RAL 6032	M12	50	24	31	51	5,5	4,5	20
06245-04123X20	stainless steel	blue RAL5017	M12	50	24	31	51	5,5	4,5	20
06245-04125X20	stainless steel	light grey RAL 7035	M12	50	24	31	51	5,5	4,5	20
06245-04126X20	stainless steel	traffic red RAL 3020	M12	50	24	31	51	5,5	4,5	20
06245-04127X20	stainless steel	colza yellow RAL 1021	M12	50	24	31	51	5,5	4,5	20
06245-0412X30	stainless steel	black grey RAL 7021	M12	50	24	31	51	5,5	4,5	30
06245-04121X30	stainless steel	orange RAL 2004	M12	50	24	31	51	5,5	4,5	30
06245-04122X30	stainless steel	signal green RAL 6032	M12	50	24	31	51	5,5	4,5	30
06245-04123X30	stainless steel	blue RAL5017	M12	50	24	31	51	5,5	4,5	30
06245-04125X30	stainless steel	light grey RAL 7035	M12	50	24	31	51	5,5	4,5	30
06245-04126X30	stainless steel	traffic red RAL 3020	M12	50	24	31	51	5,5	4,5	30
06245-04127X30	stainless steel	colza yellow RAL 1021	M12	50	24	31	51	5,5	4,5	30
06245-0412X40	stainless steel	black grey RAL 7021	M12	50	24	31	51	5,5	4,5	40
06245-04121X40	stainless steel	orange RAL 2004	M12	50	24	31	51	5,5	4,5	40
06245-04122X40	stainless steel	signal green RAL 6032	M12	50	24	31	51	5,5	4,5	40
06245-04123X40	stainless steel	blue RAL5017	M12	50	24	31	51	5,5	4,5	40
06245-04125X40	stainless steel	light grey RAL 7035	M12	50	24	31	51	5,5	4,5	40
06245-04126X40	stainless steel	traffic red RAL 3020	M12	50	24	31	51	5,5	4,5	40
06245-04127X40	stainless steel	colza yellow RAL 1021	M12	50	24	31	51	5,5	4,5	40