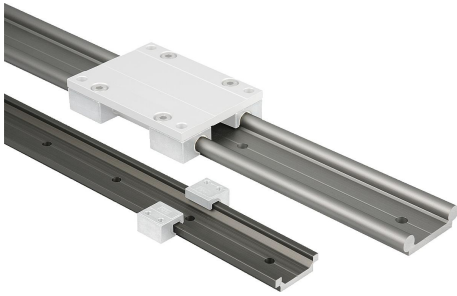


## Item description/product images

**Description****Material:**

Aluminium.

**Version:**

Hard anodised, layer thickness 50 µm.

Hardness 500 HV

**Note:**


Extremely flat rails with wide guides reaching to the edge for optimally support high torque. Robust and dirt resistant for transporting heavy loads safely and maintenance-free.

\*\* length L2 = 20 mm and

\* L = 500 mm included

L2 and L only available in full mm.

Drawings

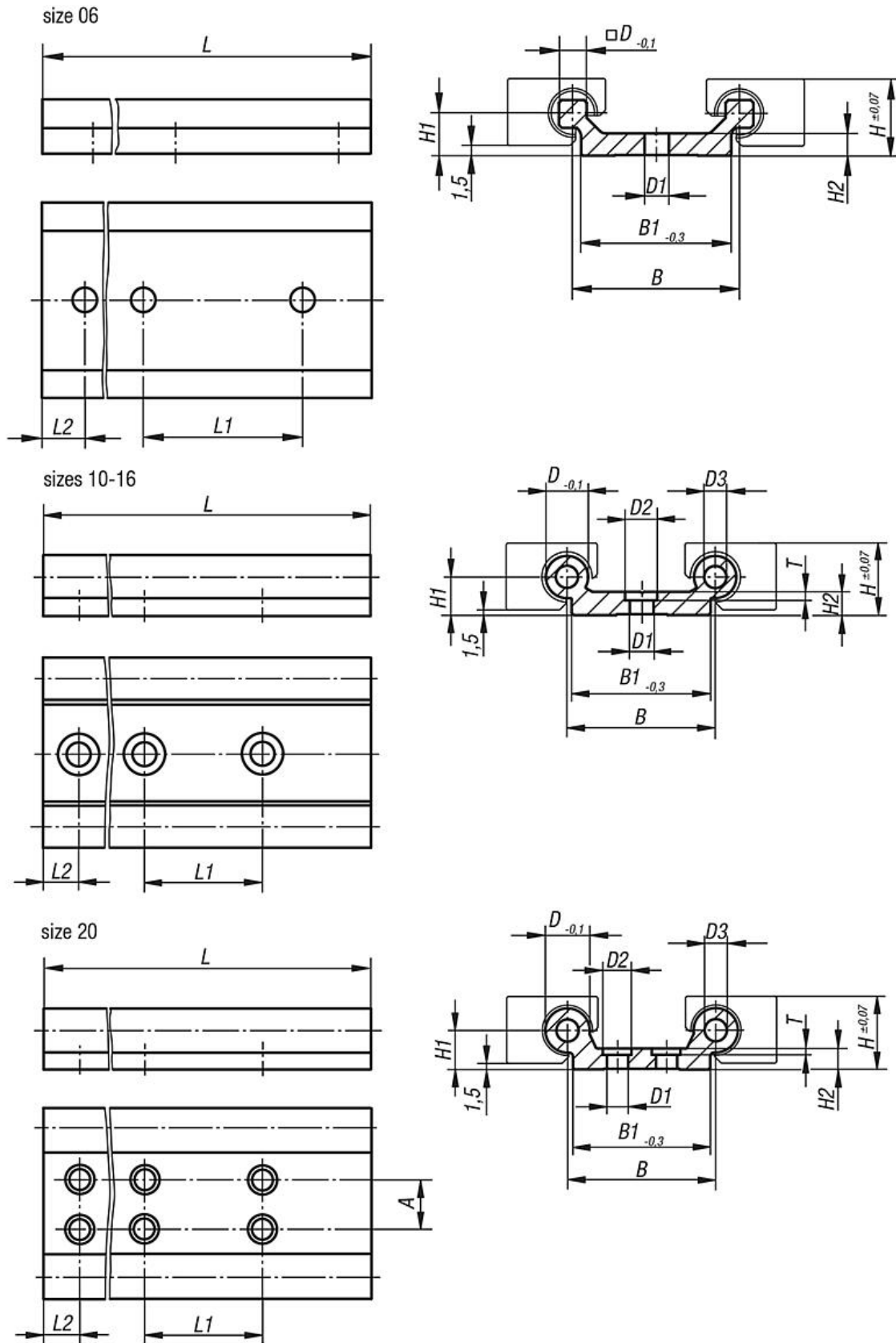

## Overview of items

Order No.	Version 1	Size	L max.	L	L2	L2 min.	L2 max.	A	B	B1	D	D1	D2	D3	H	H1	H2	L1	T
21240-20630X3000	-	6	3000	3000	30	-	-	-	30	27	5	4,5	-	-	14	7,5	4	60	-
21240-21030X4000	-	10	4000	4000	20	-	-	-	40	40	10	6,6	-	-	18	9	5,5	120	-
21240-21630X4000	-	16	4000	4000	20	-	-	-	58	54	16	9	15	8	27	14	7,5	120	4
21240-22030X4000	-	20	4000	4000	20	-	-	40	82	74	20	9	15	14	36	20	9,5	120	5
21240-206**X*	L2 and L customer specific	6	3000	*	**	20	49,5	-	30	27	5	4,5	-	-	14	7,5	4	60	-
21240-210**X*	L2 and L customer specific	10	4000	*	**	20	79,5	-	40	40	10	6,6	-	-	18	9	5,5	120	-
21240-216**X*	L2 and L customer specific	16	4000	*	**	20	79,5	-	58	54	16	9	15	8	27	14	7,5	120	4
21240-220**X*	L2 and L customer specific	20	4000	*	**	20	79,5	40	82	74	20	9	15	14	36	20	9,5	120	5