

Item description/product images



Description

Material:

Handwheel in aluminium


Version:

Wheel rim turned and polished.

On request:

Hubs with square socket or powder-coated handwheels.

Drawings

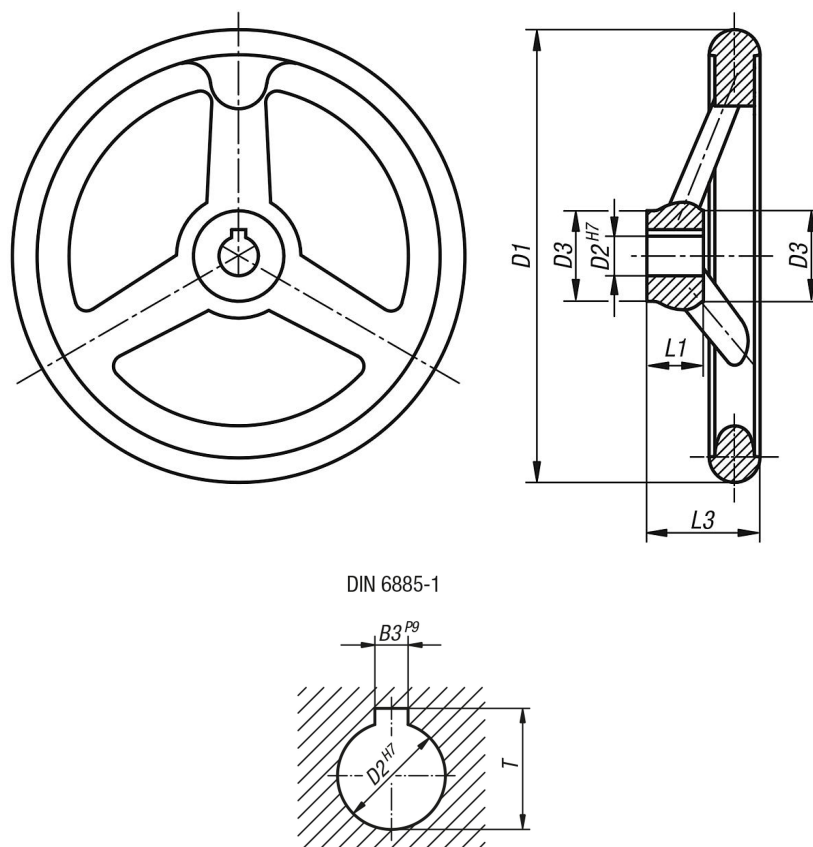

Overview of items

Order No.	Version 1	D1	D2	D3≈	L1	L3	B3	T	Number of spokes
06273-0080X10	Cam screw	80	10H7	24	16	29	-	-	3
06273-0080X12	Cam screw	80	12H7	24	16	29	-	-	3
06273-0100X10	Cam screw	100	10H7	26	17	33	-	-	3
06273-0100X12	Cam screw	100	12H7	26	17	33	-	-	3
06273-0125X12	Cam screw	125	12H7	28	18	36	-	-	3
06273-0125X14	Cam screw	125	14H7	28	18	36	-	-	3
06273-0140X14	Cam screw	140	14H7	30	19	39	-	-	3
06273-0140X16	Cam screw	140	16H7	30	19	39	-	-	3
06273-0160X14	Cam screw	160	14H7	32	20	40	-	-	3
06273-0160X16	Cam screw	160	16H7	32	20	40	-	-	3
06273-0180X16	Cam screw	180	16H7	37	22	43	-	-	3
06273-0180X18	Cam screw	180	18H7	37	22	43	-	-	3
06273-0200X18	Cam-action indexing plungers	200	18H7	38	24	45	-	-	3
06273-0200X22	Cam-action indexing plungers	200	22H7	38	24	45	-	-	3
06273-0250X22	Cam-action indexing plungers	250	22H7	45	28	50	-	-	5
06273-0250X26	Cam-action indexing plungers	250	26H7	45	28	50	-	-	5
06273-0315X26	Cam-action indexing plungers	315	26H7	53	33	56	-	-	5
06273-0315X30	Cam-action indexing plungers	315	30H7	53	33	56	-	-	5
06273-0400X30	Cam-action indexing plungers	400	30H7	65	38	63	-	-	5
06273-0400X34	Cam-action indexing plungers	400	34H7	65	38	63	-	-	5
06273-0500X34	Cam-action indexing plungers	500	34H7	78	45	72	-	-	5
06273-0500X40	Cam-action indexing plungers	500	40H7	78	45	72	-	-	5
06273-1080X10	1 kg can	80	10H7	24	16	29	3	11,4	3
06273-1080X12	1 kg can	80	12H7	24	16	29	4	13,8	3
06273-1100X10	1 kg can	100	10H7	26	17	33	3	11,4	3
06273-1100X12	1 kg can	100	12H7	26	17	33	4	13,8	3
06273-1125X12	1 kg can	125	12H7	28	18	36	4	13,8	3
06273-1125X14	1 kg can	125	14H7	28	18	36	5	16,3	3
06273-1140X14	1 kg can	140	14H7	30	19	39	5	16,3	3

Overview of items

Order No.	Version 1	D1	D2	D3≈	L1	L3	B3	T	Number of spokes
06273-1140X16	1 kg can	140	16H7	30	19	39	5	18,3	3
06273-1160X14	1 kg can	160	14H7	32	20	40	5	16,3	3
06273-1160X16	1 kg can	160	16H7	32	20	40	5	18,3	3
06273-1180X16	1 kg can	180	16H7	37	22	43	5	18,3	3
06273-1180X18	1 kg can	180	18H7	37	22	43	6	20,8	3
06273-1200X18	1 kg can	200	18H7	38	24	45	6	20,8	3
06273-1200X22	1 kg can	200	22H7	38	24	45	6	24,8	3
06273-1250X22	1 kg can	250	22H7	45	28	50	6	24,8	5
06273-1250X26	1 kg can	250	26H7	45	28	50	8	29,3	5
06273-1315X26	1 kg can	315	26H7	53	33	56	8	29,3	5
06273-1315X30	1 kg can	315	30H7	53	33	56	8	33,3	5
06273-1400X30	1 kg can	400	30H7	65	38	63	8	33,3	5
06273-1400X34	1 kg can	400	34H7	65	38	63	10	37,3	5
06273-1500X34	1 kg can	500	34H7	78	45	72	10	37,3	5
06273-1500X40	1 kg can	500	40H7	78	45	72	12	43,3	5