

Item description/product images

**Description****Material:**

Rails steel.
Screws steel.
Parallel key stainless steel.
Plug plastic.

Version:

Rails bright and hardened.
Screws electro zinc-plated steel.

Note:

The linear guide rails are screwed down from above. One or more roller guide carriages can be mounted on these. The slot on both sides makes it easy to assemble the rails using parallel keys.

As standard, the plugs are always supplied in blue RAL 5002.

Other items suitable for this system:

Roller carriage for linear guide rails 21351.
Straight linear guide rails 21355.
Cap screws 07160 M5 for size 2 or M8 for size 3.

Advantages:

Complex geometries consisting of straight and curved linear guide rails can be constructed.

On request:

Other angles and radii.
Plug in other colours.
Diamond coating.


Supplied with:

Plug blue RAL 5002.
Parallel keys.

Accessory:

Parallel keys 03288-06X22 and 03288-106X22 for size 2, 03288-08X28 and 03288-108X28 for size 3.

Drawings

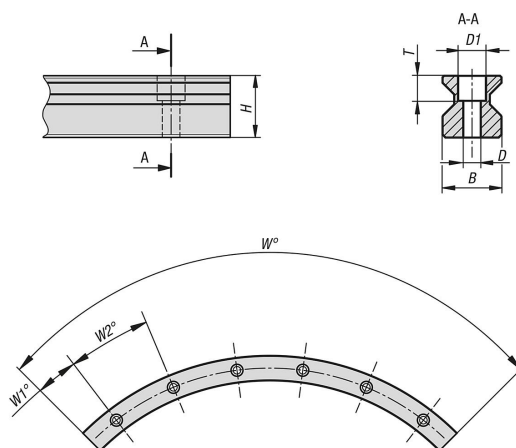

Overview of items

Order No.	Size	B	D	D1	H	R	T	W°	W1°	W2°
21356-2120200045	2	20	6	9,5	21	200	8,5	45	7,5	15
21356-2120200090	2	20	6	9,5	21	200	8,5	90	7,5	15
21356-2120200180	2	20	6	9,5	21	200	8,5	180	7,5	15
21356-2120300045	2	20	6	9,5	21	300	8,5	45	7,5	15
21356-2120300090	2	20	6	9,5	21	300	8,5	90	7,5	15
21356-2120300180	2	20	6	9,5	21	300	8,5	180	7,5	15
21356-2120400045	2	20	6	9,5	21	400	8,5	45	3,75	7,5
21356-2120400090	2	20	6	9,5	21	400	8,5	90	3,75	7,5
21356-2120400180	2	20	6	9,5	21	400	8,5	180	3,75	7,5
21356-3120300045	3	28	9	14	28	300	12	45	7,5	15
21356-3120300090	3	28	9	14	28	300	12	90	7,5	15
21356-3120300180	3	28	9	14	28	300	12	180	7,5	15
21356-3120400045	3	28	9	14	28	400	12	45	3,75	7,5
21356-3120400090	3	28	9	14	28	400	12	90	3,75	7,5
21356-3120400180	3	28	9	14	28	400	12	180	3,75	7,5
21356-3120500045	3	28	9	14	28	500	12	45	3,75	7,5
21356-3120500090	3	28	9	14	28	500	12	90	3,75	7,5