



## Description

### Material:

Handle die-cast zinc DIN EN 12844.  
Steel parts grade 5.8.

### Version:

Handle powder-coated.  
Steel parts trivalent blue-passivated.

### Note:

Standard colours are:  
orange RAL 2004, silver metallic.

Where  $L \geq 60$  mm the thread length is 60 mm.

### On request:

Other threads, colours and special versions.  
Dimension "H1" available in other lengths at extra charge.


### Drawing reference:

1) flat point DIN EN ISO 4753

Item description/product images



Drawings

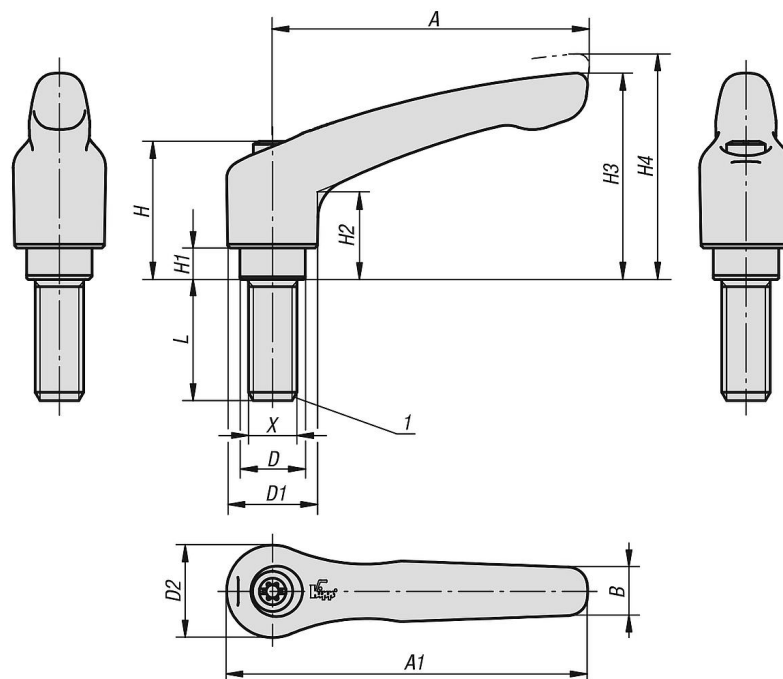

Overview of items

Order No.	Main colour	Surface finish body	Size	X	D	D1	D2	H	H1	H2	H3	H4	A	A1	B	No. of teeth	L
06460-05-0042X10	orange RAL 2004	plastic-coated	0	M4	10	13	14	24,5	4	14,5	30	33	30	37	7	16	10
06460-05-0042X15	orange RAL 2004	plastic-coated	0	M4	10	13	14	24,5	4	14,5	30	33	30	37	7	16	15
06460-05-0042X20	orange RAL 2004	plastic-coated	0	M4	10	13	14	24,5	4	14,5	30	33	30	37	7	16	20
06460-05-0042X25	orange RAL 2004	plastic-coated	0	M4	10	13	14	24,5	4	14,5	30	33	30	37	7	16	25
06460-05-0042X30	orange RAL 2004	plastic-coated	0	M4	10	13	14	24,5	4	14,5	30	33	30	37	7	16	30
06460-05-0042X35	orange RAL 2004	plastic-coated	0	M4	10	13	14	24,5	4	14,5	30	33	30	37	7	16	35
06460-05-0042X40	orange RAL 2004	plastic-coated	0	M4	10	13	14	24,5	4	14,5	30	33	30	37	7	16	40
06460-05-0042X45	orange RAL 2004	plastic-coated	0	M4	10	13	14	24,5	4	14,5	30	33	30	37	7	16	45
06460-05-0042X50	orange RAL 2004	plastic-coated	0	M4	10	13	14	24,5	4	14,5	30	33	30	37	7	16	50
06460-05-0043X10	silver metallic	plastic-coated	0	M4	10	13	14	24,5	4	14,5	30	33	30	37	7	16	10
06460-05-0043X15	silver metallic	plastic-coated	0	M4	10	13	14	24,5	4	14,5	30	33	30	37	7	16	15







# 06460-05 Clamping levers, die-cast zinc with external thread, threaded insert blue passivated steel



## Overview of items

Order No.	Main colour	Surface finish body	Size	X	D	D1	D2	H	H1	H2	H3	H4	A	A1	B	No. of teeth	L
06460-05-4122X80	orange RAL 2004	plastic-coated	4	M12	19	27	27,5	43	10	27	63	67,5	95	109	13	24	80
06460-05-4122X90	orange RAL 2004	plastic-coated	4	M12	19	27	27,5	43	10	27	63	67,5	95	109	13	24	90
06460-05-4123X20	silver metallic	plastic-coated	4	M12	19	27	27,5	43	10	27	63	67,5	95	109	13	24	20
06460-05-4123X25	silver metallic	plastic-coated	4	M12	19	27	27,5	43	10	27	63	67,5	95	109	13	24	25
06460-05-4123X30	silver metallic	plastic-coated	4	M12	19	27	27,5	43	10	27	63	67,5	95	109	13	24	30
06460-05-4123X35	silver metallic	plastic-coated	4	M12	19	27	27,5	43	10	27	63	67,5	95	109	13	24	35
06460-05-4123X40	silver metallic	plastic-coated	4	M12	19	27	27,5	43	10	27	63	67,5	95	109	13	24	40
06460-05-4123X45	silver metallic	plastic-coated	4	M12	19	27	27,5	43	10	27	63	67,5	95	109	13	24	45
06460-05-4123X50	silver metallic	plastic-coated	4	M12	19	27	27,5	43	10	27	63	67,5	95	109	13	24	50
06460-05-4123X55	silver metallic	plastic-coated	4	M12	19	27	27,5	43	10	27	63	67,5	95	109	13	24	55
06460-05-4123X60	silver metallic	plastic-coated	4	M12	19	27	27,5	43	10	27	63	67,5	95	109	13	24	60
06460-05-4123X70	silver metallic	plastic-coated	4	M12	19	27	27,5	43	10	27	63	67,5	95	109	13	24	70
06460-05-4123X80	silver metallic	plastic-coated	4	M12	19	27	27,5	43	10	27	63	67,5	95	109	13	24	80
06460-05-4123X90	silver metallic	plastic-coated	4	M12	19	27	27,5	43	10	27	63	67,5	95	109	13	24	90
06460-05-5122X25	orange RAL 2004	plastic-coated	5	M12	23	31	32	49	12	31,5	73	77,5	110	126	15	26	25
06460-05-5122X30	orange RAL 2004	plastic-coated	5	M12	23	31	32	49	12	31,5	73	77,5	110	126	15	26	30
06460-05-5122X35	orange RAL 2004	plastic-coated	5	M12	23	31	32	49	12	31,5	73	77,5	110	126	15	26	35
06460-05-5122X40	orange RAL 2004	plastic-coated	5	M12	23	31	32	49	12	31,5	73	77,5	110	126	15	26	40
06460-05-5122X45	orange RAL 2004	plastic-coated	5	M12	23	31	32	49	12	31,5	73	77,5	110	126	15	26	45
06460-05-5122X50	orange RAL 2004	plastic-coated	5	M12	23	31	32	49	12	31,5	73	77,5	110	126	15	26	50
06460-05-5122X55	orange RAL 2004	plastic-coated	5	M12	23	31	32	49	12	31,5	73	77,5	110	126	15	26	55
06460-05-5122X60	orange RAL 2004	plastic-coated	5	M12	23	31	32	49	12	31,5	73	77,5	110	126	15	26	60
06460-05-5122X70	orange RAL 2004	plastic-coated	5	M12	23	31	32	49	12	31,5	73	77,5	110	126	15	26	70
06460-05-5122X80	orange RAL 2004	plastic-coated	5	M12	23	31	32	49	12	31,5	73	77,5	110	126	15	26	80
06460-05-5122X90	orange RAL 2004	plastic-coated	5	M12	23	31	32	49	12	31,5	73	77,5	110	126	15	26	90
06460-05-5123X25	silver metallic	plastic-coated	5	M12	23	31	32	49	12	31,5	73	77,5	110	126	15	26	25
06460-05-5123X30	silver metallic	plastic-coated	5	M12	23	31	32	49	12	31,5	73	77,5	110	126	15	26	30
06460-05-5123X35	silver metallic	plastic-coated	5	M12	23	31	32	49	12	31,5	73	77,5	110	126	15	26	35
06460-05-5123X40	silver metallic	plastic-coated	5	M12	23	31	32	49	12	31,5	73	77,5	110	126	15	26	40
06460-05-5123X45	silver metallic	plastic-coated	5	M12	23	31	32	49	12	31,5	73	77,5	110	126	15	26	45
06460-05-5123X50	silver metallic	plastic-coated	5	M12	23	31	32	49	12	31,5	73	77,5	110	126	15	26	50
06460-05-5123X55	silver metallic	plastic-coated	5	M12	23	31	32	49	12	31,5	73	77,5	110	126	15	26	55
06460-05-5123X60	silver metallic	plastic-coated	5	M12	23	31	32	49	12	31,5	73	77,5	110	126	15	26	60
06460-05-5123X70	silver metallic	plastic-coated	5	M12	23	31	32	49	12	31,5	73	77,5	110	126	15	26	70
06460-05-5123X80	silver metallic	plastic-coated	5	M12	23	31	32	49	12	31,5	73	77,5	110	126	15	26	80
06460-05-5123X90	silver metallic	plastic-coated	5	M12	23	31	32	49	12	31,5	73	77,5	110	126	15	26	90
06460-05-5162X25	orange RAL 2004	plastic-coated	5	M16	23	31	32	49	12	31,10	73	77,10	110	126	15	26	25
06460-05-5162X30	orange RAL 2004	plastic-coated	5	M16	23	31	32	49	12	31,10	73	77,10	110	126	15	26	30
06460-05-5162X35	orange RAL 2004	plastic-coated	5	M16	23	31	32	49	12	31,10	73	77,10	110	126	15	26	35
06460-05-5162X40	orange RAL 2004	plastic-coated	5	M16	23	31	32	49	12	31,10	73	77,10	110	126	15	26	40
06460-05-5162X45	orange RAL 2004	plastic-coated	5	M16	23	31	32	49	12	31,10	73	77,10	110	126	15	26	45
06460-05-5162X50	orange RAL 2004	plastic-coated	5	M16	23	31	32	49	12	31,10	73	77,10	110	126	15	26	50
06460-05-5162X55	orange RAL 2004	plastic-coated	5	M16	23	31	32	49	12	31,10	73	77,10	110	126	15	26	55
06460-05-5162X60	orange RAL 2004	plastic-coated	5	M16	23	31	32	49	12	31,10	73	77,10	110	126	15	26	60
06460-05-5162X70	orange RAL 2004	plastic-coated	5	M16	23	31	32	49	12	31,10	73	77,10	110	126	15	26	70
06460-05-5162X80	orange RAL 2004	plastic-coated	5	M16	23	31	32	49	12	31,10	73	77,10	110	126	15	26	80
06460-05-5162X90	orange RAL 2004	plastic-coated	5	M16	23	31	32	49	12	31,10	73	77,10	110	126	15	26	90
06460-05-5163X25	silver metallic	plastic-coated	5	M16	23	31	32	49	12	31,10	73	77,10	110	126	15	26	25
06460-05-5163X30	silver metallic	plastic-coated	5	M16	23	31	32	49	12	31,10	73	77,10	110	126	15	26	30
06460-05-5163X35	silver metallic	plastic-coated	5	M16	23	31	32	49	12	31,10	73	77,10	110	126	15	26	35
06460-05-5163X40	silver metallic	plastic-coated	5	M16	23	31	32	49	12	31,10	73	77,10	110	126	15	26	40
06460-05-5163X45	silver metallic	plastic-coated	5	M16	23	31	32	49	12	31,10	73	77,10	110	126	15	26	45
06460-05-5163X50	silver metallic	plastic-coated	5	M16	23	31	32	49	12	31,10	73	77,10	110	126	15	26	50
06460-05-5163X55	silver metallic	plastic-coated	5	M16	23	31	32	49	12	31,10	73	77,10	110	126	15	26	55
06460-05-5163X60	silver metallic	plastic-coated	5	M16	23	31	32	49	12	31,10	73	77,10	110	126	15	26	60
06460-05-5163X70	silver metallic	plastic-coated	5	M16	23	31	32	49	12	31,10	73	77,10	110	126	15	26	70
06460-05-5163X80	silver metallic	plastic-coated	5	M16	23	31	32	49	12	31,10	73	77,10	110	126	15	26	80
06460-05-5163X90	silver metallic	plastic-coated	5	M16	23	31	32	49	12	31,10	73	77,10	110	126	15	26	90

