




Istruzioni di montaggio 06894

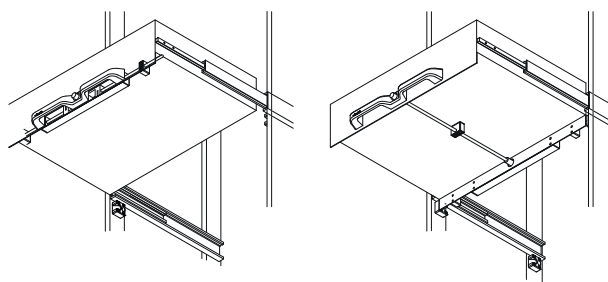


06894-060
06894-120

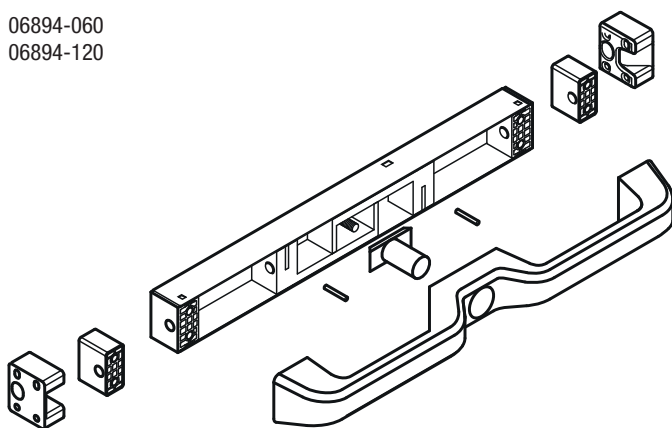

06894-91

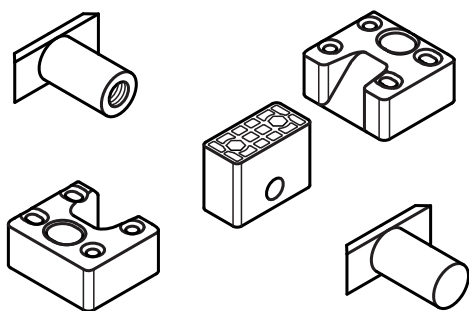


06894-900500
06894-900750
06894-910500
06894-910750

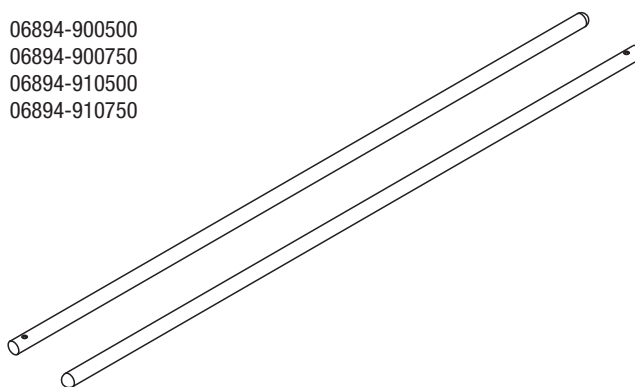


06894-060 + 06894-900500 o 06894-910500

06894-120 + 06894-900750 o 06894-910750

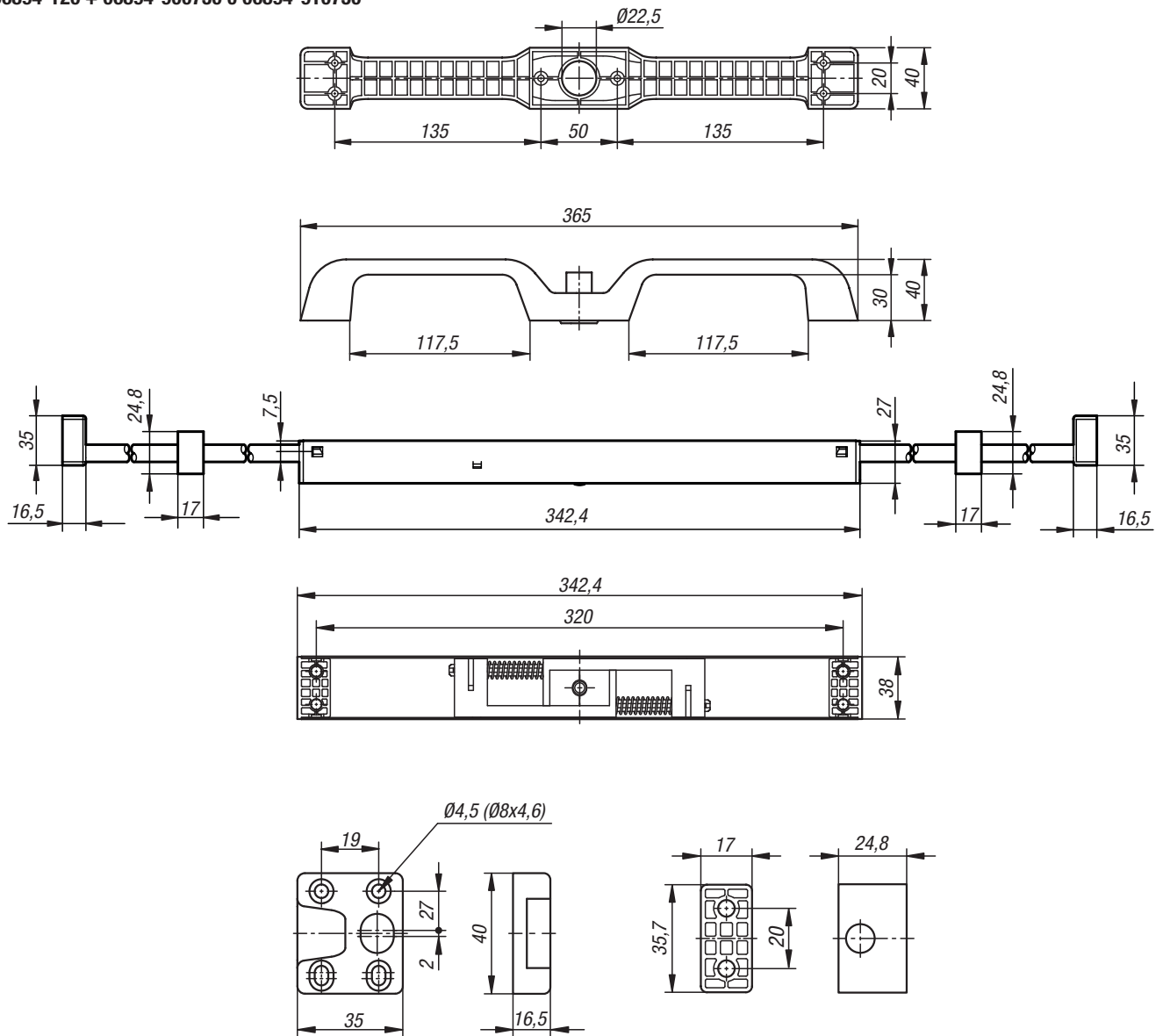


06894-060 + 06894-900500
 o 06894-910500 + 06894-91
 06894-120 + 06894-900750
 o 06894-910750


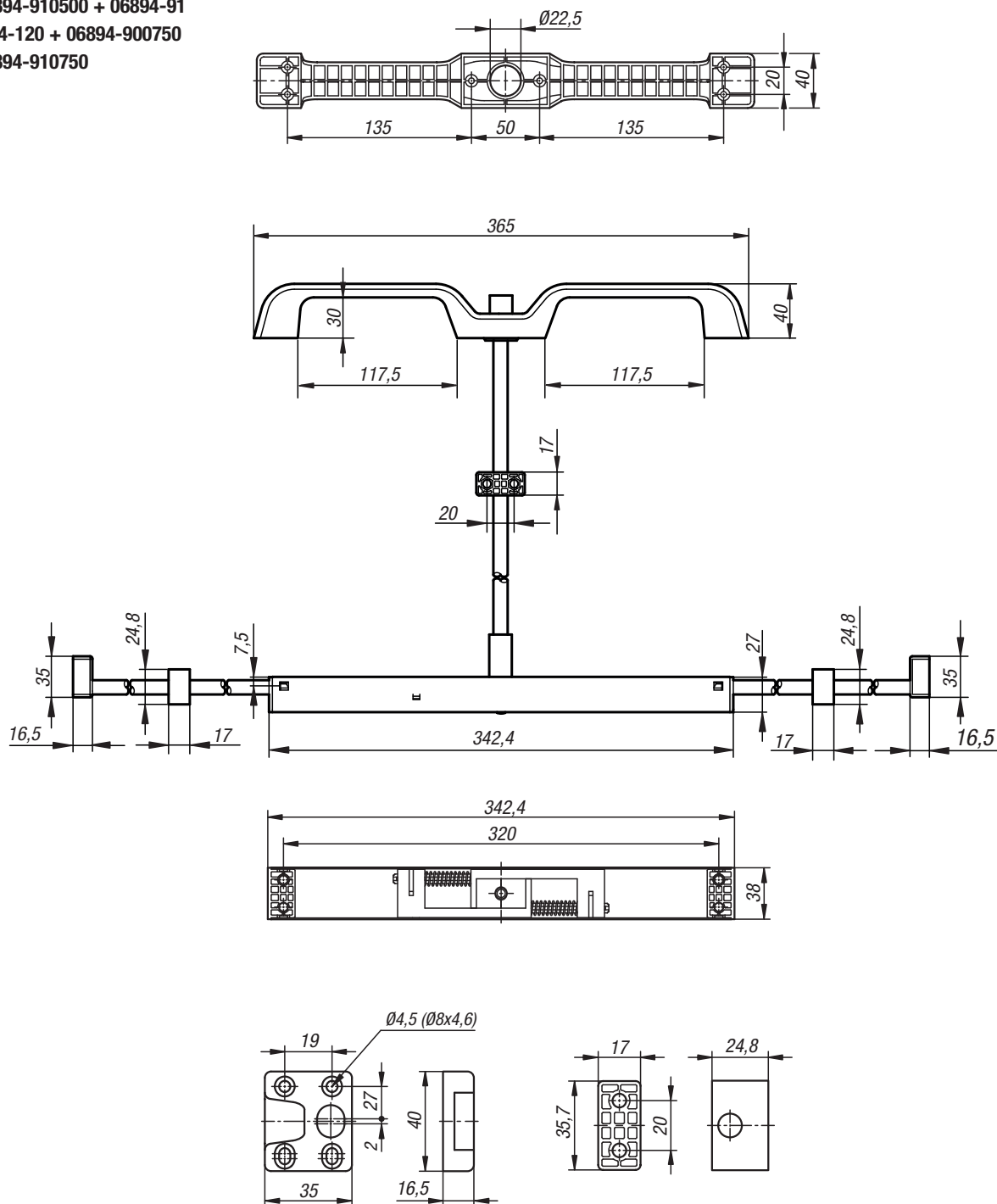




Trattenimento e bloccaggio



Il meccanismo di chiusura in posizione aperta non può essere utilizzato per le guide con estensione maggiorata (oltre il 100% di estensione).

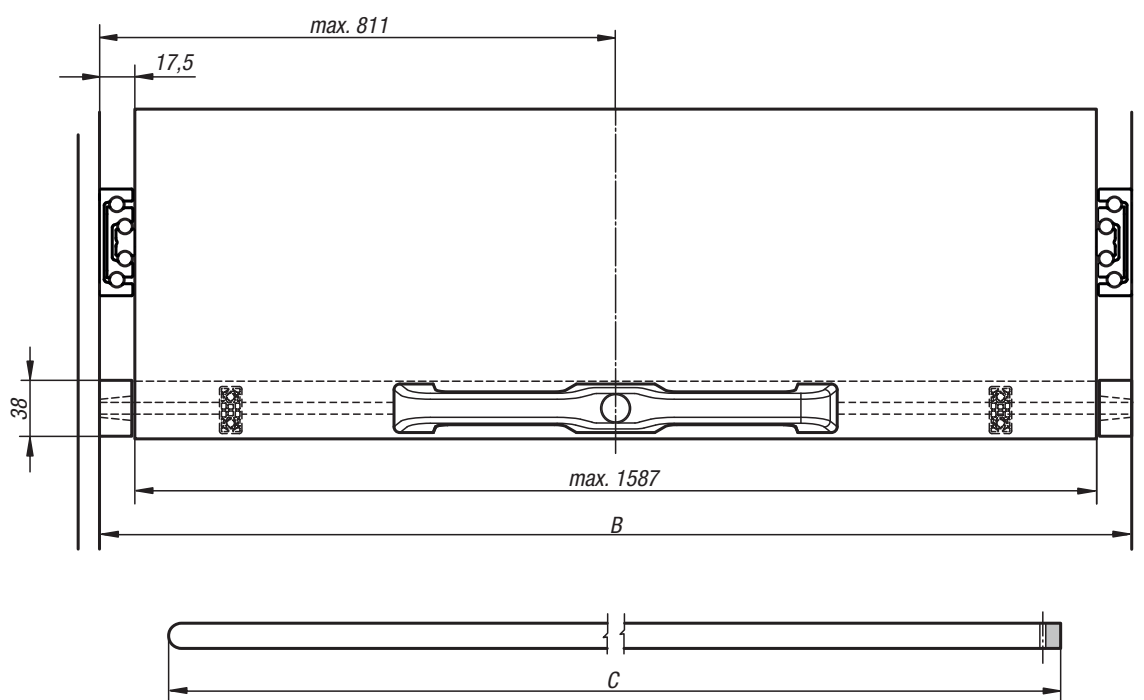


 $C = (B - 122,3) / 2$
 $C < 500$
 $C > 500$

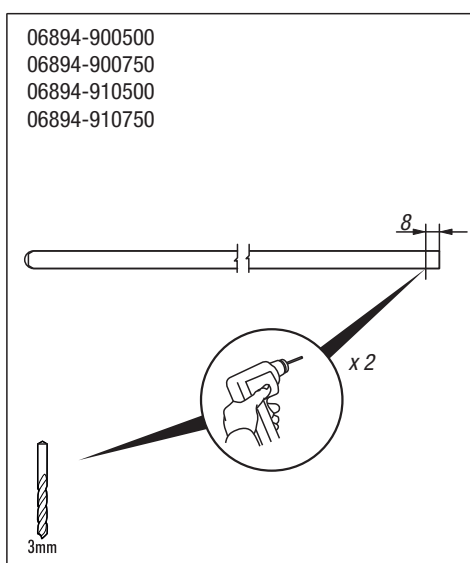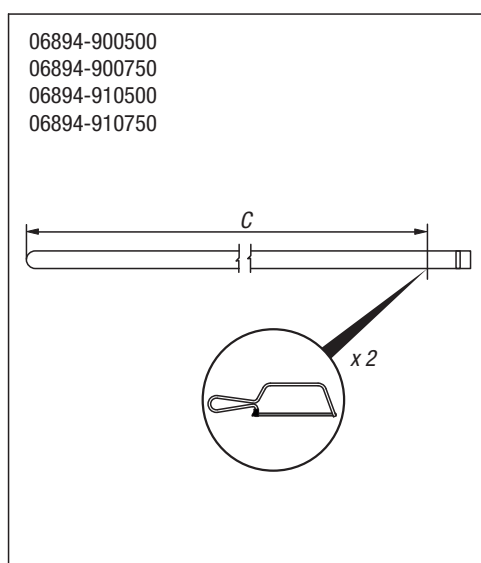

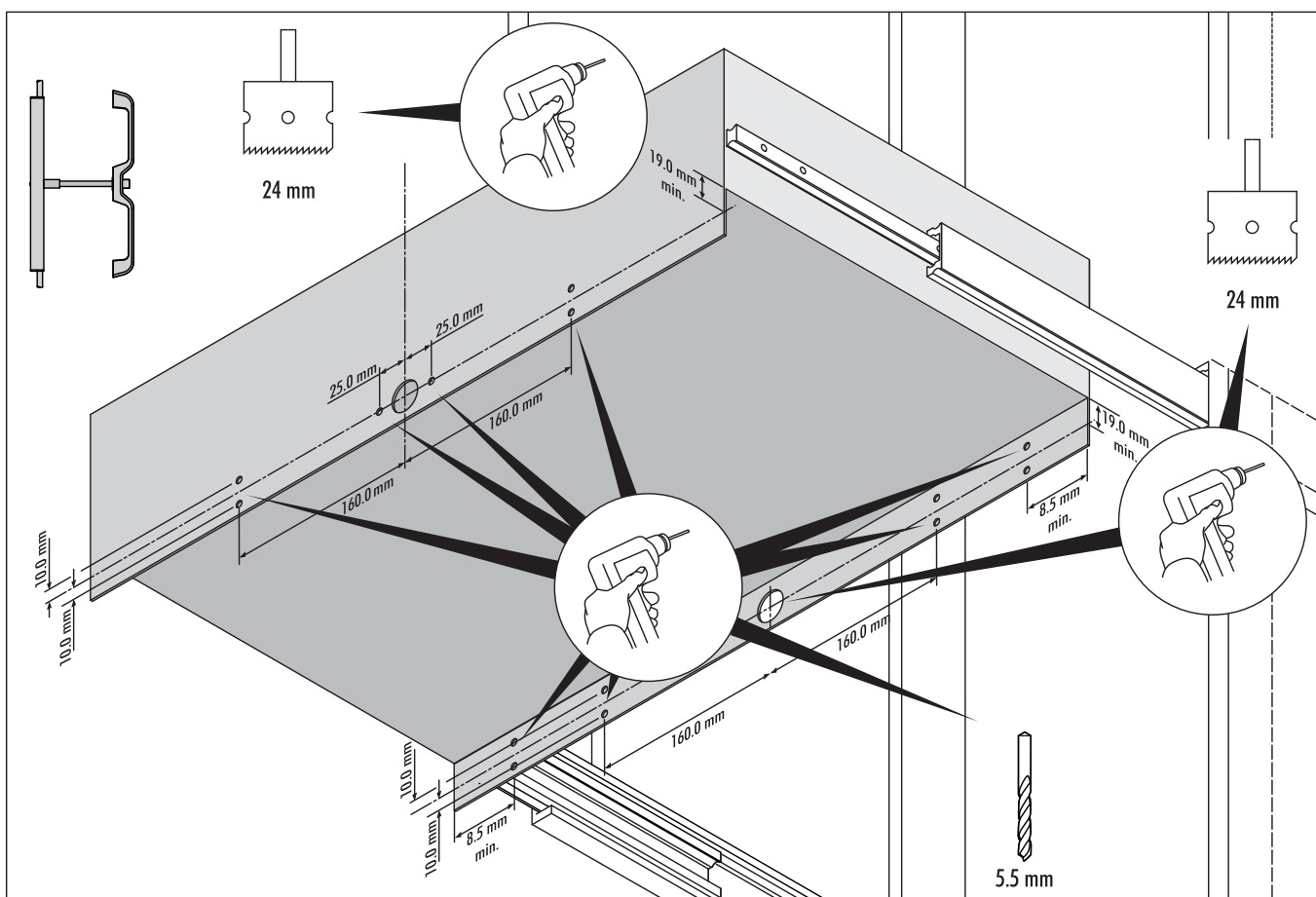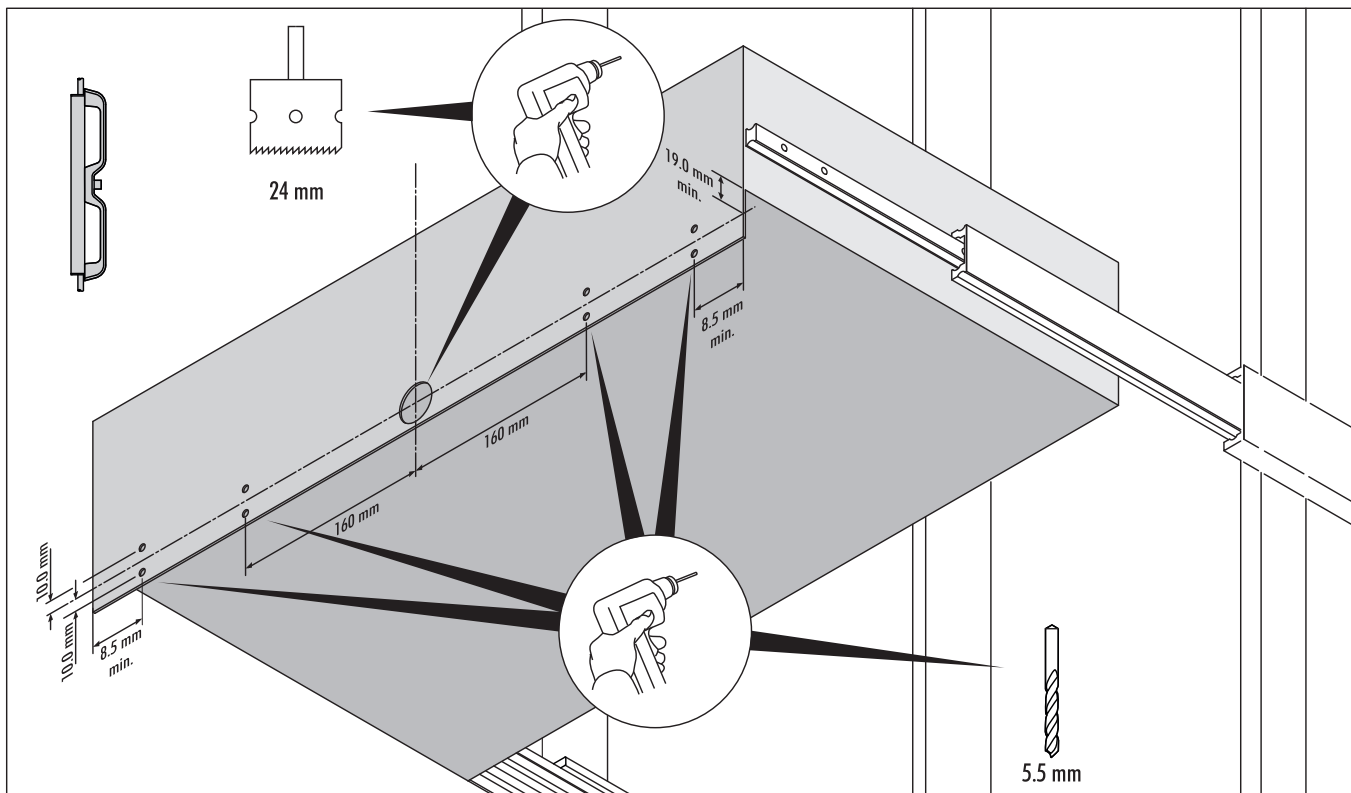

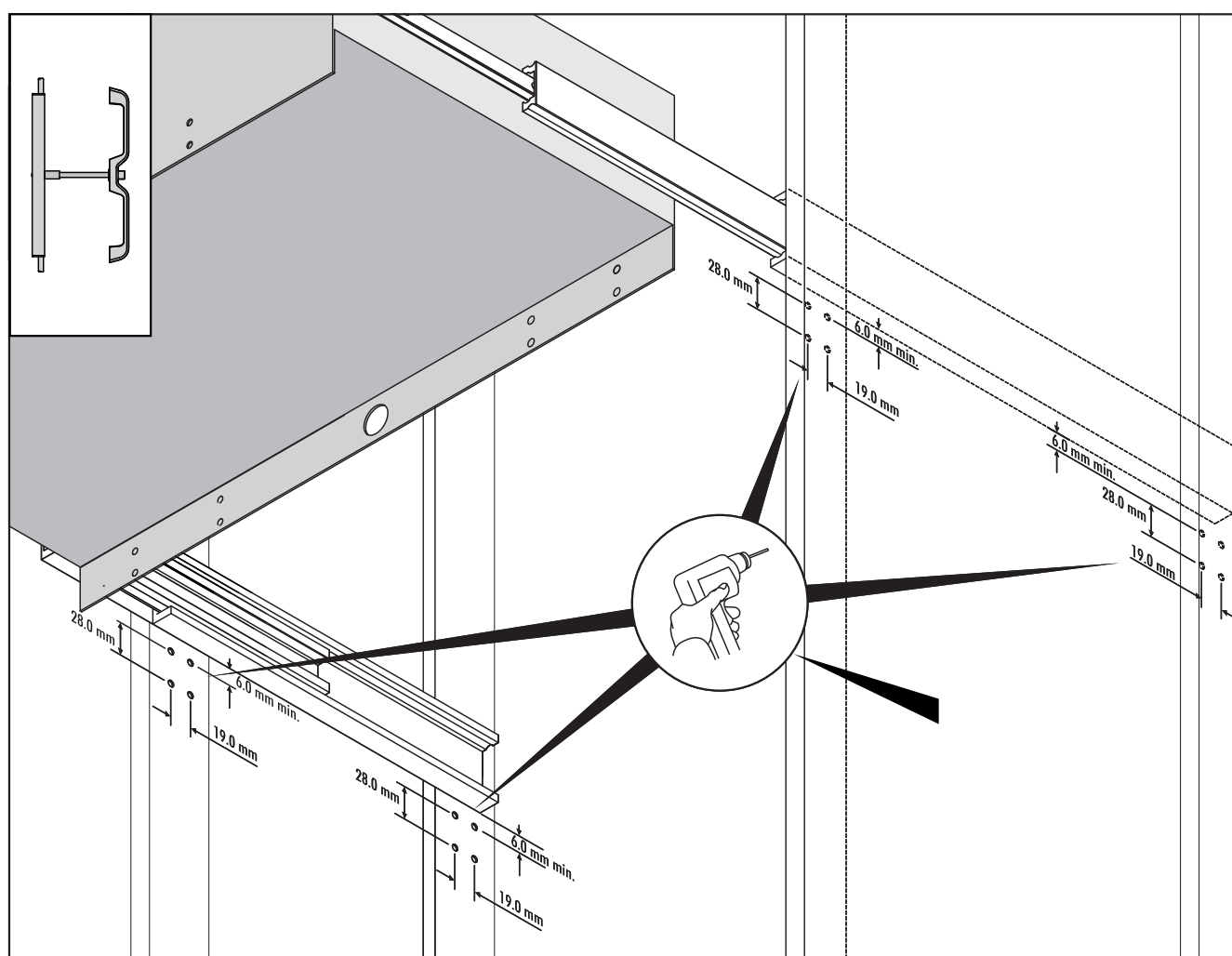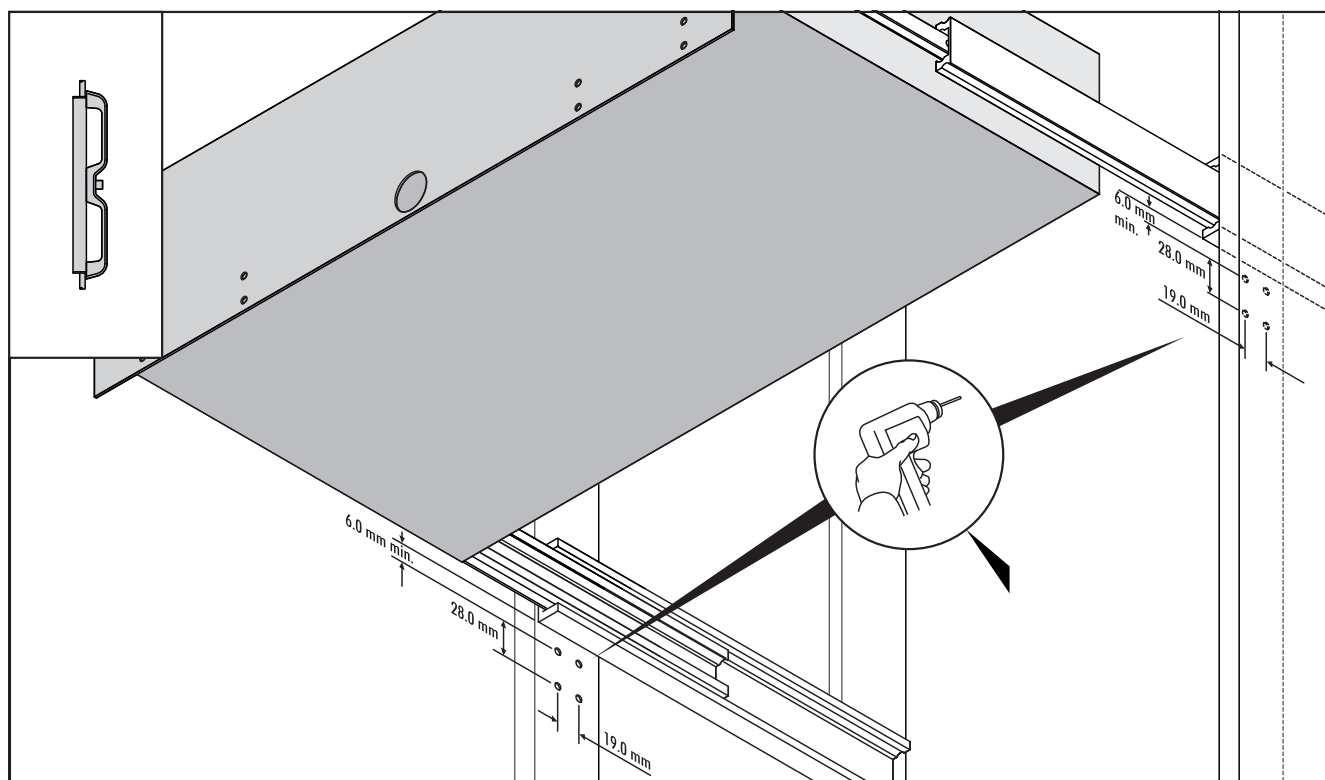

Foratura e fissaggio adeguati alla situazione

