


Descrizione articolo/immagini prodotto

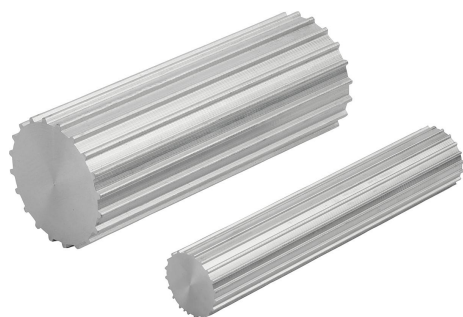

Descrizione

Materiale:

Alluminio.


Versione:

Superficie non trattata.

Nota:

Profilo AT standard con passo metrico (dentatura trapezoidale). Per la creazione di dischi dentati propri.

Disegni

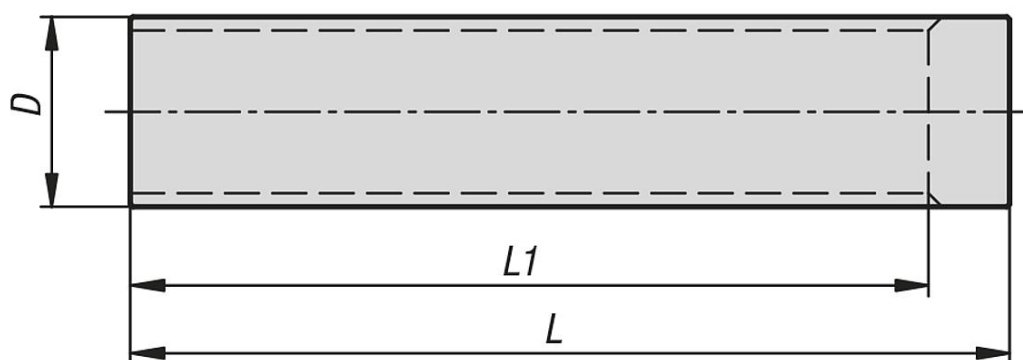

Sintesi articoli

N. ordine	Profilo	Numero denti	D	L	L1
22008-10015	AT10	15	45,9	160	160
22008-10016	AT10	16	49,05	160	160
22008-10017	AT10	17	52,25	160	160
22008-10018	AT10	18	55,45	160	160
22008-10019	AT10	19	58,6	160	160
22008-10020	AT10	20	61,8	160	160
22008-10021	AT10	21	65	160	160
22008-10022	AT10	22	68,15	160	160
22008-10023	AT10	23	71,35	160	160
22008-10024	AT10	24	74,55	160	160
22008-10025	AT10	25	77,7	160	160
22008-10026	AT10	26	80,9	160	160
22008-10027	AT10	27	84,1	160	160
22008-10028	AT10	28	87,25	160	160
22008-10030	AT10	30	93,65	160	160
22008-10032	AT10	32	100	160	160
22008-10034	AT10	34	106,4	160	160
22008-10036	AT10	36	112,75	160	160
22008-10038	AT10	38	119,1	160	160
22008-10040	AT10	40	125,45	160	160
22008-10042	AT10	42	131,85	160	160
22008-10044	AT10	44	138,2	160	160
22008-10046	AT10	46	144,55	160	160
22008-10048	AT10	48	150,95	160	160
22008-10052	AT10	52	163,65	160	160
22008-10056	AT10	56	176,4	160	160
22008-10058	AT10	58	182,75	160	160
22008-10060	AT10	60	189,1	160	160
22008-10070	AT10	70	220,95	160	160

