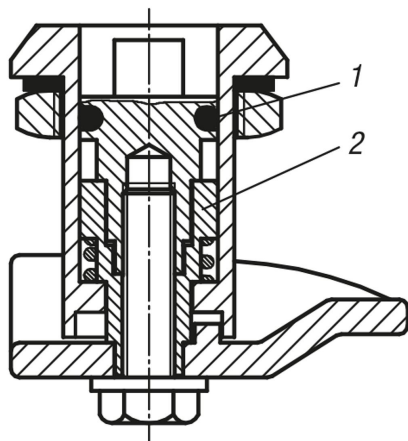


Item description/product images

**Description****Material:**

Housing, actuator and tongue die-cast zinc.
Nut steel.
Flat seal rubber.

Version:

Housing and actuator trivalent passivated.
Tongue blank.
Nut electro zinc-plated.

Note:

Quarter-turn locks with stepped cam are primarily used for doors and housings that require a higher pressure force on the seal. For right or left use. The locking process is always clockwise. The compression gap can be increased incrementally up to 9.5 mm at a maximum turning angle of 270° by turning the actuator clockwise.

Protected from water and dust to IP65.

Accessory:

Lock key 05586


Drawing reference:

Actuation:

- a) square 7 mm
- b) double lug 3 mm
- c) double lug 5 mm

- 1) O-ring
- 2) Adapter

Drawings

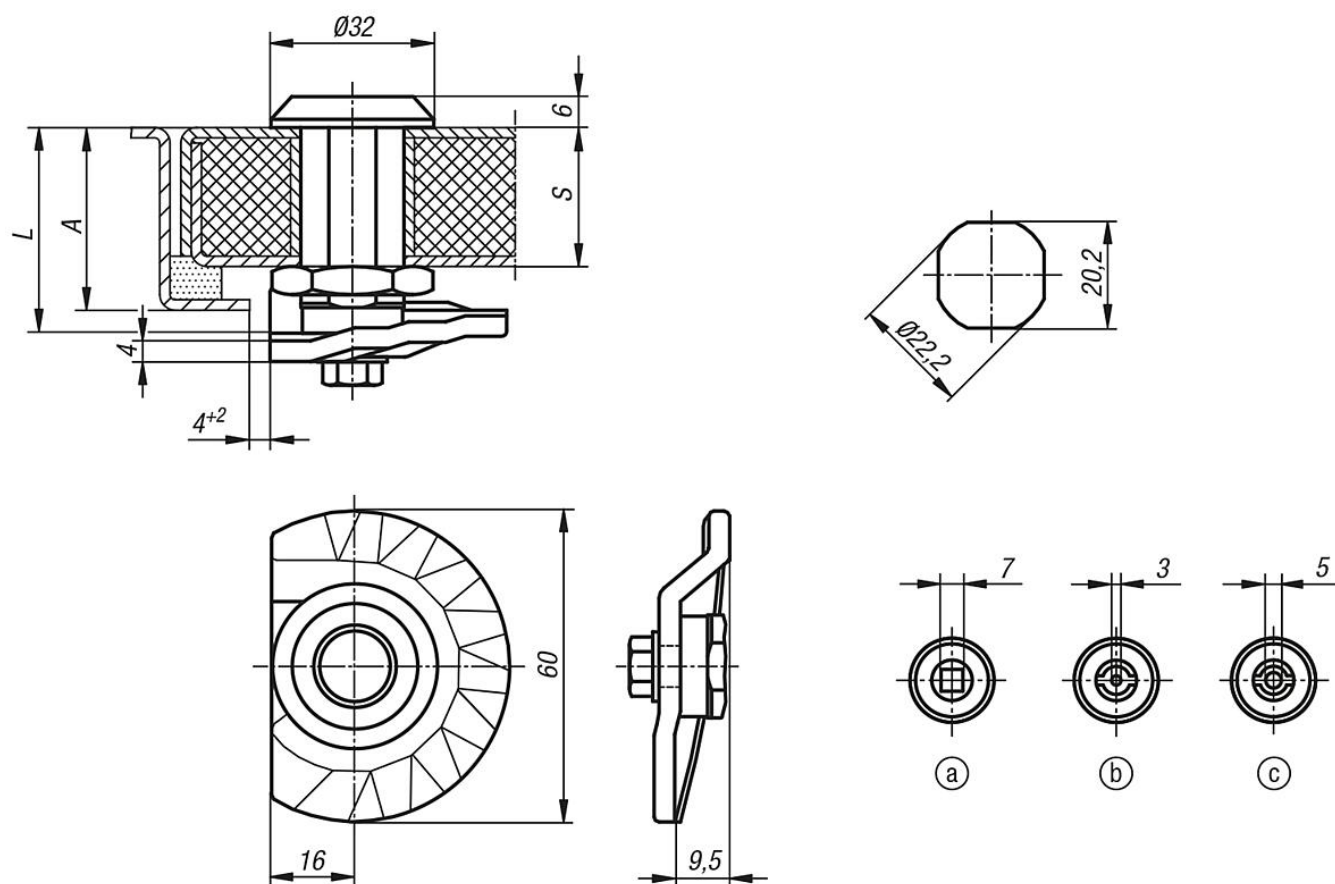

Overview of items

Order No.	Actuation	A	L	S max.
05576-17301	square 7 mm	30 -9,5	30	20
05576-17401	square 7 mm	40 -9,5	40	30
05576-17501	square 7 mm	50 -9,5	50	40
05576-17601	square 7 mm	60 -9,5	60	50
05576-43301	double lug 3 mm	30 -9,5	30	20
05576-43401	double lug 3 mm	40 -9,5	40	30
05576-43501	double lug 3 mm	50 -9,5	50	40
05576-43601	double lug 3 mm	60 -9,5	60	50
05576-45301	double lug 5 mm	30 -9,5	30	20
05576-45401	double lug 5 mm	40 -9,5	40	30
05576-45501	double lug 5 mm	50 -9,5	50	40
05576-45601	double lug 5 mm	60 -9,5	60	50